


TYANA SL-N Light duty flat hose

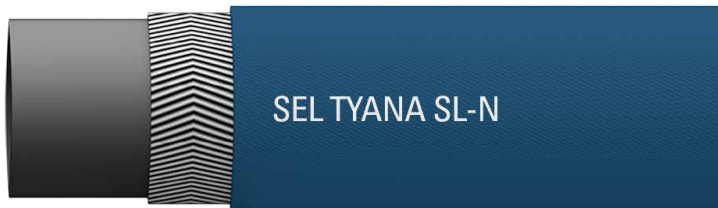

Inner diameter		Working pressure		Burst pressure		Weight	Length
In	mm	bar	psi	bar	psi	g/m	m
1"	25	7	102	22	319	160	50/100
1 1/4	32	6.5	94	20	290	180	50/100
1 1/2	38	5.5	80	17.0	247	205	50/100
-	40	5.5	80	17.0	247	240	50/100
-	50	5	73	16	232	265	50/100
2	52	5	73	16	232	275	50/100
-	55	5	73	14	203	320	50/100
-	60	5	73	14	203	330	50/100
2 1/2	63	5	73	14	203	360	50/100
3	76	4	58	13	189	420	50/100
-	81	4	58	13	189	460	50/100
4	102	4	58	13	189	610	50/100
5	127	2.5	36	8	116	955	50/100
6	153	2.5	36	8	116	1200	50/100
8	203	2	29	6	87	1850	50/100

Construction

- Flexible PVC lining
- High tensile syntetic textile reinforcement
- Light chemical and weather resistant PVC cover

Temperature range

- -10°C to +60°C
- (-14°F to +140°F)

Application

- Light duty discharge of water in agriculutre and industry