



Step 1. Remove the wooden container.

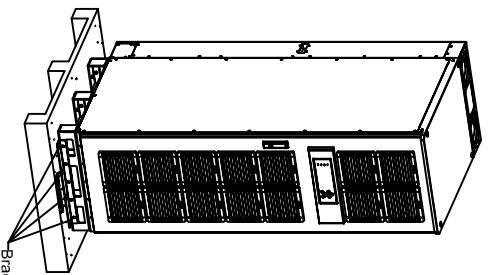


Step 2. Disassemble the bracket bolts which fixed on pallet in front side and rear side, total 8pcs.

Warning: Do not throw away the bolts, and the size is M12*40

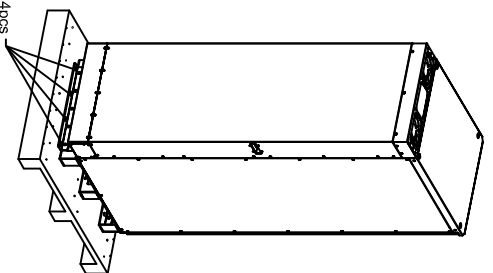

Bracket Bolts in front side, total 4pcs


Bracket Bolts on rear side, total 4pcs

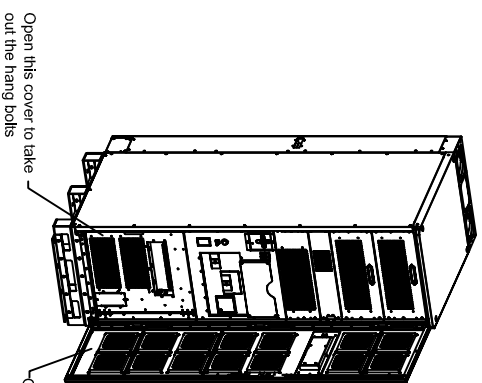


Step 3. Open the front door, and take out the M20 hang bolts (4pcs).

Open this cover to take out the hang bolts

Open the door first

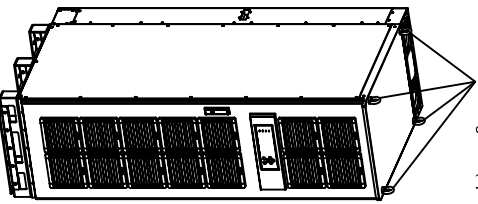


Assemble hang bolts(4pcs) at the top of the cabinet.

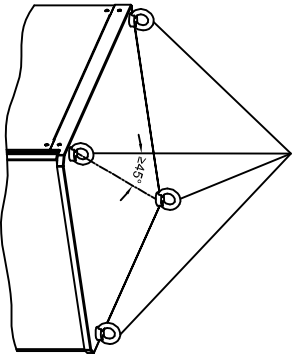


- Warning:
1. Hang bolts should be screw tightened.
 2. Must use all the four hand bolts to lift the cabinet.
 3. Make sure the load of sling and crane is larger than 2 tons .
 4. The angle between the sling and the level must greater than or equal to 45 degrees.
 5. These machine is too heavy, make sure the ground is able to withstand .


Step 4. Lift cabinet with four hang bolts, move to the right installation position and put it down.

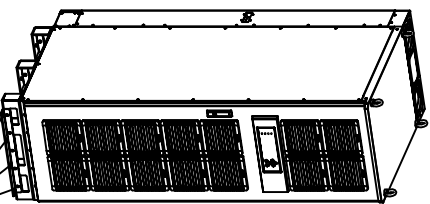

Bracket Bolts on rear side, total 4pcs
Bracket Bolts in front side, total 4pcs

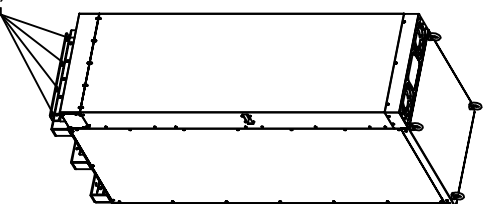

Step 5. Assemble the bracket bolts in front side and rear side, total 8pcs.

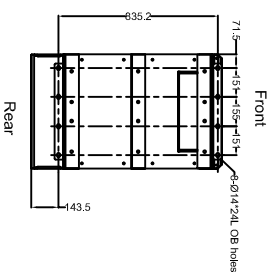

Mounting dimension of bottom installation.