

# BC55

## Top Terminal Battery Cabinet



### FEATURES:


- ▶ Unique design allows for easy battery maintenance
- ▶ Breaker and fuse options for single or multiple string applications
- ▶ Hinged, locking front door for easy and secure access
- ▶ Welded, heavy gauge steel construction
- ▶ Factory assembled and fully tested
- ▶ Listed to UL 1778 and CE Mark authorized for the EU market
- ▶ Zone 4 approved
- ▶ Seismic Certified options available

**C&C Power** offers a variety of paralleling options for multi-cabinet lineups including top hat and free standing solutions with cables. Cables come precut with compression lugs crimped at each end.

The BC55 can hold up to forty 620 watt or eighty 200 watt batteries. This NEMA I rated battery cabinet is constructed of welded, heavy gauge steel and is available in multiple colors of durable and corrosion resistant, powder coat finish.

Battery Configurations	
WPC Capacity	Max. # of Batteries
200W	80
300W	48
350W	40
400W	40
500W	40
540W	40
620W	40

### OPTIONAL CONFIGURATIONS:

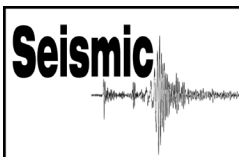

Specifications		
Style	Dimensions	Weight
BC55	40"W x 78.7"H x 29.5"D	520 lbs