



CABLE LENGTH SHOWN NOT TO SCALE

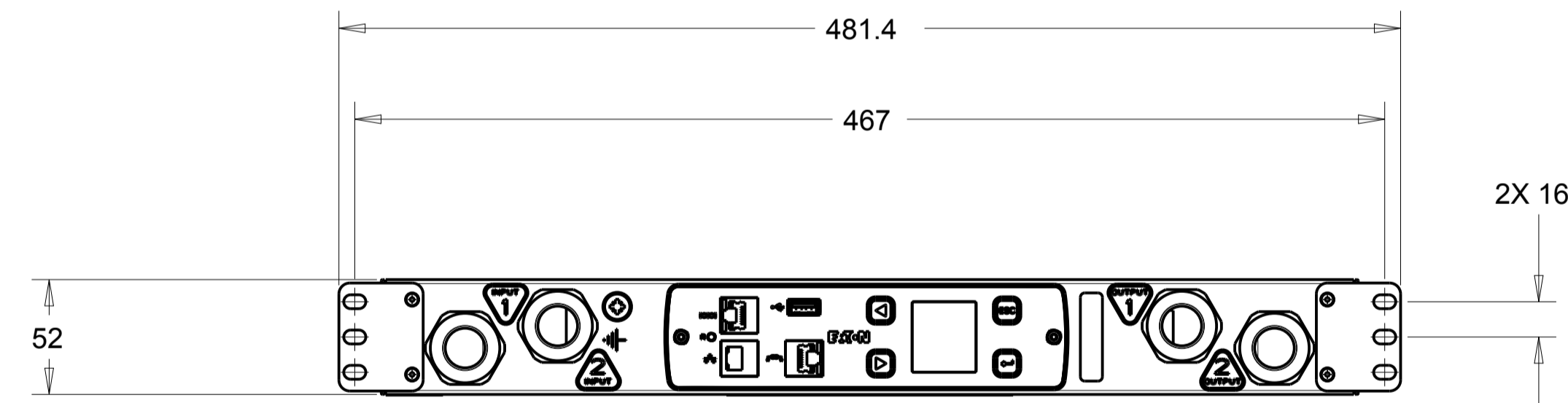

EILB25

G3 INLINE METERED, DUAL SOURCE

FUNCTIONALITY	INPUT	OUTPUT	ENVIRONMENTAL
CURRENT POWER AND ENERGY METERING FOR TWO ELECTRICAL SOURCES	2 SOURCES. EACH: IEC 60309-2 32A 230V~ W+N+PE (M) 4.0MM HO7 POWER CORD CABLE LENGTH: 3.0M	2 SOURCES. EACH: IEC 60309-2 32A 230V~ W+N+PE (F) 4.0MM HO7 POWER CORD CABLE LENGTH: 3.0M	0 TO 60° C
MECHANICAL	INPUT RATING	OUTPUT RATING	CERTIFICATIONS
LENGTH: 443 MM WIDTH: 52 MM DEPTH: 65MM ALUMINIUM CHASSIS, BLACK MNT PATTERN SK-23919-Y1	2 SOURCES. EACH: 1Ø; 200-240V~;W+N+PE 50/60HZ 32A	2 SOURCES. EACH: 1Ø; 200-240V~;W+N+PE 50/60HZ 32A	CE, CB
CIRCUIT BREAKERS	FILTER AND SPIKE/SURGE	ACCESSORIES	CONFIGURATION
NONE	NONE	STANDARD KSP016 - EMEA HOR INSTALL NETWORK PACK OPTIONAL EMP001 - ENVIRONMENTAL PROBE	EIL3YMJFAAA81AM

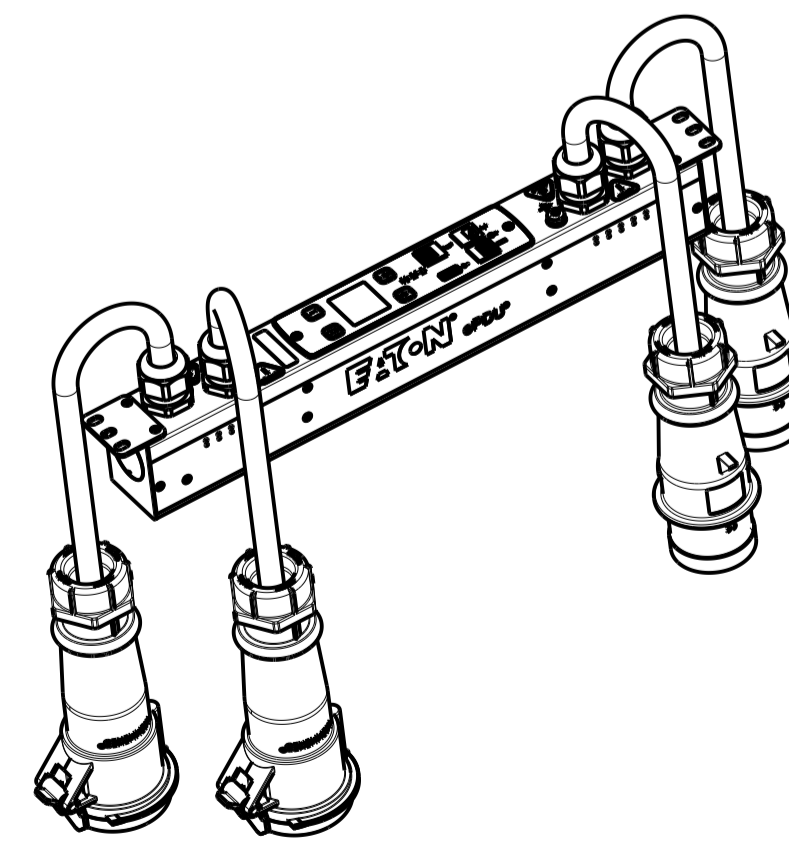

PICTORIAL VIEW
SCALE 0.200

REV. MODIFICATION		DATE	DESIGNER	VERIF.
HEINEMANN PRODUCTS		4/10		EILB25
CH-1345 LE LIEU SWITZERLAND		23.03.2015		
TOLERANCE GENERALE / GENERAL TOLERANCE		VERIFIE PAR / VERIFIED BY		
TRAITEMENT / FINISH		M.B.		
MATIERE / MATERIAL				
NIVEAU DU CERTIFICAT DE SOUMISSION REQUIS / SAMPLES APPROVAL PROCESS REPORT		DIMENSIONS AND TOLERANCES IN MILLIMETERS		
DESIGNATION		SK-59619-Y1		00
COTES A CONTROLER / INSPECTION DIMENSIONS		NUMERO DU PLAN / PLAN NUMBER		REV.
XX.XX		# XX.XX		
Ce document est propriété de Eaton Industries Manufacturing GmbH. Duplication interdite sans autorisation. This document is Eaton Industries Manufacturing GmbH property. Duplication forbidden without authorization.				