
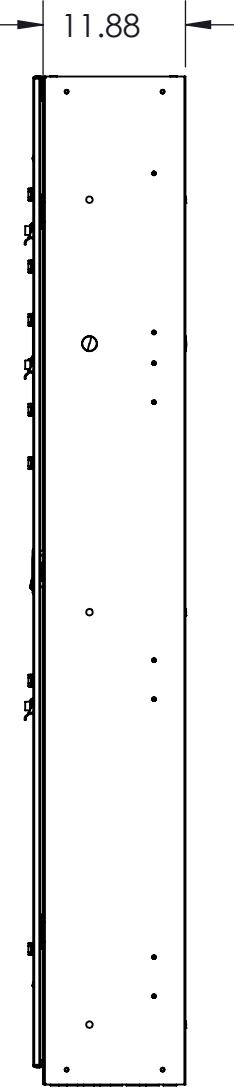


400A MOLDED CASE FIXED BREAKER

84 POLE NQ PANEL BOARD

WAVESTAR COLOR MONITOR WITH BCMS MODULE

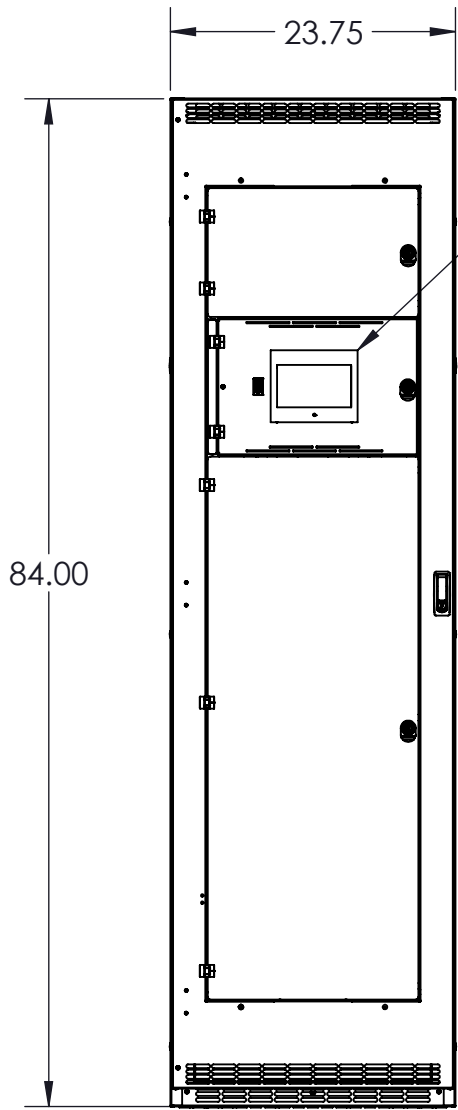

GENERAL SPECIFIED

CABINET CHARACTERISTIC:  
ENCLOSURE : NEMA 1  
LOCATION : INDOOR

MECHANICAL:  
MOUNTING: FREE STANDING  
MATERIAL: STEEL

ELECTRICAL:  
INPUT #1: 208 VAC 3PH-4W W/GND @ 60 HZ, 400A (MAX)  
OUTOUT PB #1: 84 POLE, BOLT ON CIRCUIT BREAKER

ENVIROMENTAL:  
OPERATING AMBIENT TEMPERATURE 0°C TO 40°C (32° F TO 104°F)  
RELATIVE HUMIDITY: 0% TO 95 % NON-CONDENSING  
ALTITUDE: 10,000 FT MAX

UNLESS OTHERWISE SPECIFIED:  
DIMENSIONS ARE IN INCHES  
[ ] IN MILLIMETER  
ANGULAR: ±0.5° BEND ±1°  
TWO PLACE DECIMAL ±0.02  
THREE PLACE DECIMAL ±0.005

THIS DRAWING CONTAINS  
CONFIDENTIAL & PROPRIETARY  
INFORMATION AND SHALL NOT  
BE DISCLOSED OR COPIED  
WITHOUT THE EXPRESSED,  
WRITTEN PERMISSION OF  
SMITHS POWER



THIRD ANGLE PROJECTION		DO NOT SCALE DRAWING	
APPROVALS		DATE	
DRAWN			
CHECKED			
ENG. APPR.			

TITLE: (1) 400A CKB (1) 84 POLE PANEL BOARD (1) WAVESTAR COLOR MONITOR

SIZE <b>B</b>	DWG. NO. <b>COMPACT RPP</b>	REV <b>A</b>
PART NO.		SHEET 1 OF 1