


LED Color States	
Green	Fully protected
Yellow	Loss of Neutral to Ground protection
Red	Loss of protection

SPC Catalog Number Selection

SPC 100 208Y 8 P

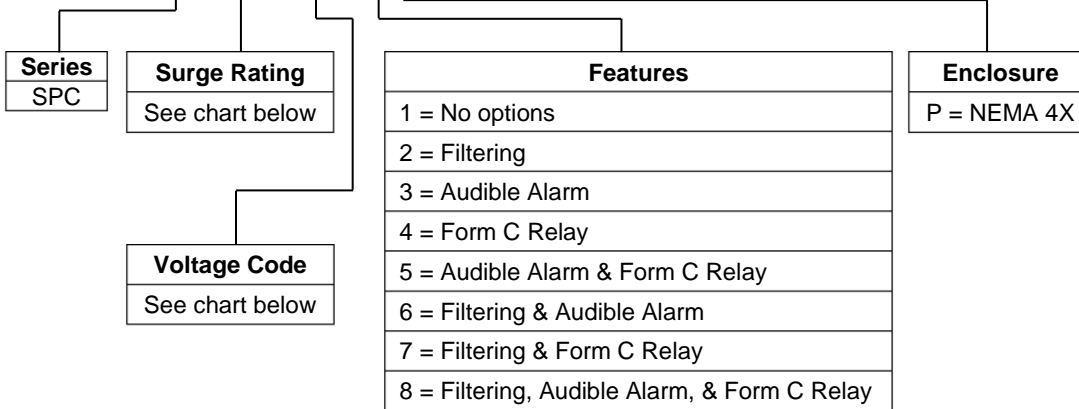

Notes:

- To maximize the SPD's performance, wire length should be less than 14" (35cm) twisted and bound together when installed
- UL1449 4th Edition Type 1 and Type 2, CSA Type 1 and Type 2, UL1283 6th Edition Co-Listed
- Mounting feet required for NEMA 4X
- Optional flush mount plate (Catalog # - FLUSHMNTPLATE13)

P1 Enclosure Configurations	
Voltage Code	Surge Rating (kA per phase)
120N/240N/277N/480N	050 – 200
240S	050 – 100
208Y/415Y/480Y/600Y	050 – 100
240D/480D	050 – 100
240H	050 – 100

EATON CORPORATION - CONFIDENTIAL AND PROPRIETARY			
NOTICE TO PERSONS RECEIVING THIS DOCUMENT AND/OR TECHNICAL INFORMATION THIS DOCUMENT, INCLUDING THE DRAWING AND INFORMATION CONTAINED THEREON, IS CONFIDENTIAL AND IS THE EXCLUSIVE PROPERTY OF EATON CORPORATION, AND IS HEREBY ON LOAN AND SUBJECT TO RECALL BY EATON AT ANY TIME. BY TAKING POSSESSION OF THIS DOCUMENT, THE RECIPIENT ACKNOWLEDGES AND AGREES THAT THIS DOCUMENT CANNOT BE USED IN ANY MANNER ADVERSE TO THE INTERESTS OF EATON AND THAT NO PORTION OF THIS DOCUMENT MAY BE COPIED OR OTHERWISE REPRODUCED WITHOUT THE PRIOR WRITTEN CONSENT OF EATON. IN THE CASE OF CONFLICTING CONTRACTUAL PROVISIONS, THIS NOTICE SHALL GOVERN THE STATUS OF THIS DOCUMENT.			
TITLE SURGE PROTECTIVE DEVICES SPC P1 ASSEMBLY			
DWG NO MKT-DL-15-002		PARTS LIST MKT-DL-15-002	
PRODUCT CODE		SHEET NO 1 OF 1	