


Clutches – Commercial Vehicles



EATON

Powering Business Worldwide



CLUTCHES COMMERCIAL VEHICLES
KUPPLUNGEN NKW/LKW
EMBRAYAGES VEHICULE INDUSTRIELS
SPRZĘGŁA DO POJAZDÓW UŻYTKOWYCH

CONTENTS LIST / INHALTSANGABEN / INDEX/ SPIS TREŚCI :

Explanations of symbols / Erklärungen der Symbole / Explications des symboles / objaśnienie symboli	3
Explanations types of covers / Erklärung der Typen bei Druckplatten / Explications des types de mécanisme Objaśnienie symboli - docisk sprzęgła	4
Explanations types of discs / Erklärung der Typen bei Kupplungsscheiben / Explications des types de disques Objaśnienie symboli - tarcza sprzęgła	5

TRUCK / LKW / POIDS LOURDS/ CIĘŻAROWE :

NEW RELEASES	6	MERCEDES-BENZ	83	STEYR	103
DAF	8	RENAULT	93	TERBERG	104
IVECO	11	SCANIA	97	VOLVO	105
MAN	41	SISU	102		

BUSES / BUSSE / BUS / AUTOBUSY:

BOVA	110	MERCEDES-BENZ	115
DAF	111	NEOPLAN	116
IRISBUS	112	SCANIA	117
MAN / STEYR	113	VOLVO	118

CROSS REFERENCE LISTS / VERGLEICHSLISTEN / LISTES DE CORRESPONDANCES /LISTA REFERENCJI

120

SD CLUTCH SELECTOR:

134

All part numbers of other manufacturers are for identification purposes only.

It is not allowed to use or reproduce anything of this catalogue without written permission of EATON TRUCK COMPONENTS SP. Z O.O.

Alle onderdeel nummers van andere producenten dienen alleen ter identificatie.

Zonder voorafgaande schriftelijke toestemming van EATON TRUCK COMPONENTS SP. Z O.O., mag niets uit deze catalogus, in welke vorm dan ook, worden vermenigvuldigd of opgeslagen.

Teilenummern von andere Hersteller dienen nur zu Vergleichszwecken.

Vervielfältigungen oder die Mitbenutzung dieses Kataloges ist ohne Zustimmung von EATON TRUCK COMPONENTS SP. Z O.O. unzulässig.

Toute les références d' autres constructeurs servent uniquement à titre d' identification

Utilisation ou reproductions de cette catalogue sans autorisation de EATON TRUCK COMPONENTS SP. Z O.O. est illicite.

Numery części innych producentów są podane tylko w celach identyfikacyjnych.

Kopowanie treści katalogu dozwolone jest tylko po otrzymaniu pisemnej zgody EATON TRUCK COMPONENTS SP. Z O.O.

EATON TRUCK COMPONENTS SP. Z O.O.

30-go Stycznia 55, 83-110 Tczew - Poland

email: ClutchEMEA@Eaton.com

Customer Service:




Patrycja Labunska
tel: +48585329623




Jaroslaw Kasperek
tel: +48585329113


 

e-mail: PatrycjaLabunska@Eaton.com


 

e-mail: JaroslawKasperek@Eaton.com



SYMBOL	EXPLANATION OF SYMBOLS
	Year
	see end of section
	extra information
⊥	kit without bearing
<	not included in kit
<nr.	till nr.
∅ + N	dimensions+number of splines
nr.<	from number
⇐	included in Cover

SYMBOL	ERKLÄRUNG DER SYMBOLE
	Jahr
	siehe Ende Sektion
	extra Informationen
⊥	Kit ohne Ausrücker
<	nicht in Kit
>nr.	bis Nr.
∅ + N	Abmessungen+Nuten
nr.>	ab Nr.
⇐	eingebaut in K-Druckplatte

SYMBOLE	EXPLICATION DES SYMBOLES
	Anneé
	voir fin de section
	Information supplémentaire
⊥	Kit sans butee
<	ne pas dans Kit
>nr.	depuis nr.
∅ + N	dimensions+cannalures
nr.>	jusqu' à nr.
⇐	compris dans mécanisme

SYMBOL	WYJAŚNIENIE SYMBOLI
	lata produkcji
	sprawdź na końcu sekcji
	informacje dodatkowe
⊥	zestaw bez łożyska
<	nie zawarte w zestawie
<nr.	do numeru
∅ + N	wymiar+liczba wypustów
nr.<	od numeru
⇐	zintegrowane z dociskiem

EXPLANATION OF ABBREVIATIONS OF CLUTCH COVER ASSEMBLIES

Numbers appearing in clutch cover types indicate the diameter :

MF	:	diaphragm type clutch for flat flywheel
MFZ	:	diaphragm pull type clutch for flat flywheel

ERKLÄRUNG DER KURZZEICHEN BEI DRUCKPLATTEN

Zahlen in den Druckplattentypen geben den Durchmesser an :

MF	:	membranfederkupplung für flaches Schwungrad
MFZ	:	membranfederkupplung für flaches Schwungrad, Ausrück auf Zug

EXPLICATION DES ABBRÉVIATIONS DE TYPE DE MÉCANISME

Les nombre dans le type de mécanisme expliquer le dimension

MF	:	embrayage à diaphragme; couvercle tole; pour volant plat
MFZ	:	embrayage à diaphragme tire; couvercle tole; pour volant plat

OBJAŚNIENIE SKRÓTÓW - DOCISK SPRZĘGŁA

Numery przy skrótach opisujących właściwości docisku odnoszą się do wymiaru

MF	:	sprzęgło ze sprężyną membranową, płaskie koło zamachowe
MFZ	:	sprzęgło ze sprężyną membranową, płaskie koło zamachowe, wysprzęganie z ciągnem

EXPLANATION OF ABBREVIATIONS OF CLUTCH DISKS

DZO	:	spring disk with pre-damper; cushion element; organic facings
------------	---	---

GZO	:	spring disk; cushion element; organic facings
------------	---	---

ERKLÄRUNG DER KURZZEICHEN BEI KUPPLUNGSSCHEIBEN

DZO	:	torsionsdämpfer für NKW; mit Vordämpfer; Zwischenblechfederung; organischer Belag
------------	---	---

GZO	:	torsionsdämpfer für NKW; Zwischenblechfederung; organischer Belag
------------	---	---

EXPLICATION DES ABBRÉVIATIONS DE TYPE DES DISQUES


DZO	:	amortisseur pour véhicules utilitaires; avec pre-amortisseur; progressivité; garniture organique
------------	---	--

GZO	:	amortisseur pour véhicules utilitaires; progressivité; garniture organique
------------	---	--

OBJANIEŃIE SKRÓTÓW - TARCZA SPRZĘGŁA

DZO	:	łumik drgań skrętnych, tłumik wstępny, elastyczne okładziny
------------	---	---

GZO	:	łumik drgań skrętnych, elastyczne okładziny
------------	---	---

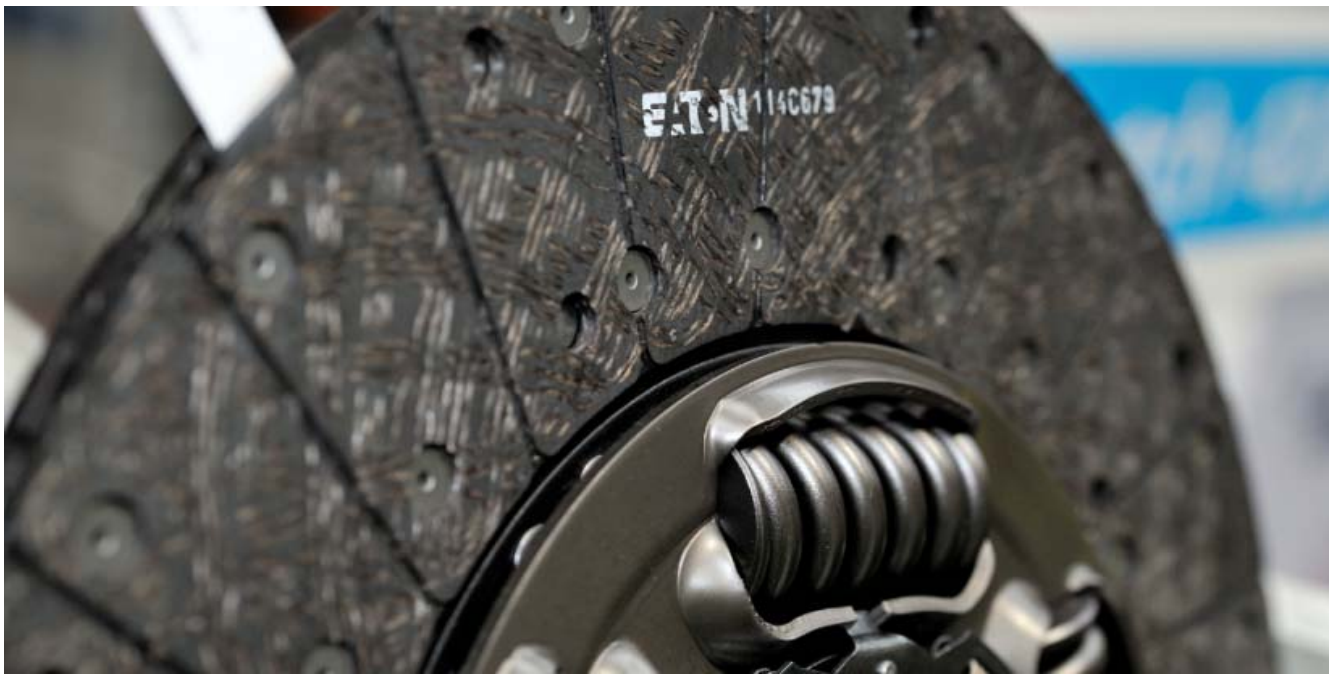

NEW RELEASES - SEPTEMBER 2016

Part number	Sachs reference part number	OE	OE part number	Designation	Diameter	Clutch type		
1040116-1	3400 700 370	SCANIA	572944	Clutch Kit	430 mm	Single plate	Pull	
		SCANIA	572949					
		SCANIA	574916					
	3400 700 371	SCANIA	572945					
		SCANIA	572950					
	3400700491		SCANIA					
	3400 700 610		SCANIA	574916				
			SCANIA	574919				
			SCANIA	574917				
	1040117-1	3400 700 374	SCANIA	572954	Clutch Kit	430 mm	Single plate	Pull
104680-1	3400 700 307	DAF	1740017	Clutch Kit	362 mm	Single plate	Push	
		DAF	1740017R					
		DAF	1808123R					
		DAF	1815112R					
		DAF	1817774R					
104681-1	3400 127 701	MERCEDES-BENZ	A 018 250 94 01	Clutch Kit	362 mm	Single plate	Push	
		MERCEDES-BENZ	A 021 250 34 01					
		MERCEDES-BENZ	A 021 250 35 01					
		MERCEDES-BENZ	A 025 250 23 01					
		MERCEDES-BENZ	A 025 250 25 01					
104682-1	3400 700 303	M.A.N		Clutch Kit	362 mm	Single plate	Push	
104822-1	3400 700 466	RENAULT TRUCKS	5001 872 322	Clutch Kit	395 mm	Single plate	Push	
		RENAULT TRUCKS	5001 872 324					
		RENAULT TRUCKS	7485013826					
		VOLVO	85000791					


Part number	Sachs reference part number	OE	OE part number	Designation	Diameter	Clutch type
104823-1	3400 121 301	MERCEDES-BENZ	A 018 250 96 01	Clutch Kit	395 mm	Single plate Push
		MERCEDES-BENZ	A 019 250 65 01			
		MERCEDES-BENZ	A 021 250 38 01			
		MERCEDES-BENZ	A 021 250 39 01			
		MERCEDES-BENZ	A 021 250 90 01			
		MERCEDES-BENZ	A 022 250 62 01			
		MERCEDES-BENZ	A 022 250 63 01			
104824-1	3400 121 201	MERCEDES-BENZ	A 018 250 95 01	Clutch Kit	395 mm	Single plate Push
		MERCEDES-BENZ	A 021 250 36 01			
		MERCEDES-BENZ	A 021 250 37 01			
		MERCEDES-BENZ	A 021 250 89 01			
		MERCEDES-BENZ	A 022 250 58 01			
		MERCEDES-BENZ	A 022 250 59 01			
104825-1	3400 700 308	DAF	1736890	Clutch Kit	395 mm	Single plate Push
		DAF	1736890R			
104951-1	3400 121 501	MERCEDES-BENZ	A 018 250 97 01	Clutch Kit	400 mm	Twin plate Pull
		MERCEDES-BENZ	A 021 250 07 01			
		MERCEDES-BENZ	A 021 250 68 01			
		MERCEDES-BENZ	A 022 250 48 01			
		MERCEDES-BENZ	A 024 250 49 01			
	3400 700 355	MERCEDES-BENZ	A 021 250 75 01			
		MERCEDES-BENZ	A 022 250 43 01			
		MERCEDES-BENZ	A 022 250 44 01			
		MERCEDES-BENZ	A 024 250 51 01			
		MERCEDES-BENZ	A 024 250 52 01			
		MERCEDES-BENZ	A 025 250 87 01			
		MERCEDES-BENZ	A 026 250 78 01			
		MERCEDES-BENZ	A 026 250 79 01			
		MERCEDES-BENZ	A 026 250 81 01			
		MERCEDES-BENZ	A 026 250 85 01			
		MERCEDES-BENZ	A 027 250 16 01			
		MERCEDES-BENZ	A 027 250 17 01			
104952-1	3400 700 360	VOLVO	85000773	Clutch Kit	400 mm	Twin plate Pull
	3400 700 422	VOLVO				
104953-1	3400 700 406	VOLVO	85000313	Clutch Kit	400 mm	Twin plate Pull
		VOLVO	85000566			
		VOLVO	85003001			
104954-1	3400 117 532	RENAULT TRUCKS	5001 843 361	Clutch Kit	400 mm	Twin plate Pull
		RENAULT TRUCKS	5001 875 223			
104955-1	3400 700 426	VOLVO		Clutch Kit	380 mm	Twin plate Pull

You can find more information about Eaton clutch products on TecDoc



TRUCK

DAF

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete			
	ltr	Type			Ref	Ref.	Type	Ref.	Ø+N	Type	Ref.
SERIE 75 CF 9802- 0012											
75 CF 320		PF 235M	ZF 8S151	9802-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
75 CF 320		PF 235M	ZF 16S151	9802-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
SERIE CF 75 0101-											
CF 75.250		PE183C	ZF 8S151	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 75.250		PE183C	ZF 16S151	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 75.250		PE183C	ZF AS-tronic <i>release fork with rollers</i>	0101-	104080-1	170052-35	MFZ430	128986	430x2"x10	DZO	125854
CF 75.310		PE228C	ZF 8S151	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 75.310		PF228C	ZF 16S151	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 75.310		PE228C	ZF AS-tronic <i>release fork with rollers</i>	0101-	104080-1	170052-35	MFZ430	128986	430x2"x10	DZO	125854
CF 75.360	Euro 3	PE265C	ZF Ecosplit 3	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 75.360	Euro 4/ Euro 5	PE265C	ZF Ecosplit 3	0101-	104078-1	170052-35	MFZ430	128986	430x2"x10	DZO	125849
CF 75.360		PE265C	ZF Ecosplit 4	0101-	104080-1	170052-35	MFZ430	128986	430x2"x10	DZO	125854
CF 75.360		PE265C	ZF AS-tronic <i>release fork with rollers</i>	0101-	104080-1	170052-35	MFZ430	128986	430x2"x10	DZO	125854
SERIE 85 9207-9802											
85.400		WS 295 M	8S151		104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
85.400		WS 295 M	16S151		104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
85.400		WS 295 M	16S181		104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
85.400		WS 295 M	16S221		104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
SERIE 85 CF 9802-0012											
85 CF 340		XF250M	ZF S16-151		104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
85 CF 380		XF280M	ZF S16-181		104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
85 CF 430		XF315M	ZF S16-181		104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
SERIE CF 85 0101-											
CF 85.340		XE250C	ZF 16S-151	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.340		XE250C	ZF 16S-181	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.340		XE250C	ZF 16S-221	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.380		XE280C	ZF 16S-151	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.380		XE280C	ZF 16S-181	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.380		XE280C	ZF 16S-221	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.430		XE315C	ZF 16S-151	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.430		XE315C	ZF 16S-181	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.430		XE315C	ZF 16S-221	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.480		XE355C	ZF 16S-151	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.480		XE355C	ZF 16S-181	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
CF 85.480		XE355C	ZF 16S-221	0101-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
SERIE CF 85 0510-											
CF 85.360		12.9 MX265	ZF AS-Tronic <i>release fork with rollers</i>	0610-	104080-1	170052-35	MFZ430	128986	430x2"x10	DZO	125854
CF 85.360		12.9 MX265	ZF Ecosplit	0610-	104078-1	170052-35	MFZ430	128986	430x2"x10	DZO	125849

DAF

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		ltr Type				Ref. Type	Ref. Ø+N Type	Ref.
CF 85.410		12.9 MX300	ZF AS-Tronic <i>release fork with rollers</i>	0610-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
CF 85.410		12.9 MX300	ZF Ecosplit	0610-	104078-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
CF 85.460		12.9 MX340	ZF AS-Tronic <i>release fork with rollers</i>	0610-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
CF 85.460		12.9 MX340	ZF Ecosplit	0610-	104078-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
CF 85.510		12.9 MX375	ZF AS-Tronic <i>release fork with rollers</i>	0610-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
CF 85.510		12.9 MX375	ZF Ecosplit	0610-	104078-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

SERIE CF 1210- EURO6

290			MX11 210	ZF AS-Tronic <i>release fork with rollers</i>	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
330			MX11 240	ZF AS-Tronic <i>release fork with rollers</i>	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
370			MX11 271	ZF AS-Tronic <i>release fork with rollers</i>	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
400			MX11 291	ZF AS-Tronic <i>release fork with rollers</i>	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
400			MX11 291	ZF Ecosplit 4	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
410			MX13 303	ZF AS-Tronic <i>release fork with rollers</i>	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
410			MX13 303	ZF Ecosplit 4	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440			MX11 320	ZF AS-Tronic <i>release fork with rollers</i>	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440			MX11 320	ZF Ecosplit 4	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
460			MX13 340	ZF AS-Tronic <i>release fork with rollers</i>	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
460			MX13 340	ZF Ecosplit 4	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
510			MX13 375	ZF AS-Tronic <i>release fork with rollers</i>	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
510			MX13 375	ZF Ecosplit 4	1305-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854

SERIE 95 XF 9701-0209

95 XF 380			XF 280M	ZF S16-181	9701-0209	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
95 XF 380			XF 280C	ZF S16-181	9701-0209	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
95 XF 430			XE 315C	ZF S16-181	9701-0209	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
95 XF 430			XE 315M	ZF S16-181	9701-0209	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
95 XF 480			XE 355C	ZF S16-221	9701-0209	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
95 XF 480			XE 355M	ZF S16-221	9701-0209	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849

SERIE XF 95 0209-0612

XF 95.380	4x2; 6x2/4	12,6	XE280C	ZF 16S-151	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.380	4x2; 6x2/4	12,6	XE280C	ZF 16S-181	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.380	4x2; 6x2/4	12,6	XE280C	ZF 16S-221	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.380	4x2; 6x2/4	12,6	XE280C	ZF AS-Tronic		104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
XF 95.430	4x2	12,6	XE315C	ZF 16S-151	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849

DAF

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		ltr Type				Ref. Type	Ref. Ø+N Type	Ref.
XF 95.430	4x2	12,6 XE315C	ZF 16S-181	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.430	4x2	12,6 XE315C	ZF 16S-221	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.430	4x2	12,6 XE315M	ZF AS-Tronic		104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
XF 95.480	4x2	12,6 XE355C	ZF 16S-151	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.480	4x2	12,6 XE355C	ZF 16S-181	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.480	4x2	12,6 XE355C	ZF 16S-221	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.480	4x2	12,6 XE355C	ZF AS-Tronic		104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
XF 95.530	4x2	12,6 XE390C	ZF 16S-151	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.530	4x2	12,6 XE390C	ZF 16S-181	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.530	4x2	12,6 XE390C	ZF 16S-221	0209-0612	104070-1	170052-35 MFZ430	128985 430x2"x10 GZO	125849
XF 95.530	4x2	12,6 XE390C	ZF AS-Tronic		104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854

SERIE XF 105 0510-

XF 105.410	4x2; 6x2/4	12,9 MX300	ZF AS-Tronic <i>release fork with rollers</i>	0510-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
XF 105.410	4x2; 6x2/4	12,9 MX300	ZF 16S-2020	0510-	104078-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
XF 105.410	4x2; 6x2/4	12,9 MX300	ZF 16S-2220	0510-	104078-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
XF 105.460	4x2; 6x2/4	12,9 MX340	ZF AS-Tronic <i>release fork with rollers</i>	0510-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
XF 105.460	4x2; 6x2/4	12,9 MX340	ZF 16S-2020	0510-	104078-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
XF 105.460	4x2; 6x2/4	12,9 MX340	ZF 16S-2220	0510-	104078-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
XF 105.510	4x2; 6x2/4	12,9 MX375	ZF AS-Tronic <i>release fork with rollers</i>	0510-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
XF 105.510	4x2; 6x2/4	12,9 MX375	ZF 16S-2020	0510-	104078-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
XF 105.510	4x2; 6x2/4	12,9 MX375	ZF 16S-2220	0510-	104078-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

SERIE XF 1210-

410		MX-13 303	ZF AS-Tronic <i>release fork with rollers</i>	1210-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
410		MX-13 303	ZF Ecosplit 4	1210-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440		MX-11 320	ZF AS-Tronic <i>release fork with rollers</i>	1210-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440		MX-11 320	ZF Ecosplit 4	1210-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
460		MX-13 340	ZF AS-Tronic <i>release fork with rollers</i>	1210-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
460		MX-13 340	ZF Ecosplit 4	1210-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
510		MX-13 375	ZF AS-Tronic <i>release fork with rollers</i>	1210-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
510		MX-13 375	ZF Ecosplit 4	1210-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854

IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.
--	---	--	---	---	---	---	---	--

ASTRA


HD7 Serie

All Models		8210,42	standard clutch		104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
All Models		8280,42	standard clutch		104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850

EUROSTAR 9301-0202

190 E42		8210	ZF 16S221 - 16V release fork with bosses	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 42		8210	ZF release fork with rollers	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
190 E47		8210	ZF 16S221 - 16V release fork with bosses	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 47		8210	ZF release fork with rollers	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
190 E52		8280	ZF 16S221 - 16V release fork with bosses	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 52		8280	ZF release fork with rollers	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
240 E42		8210	ZF 16S221 - 16V release fork with bosses	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
240 E 42		8210	ZF release fork with rollers	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
240 E47		8210	ZF 16S221 - 16V release fork with bosses	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
240 E 47		8210	ZF release fork with rollers	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
240 E52		8280	ZF 16S221 - 16V release fork with bosses	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
240 E52		8280	ZF release fork with rollers	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E42		8210	ZF 16S221 - 16V release fork with bosses	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 42		8210	ZF release fork with rollers	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E47		8210	ZF 16S221 - 16V release fork with bosses	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 47		8210	ZF release fork with rollers	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E52		8280	ZF 16S221 - 16V release fork with bosses	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 52		8280	ZF release fork with rollers	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
400 E42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
400 E 42		8210	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440 E42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 42		8210	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440 E47		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 47		8210	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440 E52		8280	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850


EUROSTAR CURSOR 9901-0202

190 E 39		Cursor 10F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 39		Cursor 10F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	0006-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 39		Cursor 10F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0006-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 39		Cursor 10F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 39		Cursor 10F3A	ZF <i>release fork with rollers</i>	9911-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
190 E 40		Cursor 10F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0009-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 40		Cursor 10F3A	ZF <i>release fork with rollers</i>	0009-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
190 E 43		Cursor 10F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9911-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 43		Cursor 10F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	9911-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 43		Cursor 10F3A	ZF <i>release fork with rollers</i>	9911-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E 39		Cursor 10F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 39		Cursor 10F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	0006-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 39		Cursor 10F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0006-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850

IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor cc Type	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.
260 E 39		Cursor 10F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 39		Cursor 10F3A	ZF <i>release fork with rollers</i>	9911-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E 40		Cursor 10F3A	ZF <i>release fork with bosses</i>	0009-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 40		Cursor 10F3A	ZF <i>release fork with rollers</i>	0009-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E 43		Cursor 10F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 43		Cursor 10F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 43		Cursor 10F3A	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440 E 39		Cursor 10F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 39		Cursor 10F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	0006-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 39		Cursor 10F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0006-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 39		Cursor 10F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 39		Cursor 10F3A	ZF <i>release fork with rollers</i>	9911-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440 E 40		Cursor 10F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0009-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 40		Cursor 10F3A	ZF <i>release fork with rollers</i>	0009-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440 E 43		Cursor 10F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 43		Cursor 10F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 43		Cursor 10F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 43		Cursor 10F3A	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
EUROTECH								
180 E 42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
180 E 42		8210	ZF <i>release fork with rollers</i>	9201-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
190 E 42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 42		8210	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
240 E 42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
240 E 42		8210	ZF <i>release fork with rollers</i>	9201-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E 42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 42		8210	ZF <i>release fork with rollers</i>	9401-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
400 E 42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
400 E 42		8210	ZF <i>release fork with rollers</i>	9201-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440 E 42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 42		8210	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854

EUROTECH CURSOR

190 E 39		Cursor 10 F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 39		Cursor 10 F3A	ZF 16S151 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 39		Cursor 10F3A	ZF <i>release fork with rollers</i>	9911-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
190 E 43		Cursor 10 F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 43		Cursor 10 F3A	ZF 16S151 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 43		Cursor 10F3A	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E 39		Cursor 10 F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 39		Cursor 10 F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 39		Cursor 10 F3A	ZF 16S151 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 39		Cursor 10F3A	ZF <i>release fork with rollers</i>	9911-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854

IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
260 E 43		Cursor 10 F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 43		Cursor 10 F3A	ZF 16S151 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 43		Cursor 10F3A	ZF <i>release fork with rollers</i>	9911-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440 E 39		Cursor 10 F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 39		Cursor 10 F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 39		Cursor 10 F3A	ZF 16S151 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 39		Cursor 10F3A	ZF <i>release fork with rollers</i>	9911-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
440 E 43		Cursor 10 F3A	ZF 12AS1800 - 12V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 43		Cursor 10 F3A	ZF 16S151 - 16V <i>release fork with bosses</i>	9901-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E 43		Cursor 10F3A	ZF <i>release fork with rollers</i>	9911-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854

EUROTRAKKER

190 E42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 42		8210	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E37		8210	ZF 16S151 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 37		8210	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 42		8210	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
340 E37		8210	ZF 16S151 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
340 E 37		8210	ZF <i>release fork with rollers</i>	9301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
340 E42		8210	ZF <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
380 E37		8210	ZF 16S151 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
380 E42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
400 E37		8210	ZF 16S151 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
400 E42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
410 E37		8210	ZF 16S151 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
410 E42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E37		8210	ZF 16S151 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
440 E42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
720 E37		8210	ZF 16S151 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
720 E42		8210	ZF 16S221 - 16V <i>release fork with bosses</i>	9301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850


EUROTRAKKER CURSOR 0101-0411

190 E 38		Cursor 13 F3B	ZF 16S151 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 38		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
190 E 44		Cursor 13 F3B	ZF <i>release fork with bosses</i>	0009-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
190 E 44		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0009-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E 38		Cursor 13 F3B	ZF 16AS2601 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 38		Cursor 13 F3B	ZF 16S151 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 38		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
260 E 44		Cursor 13 F3B	ZF 16AS2601 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 44		Cursor 13 F3B	ZF 16S181 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260 E 44		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
340 E 38		Cursor 13 F3B	ZF 16AS2601 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor cc Type	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.
340 E 38		Cursor 13 F3B	ZF 16S151 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
340 E 38		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
340 E 44		Cursor 13 F3B	ZF 16AS2601 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
340 E 44		Cursor 13 F3B	ZF 16S181 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
340 E 44		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
380 E 38		Cursor 13 F3B	ZF 16AS2601 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
380 E 38		Cursor 13 F3B	ZF 16S151 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
380 E 38		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
380 E 44		Cursor 13 F3B	ZF 16AS2601 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
380 E 44		Cursor 13 F3B	ZF 16S181 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
380 E 44		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
410 E 38		Cursor 13 F3B	ZF 16AS2601 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
410 E 38		Cursor 13 F3B	ZF 16S151 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
410 E 38		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
410 E 44		Cursor 13 F3B	ZF 16AS2601 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
410 E 44		Cursor 13 F3B	ZF 16S181 - 16V <i>release fork with bosses</i>	0101-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
410 E 44		Cursor 13 F3B	ZF <i>release fork with rollers</i>	0101-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
STRALIS ACTIVE DAY								
AD 190 S 40		Cursor 10 F3A	ZF 12AS2301 <i>release fork with bosses</i>	0303-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 190 S 40		Cursor 10 F3A	ZF 12AS2301 <i>release fork with rollers</i>	0303-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 S 40		Cursor 10 F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	0303-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850

IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 190 S 40		Cursor 10 F3A	ZF 16S-181 <i>release fork with rollers</i>	0303-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 S 42		Cursor 11 F3G Euro 6	ZF 16S1920 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 S 42		Cursor 11 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 S 42		Cursor 11 F3G Euro 6	ZF 12AS1930 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 S 42		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 S 43		Cursor 10 F3A	ZF 12AS2301 <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 190 S 43		Cursor 10 F3A	ZF 12AS2301 <i>release fork with rollers</i>	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 S 43		Cursor 10 F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 190 S 43		Cursor 10 F3A	ZF 16S181 <i>release fork with rollers</i>	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 S 46		Cursor 13 F3A Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 S 46		Cursor 13 F3A Euro 6	ZF 16AS2630 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 S 46		Cursor 11 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 S 48		Cursor 11 F3G Euro 6	ZF 16S <i>release fork with rollers</i>	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 S 48		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 S 48		Cursor 11 F3G Euro 6	ZF 12 AS <i>release fork with rollers</i>	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 S 40		Cursor 10 F3A	ZF 16S109 <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 S 40		Cursor 10 F3A	ZF 16S109 <i>release fork with rollers</i>	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 S 40		Cursor 10 F3A	ZF 12 AS <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 S 40		Cursor 10 F3A	ZF 12 AS <i>release fork with rollers</i>	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 S 42		Cursor 11 F3G Euro 6	ZF 16S1920 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854

IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 260 S 42		Cursor 11 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 S 42		Cursor 11 F3G Euro 6	ZF 12AS1930 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 S 42		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 S 43		Cursor 10 F3A	ZF 12AS2301 release fork with bosses	0306-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 S 43		Cursor 10 F3A	ZF 12AS2301 release fork with rollers	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 S 43		Cursor 10 F3A	ZF 16S181 - 16V release fork with bosses	0306-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 S 43		Cursor 10 F3A	ZF 16S181 release fork with rollers	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 S 46		Cursor 11 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 S 46		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 S 48		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 S 48		Cursor 11 F3G	ZF 12 AS release fork with rollers	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 S 48		Cursor 11 F3G	ZF 16 AS release fork with rollers	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 S 48		Cursor 11 F3G	ZF 16 S release fork with rollers	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 440 S 40		Cursor 10 F3A	ZF 12AS2301 - 12V release fork with bosses	0303-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 440 S 40		Cursor 10 F3A	ZF 12AS2301 release fork with rollers	0303-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 440 S 40		Cursor 10 F3A	ZF 16S181 - 16V release fork with bosses	0303-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 440 S 40		Cursor 10 F3A	ZF 16S181 release fork with rollers	0303-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 440 S 42		Cursor 11 F3G Euro 6	ZF 16S1920 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 440 S 42		Cursor 11 F3G	ZF 16S1920 release fork with rollers	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 440 S 42		Cursor 11 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 440 S 42		Cursor 11 F3G Euro 6	ZF 12AS1930 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 440 S 42		Cursor 11 F3G	ZF 12AS1930 release fork with rollers	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 440 S 42		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 440 S 46		Cursor 11 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 440 S 46		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 440 S 48		Cursor 13 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854


STRALIS ACTIVE SPACE

AS 190 S 40		Cursor 10 F3A	ZF 12AS2301 release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 190 S 40		Cursor 10 F3A	ZF 16S181 - 16V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 190 S 40		Cursor 10 F3A	ZF 16S181 release fork with rollers	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 190 S 42		Cursor 11 F3G Euro 6	ZF 16S1920 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 190 S 42		Cursor 11 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 190 S 42		Cursor 11 F3G Euro 6	ZF 12AS1930 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 190 S 42		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 190 S 43		Cursor 10 F3A	ZF 12AS2301 release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 190 S 43		Cursor 10 F3A	ZF 12AS2301 release fork with rollers	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 190 S 43		Cursor 10 F3A	ZF 16S181 - 16V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 190 S 43		Cursor 10 F3A	ZF 16S181 release fork with rollers	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 190 S 46		Cursor 13 F3A Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 190 S 46		Cursor 13 F3A Euro 6	ZF 16AS2630 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 190 S 46		Cursor 11 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 190 S 46		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AS 190 S 48		Cursor 10 F3B	ZF 16AS2601 <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 190 S 48		Cursor 10 F3B	ZF 12AS2330 <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 190 S 48		Cursor 11 F3G	ZF 12AS <i>release fork with rollers</i>	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 190 S 48		Cursor 10 F3B	ZF 16S181 <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 190 S 48		Cursor 11 F3G	ZF 16S181 <i>release fork with rollers</i>	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 190 S 48		Cursor 10 F3B	ZF 16S221 <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 190 S 48		Cursor 10 F3B	ZF 16S221 <i>release fork with rollers</i>	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 190 S 50		Cursor 10 F3B	ZF 12AS2330 <i>release fork with bosses</i>	0612-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AS 190 S 50		Cursor 10 F3B	ZF 12AS2330 <i>release fork with rollers</i>	0612-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 190 S 50		Cursor 10 F3B	ZF 16S2320 <i>release fork with bosses</i>	0612-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AS 260 S 40		Cursor 10 F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 260 S 40		Cursor 10 F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 260 S 42		Cursor 11 F3G Euro 6	ZF 16S1920 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 260 S 42		Cursor 11 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 260 S 42		Cursor 11 F3G Euro 6	ZF 12AS1930 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 260 S 42		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 260 S 43		Cursor 10 F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 260 S 43		Cursor 10 F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	0201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 260 S 44		Cursor 13 F3B	ZF 16AS2601 <i>release fork with bosses</i>	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 260 S 44		Cursor 10 F3B	ZF 16AS2601 <i>release fork with rollers</i>	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AS 260 S 46		Cursor 11 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 260 S 46		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 260 S 48		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 260 S 48		Cursor 13 F3B	ZF 16AS2601 - 16V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 260 S 48		Cursor 11 F3G	ZF 16AS release fork with rollers	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 260 S 48		Cursor 13 F3B	ZF 16S221 - 16V release fork with bosses	0201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 260 S 48		Cursor 11 F3G	ZF 16S release fork with rollers	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 260 S 50		Cursor 13 F3B	ZF 12 AS / 16AS release fork with bosses	0612-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AS 260 S 54		Cursor 13 F3B	ZF 16AS2601 - 16V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 260 S 54		Cursor 13 F3B	ZF 16AS release fork with rollers	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 260 S 56		Cursor 13 F3B	ZF 12 AS release fork with bosses	0612-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AS 260 S 56		Cursor 13 F3B	ZF 16AS release fork with bosses	0612-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AS 320 S 50		Cursor 13 F3B	ZF 16 S release fork with bosses	0705-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AS 320 S 50		Cursor 13 F3B	ZF 12 AS release fork with rollers	0705-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 440 S 40		Cursor 10 F3A	ZF 12AS2301 - 12V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 440 S 40		Cursor 10 F3A	ZF 12AS release fork with rollers	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 440 S 40		Cursor 10 F3A	ZF 16S181 - 16V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 440 S 40		Cursor 10 F3A	ZF 16S release fork with rollers	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 440 S 42		Cursor 11 F3G Euro 6	ZF 16S1920 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 440 S 42		Cursor 11 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 440 S 42		Cursor 11 F3G Euro 6	ZF 12AS1930 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AS 440 S 42		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 440 S 43		Cursor 10 F3A	ZF 12AS2301 - 12V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 440 S 43		Cursor 10 F3A	ZF 16S181 - 16V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 440 S 44		Cursor 13 F3B	ZF 16AS2601 - 16V release fork with bosses	0201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 440 S 44		Cursor 13 F3B	ZF 16AS2601 release fork with rollers	0201-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 440 S 44		Cursor 13 F3B	ZF 16S221 - 16V release fork with bosses	0201-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 440 S 44		Cursor 13 F3B	ZF 16S221 release fork with rollers	0201-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 440 S 46		Cursor 11 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 440 S 46		Cursor 11 F3G Euro 6	ZF 12AS2330 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 440 S 48		Cursor 13 F3B	ZF 16AS2601 - 16V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 440 S 48		Cursor 13 F3B	ZF 16AS release fork with rollers	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 440 S 48		Cursor 13 F3B	ZF 16S221 - 16V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 440 S 48		Cursor 13 F3G Euro 6	ZF 16S2220 release fork with rollers	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 440 S 50		Cursor 13 F3B	ZF 16 S release fork with bosses	0607-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AS 440 S 50		Cursor 13 F3B	ZF 12 AS release fork with rollers	0607-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AS 440 S 54		Cursor 13 F3B	ZF 16AS2601 - 16V release fork with bosses	0202-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AS 440 S 54		Cursor 13 F3B	ZF 16AS release fork with rollers	0202-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AS 440 S 56		Cursor 13 F3B	ZF 12 AS release fork with rollers	0607-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
STRALIS ACTIVE TIME								
AT 190 S 40		Cursor 10 F3A	ZF 12AS2301 - 12V release fork with bosses	0303-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 S 40		Cursor 10 F3A	ZF 12AS2301 release fork with rollers	0303-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854

IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AT 190 S 40		Cursor 10 F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	0303-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 S 40		Cursor 10 F3A	ZF 16S181 <i>release fork with rollers</i>	0303-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 190 S 42		Cursor 11 F3G Euro 6	ZF 16S1920 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 S 42		Cursor 11 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 S 42		Cursor 11 F3G Euro 6	ZF 12AS1930 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 S 42		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 S 43		Cursor 10 F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	0306-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 S 43		Cursor 10 F3A	ZF 16S181 - <i>release fork with rollers</i>	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 190 S 43		Cursor 10 F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0306-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 S 43		Cursor 10 F3A	ZF 12AS2301 <i>release fork with rollers</i>	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 190 S 46		Cursor 13 F3A Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 S 46		Cursor 13 F3A Euro 6	ZF 16AS2630 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 S 46		Cursor 11 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 S 46		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 S 48		Cursor 11 F3G	ZF 12AS <i>release fork with rollers</i>	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 190 S 48		Cursor 11 F3G	ZF 16S <i>release fork with rollers</i>	1301-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 260 S 42		Cursor 11 F3G Euro 6	ZF 16S1920 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 260 S 42		Cursor 11 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 260 S 42		Cursor 11 F3G Euro 6	ZF 12AS1930 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 260 S 42		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor cc Type	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.
AT 260 S 43		Cursor 10 F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 260 S 43		Cursor 10 F3A	ZF 12AS2301 <i>release fork with rollers</i>	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 260 S 43		Cursor 10 F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	0301-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 260 S 43		Cursor 10 F3A	ZF 12AS2301 <i>release fork with rollers</i>	0306-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 260 S 46		Cursor 11 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 260 S 46		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 260 S 48		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 S 40		Cursor 10 F3A	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0303-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 440 S 40		Cursor 10 F3A	ZF 12AS2301 <i>release fork with rollers</i>	0303-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 440 S 40		Cursor 10 F3A	ZF 16S181 - 16V <i>release fork with bosses</i>	0303-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 440 S 40		Cursor 10 F3A	ZF 12AS2301 <i>release fork with rollers</i>	0303-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 440 S 42		Cursor 11 F3G Euro 6	ZF 16S1920 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 S 42		Cursor 11 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 S 42		Cursor 11 F3G Euro 6	ZF 12AS1930 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 S 42		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 S 46		Cursor 11 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 S 46		Cursor 11 F3G Euro 6	ZF 12AS2330 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 S 48		Cursor 13 F3G Euro 6	ZF 16S2220 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854


TRAKKER EURO 6

Trakker Euro 6		Cursor 11 420 PS	ZF 16S1920 <i>release fork with rollers</i>	1301-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
		420 PS	ZF 16S2220 <i>release fork with rollers</i>		104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.											
Trakker Euro 6		cc	Type						420 PS	ZF 12AS1930 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854		
									420 PS	ZF 12AS2330 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854		
									460 PS	ZF 16S2220 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854		
									460 PS	ZF 12 AS2330 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854		
									480 PS	ZF 16S2320 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854		
									480 PS	ZF 16S2520 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854		
									480 PS	ZF 12AS2330 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854		
									Cursor 13	1301-	450 PS	ZF 12AS2330 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854
									450 PS		ZF 16AS2630 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854	
									480 PS		ZF 16S2220 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854	
									500 PS		ZF 16S2320 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854	
									500 PS		ZF 16S2520 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854	
									500 PS		ZF 12AS2330 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854	
									500 PS		ZF 12AS2630 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854	
									560 PS		ZF 16S2520 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854	
									560 PS	ZF 12AS2530 release fork with rollers	104094-1	170053-35	MFZ430	128992	430x2"x10	DZO	125854		
TRAKKER ACTIVE DAY																			
AD 190 T 38		F3BE	ZF 12AS2301 - 12V release fork with bosses	0410-	104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850								
AD 190 T 38		F3BE	ZF 12AS2301 release fork with rollers	0410-	104080-1	170052-35	MFZ430	128986	430x2"x10	DZO	125854								
AD 190 T 38		F3BE	ZF 16S151 release fork with bosses	0410-	104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850								


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 190 T 38		F3BE	ZF 16S151 release fork with rollers	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 T 38		F3BE	ZF 12AS2330-12V release fork with bosses	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 190 T 38		F3BE	ZF 12AS2330-12V release fork with rollers	0410-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 T 38		F3BE	ZF 16S2220 - 16V release fork with bosses	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 190 T 41		F3BE	ZF 12AS2330-12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 190 T 41		F3BE	ZF 12AS2330-12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 T 41		F3BE	ZF 16S2220 - 16V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 190 T 44		F3BE	ZF 12AS2301 - 12V release fork with bosses	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 190 T 44		F3BE	ZF 12AS2301 - 12V release fork with rollers	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 T 44		F3BE	ZF 16S181 release fork with bosses	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 190 T 44		F3BE	ZF 16S181 release fork with rollers	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 T 44		F3BE	ZF 12AS2330-12V release fork with bosses	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 190 T 44		F3BE	ZF 12AS2330-12V release fork with rollers	0410-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 190 T 44		F3BE	ZF 16S2220 - 16V release fork with bosses	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 190 T 45		F3BE	ZF 12AS2301 - 12V release fork with bosses	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 190 T 45		F3BE	ZF 12AS2301 release fork with rollers	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 T 45		F3BE	ZF 16S181 release fork with bosses	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 190 T 45		F3BE	ZF 16S181 release fork with rollers	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 190 T 45		F3BE	ZF 12AS2330-12V release fork with bosses	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 190 T 45		F3BE	ZF 12AS2330-12V release fork with rollers	0410-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrucker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 190 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 260 T 38		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 T 38		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 T 38		F3BE	ZF 16S151 <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 T 38		F3BE	ZF 16S151 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 T 41		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 260 T 41		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 T 44		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 T 44		F3BE	ZF 16S181 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 T 45		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 260 T 45		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 260 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 T 48		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 T 48		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 T 48		F3BE	ZF 16S221 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 260 T 48		F3BE	ZF 16S221 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 260 T 50		F3BE	ZF 12AS2330 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 260 T 50		F3BE	ZF 12AS2330-12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 260 T 50		F3BE	ZF 16S2520 release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 340 T 38		F3BE	ZF 12AS2301 - 12V release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 340 T 38		F3BE	ZF 12AS2301 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 340 T 38		F3BE	ZF 16S151 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 340 T 38		F3BE	ZF 16S151 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 340 T 41		F3BE	ZF 12AS2330-12V release fork with bosses	0606-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 340 T 41		F3BE	ZF 12AS2330-12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 340 T 41		F3BE	ZF 16S2220 - 16V release fork with bosses	0606-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 340 T 44		F3BE	ZF 12AS2301 - 12V release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 340 T 44		F3BE	ZF 12AS2301 - release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 340 T 44		F3BE	ZF 16S181 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 340 T 44		F3BE	ZF 16S181 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 340 T 45		F3BE	ZF 12AS2330-12V release fork with bosses	0606-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 340 T 45		F3BE	ZF 12AS2330-12V release fork with rollers	0606-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 380 T 38		F3BE	ZF 12AS2301 - 12V release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 380 T 38		F3BE	ZF 12AS2301 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 380 T 38		F3BE	ZF 16S151 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 380 T 38		F3BE	ZF 16S151 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 380 T 38		F3BE	ZF 16S221 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 380 T 38		F3BE	ZF 16S221 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 380 T 41		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 380 T 41		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 380 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 380 T 44		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 380 T 44		F3BE	ZF 16S181 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 380 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 380 T 45		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 380 T 45		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0410-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 380 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 380 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 380 T 48		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 380 T 48		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 380 T 48		F3BE	ZF 16S221 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 380 T 48		F3BE	ZF 16S221 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 380 T 50		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 380 T 50		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 380 T 50		F3BE	ZF 16S2520 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 400 T 38		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 400 T 38		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 400 T 38		F3BE	ZF 16S151 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 400 T 38		F3BE	ZF 16S151 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 400 T 41		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 400 T 41		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 400 T 41		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 400 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 400 T 44		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 400 T 44		F3BE	ZF 16S181 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 400 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 400 T 45		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 400 T 45		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 400 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 410 T 38		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 410 T 38		F3BE	ZF 12AS2301 - 12V <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 410 T 38		F3BE	ZF 16S151 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 410 T 38		F3BE	ZF 16S151 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 410 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 410 T 44		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 410 T 44		F3BE	ZF 16S181 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 410 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 410 T 45		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 410 T 45		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 410 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 410 T 48		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 410 T 48		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 410 T 48		F3BE	ZF 16S221 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 410 T 48		F3BE	ZF 16S221 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 410 T 50		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 410 T 50		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 410 T 50		F3BE	ZF 16S2520 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 440 T 38		F3BE	ZF 16S151 <i>release fork with bosses</i>	0504-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 440 T 38		F3BE	ZF 16S151 <i>release fork with rollers</i>	0504-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 440 T 41		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 440 T 41		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 440 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 440 T 44		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 440 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 440 T 45		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 440 T 45		F3BE	ZF 12AS2330-12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 440 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 440 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 440 T 50		F3BE	ZF 12AS2330-12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AD 440 T 50		F3BE	ZF 12AS2330-12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 440 T 50		F3BE	ZF 16S2520 - 16V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 720 T 38		F3BE	ZF 16S151 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 720 T 38		F3BE	ZF 16S151 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 720T 44		F3BE	ZF 12AS2301 - 12V release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 720T 44		F3BE	ZF 12AS2301 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 720T 44		F3BE	ZF 16S181 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 720T 44		F3BE	ZF 16S181 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 720 T 45		F3BE	ZF 12AS2330-12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 720 T 45		F3BE	ZF 12AS2330-12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 720 T 45		F3BE	ZF 16S2220 - 16V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 720T 48		F3BE	ZF 12AS2301 - 12V release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 720T 48		F3BE	ZF 12AS2301 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 720T 48		F3BE	ZF 16S221 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AD 720T 48		F3BE	ZF 16S221 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AD 720 T 50		F3BE	ZF 12AS2330-12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AD 720 T 50		F3BE	ZF 12AS2330-12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AD 720 T 50		F3BE	ZF 16S2220 - 16V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
TRAKKER ACTIVE TIME								
AT 190 T 38		F3BE	ZF 12AS2301 - 12V	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 T 38		F3BE	ZF 12AS2301 release fork with rollers	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Chassis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AT 190 T 38		F3BE	ZF 16S151 <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 T 38		F3BE	ZF 16S151 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 190 T 38		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 190 T 38		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0410-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 T 38		F3BE	ZF 16S181 - 16V	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 T 38		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 190 T 41		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 190 T 41		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 T 41		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 190 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 T 44		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 190 T 44		F3BE	ZF 16S181 <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 190 T 44		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 190 T 44		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0410-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 T 44		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 190 T 45		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 T 45		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 190 T 45		F3BE	ZF 16S181 <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 190 T 45		F3BE	ZF 16S181 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AT 190 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 190 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0410-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 190 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0410-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 260 T 38		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 260 T 38		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 260 T 38		F3BE	ZF 16S151 <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 260 T 38		F3BE	ZF 16S151 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 260 T 41		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 260 T 41		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 260 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 260 T 44		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 260 T 44		F3BE	ZF 16S181 <i>release fork with bosses</i>	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 260 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 260 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 260 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 260 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 260 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 260 T 48		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 260 T 48		F3BE	ZF 12AS2301 - 12V <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 260 T 48		F3BE	ZF 16S221 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.
AT 260 T 48		F3BE	ZF 16S221 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 260 T 50		F3BE	ZF 12AS2330 - 12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 260 T 50		F3BE	ZF 12AS2330 - 12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 260 T 50		F3BE	ZF 16S2520 - 16V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 340 T 41		F3BE	ZF 12AS2330 - 12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 340 T 41		F3BE	ZF 12AS2330 - 12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 340 T 41		F3BE	ZF 16S2220 - 16V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 340 T 44		F3BE	ZF 12AS2301 - 12V release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 340 T 44		F3BE	ZF 12AS2301 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 340 T 44		F3BE	ZF 16S181 release fork with bosses	0410-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 340 T 44		F3BE	ZF 16S181 release fork with rollers	0410-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 340 T 45		F3BE	ZF 12AS2330 - 12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 340 T 45		F3BE	ZF 12AS2330 - 12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 380 T 38		F3BE	ZF 12AS2301 - 12V release fork with bosses	0501-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 380 T 38		F3BE	ZF 12AS2301 - 12V release fork with rollers	0501-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 380 T 38		F3BE	ZF 16S151 release fork with bosses	0501-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 380 T 38		F3BE	ZF 16S151 release fork with rollers	0501-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 380 T 38		F3BE	ZF 16S221 release fork with bosses	0501-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 380 T 38		F3BE	ZF 16S221 release fork with rollers	0501-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 380 T 41		F3BE	ZF 12AS2330 - 12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AT 380 T 41		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 380 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 380 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 380 T 44		F3BE	ZF 16S181 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 380 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 380 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 380 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 380 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 380 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 380 T 50		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 380 T 50		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 380 T 50		F3BE	ZF 16S2520 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 400 T 38		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 400 T 38		F3BE	ZF 12AS2301 - 12V <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 400 T 38		F3BE	ZF 16S151 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 400 T 38		F3BE	ZF 16S151 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 400 T 41		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 400 T 41		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 400 T 41		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 400 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AT 400 T 44		F3BE	ZF 12AS2301 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 400 T 44		F3BE	ZF 16S181 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 400 T 44		F3BE	ZF 16S181 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 400 T 45		F3BE	ZF 12AS2330 - 12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 400 T 45		F3BE	ZF 12AS2330 - 12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 400 T 45		F3BE	ZF 16S2220 - 16V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 400 T 50		F3BE	ZF 12AS2330 - 12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 410 T 38		F3BE	ZF 12AS2301 - 12V release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 410 T 38		F3BE	ZF 12AS2301 - 12V release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 410 T 38		F3BE	ZF 16S151 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 410 T 38		F3BE	ZF 16S151 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 410 T 44		F3BE	ZF 12AS2301 - 12V release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 410 T 44		F3BE	ZF 12AS2301 - 12V release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 410 T 44		F3BE	ZF 16S181 release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 410 T 44		F3BE	ZF 16S181 release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 410 T 45		F3BE	ZF 12AS2330 - 12V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 410 T 45		F3BE	ZF 12AS2330 - 12V release fork with rollers	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 410 T 45		F3BE	ZF 16S2220 - 16V release fork with bosses	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 410 T 48		F3BE	ZF 12AS2301 - 12V release fork with bosses	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 410 T 48		F3BE	ZF 12AS2301 - 12V release fork with rollers	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854

IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		cc Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AT 410 T 48		F3BE	ZF 16S221 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 410 T 48		F3BE	ZF 16S221 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 410 T 50		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 410 T 50		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 410 T 50		F3BE	ZF 16S2520 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 440 T 38		F3BE	ZF 16S151 <i>release fork with bosses</i>	0504-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 440 T 38		F3BE	ZF 16S151 <i>release fork with rollers</i>	0504-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 440 T 41		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 440 T 41		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 440 T 44		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 440 T 44		F3BE	ZF 16S181 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 440 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 440 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 440 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>		104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 440 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 T 50		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 440 T 50		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 440 T 50		F3BE	ZF 16S2520 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850


IVECO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrucker Butée Cojinete
	cc	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
AT 720 T 38		F3BE	ZF 16S151 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 720 T 38		F3BE	ZF 16S151 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 720 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 720 T 44		F3BE	ZF 12AS2301 - 12V <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 720 T 44		F3BE	ZF 16S181 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 720 T 44		F3BE	ZF 16S181 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 720 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 720 T 45		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 720 T 45		F3BE	ZF 16S2220 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 720 T 48		F3BE	ZF 12AS2301 - 12V <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 720 T 48		F3BE	ZF 12AS2301 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 720 T 48		F3BE	ZF 16S221 <i>release fork with bosses</i>	0506-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
AT 720 T 48		F3BE	ZF 16S221 <i>release fork with rollers</i>	0506-	104080-1	170052-35 MFZ430	128986 430x2"x10 DZO	125854
AT 720 T 50		F3BE	ZF 12AS2330 - 12V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850
AT 720 T 50		F3BE	ZF 12AS2330 - 12V <i>release fork with rollers</i>	0603-	104094-1	170053-35 MFZ430	128992 430x2"x10 DZO	125854
AT 720 T 50		F3BE	ZF 16S2520 - 16V <i>release fork with bosses</i>	0603-	104093-1	170053-35 MFZ430	128992 430x2"x10 DZO	125850


TURBO STAR


190,48		8280	ZF	8903-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
240,36		8280	ZF	8801-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
240,48		8280	ZF	8801-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850
260,48		8280	ZF	8801-	104082-1	170052-35 MFZ430	128986 430x2"x10 DZO	125850


MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
F 90								
19.262		D-2865LF	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.272		D-2865LF	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.292		D-2866LF	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.292		D-2866LF	Eaton RTO116.13	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.292		D-2866LF	ZF 16S150	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.302		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.302		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.322		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.322		D-2865	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.322		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.322		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.322		D-2865	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.332		D-2866LF	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.332		D-2866LF	Eaton RTO116.13	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.332		D-2866LF	ZF 16S150	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.362		D-2866KF	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.362		D-2866KF	Eaton RTO116.13	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.362		D-2866LXF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.362		D-2866LXF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.362		D-2866LXF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.372		D-2866LF	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.372		D-2866LF	Eaton TSO126.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.372		D-2866LF	Eaton RTO116.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.372		D-2866LF	ZF 16S150	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.402		D-2866	Eaton TSO116.12	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.402		D-2866	Eaton RTO156.13	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.402	F01,F02,F03,F04	D-2866	ZF 16S150	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.402		D-2866	ZF 16S151	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.422		D-2866LF	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.422		D-2866LF	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.422		D-2866LF	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.422		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.422		D-2866LF	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.432		D-2866LF	ZF 16S150	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.462		D-2840LF	Eaton RTO156.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.462		D-2840LF	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.502		D-2840LF	Eaton RTO156.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.502		D-2840LF	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.292		D-2866LF	Eaton TSO116.12	8501-9401	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.292		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.292		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.302		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849


MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
22.302	F05,F06,F07,F08,F16	D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.322		D-2865LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.322		D-2865LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.322		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.322		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.332		D-2866LF	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.332		D-2866LF	Eaton RTO116.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.362		D-2866KF/LXF	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.362		D-2866KF/LXF	Eaton RTO116.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.362		D-2866KF/LXF	ZF 16S150	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.372		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.372		D-2866	Eaton TSO126.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.372		D-2866	Eaton RTO116.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.372		D-2866	ZF 16S150	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.422		D-2866LF		9101-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.462		D-2840		8901-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
22.502		D-2840		8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.262		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.272		D-2865	Eaton TSO116.12	9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.272		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.322		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.322		D-2865	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.322		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.322		D-2865	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.322		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.342	F20	D-2865	Eaton RTSO123.16	9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.342	F20	D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.362		D-2866LF	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.362		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.362		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.372		D-2866LF	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.372		D-2866LF	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.372		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.372		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.422		D-2866LF	Eaton TSO116.12	9112-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.422		D-2866LF	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.422		D-2866LF	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.422		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.422		D-2866LF	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.462		D-2840	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.462		D-2840	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.502		D-2840	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.502		D-2840	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
24.272	F20	D-2865	Eaton TSO116.12	9307-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.272		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.292		D-2866LF	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.292		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.292		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.302		D-2866LF	Eaton TSO116.12	9001-9501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.302		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.322		D-2865LF	Eaton TSO126.12	9101-9307	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.322		D-2865LF	Eaton RTO116.13	9307-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.322		D-2865LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.322		D-2865LF	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.332		D-2866LF	Eaton TSO116.12	8601-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.332		D-2866LF	Eaton RTO116.13	8601-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.332		D-2866LF	ZF 16S150	8601-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.362		D-2866	Eaton TSO116.12	8501-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.362		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.362		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.372		D-2866	Eaton TSO116.12	9001	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.372		D-2866	Eaton TSO126.12	9001	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.372	F20	D-2866	Eaton RTO116.13	9001	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.372	F20	D-2866	ZF 16S150	9001	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.422		D-2866	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.422		D-2866	Eaton TSO126.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.422		D-2866	Eaton RTO156.13	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.422		D-2866	ZF 16S150	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.422		D-2866	ZF 16S151	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.462		D-2840	Eaton RTO156.13	8901-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.462		D-2840	ZF 16S220	8901-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.502		D-2840	Eaton RTO156.13	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.502		D-2840	ZF 16S220	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.292		D-2866LF	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.292		D-2866LF	Eaton RTO116.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.292		D-2866LF	ZF 16S150	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.302		D-2866LF	Eaton TSO116.12	8901-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.302		D-2866LF	ZF 16S150	8901-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.322	serieF	D-2865LF	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.322	serieF	D-2865LF	Eaton RTO116.13	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.322	serieF	D-2865LF	Eaton TSO126.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.322	serieF	D-2865LF	ZF 16S150	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.322	serieF	D-2865LF	ZF 16S151	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.332	serieF	D-2866LF	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.332	serieF	D-2866LF	Eaton RTO116.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.362	serieF	D-2866	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
25.362	serieF	D-2866	Eaton RTO116.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.362	serieF	D-2866	ZF 16S150	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.372	serieF	D-2866LF	Eaton TSO116.12	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.372	serieF	D-2866LF	Eaton TSO126.12	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.372	serieF	D-2866LF	Eaton RTO116.13	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.372	serieF	D-2866LF	ZF 16S150	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.422	serieF	D-2866	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.422	serieF	D-2866	Eaton TSO126.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.422	serieF	D-2866	Eaton RTO156.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.422	serieF	D-2866	ZF 16S150	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.422	serieF	D-2866	ZF 16S151	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.462		D-2840		8801-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.272		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.272		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.292	serieF>19	D-2866LF	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.292	serieF>19	D-2866LF	Eaton RTO116.13	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.292	serieF>19	D-2866LF	ZF 16S150	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.322		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.322		D-2865	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.322		D-2865	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.322		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.322		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.332	serieF>19	D-2866	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.332	serieF>19	D-2866	Eaton RTO116.13	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.332	serieF>19	D-2866	ZF 16S150	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.362		D-2866	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.362		D-2866	Eaton RTO116.13	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.362		D-2866	ZF 16S150	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.372	serieF	D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.372	serieF	D-2866	Eaton TSO126.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.372	serieF	D-2866	Eaton RTO116.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.372	serieF	D-2866	ZF 16S150	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.422		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.422		D-2866	Eaton TSO126.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.422		D-2866	Eaton RTO156.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.422		D-2866	ZF 16S150	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.422		D-2866	ZF 16S151	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.462		D-2840	Eaton RTO156.13	8801-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.462		D-2840	ZF 16S220	8801-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.502		D-2840	Eaton RTO156.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.502		D-2840	ZF 16S220	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.262		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.272		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849


MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
27.272		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.292		D-2866	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.292		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.292		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.302		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.302		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.322		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.322		D-2865	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.322		D-2865	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.322		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.322		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.332		D-2866	Eaton TSO116.12	8601-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.332		D-2866	Eaton RTO116.13	8601-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.332		D-2866	ZF 16S150	8601-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.362		D-2866 LXF	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.362		D-2866 LXF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.362		D-2866 LXF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.372		D-2866	Eaton TSO116.12	8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.372		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.372		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.372		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.422		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.462		D-2840	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.462		D-2840	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.502		D-2840	Eaton RTO156.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.502		D-2840	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.292		D-2866	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.292		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.292		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.302		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.332		D-2866	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.332		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.332		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.332		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.332		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.342		D-2865		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.362		D-2866	Eaton TSO116.12	8701-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.362		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.362		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849


MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
28.372		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.372		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.372		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.372		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.402		D-2866	Eaton TSO116.12	8701-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.402		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.402		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.402		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.422		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.292		D-2866	Eaton TSO116.12	8701-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.292		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.292		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.302		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.302		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.322		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.322		D-2865	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.322		D-2865	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.322		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.322		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.332		D-2866	Eaton TSO116.12	8701-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.332		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.332		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.342		D-2865	Eaton RTO123.16	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.342		D-2865	ZF 16S151	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.362		D-2866	Eaton TSO116.12	8701-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.362		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.362		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.372		D-2866	Eaton TSO116.12	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.372		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.372		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.372		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.402		D-2866	Eaton TSO116.12	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.402		D-2866	Eaton RTO156.13	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.402		D-2866	ZF 16S150	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.402		D-2866	ZF 16S151	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.422		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849


MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
30.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.292		D-2866	Eaton TSO116.12	8701-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.292		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.292		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.302		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.302		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.322		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.322		D-2865	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.322		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.332		D-2866	Eaton TSO116.12	8701-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.332		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.332		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.342		D-2865	Eaton RTSO123.16	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.342		D-2865	ZF 16S151	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.362		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.362		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.362		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.372		D-2866	Eaton TSO116.12	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.372		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.372		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.372		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.402		D-2866	Eaton TSO116.12	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.402		D-2866	Eaton RTO156.13	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.402		D-2866	ZF 16S150	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.402		D-2866	ZF 16S151	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.422		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
31.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.262		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.272		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.272		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.292		D-2866LF	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.292		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.292		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.302		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.302		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.332		D-2866LF			104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.342		D-2865	Eaton RTSO 123.16	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.342		D-2865	ZF 16S151	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.362		D-2866LXF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.362		D-2866LXF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
32.362		D-2866LXF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.372		D-2866LF	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.372		D-2866LF	Eaton TSO126.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.372		D-2866LF	Eaton RTO116.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.372		D-2866LF	ZF 16S150	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.402		D-2866	Eaton TSO116.12	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.402		D-2866	Eaton RTO156.13	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.422		D-2866	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.462		D-2840	Eaton RTO156.13	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.462		D-2840	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.292		D-2866LF	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.292		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.292		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.302		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.302		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.322		D-2865LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.322		D-2865LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.322		D-2865LF	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.322		D-2865LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.322		D-2865LF	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.332		D-2866LF	Eaton TSO116.12	-8501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.332		D-2866LF	Eaton RTO116.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.332		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.362		D-2866LXF	Eaton TSO116.12	-8501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.362		D-2866LXF	Eaton RTO116.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.362		D-2866LXF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.372		D-2866LF	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.372		D-2866LF	Eaton RTO116.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.372		D-2866LF	Eaton TSO126.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.372		D-2866LF	ZF 16S150	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.422		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.462		D-2840 LF	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.462		D-2840 LF	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.502		D-2840LF	Eaton RTO156.13	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.502		D-2840LF	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
34.342		D-2865	Eaton RTSO 123.16	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
34.342		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
34.372		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
34.372		D-2866	Eaton TSO126.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
34.372		D-2866	Eaton RTO116.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
34.372		D-2866	ZF 16S150	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
34.402		D-2866	Eaton TSO116.12	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
34.402		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
34.402		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
34.402		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.272		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.272		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.292		D-2866LF	Eaton TSO116.12	8801-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.292		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.292		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.302		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.302		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.322		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.322		D-2865	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.322		D-2865	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.322		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.322		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.332		D-2866LF	Eaton TSO116.12	8801-9401	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.332		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.332		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.342		D-2865	Eaton RTSO 123.16	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.342		D-2865	ZF 16S151	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.362		D-2866	Eaton TSO116.12	8801-9401	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.362		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.362		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.372		D-2866LF	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.372		D-2866LF	Eaton TSO126.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.372		D-2866LF	Eaton RTO116.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.372		D-2866LF	ZF 16S150	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.402		D-2866	Eaton TSO116.12	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.402		D-2866	Eaton RTO156.13	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.402		D-2866	ZF 16S150	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.402		D-2866	ZF 16S151	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.422		D-2866	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.462		D-2840	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
35.462		D-2840	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.292		D-2866	Eaton TSO116.12	8701-9401	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.292		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.292		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.302		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.302		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.332		D-2866	Eaton TSO116.12	8601-9201	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.332		D-2866	Eaton RTO116.13	8601-9201	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.332		D-2866	ZF 16S150	8601-9201	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.342		D-2865	Eaton RTSO123.16	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.342		D-2865	ZF 16S151	9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.362		D-2866	Eaton TSO116.12	8701-9312	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.362		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.362		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.372		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.372		D-2866	Eaton TSO126.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.372		D-2866	Eaton RTO116.13	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.372		D-2866	ZF 16S150	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.402		D-2866	Eaton TSO116.12	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.402		D-2866	Eaton RTO156.13	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.402		D-2866	ZF 16S150	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.402		D-2866	ZF 16S151	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.422		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
36.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.292		D-2866LF	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.292		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.292		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.302		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.302		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.332		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.332		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.332		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.362		D-2866LXF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.362		D-2866LXF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.362		D-2866LXF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.372		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.372		D-2866LF	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.372		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.372		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.422		D-2866	Eaton TSO116.12	8901-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849


MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
38.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.292		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.292		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.292		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.332		D-2866LF	Eaton TSO116.12	-8501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.332		D-2866LF	Eaton RTO116.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.332		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.362		D-2866LXF	Eaton TSO116.12	-8501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.362		D-2866LXF	Eaton RTO116.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.362		D-2866LXF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.372		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.372		D-2866LF	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.372		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.372		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.422		D-2866	Eaton TSO116.12	9001-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.462		D-2840LF	Eaton RTO156.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.462		D-2840LF	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.292		D-2866LF	Eaton TSO116.12	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.292		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.292		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.302		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.302		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.322		D-2865	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.322		D-2865	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.322		D-2865	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.322		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.322		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.332		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.332		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.332		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.342		D-2865	Eaton RTSO123.16		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.342		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.362		D-2866LXF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.362		D-2866LXF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.362		D-2866LXF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.372		D-2866LF	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
41.372		D-2866LF	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.372		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.372		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.402		D-2866	Eaton TSO116.12	9301-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.402		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.402		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.402		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.422		D-2866	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.462		D-2840LF	Eaton RTO156.13	8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.462		D-2840LF	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.502		D-2840LF	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.502		D-2840LF	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
47.292		D-2866	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
47.292		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
47.292		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.292		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.292		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.292		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.322		D-2865	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.322		D-2865	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.322		D-2865	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.322		D-2865	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.332		D-2866LF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.332		D-2866LF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.332		D-2866LF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.362		D-2866 LXF	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.362		D-2866 LXF	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.362		D-2866 LXF	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.372		D-2866	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.372		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.372		D-2866	Eaton RTO116.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.372		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.402		D-2866	Eaton TSO116.12	8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.402		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.402		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.402		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.422		D-2866	Eaton TSO116.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.422		D-2866	Eaton TSO126.12		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.422		D-2866	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinetes
48.422		D-2866	ZF 16S150		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.422		D-2866	ZF 16S151		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.462		D-2840	Eaton RTO156.13		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
48.462		D-2840	ZF 16S220		104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849


F 90 Unterflur

24.332	U05/06	D-2866LF		8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.362	serieU	D-2866		-8501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.362	serieU	D-2866		8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.372	U16	D-2866		8912-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.422	U15	D-2866LF		8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.322	U15	D-2866LF			104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.332	serieU	D-2866LF		-8501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.332	serieU	D-2866LF		8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.362	serieU	D-2866KF/LXF		-8501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.362	serieU	D-2866KF/LXF		8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.372	U16	D-2866		8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.422	U15	D-2866LF		9101-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.332	serieU	D-2866LF		-8501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.332	serieU	D-2866LF		8501-9301	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.362	serieU	D-2866KF/LXF		-8501	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.362	serieU	D-2866KF/LXF		8501-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.372	U16	D-2866		8801-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.422	U15	D-2866LF		9101-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

F 2000

18.373		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
18.403		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
18.423		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
18.463		D-2876		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.233		D-2866		0003-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.314		D-2866		9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.364		D-2866		9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.373		D-2866		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.403		D-2866		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.404		D-2866		9501-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.414		D-2866		9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.423		D-2866		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.463		D-2876		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.464		D-2876		9501-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
21.373		D-2866		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
21.403		D-2866		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
21.423		D-2866		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
21.463		D-2876		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.373		D-2866LF		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
23.403		D-2866		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.404		D-2866		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.423		D-2866LF		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.463		D-2876		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
23.464		D-2876		9312-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.373		D-2866		9307-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.403		D-2866		9307-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.423		D-2866		9307-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
24.463		D-2876		9307-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
25.403		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.273		D-2865		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.373		D-2866		9512-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.403		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.404		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.413		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.423		D-2866		9512-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.463		D-2876		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.464		D-2876		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.373		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.402		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.403		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.423		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.463		D-2876		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.403		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.423		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.463		D-2876		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.373		D-2866		9401-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.403		D-2866		9508-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.423		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.463		D-2876		9508-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.373		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.403		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.423		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.463		D-2876		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.314		D-2866		9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.364		D-2866		9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.373		D-2866		9401-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.403		D-2866		9508-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.414		D-2866		9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.423		D-2866		9605-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.463		D-2866		9508-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.464		D-2876		9805-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
37.373		D-2866		9401-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
37.403		D-2866		9401-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
37.423		D-2866		9401-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
37.463		D-2876		9401-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
38.463		D-2876		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.463		D-2876		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.364		D-2866		9401-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.373		D-2866		9401-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.403		D-2866		9508-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.423		D-2866		9401-9605	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.463		D-2866		9508-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

F 2000 EVO

19.314		D2866LF34	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.364		D2866LF35	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
19.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.314		D2866LF34	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.364		D2866LF35	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
26.464		D2866LF06	ZF 16S181 / 221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.314		D2866LF34	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.364		D2866LF35	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
27.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.314		D2866LF34	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.364		D2866LF35	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
28.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
28.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.364		D2866LF35	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
30.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.314		D2866LF34	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.364		D2866LF35	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
32.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.314		D2866LF34	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.364		D2866LF35	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
33.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.364		D2866LF35	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
35.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
40.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849

MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
41.364		D2866LF35	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
41.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
47.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
47.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
47.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
47.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
47.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
47.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
50.414		D2866LF31	Eaton RTS123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
50.414		D2866LF31	Eaton RTSO123.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
50.414		D2866LF31	ZF 16S151	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
50.414		D2866LF31	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
50.464		D2866LF06	Eaton RTSO173.16	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
50.464		D2866LF06	ZF 16S181	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849
50.464		D2866LF06	ZF 16S221	9806-	104083-1	170052-35 MFZ430	128986 430x2"x10 DZO	125849


TG-A
0001-0405

18.310		D2866	Ecosplit	0004-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.310		D2866	AS-tronic <i>old style release fork with bosses</i>	0004-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.360		D2866	Ecosplit	0004-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.360		D2866	AS-tronic <i>old style release fork with bosses</i>	0004-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.360		D2866	AS-tronic <i>new style release fork with rollers</i>	0004-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.410		D2866	Ecosplit	0004-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.410		D2866	AS-tronic <i>old style release fork with bosses</i>	0004-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0004-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.420		D2866	AS-tronic <i>new style release fork with rollers</i>	0004-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.460		D2876	Ecosplit	0001-0405	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0004-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
18.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0004-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
18.480		D2876	Ecosplit	0001-0405	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
18.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
18.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
18.510		D2876	Ecosplit	0001-0405	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.510		D2876	AS-tronic <i>old style release fork with bosses</i>	0009-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
18.510		D2876	AS-tronic <i>new style release fork with rollers</i>	0004-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
18.530		D2876	Ecosplit	0001-0405	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.530		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
18.530		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
19.460		D2876	Ecosplit	0405-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
19.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0405-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
19.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0405-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
19.480		D2876	Ecosplit	0405-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
19.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0405-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
19.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0405-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.360		D2866	Ecosplit	0109-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.360		D2866	AS-tronic <i>old style release fork with bosses</i>	0109-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
24.410		D2866	Ecosplit	0109-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.410		D2866	AS-tronic <i>old style release fork with bosses</i>	0109-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
24.460		D2876	Ecosplit	0109-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0109-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
24.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0109-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.480		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
24.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.510		D2876	Ecosplit	0109-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.510		D2876	AS-tronic <i>old style release fork with bosses</i>	0109-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850

MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
24.510		D2876	AS-tronic <i>new style release fork with rollers</i>	0109-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.530		D2876	Ecosplit	0109-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.530		D2876	AS-tronic <i>old style release fork with bosses</i>	0109-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
24.530		D2876	AS-tronic <i>new style release fork with rollers</i>	0109-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.540		D2876	AS-tronic <i>new style release fork with rollers</i>	0109-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.310		D2866	Ecosplit	0009-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.310		D2866	AS-tronic <i>old style release fork with bosses</i>	0010-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.310		D2866	AS-tronic <i>new style release fork with rollers</i>	0309-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.360		D2866	Ecosplit	0009-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.360		D2866	AS-tronic <i>old style release fork with bosses</i>	0009-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.360		D2866	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.410		D2866	Ecosplit	0004-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.410		D2866	AS-tronic <i>old style release fork with bosses</i>	0004-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0004-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.430		D2866	AS-tronic <i>new style release fork with rollers</i>	0012-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.460		D2876	Ecosplit	0004-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0004-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0004-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.480		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.510		D2876	Ecosplit	0012-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.510		D2876	AS-tronic <i>old style release fork with bosses</i>	0012-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.510		D2876	AS-tronic <i>new style release fork with rollers</i>	0012-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.530		D2876	Ecosplit	0101-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
26.530		D2876	AS-tronic <i>old style release fork with bosses</i>	0101-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.530		D2876	AS-tronic <i>new style release fork with rollers</i>	0101-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.310		D2866	Ecosplit	0209-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.310		D2866	AS-tronic <i>old style release fork with bosses</i>	0209-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
28.310		D2866	AS-tronic <i>new style release fork with rollers</i>	0209-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.360		D2866	Ecosplit	0209-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.360		D2866	AS-tronic <i>old style release fork with bosses</i>	0209-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
28.360		D2866	AS-tronic <i>new style release fork with rollers</i>	0209-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.410		D2866	Ecosplit	0209-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.410		D2866	AS-tronic <i>old style release fork with bosses</i>	0209-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
28.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0209-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.460		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
28.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.480		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
28.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.510		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.510		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
28.510		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.530		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.530		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
28.530		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
32.310		D2866	Ecosplit	0201-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
32.310		D2866	AS-tronic <i>old style release fork with bosses</i>	0201-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
32.310		D2866	AS-tronic <i>new style release fork with rollers</i>	0201-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.360		D2866	Ecosplit	0201-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
32.360		D2866	AS-tronic <i>old style release fork with bosses</i>	0201-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
32.360		D2866	AS-tronic <i>new style release fork with rollers</i>	0201-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.410		D2866	Ecosplit	0201-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
32.410		D2866	AS-tronic <i>old style release fork with bosses</i>	0201-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
32.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0201-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.460		D2876	Ecosplit	0201-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
32.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0201-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
32.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0201-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
32.480		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
32.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
32.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.360		D2866	Ecosplit	0010-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.360		D2866	AS-tronic <i>old style release fork with bosses</i>	0010-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
33.360		D2866	AS-tronic <i>new style release fork with rollers</i>	0010-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.410		D2866	Ecosplit	0010-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.410		D2866	AS-tronic <i>old style release fork with bosses</i>	0010-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
33.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0010-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.460		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
33.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.480		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
33.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
33.310		D2866	AS-tronic <i>new style release fork with rollers</i>	0306-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.510		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.510		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
33.510		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.530		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.530		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
33.530		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.310		D2866	Ecosplit	0306-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.310		D2866	AS-tronic <i>old style release fork with bosses</i>	0306-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
35.360		D2866	Ecosplit	0310-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.360		D2866	AS-tronic <i>new style release fork with rollers</i>	0310-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.410		D2866	Ecosplit	0310-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.410		D2866	AS-tronic <i>old style release fork with bosses</i>	0310-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
35.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0310-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.460		D2876	Ecosplit	0310-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0310-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
35.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0310-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.480		D2876	Ecosplit	0310-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0310-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
35.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0310-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.530		D2876	Ecosplit	0404-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.530		D2876	AS-tronic <i>old style release fork with bosses</i>	0404-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
35.530		D2876	AS-tronic <i>new style release fork with rollers</i>	0404-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
37.460		D2876	Ecosplit	0412-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
37.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0412-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
37.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0412-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854

MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
37.480		D2876	Ecosplit	0412-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
37.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0412-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
37.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0412-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
37.530		D2876	Ecosplit	0412-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
37.530		D2876	AS-tronic <i>old style release fork with bosses</i>	0412-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
37.530		D2876	AS-tronic <i>new style release fork with rollers</i>	0412-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
40.460		D2876	Ecosplit	0404-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
40.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0404-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
40.460		D2876	AS-tronic <i>new style release fork with rollers</i>	0404-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
40.480		D2876	Ecosplit	0404-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
40.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0404-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
40.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0404-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
41.360		D2866	Ecosplit	0301-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.360		D2866	AS-tronic <i>old style release fork with bosses</i>	0301-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
41.360		D2866	AS-tronic <i>new style release fork with rollers</i>	0309-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0309-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.460		D2876	Ecosplit	0309-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.460		D2876	AS-tronic <i>old style release fork with bosses</i>	0309-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
41.480		D2876	Ecosplit	0602-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.480		D2876	AS-tronic <i>old style release fork with bosses</i>	0602-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
41.480		D2876	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
41.530		D2876	Ecosplit	0209-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.530		D2876	AS-tronic <i>old style release fork with bosses</i>	0209-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
41.530		D2876	AS-tronic <i>new style release fork with rollers</i>	0209-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
TG-A					0405-			
18.310		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
18.310		D2066	AS-tronic <i>old style release fork with bosses</i>	0405-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.310		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.320		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.320		D2066	AS-tronic <i>old style release fork with bosses</i>	0405-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.320		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.350		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.350		D2066	AS-tronic <i>old style release fork with bosses</i>	0405-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.360		D2066	Ecosplit	0601-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.390		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.390		D2066	AS-tronic <i>old style release fork with bosses</i>	0405-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.400		D2066	Ecosplit	0510-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0510-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.430		D2066	Ecosplit	0405-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.430		D2066	AS-tronic <i>old style release fork with bosses</i>	0405-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
18.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
18.440		D2066	Ecosplit	0405-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0405-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
18.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
18.480		D2676	Ecosplit	0601-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0601-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
18.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0601-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
18.540		D2676	Ecosplit	0608-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.540		D2676	AS-tronic <i>old style release fork with bosses</i>	0601-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
18.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0608-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
19.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
19.350		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
19.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
19.360		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
19.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
19.390		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
19.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
19.400		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
19.410		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
19.410		D2866	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
19.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
19.430		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
19.440		D2676	Ecosplit	0602-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
19.440		D2676	AS-tronic <i>old style release fork with bosses</i>	0601-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
19.440		D2676	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
19.480		D2676	Ecosplit	0602-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
19.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0602-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
19.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.350		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.360		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.390		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.430		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.440		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.480		D2676	Ecosplit	0601-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849

MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
24.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0601-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
24.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0601-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.540		D2676	Ecosplit	0601-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.540		D2676	AS-tronic <i>old style release fork with bosses</i>	0601-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.310		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.310		D2066	AS-tronic <i>new style release fork with rollers</i>	0401-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.320		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.320		D2066	AS-tronic <i>new style release fork with rollers</i>	0506-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.350		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.360		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.390		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0401-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.400		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0401-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.410		D2866	Ecosplit	0407-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.430	H18, H26, H30, H42	D2066	Ecosplit	0405-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.430		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.430	H18, H26, H30, H42	D2066	AS-tronic <i>old style release fork with bosses</i>	0402-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.430	H18, H26, H30, H42	D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0401-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.440	H18, H26, H30, H42	D2066	Ecosplit	0405-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.440		D2676	Ecosplit	0602-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.440		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.440	H18, H26, H30, H42	D2066	AS-tronic <i>old style release fork with bosses</i>	0602-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.440	H18, H26, H30, H42	D 2066	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
26.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0401-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.440	H18, H26, H30, H42	D 2676	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.480		D2676	Ecosplit	0601-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0601-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0601-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.540		D2676	Ecosplit	0608-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.540		D2676	AS-tronic <i>old style release fork with bosses</i>	0608-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0608-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
27.440		D2676	Ecosplit	0810-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
27.440		D2676	AS-tronic <i>old style release fork with bosses</i>	0810-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
27.440		D2676	AS-tronic <i>new style release fork with rollers</i>	0810-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.310		D2066	AS-tronic <i>new style release fork with rollers</i>	0406-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.310		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.320		D2066	AS-tronic <i>new style release fork with rollers</i>	0406-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.320		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.350		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0604-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.360		D2866	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0604-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.390		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0604-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.400		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0607-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.410		D2866	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
28.430		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0509-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.440		D2066	Ecosplit	0509-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.480		D2676	Ecosplit	0602-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0602-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
28.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.540		D2676	Ecosplit	0608-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.540		D2676	AS-tronic <i>old style release fork with bosses</i>	0608-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
28.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0608-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
32.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.350		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
32.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.390		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
32.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.430		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
32.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.480		D2676	Ecosplit	0602-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
32.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0602-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
32.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.350		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.360		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.360		D2066	AS-tronic <i>old style release fork with bosses</i>		104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
33.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.390		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
33.400		D2066	Ecosplit	0405-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.430	H26	D2066	Ecosplit	0405-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.430		D2066	Ecosplit	0506-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.430	H26	D2066	AS-tronic <i>old style release fork with bosses</i>	0405-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
33.430	H26	D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.440	H26	D2066	Ecosplit	0405-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.440	H26	D2066	AS-tronic <i>old style release fork with bosses</i>		1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
33.440	H26	D2066	AS-tronic <i>new style release fork with rollers</i>	0405-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.440		D2676	AS-tronic <i>old style release fork with bosses</i>	0506-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
33.440		D2676	AS-tronic <i>new style release fork with rollers</i>	0506-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.480		D2066	Ecosplit	0405-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.480		D2676	Ecosplit	0601-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0601-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
33.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0601-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.310		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.310		D2066	Ecosplit	0402-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.350		D2066	Ecosplit	0402-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.360		D2066	Ecosplit	0607-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.390		D2066	Ecosplit	0402-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.400		D2066	Ecosplit	0402-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.410		D2866	Ecosplit	0607-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
35.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.430		D2066	Ecosplit	0402-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.440		D2066	Ecosplit	0607-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.480		D2676	Ecosplit	0607-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0607-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
35.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
37.310		D2866	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.310		D2866	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.320		D2866	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.350		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.360		D2866	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.360		D2866	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.390		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.400		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.410		D2866	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0402-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.430		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.440		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.480		D2676	Ecosplit	0602-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
37.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0602-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
37.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
39.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0607-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
39.390		D2066	Ecosplit	0607-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
39.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0607-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
39.400		D2066	Ecosplit	0607-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
39.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0607-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
39.430		D2066	Ecosplit	0607-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
39.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0607-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
39.440		D2066	Ecosplit	0607-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
39.480		D2676	Ecosplit	0607-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
39.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0607-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
39.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0607-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
40.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0506-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
40.390		D2066	Ecosplit	0506-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
40.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0506-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
40.400		D2066	Ecosplit	0506-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
40.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0404-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
40.410		D2866	Ecosplit	0404-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
40.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0506-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
40.430		D2066	Ecosplit	0506-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
40.440		D2676	Ecosplit	0506-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
40.440		D2676	AS-tronic <i>old style release fork with bosses</i>	0506-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
40.440		D2676	AS-tronic <i>new style release fork with rollers</i>	0506-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
40.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0506-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
40.480		D2676	Ecosplit	0506-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.350		D2066	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.350		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854


MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
41.360		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.360		D2866	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.360		D2866	Ecosplit	0309-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.390		D2066	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.390		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0612-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.400		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.410		D2866	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.410		D2866	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.430		D2066	AS-tronic <i>new style release fork with rollers</i>	0412-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.430		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0607-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.440		D2066	Ecosplit	0412-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.440		D2676	Ecosplit	0412-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.440		D2676	AS-tronic <i>old style release fork with bosses</i>	0412-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
41.440		D2676	AS-tronic <i>new style release fork with rollers</i>	0506-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
41.480		D2676	Ecosplit	0506-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0602-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
41.540		D2676	Ecosplit	0611-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.540		D2676	AS-tronic <i>old style release fork with bosses</i>	0611-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
41.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0611-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
TG-S								
18.320		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.320		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.320		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854


MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
18.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0709-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
18.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
18.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.540		D2676	AS-tronic <i>old style release fork with bosses</i>	0709-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
18.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.320		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
24.320		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.320		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
24.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
24.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
24.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
24.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0709-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
24.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.540		D2676	AS-tronic <i>old style release fork with bosses</i>	0709-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
24.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.320		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.320		D2066	Ecosplit	0807-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.360		D2066	Ecosplit	0807-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.480		D2676	AS-tronic <i>old style release fork with bosses</i>	0709-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.540		D2676	AS-tronic <i>old style release fork with bosses</i>	0709-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850
26.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.320		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
28.320		D2066	Ecosplit	0807-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850

MAN


Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
28.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.360		D2066	Ecosplit	0808-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
28.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.400		D2066	Ecosplit	0808-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.440		D2066	Ecosplit	0808-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
28.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.480		D2676	Ecosplit	0808-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.540		D2676	Ecosplit	0806-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0806-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
32.320		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
32.320		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.320		D2066	Ecosplit	0902-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
32.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
32.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
32.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
32.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
32.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
32.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430 MFZ430	128986 430x2"x10 DZO	125850
32.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
32.480		D2676	Ecosplit	0808-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
32.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0808-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
33.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
33.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
33.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.400		D2066	Ecosplit	0807-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
33.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.540		D2676	Ecosplit	0902-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0902-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.320		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
35.320		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
35.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0806-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
35.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0806-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.440		D2066	ZF 16S222	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
35.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0902-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
35.540		D2676	Ecosplit	0806-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0902-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
37.320		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
37.320		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.320		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
37.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
37.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
37.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
37.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
37.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
37.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
37.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
37.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
37.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
41.320		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
41.320		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.320		D2066	Ecosplit	0806-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
41.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
41.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
41.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
41.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
41.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
41.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
41.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854


TG-X EURO 4

18.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.360		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.400		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
18.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
18.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
24.360		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
24.400		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
24.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
24.440		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.320		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
26.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
26.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
28.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
28.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
28.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
28.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.360		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
33.360		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854


MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
33.360		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.400		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
33.400		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.400		D2066	Ecosplit	0709-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
33.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.440		D2066	AS-tronic <i>old style release fork with bosses</i>	0709-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
33.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.360		D2066	Ecosplit	0806-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849
35.400		D2066	Ecosplit	0806-	104077-1	170054-35 MFZ430	128986 430x2"x10 DZO	125849

TG-X EURO 5

18.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
18.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
24.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.320		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
26.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
26.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
28.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.440		D2066	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
33.480		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.540		D2676	Ecosplit	0709-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0709-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.360		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.400		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.440		D2066	Ecosplit	0806-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.440		D2066	AS-tronic <i>new style release fork with rollers</i>	0709-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
35.480		D2676	Ecosplit	0806-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849

MAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
35.480		D2676	AS-tronic <i>new style release fork with rollers</i>	0806-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
35.540		D2676	Ecosplit	0806-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
35.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0806-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
41.540		D2676	Ecosplit	0806-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
41.540		D2676	AS-tronic <i>new style release fork with rollers</i>	0806-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854

 





 





 











 


 
 

 

 


 

 
 
 
 
 
 
 
 

 
 
 
 
 

 
 
 
 
 
 
 
 
 
 
 
 
 

 
 
 

TG-X EURO 6

18.440		D2676	Ecosplit	1210-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
18.440		D2676	AS-tronic <i>new style release fork with rollers</i>	1210-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
24.440		D2676	Ecosplit	1210-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
24.440		D2676	AS-tronic <i>new style release fork with rollers</i>	1210-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
26.440		D2676	Ecosplit	1210-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
26.440		D2676	AS-tronic <i>new style release fork with rollers</i>	1210-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
28.440		D2676	Ecosplit	1210-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
28.440		D2676	AS-tronic <i>new style release fork with rollers</i>	1210-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
33.440		D2676	Ecosplit	1210-	104091-1	170055-35 MFZ430	128993 430x2"x10 DZO	125849
33.440		D2676	AS-tronic <i>new style release fork with rollers</i>	1210-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854

MERCEDES-BENZ

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Lożysko Bearing Ausrücker Butée Cojinetes
		ltr Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.








 



 
 
 
 
 
 
 
 


 
 










 
 
 

 
 
 
 
 
 
 
 














 
 

 
 
 
 
 
 

 
 
ACTROS MP1

1831		12	OM501LA- V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
1835		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
1840		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
1843		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
1846		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
1848		16	OM502LA-V8	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
1853		16	OM502LA-V8	MB	9601- 0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2031		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2035		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2040		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2531		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2535		12	OM501LA-v6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2540		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2543		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2548		16	OM502LA-V8	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2553		16	OM502LA-V8	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2631		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2635		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2640		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2643		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2648		16	OM502LA-V8	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
2653		16	OM502LA-V8	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3231		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3235		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3240		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3243		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3331		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3335		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3340		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3343		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3348		16	OM502LA-V8	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
3353		16	OM502LA-V8	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
4140		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
4143		12	OM501LA-V6	MB	9601-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
4148		16	OM502LA-V8	MB	9704-0212	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 


ACTROS MP2

1832		12	OM501LA- V6 - EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
1832	SA504682-22/24	12	OM541LA- V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991	430x50x18	DZO	← 
1836		12	OM501LA- V6 - EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
1836	SA504682-22/24	12	OM541LA- V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991	430x50x18	DZO	← 
1841		12	OM501LA- V6 - EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991	430x50x18	DZO	← 
1841	SA504682-22/24	12	OM541LA- V6 - EURO 3	MB	0301-0712	1040108-1	180058-38  MFZ430	128991	430x50x18	DZO	← 

MERCEDES-BENZ

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Lożysko Bearing Ausrücker Butée Cojinete
		ltr Type			Ref.	Type	Ref. Ø+N Type	Ref.
1844		12 OM501LA- V6 - EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
1844	SA504682-22/24	12 OM541LA- V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
1846		12 OM501LA- V6 - EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
1846	SA504682-22/24	12 OM541LA- V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
1848		12 OM501LA- V6 - EURO 4	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
1848	SA504682-22/24	12 OM541LA- V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
1850		16 OM502LA- V8 - EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
1850	SA504682-22/24	16 OM542LA- V8	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
1854		16 OM502LA- V8 - EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
1854	SA504682-22/24	16 OM542LA- V8	MB		1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2032		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2032	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2036		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2036	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2041		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2041	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2044		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2044	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2046		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2046	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2048		12 OM501LA- V6 - EURO 4	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2048	SA504682-22/24	12 OM541LA- V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2532		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2532	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2536		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2536	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2541		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2541	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2544		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2544	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2546		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2546	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2548	SA504682-22/24	12 OM541LA	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2632		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
2632	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 



















































MERCEDES-BENZ

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Lożysko Bearing Ausrücker Butée Cojinete
		litr Type				Ref. Type	Ref. Ø+N Type	Ref.
2636		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
2636	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
2641		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
2641	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
2644		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
2644	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
2646		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
2646	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
2650		16 OM502LA-V8-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
2650	SA504682-22/24	16 OM542LA-V8	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3232		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3232	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3241		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3241	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3244		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3244	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3246		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3246	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3248	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3332		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3332	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3336		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3336	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3341		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3341	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3344		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3344	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3346		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3346	SA504682-22/24	12 OM541LA-V6	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3348		12 OM541LA-V6-EURO 4	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3348	SA504682-22/24	12 OM541LA-V6-EURO 4	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3350		16 OM502LA-V8-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3350	SA504682-22/24	16 OM542LA-V8-EURO 3	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
3354		16 OM502LA-V8-EURO 3	MB	0301-0712	104074-1	180054-38 MFZ 430	128991 430x50x18 DZO	←
3354	SA504682-22/24	16 OM542LA-V8-EURO 3	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←
4141	SA504682-22/24	12 OM541LA-V6-EURO 3,4	MB	0301-0712	1040108-1	180058-38 MFZ430	128991 430x50x18 DZO	←




 
 
 
 


 

 
 
 
 
 
 






 
 
 
 
 
 


 

 
 

 
 
 






 
 
 
 




 









MERCEDES-BENZ

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Lożysko Bearing Ausrücker Butée Cojinetes
		litr Type				Ref. Type	Ref. Ø+N Type	Ref.
4144		12 OM501LA-V6-EURO 3	MB	0301-0712	104074-1	180054-38  MFZ 430	128991 430x50x18 DZO	← 
4144	SA504682-22/24	12 OM541LA-V6-EURO 3,4	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
4146	SA504682-22/24	12 OM541LA-V6-EURO 3,4	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
4148	SA504682-22/24	12 OM541LA-V6-EURO 4	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
4150	SA504682-22/24	16 OM542LA-V8-EURO 3	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
4154	SA504682-22/24	16 OM542LA-V8-EURO 3	MB	0301-0712	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 














































ACTROS MP3

1832		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
1832	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
1836		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
1836	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
1841		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
1841	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
1844		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
1844	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
1846		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
1846	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
1848		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
1848	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2032		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2032	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2036		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2036	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2041		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2041	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2044		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2044	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2046		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2046	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2048		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2048	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2432	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 











 
 
 
 
 
 
 
 
 
 
 
 


MERCEDES-BENZ

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Lożysko Bearing Ausrücker Butée Cojinetes
		litr Type				Ref. Type	Ref. Ø+N Type	Ref.
2436	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2441	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2444	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2446	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2448	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2532		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2532	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2536		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2536	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2541		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2541	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2544		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2544	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2546		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2546	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2548		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2548	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2632		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2632		12 OM541LA-V6-EURO 5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2632	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2636	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2641	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2644	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2646		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38  430 ELW MFZ430	128991 430x50x18 DZO	← 
2646	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2732	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2736	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2741	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2744	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2746	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
2748	SA504682-22/24	12 OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38  MFZ430	128991 430x50x18 DZO	← 
3232		12 OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38 430 ELW MFZ430	128991 430x50x18 DZO	←

MERCEDES-BENZ










 
 
 
 
 
 
 
 
 
 

 
 
 








 
 




Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Itr	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo		Tarcza Drivenplate K-Scheibe Disque Disco			Łożysko Bearing Ausrücker Butée Cojinetes Ref.
							Ref.	Type	Ref.	Ø+N	Type	
3232	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3236	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3241		12	OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38	 430 ELW MFZ430	128991	430x50x18	DZO	← 
3241	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3244		12	OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38	 430 ELW MFZ430	128991	430x50x18	DZO	← 
3244	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3246		12	OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38	 430 ELW MFZ430	128991	430x50x18	DZO	← 
3246	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3248		12	OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38	 430 ELW MFZ430	128991	430x50x18	DZO	← 
3248	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3332	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3336	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3341	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3344	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3346	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
3348	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
4141	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
4144		12	OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38	 430 ELW MFZ430	128991	430x50x18	DZO	← 
4144	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
4146	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
4148		12	OM541LA-V6-EURO 4/5	MB	0801-1212	104074-1	180054-38	 430 ELW MFZ430	128991	430x50x18	DZO	← 
4148	SA504682-22/24	12	OM541LA-V6-EURO 5	MB	0801-1212	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 

AXOR

1835	SA531129	12	OM457-L6		0201-	104074-1	180054-38	 430ELW MFZ 430	128991	430x50x18	DZO	← 
1835	SA504682	12	OM457-L6		0201-0412	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
1840	SA531129	12	OM457-L6		0201-	104074-1	180054-38	 430ELW MF7 430	128991	430x50x18	DZO	← 
1840	SA504682	12	OM457-L6		0201-0412	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
1843	SA531129	12	OM457-L6		0201-	104074-1	180054-38	 430ELW MF7 430	128991	430x50x18	DZO	← 
1843	SA504682	12	OM457-L6		0201-0412	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
2535	SA531129	12	OM457-L6		0201-	104074-1	180054-38	 430ELW MFZ 430	128991	430x50x18	DZO	← 
2535	SA504682	12	OM457-L6		0201-0412	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
2540	SA531129	12	OM457-L6		0201-	104074-1	180054-38	 430ELW MF7 430	128991	430x50x18	DZO	← 
2540	SA504682	12	OM457-L6		0201-0412	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 
2543	SA531129	12	OM457-L6		0201-	104074-1	180054-38	 430ELW MFZ 430	128991	430x50x18	DZO	← 
2543	SA504682	12	OM457-L6		0201-0412	1040108-1	180058-38	 MFZ430	128991	430x50x18	DZO	← 

AXOR Euro 4/5

MERCEDES-BENZ

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete	
		ltr Type			Ref.	Type	Ref.	Ø+N Type	Ref.
1836	SA531129	12 OM457-L6		0607-	104074-1	180054-38  430ELW MFZ 430	128991	430x50x18 DZO	← 
1836	SA504682	12 OM457-L6		0410-	1040108-1	180058-38  MFZ430	128991	430x50x18 DZO	← 
1840	SA531129	12 OM457-L6		0607-	104074-1	180054-38  430ELW MFZ 430	128991	430x50x18 DZO	← 
1840	SA504682	12 OM457-L6		0410-	1040108-1	180058-38  MFZ430	128991	430x50x18 DZO	← 
1843	SA531129	12 OM457-L6		0607-	104074-1	180054-38  430ELW MFZ 430	128991	430x50x18 DZO	← 
1843	SA504682	12 OM457-L6		0410-	1040108-1	180058-38  MFZ430	128991	430x50x18 DZO	← 
2536	SA531129	12 OM457-L6		0607-	104074-1	180054-38  430ELW MFZ 430	128991	430x50x18 DZO	← 
2536	SA504682	12 OM457-L6		0410-	1040108-1	180058-38  MFZ430	128991	430x50x18 DZO	← 
2540	SA531129	12 OM457-L6		0607-	104074-1	180054-38  MFZ 430	128991	430x50x18 DZO	← 
2540	SA504682	12 OM457-L6		0410-	1040108-1	180058-38  MFZ430	128991	430x50x18 DZO	← 
2543	SA531129	12 OM457-L6		0607-	104074-1	180054-38  MFZ 430	128991	430x50x18 DZO	← 
2543	SA504682	12 OM457-L6		0410-	1040108-1	180058-38  MFZ430	128991	430x50x18 DZO	← 
2636		12 OM457-L6		0610-	104074-1	180054-38  MFZ 430	128991	430x50x18 DZO	← 
2640		12 OM457-L6		0610-	104074-1	180054-38  MFZ 430	128991	430x50x18 DZO	← 
2643		12 OM457-L6		0610-	104074-1	180054-38  MFZ 430	128991	430x50x18 DZO	← 
3236		12 OM457-L6		0610-	104074-1	180054-38  MFZ 430	128991	430x50x18 DZO	← 
3240		12 OM457-L6		0610-	104074-1	180054-38  MFZ 430	128991	430x50x18 DZO	← 
3243		12 OM457-L6		0610-	104074-1	180054-38  MFZ 430	128991	430x50x18 DZO	← 

SERIE 17..

1735		OM442A		8801-	104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
1748 S, LS	nr.11864<	OM442LA		8801-	1040100-1	170052-35 MFZ430	128985	430x2"x10 GZO	125855

SERIE 18..

1831		OM442A		8801-9609	104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
1838		OM402LA		8801-9609	104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
1838	SA033617-01	OM402LA		8801-	104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856
1844		OM442LA			104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
1844	nr.11864<	OM442LA		8801-	104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856
1850		OM442LA		8801-	104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
1850	nr.11864<	OM442LA			104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856
1853		OM442LA		9601-9609	104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
1853		OM442LA		8707-9608	104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856

SERIE 19..


1935		OM442A		8801-	104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
1948	nr.11864<	OM442		8801-	104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856

SERIE 20..

2038		OM402LA		9001-	104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
2038	SA033617-01	OM402LA		9111-9609	104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856
2038		OM442LA		9001-	104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
2038	SA033617-01	OM442LA		9111-9609	104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856
2038		OM446		9001-	104072-1	170052-35 MFZ430	128986	430x2"x10 DZO	125856
2038	SA033617-01	OM446		9111-9609	104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856
2044	nr.11864<	OM442LA		8801-	104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856
2050	nr.11864<	OM442LA		8801-	104099-1	170052-35 MFZ430	128985	430x2"x10 GZO	125856

SERIE 24..

MERCEDES-BENZ

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
		ltr Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
2435		OM442A		8801-	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2448		OM442		8801-	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2448	nr.11864<	OM442LA		8801-	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856


SERIE 25..

2535		OM442A			104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2538		OM402		8707-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2538	SA033617-01	OM402		8707-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2538		OM442A		8707-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2538	SA033617-01	OM442LA		8707-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2544		OM440		8707-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2544	nr.11864< SA033617-01	OM440		8707-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2544		OM442A		8707-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2544	nr.11864< SA033617-01	OM442A		8707-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2544		OM442LA		8707-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2544	nr.11864< SA033617-01	OM442LA		8707-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2550		OM402		8707-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2550	nr.11864<	OM402		8707-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2550		OM402A		8707-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2550		OM442LA		8707-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2550	nr.11864<	OM442LA		8707-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856


SERIE 26..

2631		OM401			104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2634		OM401			104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2635		OM442A		8807-9408	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2637	659,343	OM402			104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2638		OM402LA		9109-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2638	SA033617-01	OM402LA		9109-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2638		OM422LA		9109-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2638	SA033617-01	OM422LA		9109-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2644		OM402		9201-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2644	SA033617-01	OM402		9201-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2644	nr.11864<	OM440		9201-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2644		OM442LA		9201-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2644	SA033617-01	OM442LA		9201-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2645		OM442LA		9002-9609	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2648	nr.11864<	OM440		8812-9207	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2648		OM442LA		9002-9408	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2650		OM402		8807-9408	104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
2650	nr.11864<	OM402		9207-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856
2650	nr.11864<	OM442		9207-9609	104099-1	170052-35 MFZ430	128985 430x2"x10 GZO	125856

MERCEDES-BENZ

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinetes			
	nr.11864<	litr Type			Ref	Ref.	Type	Ref.	Ø+N	Type	Ref.
2650	nr.11864<	OM442LA		9207-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
2650		OM442LA		8807-9408	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
SERIE 30..											
3050	625.036, 625.037, 625.196, 625.197	OM442LA		9401-9609	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
3053	625.036, 625.037, 625.196, 625.197	OM442LA		9312-9609	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
SERIE 32..											
3235		OM442A		8707-9609	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
3238	SA033617-01	OM402LA		9010-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3238	SA033617-01	OM442LA		9010-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3244	SA033617-01	OM402LA		9401-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3244	SA033617-01	OM442LA		9401-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3248	nr.11864<	OM442LA		8707-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3250	nr.11864<	OM442LA		8707-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3253	SA033617-01	OM442LA		9601-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3255	nr.11864<	OM442LA		8707-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
SERIE 35..											
3535		OM442A		8810-9408	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
3538		OM402LA		9103-9609	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
3538	SA33613, SA33617	OM402LA		9103-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3544	SA033617-01	OM440		9201-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3544		OM402LA		9103-9609	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
3544	SA033617-01	OM402LA		9103-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3544		OM442LA		9103-9609	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
3544	SA033617-01	OM442LA		9103-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3548		OM402LA		9205-9609	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
3548	nr.11863<	OM440		9205-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3548		OM442LA		9205-9609	104072-1	170052-35	430ELW MFZ 430	128986	430x2"x10	DZO	125856
3550		OM442		9103-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
3550		OM442LA		9103-9609	104072-1	170052-35	430ELW MFZ 430	128986	430x2"x10	DZO	125856
3553		OM442LA		9204-	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
SERIE 44..											
4435		OM442A			104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
SERIE 46..											
4635		OM442A			104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
4644		OM442LA			104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
SERIE 48..											
4844		OM442LA		9103-9609	104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
4844	SA033617-01	OM442LA		9103-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
4850		OM442LA			104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
4850	SA033617-01	OM442LA		9103-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
4853		OM442LA			104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
4853	SA033617-01	OM442LA		9103-9609	104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856

MERCEDES-BENZ

Producent	Podwozie	Silnik	Skrz. Biegów		Zestaw	Tarcza Dociskowa		Tarcza Drivenplate		Łożysko	
Manufacturer	Chassis	Engine	Gearbox		Kit	Clutchcover		K-Scheibe		Bearing	
Hersteller	Chassis	Motor	Getriebe		Kit	K-Druckplatte		Disque		Ausrücker	
Fabricant	Châssis	Moteur	Boîte d.Vit.		Kit	Mécanisme		Disco		Butée	
Fabricante	Chasis	Motor	Cambio		Ref	Mecanismo		Disco		Cojinete	
		ltr	Type			Ref.	Type	Ref.	Ø+N	Type	Ref.

SERIE 50..>

5035		OM442LA			104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
5038		OM442LA			104072-1	170052-35	MFZ430	128986	430x2"x10	DZO	125856
5038	SA033617-01	OM442LA			104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856
5248	nr.11863<	OM440			104099-1	170052-35	MFZ430	128985	430x2"x10	GZO	125856



Drivenplate Bearing

180054-38 : 160072-38 + 125843K

180058-38 : 160072-38 + 125961K

RENAULT

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor Type	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Łożyisko Bearing Ausrücker Butée Cojinete Ref.
--	---	--	---	---	---	---	---	---

KERAX 9701 - 0101

260		MIDR062045	ZF16S151	9706-9912	1040109-1	170050-35	MFZ430	128986	430x2"x10	DZO	125960
260		MIDR062045	ZF16S151	0001-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857
300		MIDR062045 E II	ZF16S151	9701-9912	1040109-1	170050-35	MFZ430	128986	430x2"x10	DZO	125960
300		MIDR062045 E II	ZF16S151	0001-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857
340		MIDR062045 E II	ZF8S151	9701-9912	1040109-1	170050-35	MFZ430	128986	430x2"x10	DZO	125960
340		MIDR062045 E II	ZF16S151	0001-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857
385		MIDR062356 E II	ZF8S151	9706-	1040109-1	170050-35	MFZ430	128986	430x2"x10	DZO	125960
385	<CAM16E1	MIDR062356 E II	ZF16S151	9706-0105	1040109-1	170050-35	MFZ430	128986	430x2"x10	DZO	125960
385	CAM17E1 <	MIDR062356 E II	ZF16S151	0105-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857
400		MIDR062356 E II	ZF8S151	9809-	1040109-1	170050-35	MFZ430	128986	430x2"x10	DZO	125960
400	<CAM16E1	MIDR062356 E II	ZF16S151	0001-0105	1040109-1	170050-35	MFZ430	128986	430x2"x10	DZO	125960
400	CAM17E1<	MIDR062356 E II	ZF16S151	0105-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857

KERAX 0101 - 0510

320		dCi 11	ZF8S151	0101-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857
320		dCi 11	ZF16S151	0101-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857
420		dCi 11	ZF8S151	0101-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857
420		dCi 11	ZF16S151	0101-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857
420		dCi 11	ZF16S221	0101-	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857




KERAX 0601 -

370		Dxi 11	AT2412C	0601-	104460-1 ↓	160522-33AM	MF430	128998	430x50x24	DZO	<
370		Dxi 11	AT/ATO2512C	0601-	104460-1 ↓	160522-33AM	MF430	128998	430x50x24	DZO	<
370		Dxi 11	ZF 16S	0601-	104081-1	170052-35	MFZ430	128986	430x2"x10	DZO	125857
410		Dxi 11	AT2412C	0601-	104460-1 ↓	160522-33AM	MF430	128998	430x50x24	DZO	<
410		Dxi 11	AT/ATO2512C	0601-	104460-1 ↓	160522-33AM	MF430	128998	430x50x24	DZO	<
410		Dxi 11	ZF 16S	0601-	104081-1	170052-35	MFZ430	128986	430x2"x10	DZO	125857
450		Dxi 11	AT2412C	0510-	104461-1 ↓	160521-33AM	MF430	128995	430x50x24	DZO	<
450		Dxi 11	ATO2512C	0510-	104461-1 ↓	160521-33AM	MF430	128995	430x50x24	DZO	<
450		Dxi 11	ZF 16S	0601-	104081-1	170052-35	MFZ430	128986	430x2"x10	DZO	125857
460		Dxi 13	AT2412C	0605-	104461-1 ↓	160521-33AM	MF430	128995	430x50x24	DZO	<
460		Dxi 13	AT/ATO2512C	0605-	104461-1 ↓	160521-33AM	MF430	128995	430x50x24	DZO	<
500		Dxi 13	AT2412C	0605-	104461-1 ↓	160521-33AM	MF430	128995	430x50x24	DZO	<
500		Dxi 13	AT/ATO2512C	0605-	104461-1 ↓	160521-33AM	MF430	128995	430x50x24	DZO	<


MAGNUM 0001 - 0409

400		MACK E-Tech E III	ZF 16AS2601 <i>release fork with bosses</i>	0303-	104097-1	170050-35	MFZ430	128986	430x2"x10	DZO	125850
400		MACK E-Tech E III	ZF 16AS2601 <i>release fork with rollers</i>		104098-1	170050-35	MFZ430	128986	430x2"x10	DZO	125854
400		MACK E-Tech E III	ZF 16S181	0005-0303	104084-1	170050-35	MFZ430	128986	430x2"x10	DZO	125857
440		MACK E-Tech E III	ZF 16AS2601 <i>release fork with bosses</i>	0001-	104097-1	170050-35	MFZ430	128986	430x2"x10	DZO	125850

RENAULT

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor Type	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Łożyisko Bearing Ausrücker Butée Cojinete Ref.
440		MACK E-Tech E III	ZF 16AS2601 <i>release fork with rollers</i>		104098-1	170050-35 MFZ430	128986 430x2"x10 DZO	125854
440		MACK E-Tech E III	ZF 16S181	0002-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
480		MACK E-Tech E III	ZF 16AS2601 <i>release fork with bosses</i>	0303-	104097-1	170050-35 MFZ430	128986 430x2"x10 DZO	125850
480		MACK E-Tech E III	ZF 16AS2601 <i>release fork with rollers</i>		104098-1	170050-35 MFZ430	128986 430x2"x10 DZO	125854
480		MACK E-Tech E III	ZF 16S181	0005-0303	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
MAGNUM 0409 - 0606								
440		DXi 12	ZF 16S	0409-0606	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
480		DXi 12	VT2412B	0410-0604	104089-1	180055-34 MFZ430	128995 430x50x24 DZO	
480		DXi 12	ZF 16S-122		1040104-1	170055-35 MFZ430	128992 430x2"x10 DZO	125857
480		DXi 12	ZF 16S-181		1040104-1	170055-35 MFZ430	128992 430x2"x10 DZO	125857
480		DXi 12	ZF 16S-221DD		1040104-1	170055-35 MFZ430	128992 430x2"x10 DZO	125857
480		DXi 12	ZF 16S-222	0409-0606	104095-1	170053-38 MFZ430	128992 430x2"x10 DZO	125857
480		DXi 12	ZF 16S-2220	0409-0606	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
MAGNUM 0606 -								
440		DXi13	AT2412C	0903-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
440		DXi13	AT/ATO 2512C	0903-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
460		DXi13	AT2412C	0606-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
460		DXi13	AT/ATO2512C	0606-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
480		DXi13	AT2412C	0903-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
480		DXi13	AT/ATO 2512C	0903-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
500		DXi13	AT2412C	0606-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
500		DXi13	AT/ATO2512C	0606-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
520		DXi13	AT2412C	0908-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
520		DXi13	AT/ATO 2512C	0908-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
PREMIUM 9601 - 0101								
340		MIDR 062045 E II	ZF 16S151	9908-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
385		MIDR 062356 E II	ZF 16S151	9908-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
400		MIDR 062356 E II	ZF 16S151	9908-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
400		MIDR 062356	B9	0001-	104090-1	180057-34 MFZ430	128997 430x2"x10 DZO	
PREMIUM 0101 - 0512								
320		dCi 11	ZF 12AS <i>release fork with bosses</i>	0008-	104097-1	170050-35 MFZ430	128986 430x2"x10 DZO	125850
320		dCi 11	ZF 12AS <i>release fork with rollers</i>	0008-	104098-1	170050-35 MFZ430	128986 430x2"x10 DZO	125854
370		dCi 11	ZF 12AS <i>release fork with bosses</i>	0008-	104097-1	170050-35 MFZ430	128986 430x2"x10 DZO	125850
370		dCi 11	ZF 12AS <i>release fork with rollers</i>	0008-	104098-1	170050-35 MFZ430	128986 430x2"x10 DZO	125854
370		dCi 11	ZF 8S151	0101-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857

RENAULT

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor Type	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.
370		dCi 11	ZF 16S151	0101-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
370		dCi 11	ZF 16S181	0101-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
420		dCi 11	ZF 12AS <i>release fork with bosses</i>	0008-	104097-1	170050-35 MFZ430	128986 430x2"x10 DZO	125850
420		dCi 11	ZF 12AS <i>release fork with rollers</i>	0008-	104098-1	170050-35 MFZ430	128986 430x2"x10 DZO	125854
420		dCi 11	ZF 8S151	0008-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
420		dCi 11	ZF 16S151	0008-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
420		dCi 11	ZF 16S181	0008-	104084-1	170050-35 MFZ430	128986 430x2"x10 DZO	125857
PREMIUM II 0512 - EURO 3								
330		Dxi 11	ZF 16S1620	0509-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
380		Dxi 11	ZF 16S1920	0509-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
440		Dxi 11	ZF 16S2220	0509-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
PREMIUM II 0512 - EURO 4/5								
330		Dxi 11	AT2412	0510-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
370		Dxi 7	AT2412C	0510-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
370		Dxi 7	ATO2512C	0510-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
370		Dxi 11	AT2412	0510-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
370		Dxi 11	ZF 16S1620	0605-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
370		Dxi 11	ZF 16S2220	0605-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
380		Dxi 11	AT2412	0610-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
410		Dxi 7	AT2412C	0510-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
410		Dxi 7	ATO2512C	0510-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
410		Dxi 11	AT2412	0510-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
410		Dxi 11	ZF 16S1820	0605-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
410		Dxi 11	ZF 16S1920	0605-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
410		Dxi 11	ZF 16S2220	0605-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
430	Lander 430.18 & 430.26	Dxi 11	AT2412	0610-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
430	Distribution 430.18, 430.19, 430.26; Lander 430.32, Route 430.18, 430.19, 430.26	Dxi 11	AT2412C	0610-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
430		Dxi 11	ZF 16S2220	0610-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
440		Dxi 11	AT2412C	0510-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
450		Dxi 7	AT2412C	0510-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
450		Dxi 7	ATO2512C	0510-	104460-1 ↓	160522-33AM MF430	128998 430x50x24 DZO	<
450		Dxi 11	AT2412C	0510-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
450		Dxi 11	ATO2512C	0510-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<
450		Dxi 11	ZF 16S2220	0605-	104081-1	170052-35 MFZ430	128986 430x2"x10 DZO	125857
460		Dxi 11	AT2412C	0610-	104461-1 ↓	160521-33AM MF430	128995 430x50x24 DZO	<

RENAULT

Producent	Podwozie	Silnik	Skrz. Biegów		Zestaw	Tarcza Dociskowa	Tarcza	Łożysko
Manufacturer	Chassis	Engine	Gearbox		Kit	Clutchcover	Drivenplate	Bearing
Hersteller	Chassis	Motor	Getriebe		Kit	K-Druckplatte	K-Scheibe	Ausrücker
Fabricant	Châssis	Moteur	Boîte d.Vit.		Kit	Mécanisme	Disque	Butée
Fabricante	Chasis	Motor	Cambio		Kit	Mecanismo	Disco	Cojinete
		Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.



Drivenplate Bearing


 






180055-34 : 160071-34 + 125846K

180057-34 : 160071-34 + 125848K

SCANIA

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	ltr	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.







SERIE 93

93-220		K432-7, K432-8, K432-10, K432-14		9112-	1040107-1	180050-35  MFZ430	128990 430x50x24 DZO	← 
93-230		K432-7, K432-8, K432-10, K432-14		8803-	1040107-1	180050-35  MFZ430	128990 430x50x24 DZO	← 
93-250		K432-7, K432-8, K432-10, K432-14		8803-	1040107-1	180050-35  MFZ430	128990 430x50x24 DZO	← 
93-280		DSC908 K432-7, K432-8, K432-10, K432-14		9306-	1040107-1	180050-35  MFZ430	128990 430x50x24 DZO	← 

SERIE 94

94-220		DSC911 K432-16	GR801/900	9608-	104065-1 ⊥	170060-35 MFZ430	128990 430x50x24 DZO	<
94-220		K432-19		9509-0409	1040106-1 ⊥	170061-38 MFZ430	128996 430x50x24 DZO	<
94-230		DC901 K432-30, K432-31, K432-32	GR801/900	0307-	104071-1	170050-38 MFZ430	128990 430x50x24 DZO	125851
94-260		DSC 912 K432-16	GR801/890/900	9612-	104065-1 ⊥	170060-35 MFZ430	128990 430x50x24 DZO	<
94-260		DSC902 K432-30, K432-31, K432-32	GR801/860/900	0307-	104071-1	170050-38 MFZ430	128990 430x50x24 DZO	125851
94-260		K432-33		9612-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
94-260		K432-19		9509-0409	1040106-1 ⊥	170061-38 MFZ430	128996 430x50x24 DZO	<
94-300		DSC903 K432-30, K432-31, K432-32	GR801/860/900	0307-	104071-1	170050-38 MFZ430	128990 430x50x24 DZO	125851
94-300		K432-33		9612-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
94-300		K432-19		9509-0409	1040106-1 ⊥	170061-38 MFZ430	128996 430x50x24 DZO	<
94-310		DSC 913 K432-16	GR900/890/GRS900	9608-	104065-1 ⊥	170060-35 MFZ430	128990 430x50x24 DZO	<
94-310		K432-33		9612-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
94-310		K432-19		9509-0409	1040106-1 ⊥	170061-38 MFZ430	128996 430x50x24 DZO	<

SERIE 113

113-360		DSC1123 K432-7, K432-8, K432-10, K432-14		9001-	1040107-1	180050-35  MFZ430	128990 430x50x24 DZO	← 
113-380		DSC1122 K432-7, K432-8, K432-10, K432-14		9001-	1040107-1	180050-35  MFZ430	128990 430x50x24 DZO	← 
113-400		DTC1101 K432-7, K432-8, K432-10, K432-14		9301-	1040107-1	180050-35  MFZ430	128990 430x50x24 DZO	← 

SERIE 114

114-340		DSC1179 K432-16	GR890,GR900,GRS900	9605-	104065-1 ⊥	170060-35 MFZ430	128990 430x50x24 DZO	<
114-340		DSC1103 K432-30, K432-31, K432-32	GR890,GR900	0307-	104071-1	170050-38 MFZ430	128990 430x50x24 DZO	125851
114-340		DSC1103 K432-30, K432-31, K432-32	GRS900,GRSO900	0307-	104071-1	170050-38 MFZ430	128990 430x50x24 DZO	125851
114-340		K432-33		9612-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
114-360		K432-33		9612-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
114-360		K432-19		9509-0409	1040106-1 ⊥	170061-38 MFZ430	128996 430x50x24 DZO	<
114-380		DSC1102 K432-16	GR890,GR900,GRS900,GRSO900	9601-	104065-1 ⊥	170060-35 MFZ430	128990 430x50x24 DZO	<

SCANIA

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete Ref.			
	ltr	Type			Ref.	Type	Ref.	Ø+N	Type		
114-380		DSC1104 K432-30, K432-31, K432-32	GR890,GR900	0307-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
114-380		DSC1104 K432-30, K432-31, K432-32	GRS900,GRSO900	0307-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
114.380		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
114.380		K432-19		9509-0409	1040106-1	170061-38	MFZ430	128996	430x50x24	DZO	<






SERIE 124

124-360		DSC1202 K432-16	GR900,GRS900	9601-	104065-1	170060-35	MFZ430	128990	430x50x24	DZO	<
124-360		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
124-360		K432-19		9509-0409	1040106-1	170061-38	MFZ430	128996	430x50x24	DZO	<
124-400		DSC1201 K432-16	GR900,GRS900	9601-	104065-1	170060-35	MFZ430	128990	430x50x24	DZO	<
124-400		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
124-420		K432-19		9509-0409	1040106-1	170061-38	MFZ430	128996	430x50x24	DZO	<
124-420		DSC1205 K432-16	GR-,GRS-900	9601-	104065-1	170060-35	MFZ430	128990	430x50x24	DZO	<
124-420		DSC1201 K432-30, K432-31, K432-32	GR890,GR900	0307-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
124-420		DSC1201 K432-30, K432-31, K432-32	GRS900,GRSO900	0307-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
124-420		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
124-440		DT1208 K432-16	GR890,GR900	0109-0307	104065-1	170060-35	MFZ430	128990	430x50x24	DZO	<
124-440		DT1208 K432-16	GRS900,GRSO900	0109-0307	104065-1	170060-35	MFZ430	128990	430x50x24	DZO	<
124-440		DT1208 K432-30, K432-31, K432-32	GR890,GR900	0307-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
124-440		DT1208 K432-30, K432-31, K432-32	GRS900,GRSO900	0307-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
124-440		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
124-440		K432-19		9509-0409	1040106-1	170061-38	MFZ430	128996	430x50x24	DZO	<
124-470		DT1202 K432-16	GR890,GR900	0109-0307	104065-1	170060-35	MFZ430	128990	430x50x24	DZO	<
124-470		DT1202 K432-16	GRS900,GRSO900	0109-0307	104065-1	170060-35	MFZ430	128990	430x50x24	DZO	<
124-470		DT1202 K432-30, K432-31, K432-32	GR890,GR900	0307-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
124-470		DT1202 K432-30, K432-31, K432-32	GRS900,GRSO900	0307-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
124-470		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851

SERIE 143

143-420		DSC 1408 K432-7, K432-8, K432-10, K432-14		8805-	1040107-1	180050-35	MFZ430	128990	430x50x24	DZO	⇐ ⇨
143-450		DSC 1410 K432-7, K432-8, K432-10, K432-14		8805-	1040107-1	180050-35	MFZ430	128990	430x50x24	DZO	⇐ ⇨

SCANIA

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete			
	ltr	Type			Ref.	Ref.	Type	Ref.	Ø+N	Type	Ref.
143-470		DSC 1404 K432-7, K432-8, K432-10, K432-14		8805-	1040107-1	180050-35 	MFZ430	128990	430x50x24	DZO	← 
143-500		DSC 1409 K432-7, K432-8, K432-10, K432-14		9101-	1040107-1	180050-35 	MFZ430	128990	430x50x24	DZO	← 

SERIE 144

144-460		DSC1415 K432-16	GRS900	9601-	104065-1 ↓	170060-35	MFZ430	128990	430x50x24	DZO	<
144-460		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
144-460		K432-19		9509-0409	1040106-1 ↓	170061-38	MFZ430	128996	430x50x24	DZO	<
144-530		DSC1413 K432-16	GRS900	9601-	104065-1 ↓	170060-35	MFZ430	128990	430x50x24	DZO	<
144-530		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
144-530		K432-19		9509-0409	1040106-1 ↓	170061-38	MFZ430	128996	430x50x24	DZO	<

SERIE 164

164-480		DSC1602 K432-16	GR890,GR/GRS900	0006-0307	104065-1 ↓	170060-35	MFZ430	128990	430x50x24	DZO	<
164-480		DSC1602	GR890,GR/GRS900	0307-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
164-480		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
164-480		K432-19		9509-0409	1040106-1 ↓	170061-38	MFZ430	128996	430x50x24	DZO	<
164-580		DSC1601	GRS920	0006-0307	1040106-1 ↓	170061-38	MFZ430	128996	430x50x24	DZO	<
164-580		K432-33		9612-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851


Serie G

G340	10,6	DC1108 K432-36, K432-37		0404-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G340		K32-33, K432-35, K432-39		0404-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
G360		K432-36, K432-37		1004-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G360		K32-33, K432-35, K432-39		1004-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
G380	11,7	DC1217 K432-36, K432-37		0404-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G380		K32-33, K432-35, K432-39		0404-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
G400		K432-36, K432-37		0308-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G400		K32-33, K432-35, K432-39		0803-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
G410		K432-36, K432-37		1309-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G410		K32-33, K432-35, K432-39		1309-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
G420	11,7	DC1206 K432-36, K432-37		0403-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G420		K32-33, K432-35, K432-39		0403-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
G440	11,7	DT1218 K432-36, K432-37		0803	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G440		K32-33, K432-35, K432-39		0803-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
G450		K432-36, K432-37		1309-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G450		K32-33, K432-35, K432-39		1309-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
G470	11,7	DT1206 K432-36, K432-37		0509-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G470		K32-33, K432-35, K432-39		0403-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851

SCANIA

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete			
	ltr	Type			Ref	Ref.	Type	Ref.	Ø+N	Type	Ref.
G480		11,7 DT1217 <i>K432-36, K432-37</i>		0509-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G480		K32-33, K432-35, K432-39		0404-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
G490		<i>K432-36, K432-37</i>		1309-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
G490		K32-33, K432-35, K432-39		1309-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
Serie P											
P340		10,6 DC1108 <i>K432-36, K432-37</i>		0401-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P340		DC1108 K32-33, K432-35, K432-39	GR890, GR900, GRS900	0401-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P360		<i>K432-36, K432-37</i>		0410-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P360		K32-33, K432-35, K432-39		1004-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P370		<i>K432-36, K432-37</i>		1309-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P370		K32-33, K432-35, K432-39		1309-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P380		11,7 DC1217 <i>K432-36, K432-37</i>		0404-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P380		DC1109 K32-33, K432-35, K432-39	GR890, GR900, GRS900	0404-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P400		<i>K432-36, K432-37</i>		0803-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P400		K32-33, K432-35, K432-39		0803-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P410		<i>K432-36, K432-37</i>		1309-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P410		K32-33, K432-35, K432-39		1309-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P420		11,7 DC1206 <i>K432-36, K432-37</i>		0404-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P420		DC1214 K32-33, K432-35, K432-39	GR890, GR900, GRS900	0404-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P440		<i>K432-36, K432-37</i>		1004-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P450		<i>K432-36, K432-37</i>		1309-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P450		K32-33, K432-35, K432-39		1309-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P470		<i>K432-36, K432-37</i>		0509-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P470		<i>K432-33, K432-35, K432-39</i>		0403-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P480		<i>K432-36, K432-37</i>		0509-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
P480		<i>K432-33, K432-35, K432-39</i>		0404-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P500		<i>K432-33, K432-35, K432-39</i>		0403-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P560		<i>K432-33, K432-35, K432-39</i>		0404-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
P580		<i>K432-33, K432-35, K432-39</i>		0404-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851
Serie R											
R340		10,6 DC1108 <i>K432-36, K432-37</i>		0404-	104096-1	170051-38	MFZ430	1281060	430x50x24	DZO	125851
R340		DC1108 K32-33, K432-35, K432-39	GR890, GR900, GRS900	0608-	104086-1	170051-38	MFZ430	128996	430x50x24	DZO	125851

SCANIA

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożysko Bearing Ausrücker Butée Cojinete
	ltr	Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.
R360		K432-36, K432-37		1004-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R360		K32-33, K432-35, K432-39		1004-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R380	11,7	DC1217 K432-36, K432-37		0404-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R380		K32-33, K432-35, K432-39		0404-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R400		K432-36, K432-37		0803-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R400		K32-33, K432-35, K432-39		0803-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R410		K432-36, K432-37		1309-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R410		K32-33, K432-35, K432-39		1309-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R420		K432-36, K432-37		0403-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R420		K32-33, K432-35, K432-39		0403-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R440		K432-36, K432-37		0803-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R440		K32-33, K432-35, K432-39		0803-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R450		K432-36, K432-37		1309-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R450		K32-33, K432-35, K432-39		1309-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R470		K432-36, K432-37		0509-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R470		K32-33, K432-35, K432-39		0403-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R480		K432-36, K432-37		0404-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R480		K32-33, K432-35, K432-39		0404-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R490		K432-36, K432-37		1309-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R490		K32-33, K432-35, K432-39		1309-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R500	15,6	DC1604 K432-36, K432-37		0401-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
R500		K32-33, K432-35, K432-39		0403-	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R560	15,6	DC1605, DC1618 K432-33, K432-35, K432-39		0404--	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851
R580	15,6	DC1603 K432-33, K432-35, K432-39		0404--	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851

Serie R - EURO 4

R420	11,7	DT1212 K432-36, K432-37		0601-	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
------	------	----------------------------	--	-------	-----------------	-------------------------	------------------------------	---------------

Serie T

T470		K432-36, K432-38		0409-0510	104096-1	170051-38 MFZ430	1281060 430x50x24 DZO	125851
T470		K32-33, K432-35, K432-39		0409-0510	104086-1	170051-38 MFZ430	128996 430x50x24 DZO	125851



Drivenplate Bearing

180050-35 : 160050-35 + 125845K


SISU

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d. Vit. Cambio		Zestaw Kit Kit Kit Kit Ref.	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref.	Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref.	Ø+N	Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.
--	---	--	--	---	--	--	------	---	-----	------	--


SM - SERIE

		Cummins N11	ZF	9501-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
		Cummins N11	RVI	9501-	1040110-1	170052-35	MFZ430	128985	430x2"x10	GZO	125960
		Cummins N14	ZF	9501-	104070-1	170052-35	MFZ430	128985	430x2"x10	GZO	125849
		Cummins N14	RVI	9501-	1040110-1	170052-35	MFZ430	128985	430x2"x10	GZO	125960


STEYR

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Chassis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref.	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref.	Type	Tarcza Drivenplate K-Scheibe Disque Disco Ref.	Ø+N	Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.
SERIE 23 S .. - 42 S ..											
23 S 40		MAN D2866		9401-	104083-1	170052-35	MFZ430	128986	430x2"x10	DZO	125849
23 S 46		MAN D2866		9401-	104083-1	170052-35	MFZ430	128986	430x2"x10	DZO	125849
42 S 40		MAN D2866		9603-	104083-1	170052-35	MFZ430	128986	430x2"x10	DZO	125849
42 S 46		MAN D2866		9603-	104083-1	170052-35	MFZ430	128986	430x2"x10	DZO	125849

TERBERG

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref.	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo Ref.	Tarcza Drivenplate K-Scheibe Disque Disco Ref.	Ø+N Type	Łożysko Bearing Ausrücker Butée Cojinete Ref.
FM2000			ZF manual shift		1040101-1	170055-35 MFZ430	128997 430x2"x10	DZO	125849
FM2000			ZF AS-tronic <i>old style release fork with bosses</i>		1040102-1	170055-35 MFZ430	128997 430x2"x10	DZO	125850
FM2000			ZF AS-tronic <i>new style release fork with rollers</i>		1040103-1	170055-35 MFZ430	128997 430x2"x10	DZO	125854



















VOLVO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Zestaw Kit Kit Kit Kit Ref	Tarcza Dociskowa Clutchcover K-Druckplatte Mécanisme Mecanismo	Tarcza Drivenplate K-Scheibe Disque Disco	Łożyisko Bearing Ausrücker Butée Cojinete			
	Itr	Type			Ref	Ref.	Type	Ref.	Ø+N	Type	Ref.



 




 
F 12

F12		TD122/123	R/SR 1400/1700	8701-	104085-1	180052-34  MFZ430	128988	430x2"x10	DZO	← 
-----	--	-----------	----------------	-------	-----------------	---	---------------	-----------	-----	---




 










FH / 2006-2008 / Euro 4

FH 400		12.8 D13A/D13B	VT2009B	0509-	104087-1	180056-34  MFZ430	128995	430x50x24	DZO	← 	
FH 400		12.8 D13A/D13B	VT/VTO2214B	0509-	104088-1	180057-34  MFZ430	128995	430x50x24	DZO	← 	
FH 400		12.8 D13A/D13B	VT/VTO2514B	0509-	104088-1	180057-34  MFZ430	128995	430x50x24	DZO	← 	
FH 400		D13A/D13B	AT 2412C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 400		D13A/D13B	AT 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 400		D13A/D13B	ATO 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 440		12.8 D13A/D13B	VT/VTO2214B	0509-	104088-1	180057-34  MFZ430	128995	430x50x24	DZO	← 	
FH 440		12.8 D13A/D13B	VT/VTO2514B	0509-	104088-1	180057-34  MFZ430	128995	430x50x24	DZO	← 	
FH 440		D13A/D13B	AT 2412C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 440		D13A/D13B	AT 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 440		D13A/D13B	ATO 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 480		D13A	VT/VTO2214B	0509-	104088-1	180057-34  MFZ430	128995	430x50x24	DZO	← 	
FH 480		D13A	VT/VTO2514B		104088-1	180057-34  MFZ430	128995	430x50x24	DZO	← 	
FH 480		D13A/D13B	AT 2412C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 480		D13A/D13B	AT 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 480		D13A/D13B	ATO 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 520		D13A	VT/VTO2214B	0509-	104088-1	180057-34  MFZ430	128995	430x50x24	DZO	← 	
FH 520		D13A	VT/VTO2514B		104088-1	180057-34  MFZ430	128995	430x50x24	DZO	← 	
FH 520		D13A/D13B	AT 2412C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 520		D13A/D13B	AT 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FH 520		D13A/D13B	ATO 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<



 

 




 



 
FH 12-340

FH12-340		D12A,C	SR1700	9308-0509	104085-1	180052-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-340		D12A,C	SR1900	9308-0509	104085-1	180052-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-340		D12C	VT2014	9308-	104069-1	180053-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-340		D12C	VT2014OD	9308-	104069-1	180053-34  MFZ430	128988	430x2"x10	DZO	← 



 
 
 
 
FH 12-380

FH12-380		D12A,C	SR1700	9308-0509	104085-1	180052-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-380		D12A,C	SR1900	9308-0509	104085-1	180052-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-380		D12D	VT2009B	9308-	104067-1	180052-34  MFZ430	128989	430x50x24	DZO	← 
FH12-380		D12C	VT2014	9308-	104069-1	180053-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-380		D12C	VT2014OD	9308-	104069-1	180053-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-380		D12D	VT/VTO 2214B	9308-	104068-1	180053-34  MFZ430	128989	430x50x24	DZO	← 
FH12-380		D12D	VT2412B	9308-	104066-1	180051-34  MFZ430	128989	430x50x24	DZO	← 

FH 12-420

FH12-420		D12A,C	SR1700	9308-0509	104085-1	180052-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-420		D12A,C	SR1900	9308-0509	104085-1	180052-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-420		D12D	VT2009B	9308-	104067-1	180052-34  MFZ430	128989	430x50x24	DZO	← 
FH12-420		D12C	VT2014	9308-	104069-1	180053-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-420		D12C	VT2014OD	9308-	104069-1	180053-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-420		D12D	VT/VTO 2214B	9308-	104068-1	180053-34  MFZ430	128989	430x50x24	DZO	← 
FH12-420		D12D	VT2412B	9308-	104066-1	180051-34  MFZ430	128989	430x50x24	DZO	← 

FH 12-460

FH12-460		D12C	VT2014	9308-	104069-1	180053-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-460		D12C	VT2014OD	9308-	104069-1	180053-34  MFZ430	128988	430x2"x10	DZO	← 
FH12-460		D12C	VT2514	9806-	104090-1	180057-34  MFZ430	128997	430x2"x10	DZO	← 

VOLVO

FH12-460		D12D	VT2412B	9808-	104089-1	180055-34	MFZ430	128995	430x50x24	DZO	←	↻
FH 12-500												
FH12-500		D12D	VT2412B	0109-	104089-1	180055-34	MFZ430	128995	430x50x24	DZO	←	↻
FL 12												
FL12-380		D12A	R/SR 1700	9509-9809	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↻
FL12-380		D12A	R/SR 1900	9509-9809	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↻
FL12-420		D12A	R/SR 1700		104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↻
FL12-420		D12A	R/SR 1900		104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↻
FM Series 2005-												
FM 300		D9A/D9B	AT2412C	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 300		D9A/D9B	AT2512C	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 330	10.8	D11C	VT2009B	0509-	104087-1	180056-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 330		D11C	VT/VTO2214B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 330		D11C	VT/VTO2514B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 330		D11C	AT2412D	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 330		D11C	AT2612D	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 330		D11C	ATO2612D	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 340		D9A/D9B	VT2009B	0509-	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	←	↻
FM 340		D9A/D9B	VT/VTO2214B	0509-	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↻
FM 340		D9A/D9B	AT2412C	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 340		D9A/D9B	AT2512C	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 360	12.8	D13A/D13B	VT2009B	0511-	104087-1	180056-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 360		D13A/D13B	VT/VTO2214B	0511-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 360		D13A/D13B	VT/VTO2514B	0511-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 360		D13A/D13B	AT 2412C	0511-	104461-1	160521-33AM	MF430	128995	430x50x24	DZO		<
FM 360		D13A/D13B	AT 2512C	0511-	104461-1	160521-33AM	MF430	128995	430x50x24	DZO		<
FM 360		D13A/D13B	ATO 2512C	0511-	104461-1	160521-33AM	MF430	128995	430x50x24	DZO		<
FM 370	10.8	D11C	VT2009B	0509-	104087-1	180056-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 370		D11C	VT/VTO2214B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 370		D11C	VT/VTO2514B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 370		D11C	AT2412D	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 370		D11C	AT2612D	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 370		D11C	ATO 2612D		104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 380		D9B	VT2009B	0509-	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	←	↻
FM 380		D9A/D9B	VT/VTO2214B	0509-	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↻
FM 380		D9B	AT2412C	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 380		D9B	AT2512C	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 380		D13C	VT2009B	0509-	104087-1	180056-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 380		D13C	VT/VTO2214B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 380		D13C	VT/VTO2514B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 400		D13A/D13B	VT2009B	0509-	104087-1	180056-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 400		D13A/D13B	VT/VTO2214B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 400		D13A/D13B	VT/VTO2514B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 400		D13A/D13B	AT2412C	0509-	104461-1	160521-33AM	MF430	128995	430x50x24	DZO		<
FM 400		D13A/D13B	AT 2512C	0509-	104461-1	160521-33AM	MF430	128995	430x50x24	DZO		<
FM 400		D13A/D13B	ATO 2512C	0509-	104461-1	160521-33AM	MF430	128995	430x50x24	DZO		<
FM 410		D11C	VT2009B	0509-	104087-1	180056-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 410		D11C	VT/VTO2214B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 410		D11C	VT/VTO2514B	0509-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↻
FM 410		D11C	AT2412D	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<
FM 410		D11C	AT2612D	0509-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO		<

VOLVO

FM 410		D11C	ATO 2612D	0509-	104460-1 ⊥	160522-33AM	MF430	128998	430x50x24	DZO	<
FM 420		D13C	VT2009B	0509-	104087-1	180056-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 420		D13C	VT/VTO2214B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 420		D13C	VT/VTO2514B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 420		D13C	AT2412D	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 420		D13C	AT 2612D	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 420		D13C	ATO 2612D	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 440		D13A/D13B	VT/VTO2214B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 440		D13A/D13B	VT/VTO2514B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 440		D13A/D13B	AT2412C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 440		D13A/D13B	AT 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 440		D13A/D13B	ATO 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 450		D11C	VT2009B	0509-	104087-1	180056-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 450		D11C	VT/VTO2214B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 450		D11C	VT/VTO2514B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 450		D11C	AT2412D		104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 450		D11C	AT 2612D		104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 450		D11C	ATO 2612D		104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 460		D13C	VT2009B	0509-	104087-1	180056-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 460		D13C	VT/VTO2214B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 460		D13C	VT/VTO2514B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 460		D13C	AT2412D	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 460		D13C	AT 2612D	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 460		D13C	ATO 2612D	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 480		D13A	VT/VTO2214B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 480		D13A	VT/VTO2514B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 480		D13A	AT2412C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 480		D13A	AT 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 480		D13A	ATO 2512C	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 500	12.8	D13B/D13C		0709-							
FM 500		D13B/D13C	VT2009B	0509-	104087-1	180056-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 500		D13B/D13C	VT/VTO2214B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 500		D13B/D13C	VT/VTO2514B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 500		D13B/D13C	AT2412D	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 500		D13B/D13C	AT2612D	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 500		D13B/D13C	ATO2612D	0509-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 520		D13A	VT/VTO2214B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 520		D13A	VT/VTO2514B	0509-	104088-1	180057-34 ⚡	MFZ430	128995	430x50x24	DZO	← ⚡
FM 520		D13A	AT2412C	0801-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 520		D13A	AT 2512C	0801-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 520		D13A	ATO 2512C	0801-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
FM 7-250											
FM7-250		DC7	VT2014	9808-0112	104069-1	180053-34 ⚡	MFZ430	128988	430x2"x10	DZO	← ⚡
FM7-250		DC7	VT2514	9808-0112	104069-1	180053-34 ⚡	MFZ430	128988	430x2"x10	DZO	← ⚡
FM 7-290											
FM7-290		DC7	VT2014	9808-0112	104069-1	180053-34 ⚡	MFZ430	128988	430x2"x10	DZO	← ⚡
FM7-290		DC7	VT2514	9808-0112	104069-1	180053-34 ⚡	MFZ430	128988	430x2"x10	DZO	← ⚡
FM 9-340											
FM9-340		D9A	VT1708B	0509-	104067-1	180052-34 ⚡	MFZ430	128989	430x50x24	DZO	← ⚡
FM9-340		D9A	VT2009B	0509-	104067-1	180052-34 ⚡	MFZ430	128989	430x50x24	DZO	← ⚡
FM9-340		D9A	VT2214B	0112-0509	104068-1	180053-34 ⚡	MFZ430	128989	430x50x24	DZO	← ⚡
FM9-340		D9A	VTO2214B	0112-0509	104068-1	180053-34 ⚡	MFZ430	128989	430x50x24	DZO	← ⚡

VOLVO
FM 9-380

FM9-380	D9A	VT1708B	0112-0509	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	←	↷
FM9-380	D9A	VT2009B	0112-0509	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	←	↷
FM9-380	D9A	VT2214B	0112-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷
FM9-380	D9A	VTO2214B	0112-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷

FM 10-360

FM10-360	D10B E II	R/SR 1400/1700	9901-0509	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↷
----------	-----------	----------------	-----------	-----------------	------------------	--------	---------------	-----------	-----	---	---

FM 12-340

FM12-340	D12C	R/SR 1700	9808-0509	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-340	D12C	R/SR 1900	9808-0509	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-340	D12D	VT2009B	9801-0509	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-340	D12C	VT2014	9808-0509	104069-1	180053-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-340	D12C	VT2014OD	9808-0509	104069-1	180053-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-340	D12D	VT 2214B	9801-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-340	D12D	VTO 2214B	9801-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-340	D12D	VT2412B	9801-0509	104066-1	180051-34	MFZ430	128989	430x50x24	DZO	←	↷

FM 12-380

FM12-380	D12C	R/SR 1700	9808-0509	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-380	D12C	R/SR 1900	9808-0509	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-380	D12D	VT2009B	9801-0509	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-380	D12C	VT2014	9808-0509	104069-1	180053-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-380	D12C	VT2014OD	9808-0509	104069-1	180053-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-380	D12D	VT 2214B	9801-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-380	D12D	VTO 2214B	9801-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-380	D12D	VT2412B	9801-0509	104066-1	180051-34	MFZ430	128989	430x50x24	DZO	←	↷

FM 12-420

FM12-420	D12C	R/SR1700	9801-0509	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-420	D12C	R/SR1900	9801-0509	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-420	D12D	VT2009B	9801-0509	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-420	D12C	VT2014	9808-0509	104069-1	180053-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-420	D12C	VT2014OD	9808-0509	104069-1	180053-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-420	D12D	VT2214B	9801-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-420	D12D	VTO 2214B	9801-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-420	D12D	VT2412B	9801-0509	104066-1	180051-34	MFZ430	128989	430x50x24	DZO	←	↷

FM 12-460

FM12-460	D12C	R/SR 1700	9801-0509	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-460	D12C	R/SR 1900	9801-0509	104085-1	180052-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-460	D12D	VT2009B	9801-0509	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-460	D12C	VT2014	9808-0509	104069-1	180053-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-460	D12C	VT2014OD	9808-0509	104069-1	180053-34	MFZ430	128988	430x2"x10	DZO	←	↷
FM12-460	D12D	VT 2214B	9801-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-460	D12D	VTO 2214B	9801-0509	104068-1	180053-34	MFZ430	128989	430x50x24	DZO	←	↷
FM12-460	D12D	VT2412B	0301-	104089-1	180055-34	MFZ430	128995	430x50x24	DZO	←	↷

FMX Series
2010-

330	DC11C	VT2009B	1004-	104087-1	180056-34	MFZ430	128995	430x50x24	DZO	←	↷
330	DC11C	VT/VTO2214B	1004-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↷
330	DC11C	VT/VTO2514B	1004-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↷
330	DC11C	AT2412D	1004-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO	<	
330	DC11C	AT2612D	1004-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO	<	
330	DC11C	ATO2612D	1004-	104460-1	160522-33AM	MF430	128998	430x50x24	DZO	<	
380	DC13C	VT2009B	1001-	104087-1	180056-34	MFZ430	128995	430x50x24	DZO	←	↷
380	DC13C	VT2214B	1001-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↷
380	DC13C	VTO2514B	1001-	104088-1	180057-34	MFZ430	128995	430x50x24	DZO	←	↷

VOLVO

380		D13C	AT2412D	1004-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
380		D13C	AT 2612D	1004-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<
380		D13C	ATO 2612D	1004-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO	<

NH 12

NH12-380		D12C	VT2412B	9801-0509	104066-1	180051-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-380		D12C	SR1400	9905-	104067-1	180052-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-380		D12C	SR1700	9905-	104067-1	180052-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-380		D12C	SR1900	9905-	104067-1	180052-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-380		D12C	VT2214B	9905-	104068-1	180053-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-380		D12C	VTO2214B	9905-	104068-1	180053-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-380		D12C	VT2514B	9905-	104068-1	180053-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-380		D12C	VTO2514B	9905-	104068-1	180053-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-420		D12C	VT2412B	9801-0509	104066-1	180051-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-420		D12C	SR1400	9905-	104067-1	180052-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-420		D12C	SR1400	9905-	104067-1	180052-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙
NH12-420		D12C	SR1400	9905-	104067-1	180052-34 ⚙	MFZ430	128989	430x50x24	DZO	← ⚙



Drivenplate Bearing

180051-34 : 160070-34 + 125846K

180052-34 : 160070-34 + 125847K

180053-34 : 160070-34 + 125848K


180055-34 : 160071-34 + 125846K

180056-34 : 160071-34 + 125847K

180057-34 : 160071-34 + 125848K

BUSES

BOVA

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Set Kit Kit Kit Kit Ref	Drukgroep Clutchcover K-Druckplatte Mécanisme Mecanismo	Frikatieplaat Drivenplate K-Scheibe Disque Disco	Druklager Bearing Ausrücker Butée Cojinete		
	ltr	Type			Ref.	Type	Ref.	Ø+N	Type	Ref.


FUTURA

FHX 12-370		MAN / DAF			104078-1	170052-35	MFZ430	128986	430x2"x10	DZO	125849
------------	--	-----------	--	--	-----------------	------------------	--------	---------------	-----------	-----	---------------

MAGIQ

All versions			ZF AS-Tronic <i>release fork with rollers</i>		104080-1	170052-35	MFZ430	128986	430x2"x10	DZO	125854
--------------	--	--	--	--	-----------------	------------------	--------	---------------	-----------	-----	---------------


DAF

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Set Kit Kit Kit Kit Ref	Drukgroep Clutchcover K-Druckplatte Mécanisme Mecanismo	Frikatieplaat Drivenplate K-Scheibe Disque Disco	Druklager Bearing Ausrücker Butée Cojinete Ref.	
	ltr	Type			Ref.	Type	Ref.	Ø+N	Type

SERIE - SB

SB 4000			MB		1040112-1	170052-35	MFZ430	128986	430x2"x10	DZO	125853
---------	--	--	----	--	------------------	------------------	--------	---------------	-----------	-----	---------------

IRISBUS

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Set Kit Kit Kit Kit Ref	Drukgroep Clutchcover K-Druckplatte Mécanisme Mecanismo	Frikctieplaat Drivenplate K-Scheibe Disque Disco	Drukklager Bearing Ausrücker Butée Cojinete Ref.
	Ref.	Type	Ref.	Ø+N	Type	Ref.	Type	Ref.

ARES

430		dCi11	ZF-10AS2301	0104-	104098-1	170050-35	MFZ430	128986	430x2.1/16"x10	DZO	125854
-----	--	-------	-------------	-------	-----------------	------------------	--------	---------------	----------------	-----	---------------

DOMINO

38		8460.41	ZF S8.180		104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850
43		dCi 11	ZF 10AS2301		104098-1	170050-35	MFZ430	128986	430x2.1/16"x10	DZO	125854

EUROCLASS

380.10.29		8460.41R	ZF S8.180		104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850
380.10.35		8460.41S	ZF S8.180		104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850
380.12.29		8460.41R	ZF S8.180		104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850
380.12.35		8460.41S	ZF S8.180		104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850
380.12.38		8460.41M	ZF S8.180		104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850
HD 43		dCi 11	ZF 10AS2301		104098-1	170050-35	MFZ430	128986	430x2.1/16"x10	DZO	125854
ND 36		dCi 11	ZF s6.1600		104098-1	170050-35	MFZ430	128986	430x2.1/16"x10	DZO	125854


EURORIDER

391.12.35		8460-345ps	ZF S8.180		104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850
391.12.38		8460-375ps	ZF S8.180		104082-1	170052-35	MFZ430	128986	430x2"x10	DZO	125850
43		dCi 11	ZF S8.180		104098-1	170050-35	MFZ430	128986	430x2.1/16"x10	DZO	125854

ILIADE

HD430		dCi 11 - 430ps	ZF 10AS2301		104098-1	170050-35	MFZ430	128986	430x2.1/16"x10	DZO	125854
-------	--	----------------	-------------	--	-----------------	------------------	--------	---------------	----------------	-----	---------------

MAN / STEYR

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Chassis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Set Kit Kit Kit Kit Ref	Drukgroep Clutchcover K-Druckplatte Mécanisme Mecanismo Ref. Type	Frikatieplaat Drivenplate K-Scheibe Disque Disco Ref. Ø+N Type	Drukklager Bearing Ausrücker Butée Cojinete Ref.
--	---	--	---	---	--	--	---	---

MAN LION S COACH

RH 463		D2876	AS-Tronic <i>new style release fork with rollers</i>	0001-	104092-1	170055-35	MFZ430	128993	430x2"x10	DZO	125854
RH 463		D2876	AS-Tronic <i>old style release fork with bosses</i>	0001-	1040105-1	170055-35	MFZ430	128993	430x2"x10	DZO	125850
RHC 464		D2876	AS-Tronic <i>new style release fork with rollers</i>	0001-	104092-1	170055-35	MFZ430	128993	430x2"x10	DZO	125854
RHC 464		D2876	AS-Tronic <i>old style release fork with bosses</i>	0001-	1040105-1	170055-35	MFZ430	128993	430x2"x10	DZO	125850


MAN LION S STAR

RH 414		D2866	AS-Tronic <i>new style release fork with rollers</i>	0001-	104092-1	170055-35	MFZ430	128993	430x2"x10	DZO	125854
RH 464		D2876	AS-Tronic <i>new style release fork with rollers</i>	0201-	104092-1	170055-35	MFZ430	128993	430x2"x10	DZO	125854
RHS 414		D2866	AS-Tronic <i>new style release fork with rollers</i>	0001-	104092-1	170055-35	MFZ430	128993	430x2"x10	DZO	125854
RHS 464		D2876	AS-Tronic <i>new style release fork with rollers</i>	0201-	104092-1	170055-35	MFZ430	128993	430x2"x10	DZO	125854


STEYR TG-A

18 S 31		D2866	AS-tronic <i>old style release fork with bosses</i>	0004-	104075-1	170054-35	MFZ430	128986	430x2"x10	DZO	125850
18 S 31		D2866	AS-tronic <i>new style release fork with rollers</i>	0004-	104076-1	170054-35	MFZ430	128986	430x2"x10	DZO	125854
18 S 31		D2866	Ecosplit	0004-	104077-1	170054-35	MFZ430	128986	430x2"x10	DZO	125849
18 S 36		D2866	AS-tronic <i>old style release fork with bosses</i>	0004-	104075-1	170054-35	MFZ430	128986	430x2"x10	DZO	125850
18 S 36		D2866	AS-tronic <i>new style release fork with rollers</i>	0004-	104076-1	170054-35	MFZ430	128986	430x2"x10	DZO	125854
18 S 36		D2866	Ecosplit	0004-	104077-1	170054-35	MFZ430	128986	430x2"x10	DZO	125849
18 S 41		D2866	AS-tronic <i>old style release fork with bosses</i>	0004-	104075-1	170054-35	MFZ430	128986	430x2"x10	DZO	125850
18 S 41		D2866	AS-tronic <i>new style release fork with rollers</i>	0004-	104076-1	170054-35	MFZ430	128986	430x2"x10	DZO	125854
18 S 41			Ecosplit	0004-	104077-1	170054-35	MFZ430	128986	430x2"x10	DZO	125849
18 S 46		D2876	AS-Tronic <i>new style release fork with rollers</i>	0004-	104092-1	170055-35	MFZ430	128993	430x2"x10	DZO	125854
18 S 46		D2876	AS-Tronic <i>old style release fork with bosses</i>	0004-	1040105-1	170055-35	MFZ430	128993	430x2"x10	DZO	125850
18 S 46		D2876	Ecosplit	0004-	104091-1	170055-35	MFZ430	128993	430x2"x10	DZO	125849
18 S 46		D2876	Eaton	0004-	104091-1	170055-35	MFZ430	128993	430x2"x10	DZO	125849
18 S 51		D2676	AS-Tronic <i>new style release fork with rollers</i>	0004-	104092-1	170055-35	MFZ430	128993	430x2"x10	DZO	125854

MAN / STEYR

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Chassis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Set Kit Kit Kit Kit Ref	Drukgroep Clutchcover K-Druckplatte Mécanisme Mecanismo		Friktrieplaat Drivenplate K-Scheibe Disque Disco		Drukklager Bearing Ausrücker Butée Cojinete
		ltr Type			Ref	Ref. Type		Ref. Ø+N Type		Ref.
18 S 51		D2876	AS-Tronic <i>old style release fork with bosses</i>	0004-	1040105-1	170055-35 MFZ430		128993 430x2"x10 DZO		125850
18 S 51		D2876	Ecosplit	0004-	104091-1	170055-35 MFZ430		128993 430x2"x10 DZO		125849
18 S 51		D2876	Eaton	0004-	104091-1	170055-35 MFZ430		128993 430x2"x10 DZO		125849
26 S 31		D2866	AS-tronic <i>old style release fork with bosses</i>	0009-	104075-1	170054-35 MFZ430		128986 430x2"x10 DZO		125850
26 S 31		D2866	AS-tronic <i>new style release fork with rollers</i>	0009-	104076-1	170054-35 MFZ430		128986 430x2"x10 DZO		125854
26 S 31		D2866	Ecosplit	0009-	104077-1	170054-35 MFZ430		128986 430x2"x10 DZO		125849
26 S 36		D2866	AS-tronic <i>old style release fork with bosses</i>	0009-	104075-1	170054-35 MFZ430		128986 430x2"x10 DZO		125850
26 S 36		D2866	AS-tronic <i>new style release fork with rollers</i>	0009-	104076-1	170054-35 MFZ430		128986 430x2"x10 DZO		125854
26 S 36		D2866	Ecosplit	0009-	104077-1	170054-35 MFZ430		128986 430x2"x10 DZO		125849
33 S 46		D2876			104083-1	170052-35 MFZ430		128986 430x2"x10 DZO		125849
35 S 36		D2866		9806-	104083-1	170052-35 MFZ430		128986 430x2"x10 DZO		125849
35 S 41		D2866		9806-	104083-1	170052-35 MFZ430		128986 430x2"x10 DZO		125849
41 S 36		D2866		9806-	104083-1	170052-35 MFZ430		128986 430x2"x10 DZO		125849
41 S 40		D2866		9806-	104083-1	170052-35 MFZ430		128986 430x2"x10 DZO		125849
41 S 41		D2866		9806-	104083-1	170052-35 MFZ430		128986 430x2"x10 DZO		125849
41 S 46		D2876		9806-	104083-1	170052-35 MFZ430		128986 430x2"x10 DZO		125849

MERCEDES-BENZ

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Set Kit Kit Kit Kit Ref	Drukgroep Clutchcover K-Druckplatte Mécanisme Mecanismo	Frikatieplaat Drivenplate K-Scheibe Disque Disco	Drukklager Bearing Ausrücker Butée Cojinete
		ltr Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.

O 303	600.485, 600.414, 600.415, 600.494	OM442		8709-9209	104073-1	170052-35 MFZ430	128986 430x2"x10 DZO	125855
-------	---------------------------------------	-------	--	-----------	-----------------	-------------------------	-----------------------------	---------------

SERIE O 300

O 340	600.442	OM402			104073-1	170052-35 MFZ430	128986 430x2"x10 DZO	125855
-------	---------	-------	--	--	-----------------	-------------------------	-----------------------------	---------------

O 350	613.445; 613.485	OM402LA			104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
-------	------------------	---------	--	--	-----------------	-------------------------	-----------------------------	---------------

O 350	Country Vers. : Turkey	OM402LA			104073-1	170052-35 MFZ430	128986 430x2"x10 DZO	125855
-------	---------------------------	---------	--	--	-----------------	-------------------------	-----------------------------	---------------

O 350	613.355;613.385	OM441			1040111-1	170052-35 MFZ430	128986 430x2"x10	125855
-------	-----------------	-------	--	--	------------------	-------------------------	-------------------------	---------------

SERIE O 400


O403	613.385, 613.355 Country Vers. : Turkey	OM441LA			104073-1	170052-35 MFZ430	128986 430x2"x10 DZO	125855
------	---	---------	--	--	-----------------	-------------------------	-----------------------------	---------------

O 404	356.373, 356.415, 356.495, 614.115, 614.435, 356.443, 356.445, 356.323, 356.353, 356.363, 614.428, 356.313, 356.425, 356.435, 614.313, 356.405, 356.455, 356.485, 614.415, 356.343, 356.465, 614.445	OM402LA		9109-9910	104073-1	170052-35 MFZ430	128985 430x2"x10 DZO	125855
-------	--	---------	--	-----------	-----------------	-------------------------	-----------------------------	---------------

SERIE 1300-1600

OH 1634	396.483 <nrZ.902592	OM442A			104072-1	170052-35 MFZ430	128986 430x2"x10 DZO	125856
---------	------------------------	--------	--	--	-----------------	-------------------------	-----------------------------	---------------

NEOPLAN

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Set Kit Kit Kit Kit Ref	Drukgroep Clutchcover K-Druckplatte Mécanisme Mecanismo	Frikatieplaat Drivenplate K-Scheibe Disque Disco	Druklager Bearing Ausrücker Butée Cojinete
		ltr Type			Ref	Ref. Type	Ref. Ø+N Type	Ref.

CITYLINER

N 1216 HDC		D2066	AS-tronic <i>old style release fork with bosses</i>	0609-	104075-1	170054-35 MFZ430	128986 430x2"x10 DZO	125850
N 1216 HDC		D2066	AS-Tronic <i>new style release fork with rollers</i>	0609-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
N 1216 HD		D2066	AS-tronic <i>new style release fork with rollers</i>	0609-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
N 1217 HD		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
N 1218 HD		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854

JETLINER

N 209		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
N 212		D2066	AS-tronic <i>new style release fork with rollers</i>		104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854

SKYLINER

N 1122/3		D2676	AS-Tronic <i>new style release fork with rollers</i>	0603-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
----------	--	-------	---	-------	-----------------	-------------------------	-----------------------------	---------------

STARLINER

N 2216 SHD		D2066	AS-tronic <i>new style release fork with rollers</i>	0201-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
N 5217 SHD		D2876	AS-Tronic <i>new style release fork with rollers</i>	0502-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
N 5218 SHD		D2876	AS-Tronic <i>new style release fork with rollers</i>	0505-	104092-1	170055-35 MFZ430	128993 430x2"x10 DZO	125854
N 5218 SHD		D2876	AS-Tronic <i>old style release fork with bosses</i>	0505-	1040105-1	170055-35 MFZ430	128993 430x2"x10 DZO	125850

TOURLINER

N 2216 SHD		D2066	AS-tronic <i>new style release fork with rollers</i>	0301-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
N 2216 SHDL		D2066	AS-tronic <i>new style release fork with rollers</i>	0301-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854

TRENDLINER

N 3516		D2066	AS-tronic <i>new style release fork with rollers</i>	0409-	104076-1	170054-35 MFZ430	128986 430x2"x10 DZO	125854
--------	--	-------	---	-------	-----------------	-------------------------	-----------------------------	---------------

SCANIA

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Set Kit Kit Kit Kit Ref	Drukgroep Clutchcover K-Druckplatte Mécanisme Mecanismo		Frikctieplaat Drivenplate K-Scheibe Disque Disco		Druklager Bearing Ausrücker Butée Cojinete	
		ltr	Type		Ref	Ref.	Type	Ref.	Ø+N	Type	Ref.

3 SERIES

K 113			F&S type	GRS900	9101-	1040107-1	180050-35	MFZ430	128990	430x50x24	DZO	←
-------	--	--	----------	--------	-------	------------------	------------------	--------	---------------	-----------	-----	---

4 SERIES




 

 
 
 
 
 
 
 
 
 
 
 
 
 
 




 
 
 
 

 






 
 
 
 
 
 
 
 
 
 


 
 
 
 
 







 
 


 
 
K94		K432-16	GR801	9501-	104065-1 ⊥	170060-35	MFZ430	128990	430x50x24	DZO	<
K94		K432-30, K432-31, K432-32		9501-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
K94		K432-8		9501-	1040107-1	180050-35	MFZ430	128990	430x50x24	DZO	←
L94		K432-16	GR801	9501-	104065-1 ⊥	170060-35	MFZ430	128990	430x50x24	DZO	<
L94		K432-30, K432-31, K432-32		9501-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
L94		K432-8		9501-	1040107-1	180050-35	MFZ430	128990	430x50x24	DZO	←
N94		K432-16	GR801	9501-	104065-1 ⊥	170060-35	MFZ430	128990	430x50x24	DZO	<
N94		K432-30, K432-31, K432-32		9501-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
N94		K432-8		9501-	1040107-1	180050-35	MFZ430	128990	430x50x24	DZO	←
114		K432-16	GR801	9501-	104065-1 ⊥	170060-35	MFZ430	128990	430x50x24	DZO	<
114		K432-30, K432-31, K432-32		9501-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
114		K432-8		9501-	1040107-1	180050-35	MFZ430	128990	430x50x24	DZO	←
124		K432-16	GR801	9501-	104065-1 ⊥	170060-35	MFZ430	128990	430x50x24	DZO	<
124		K432-30, K432-31, K432-32		9501-	104071-1	170050-38	MFZ430	128990	430x50x24	DZO	125851
124		K432-8		9501-	1040107-1	180050-35	MFZ430	128990	430x50x24	DZO	←



Drivenplate Bearing

180050-35 : 160050-35 + 125845K

VOLVO

Producent Manufacturer Hersteller Fabricant Fabricante	Podwozie Chassis Chassis Châssis Chasis	Silnik Engine Motor Moteur Motor	Skrz. Biegów Gearbox Getriebe Boîte d.Vit. Cambio		Set Kit Kit Kit Kit Ref	Drukgroep Clutchcover K-Druckplatte Mécanisme Mecanismo	Frikatieplaat Drivenplate K-Scheibe Disque Disco	Druklager Bearing Ausrücker Butée Cojinete			
	ltri	Type			Ref.	Type	Ref.	Ø+N	Type	Ref.	
SERIE "B"											
B 9		D9B 260	EGS-V / EGS-VR	0509-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
B 9		D9B 260	AT2412C	0509-	104460-1 ⊥	160522-33AM	MF430	128998	430x50x24	DZO	<
B 9		D9B 310	EGS-V / EGS-VR	0509-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
B 9		D9B 310	AT2412C	0509-	104460-1 ⊥	160522-33AM	MF430	128998	430x50x24	DZO	<
B 9		D9B 360	EGS-V / EGS-VR	0509-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
B 9		D9B 360	AT2412C	0509-	104460-1 ⊥	160522-33AM	MF430	128998	430x50x24	DZO	<
B 9		G9A 260	EGS-V / EGS-VR	0509-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
B 9		G9A 260	AT2412C	0509-	104460-1 ⊥	160522-33AM	MF430	128998	430x50x24	DZO	<
B 9		G9A 300	EGS-V / EGS-VR	0509-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
B 9		G9A 300	AT2412C	0509-	104460-1 ⊥	160522-33AM	MF430	128998	430x50x24	DZO	<
B 10 B		DH10A, GH10A,THD101, THD102, THD103, THD104	G7-EGS, G8-EGS		104085-1	180052-34 	MFZ430	128988	430x2"x10	DZO	⇐ 
B 12 M		DH12D	VT2412B		104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
B 12 M		DH12D 340	EGS-V, EGS-VR		104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
B 12 M		DH12D 380	EGS-V, EGS-VR		104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
B 12 M		DH12D 420	EGS-V, EGS-VR		104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8500											
8500		DH12D 340	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8500		DH12D 380	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8500		DH12D 420	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8500		DH12D 340	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8500		DH12D 380	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8500		DH12D 420	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8700											
8700		DH12D 340	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8700		DH12D 380	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8700		DH12D 420	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8700		DH12D 340	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8700		DH12D 380	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
8700		DH12D 420	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700											
9700		DH12D 340	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700		DH12D 380	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700		DH12D 420	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700		DH12E 340	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700		DH12E 380	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700		DH12E 420	VT2412B	0104-	104066-1	180051-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700		DH12D 340	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700		DH12D 380	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700		DH12D 420	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 
9700		DH12E 340	EGS-VR	0104-	104067-1	180052-34 	MFZ430	128989	430x50x24	DZO	⇐ 

9700		DH12E 380	EGS-VR	0104-	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	⇐	
9700		DH12E 420	EGS-VR	0104-	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	⇐	
9700		D12C 420	I-Shift	0901-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO		<
9700		DH12E 460	I-Shift	0710-	104460-1 ⊥	160522-33AM	MF430	128998	430x50x24	DZO		<
9700		D12C 460	I-Shift	0901-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO		<
9900												
9900		DH12D 420	VT2412B	0110-	104066-1	180051-34	MFZ430	128989	430x50x24	DZO	⇐	
9900		DH12E 420	VT2412B	0110-	104066-1	180051-34	MFZ430	128989	430x50x24	DZO	⇐	
9900		DH12D 420	EGS-VR	0110-	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	⇐	
9900		DH12E 420	EGS-VR	0110-	104067-1	180052-34	MFZ430	128989	430x50x24	DZO	⇐	
9900		D12C 420	I-Shift	0901-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO		<
9900		DH12E 460	I-Shift	0710-	104460-1 ⊥	160522-33AM	MF430	128998	430x50x24	DZO		<
9900		D12C 460	I-Shift	0901-	104461-1 ⊥	160521-33AM	MF430	128995	430x50x24	DZO		<



Drivenplate Bearing

180051-34 : 160070-34 + 125846K

180052-34 : 160070-34 + 125847K

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
ASTRA		13242345	128986	01908533	104082-1
114300	170052-35	504039135	162204-17	01908548	104082-1
122422	104082-1	1329549R	170052-35	2992486	125850
122442	104082-1	1375593R	1281405	2996743	104082-1
BOVA		1385522R	128986	4303053	125850
234502	128986	1409364R	164201-14	20569134	180051-34
267747	128986	1409478R	1281406	42062185	128986
270074	128986	1625968R	104070-1	42063099	128986
270574	128986	1689145R	128986	42100535	128986
1155874	125853	1706757R	104080-1	42100537	128986
20267747	128986	1736890R	104825-1	42102091	128986
20270074	128986	1740017R	104680-1	42102097	170052-35
20270574	128986	1789280R	104070-1	42102099	170052-35
20330806	128986	1789294R	104070-1	42102103	125850
20330807	128986	1789295R	104070-1	42102177	128986
30132605	125853	1808123R	104680-1	42102947	170052-35
41154221	125853	1813471R	128986	42103036	104082-1
41689108	128986	1814035R	104078-1	42104476	125850
DAF		1815112R	104680-1	42104793	128986
78544	170052-35	1815768R	104070-1	42104983	128986
78867	128986	1816435R	104080-1	42114680	128986
1140539	170052-35	1816436R	104080-1	42114856	125850
1142188	125853	1817774R	104680-1	42543362	125850
1154221	125853	1818190R	162204-17	42556650	125850
1239659	128986	1818190R	125978	50403994	162204-17
1272115	128986	1818191R	164201-14	50404993	1281405
1287597	128986	1818191R	125976	85000266	180051-34
1303560	128986	1820661R	104080-1	98435804	128986
1303975	125849	1820662R	104080-1	98435977	128986
1362752	125849	1829974R	170052-35	98436188	125850
1362759	128986	1829974R	128986	98484664	128986
1375593	1281405	1829974R	125854	98496006	128986
1375597	162204-17	1846416R	128986	99445713	128986
1385522	128986	1851348R	104070-1	99453752	128986
1400510	1281406	1851350R	104078-1	99463435	128986
1409478	1281406	1851351R	104070-1	500059766	104082-1
1440715	128986	1879929R	164201-14	500059768	170052-35
1614294	128986	1879929R	1281406	500059768	128986
1615927	125850	1935392R	104078-1	500059768	125850
1623295	128986	19353963R	104070-1	500059770	170052-35
1625968	104070-1	1935396R	104080-1	500059770	125850
1628626	104070-1	1935397R	104080-1	500 059 776	170053-35
1634627	125850	1935399R	104080-1	500059776	128992
1663218	128986	ATRB 246	125976	500059776	125850
1663224	128986	ATRB 247	125978	500 059 778	104093-1
1664346	125849	ATRB 257	164201-14	500059778	125850
1 665 428	170052-35	ATRB546	125976	500059788	104094-1
1685707	128986	EVOBUS		500301459	128986
1686642	125854	42508904	170052-35	500317671	125850
1688219	128986	202505703	128986	500335068	125850
1689108	128986	8383343000	170052-35	500335105	104082-1
1689145	128986	8383344000	170052-35	500335106	104082-1
1697725	125854	8383254000B	170052-35	500335107	104082-1
1702641	125976	A0012508815	125855	500371281	104082-1
1736890	104825-1	A0052508404	170052-35	500371282	104082-1
1738830	128986	FORD OTOSAN		500371283	104082-1
1740017	104680-1	7C467550BA	128986	500372079	128986
1746150	125854	T165054	128986	500372081	128986
1780332	125849	HINO		500372083	128986
1810168	125849	31230-1150A	125849	500376219	104082-1
1813471	128986	31230-E0030	125849	504004160	104082-1
1813472	128986	31250-6480A	128986	504034993	1281405
1814035	104078-1	IVECO		504039135	1281405
1822487	125854	1904751	170052-35	504064953	104082-1
1830316	125854	1904752	170052-35	504064954	128986
1912687	125854	1904779	170052-35	504068259	128986
1912689	125849	01904780	104082-1	504068261	104082-1
1935390	104070-1	01905703	104082-1	504068265	104082-1
				504120865	125850

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
504148901	125850	343 0169 10	128986	643 3253 00	104084-1
504 148 905	104093-1	343 0176 10	1281060	643 3260 00	1040109-1
504 148 906	104093-1	343 0184 10	128998	643 3267 00	104071-1
504149351	128992	343 0187 10	128992	643 3271 00	104073-1
504149354	128992	343 0192 10	128991	643 3284 00	104078-1
504 149 359	170053-35	343 0193 10	128992	643 3285 00	104080-1
504158912	125850	343 0205 10	128986	643 3288 00	104086-1
504222042	125850	343 0205 10	128988	643 3288 09	1040106-1
504 225 011	104093-1	343 0209 10	128986	643 3290 00	1040116-1
504225016	128992	343 0211 10	128986	643 3291 00	1040116-1
504 225 051	104093-1	343 0222 10	128991	643 3292 00	1040108-1
504229168	164201-14	500 0666 10	125856	643 3294 00	104096-1
504229170	1281406	500 0667 20	125855	643 3295 00	1040117-1
504237892	104094-1	500 0872 10	125845K	643 3301 00	1040118-1
504237895	125854	500 0872 20	125845K	643 3303 00	104076-1
504256059	128992	500 0889 10	125843K	643 3307 00	104082-1
504264337	104094-1	500 1038 20	125847K	643 3308 00	104092-1
504286000	104094-1	500 1071 20	125848K	643 3310 00	104086-1
504336615	128986	500 1072 20	125853	643 3313 00	104097-1
504336617	128986	500 1116 20	125857	643 3316 00	104074-1
504385079	125850	500 1158 10	125851	643 3317 00	104081-1
504385080	125854	500 1171 10	125854	643 3318 09	104461-1
504389742	164201-14	636 3005 09	104681-1	643 3319 00	104088-1
5000305439	125850	636 3011 00	104680-1	643 3320 00	104093-1
5006172148	125987	636 3025 09	104682-1	643 3324 09	104460-1
5801712140	128992	640 3006 00	104951-1	643 3326 00	104095-1
5801720105	128986	640 3006 18	104951-1	643 3327 00	1040104-1
500301459EZ	128986	640 3014 19	104823-1	643 3328 00	104089-1
LUK		640 3027 00	104952-1	643 3330 00	104094-1
643303600	104074-1	640 3027 18	104952-1	643 3343 00	104087-1
643309600	1040107-1	640 3032 00	104825-1	643 3383 00	104080-1
643 321 100	104067-1	640 3053 00	104952-1	643 3385 00	104080-1
643341900	1040115-1	640 3062 00	104822-1	643 3402 00	1040116-1
143 0203 10	170052-35	643 1026 09	104082-1	643 3415 00	1040121-1
143 0235 10	180050-35	643 2917 00	104072-1	643 3421 09	104460-1
143 0235 20	180050-35	643 2954 00	104083-1		
143 0239 10	170052-35	643 2981 00	104085-1	MACK	
143 0257 30	170052-35	643 3001 00	104070-1	2102889	160522-33AM
143 0288 20	170060-35	643 3001 10	104070-1	21459173	160521-33AM
143 0299 10	170050-35	643 3006 00	104083-1	21459176	128995
143 0299 20	170050-35	643 3007 00	104083-1	21593960	128995
143 0307 10	170061-38	643 3009 00	104082-1	MAN	
143 0307 20	170061-38	643 3009 50	104082-1	81303010420	128986
143 0312 10	170054-35	643 3013 00	104083-1	81303010545	128986
143 0312 20	170054-35	643 3013 00	104083-1	81303010546	128986
143 0331 10	170050-38	643 3014 00	1040100-1	81303010559	128986
143 0345 10	170052-35	643 3015 00	104099-1	81303010574	128986
143 0347 10	170052-35	643 3067 00	104074-1	81303019627	128986
143 0347 10	170052-35	643 3068 00	104074-1	81303050193	170052-35
143 0349 10	160521-33AM	643 3087 09	104065-1	81305500104	125850
143 0351 10	160522-33AM	643 3088 00	104070-1	81305500249	125854
143 0352 10	170053-35	643 3090 00	104074-1	36.30550.0001	125850
143 0355 10	170053-38	643 3117 00	1040107-1	64.30500.001	125851
143 9235 10	180050-35	643 3183 00	1040119-1	81.30000.6572	1040105-1
143 9341 10	180058-38	643 3184 00	104069-1	81.30000.6577	104091-1
143 9357 10	180056-34	643 3190 00	104083-1	81.30000.6579	104075-1
343 0055 10	128986	643 3201 00	104077-1	81.30000.6581	104077-1
343 0055 10	128988	643 3204 00	104068-1	81.30000.6582	104077-1
343 0134 10	128996	643 3205 00	104088-1	81.30000.6587	170052-35
343 0134 20	128996	643 3207 00	104091-1	81.30000.6587	125849
343 0135 10	128991	643 3209 00	1040105-1	81.30000.6592	1040105-1
343 0136 10	128991	643 3212 00	104074-1	81.30000.6593	104091-1
343 0137 10	128993	643 3214 00	104074-1	81.30000.6600	170052-35
343 0139 10	128995	643 3216 00	104066-1	81.30000.6600	125849
343 0144 10	128986	643 3217 00	104075-1	81.30000.6601	170052-35
343 0149 10	128997	643 3220 00	104067-1	81.30000.6602	170052-35
343 0149 20	128997	643 3221 00	104083-1	81.30000.6606	104075-1
343 0153 10	128986	643 3230 00	104090-1	81.30000.6617	104077-1
343 0157 10	128990	643 3250 00	104068-1	81.30000.6620	104091-1
				81.30000.6621	104091-1

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
81.30000.6628	104075-1	81.30301.9534	128986	0012504815	125856
81.30000.6630	104077-1	81.30301.9548	128986	0012504915	125855
81.30000.6634	104091-1	81.30301.9549	128986	0012506415	125856
81.30000.6635	104091-1	81.30301.9567	128986	0012506515	125856
81.30000.6650	104077-1	81.30301.9627	128986	0012506615	125855
81.30000.6653	104077-1	81.30301-0526	128993	0012506715	125855
81.30000.6654	104077-1	81.30301-0547	128986	0012507915	125856
81.30000.6657	104075-1	81.30301-0549	128986	0012508015	125855
81.30000.6673	104077-1	81.30301-0578	128986	0012508615	125856
81.30005.9012	104083-1	81.30301-9575	128993	0012508815	125855
81.30005.9013	104083-1	81.30305.0138	170052-35	0012508815	125855
81.30005.9018	104083-1	81.30305.0139	170052-35	0012509701	104074-1
81.30005.9020	104083-1	81.30305.0158	170052-35	0012509815	125856
81.30005.9021	104083-1	81.30305.0165	170052-35	0022500815	125855
81.30005.9022	104077-1	81.30305.0179	170052-35	0022500815	125855
81.30005.9023	104077-1	81.30305.0182	170052-35	0022503415	125843K
81.30005.9026	104091-1	81.30305.0191	170052-35	0022506315	125853
81.30005.9027	104091-1	81.30305.0194	170052-35	0022506815	125961K
81.30005.9028	104077-1	81.30305.0205	170054-35	0022507715	125961K
81.30005.9029	104083-1	81.30305.0213	170054-35	0022508215	125961K
81.30005.9032	104076-1	81.30305.0218	170054-35	0022508315	125853
81.30005.9033	104092-1	81.30305.0220	170054-35	0022509915	125961K
81.30005.9034	104077-1	81.30305.0232	164203-15	0032501415	125853
81.30005.9036	104091-1	81.30305.9191	170052-35	0032502215	125854
81.30005.9037	104077-1	81.30305.9193	170052-35	0032504815	125853
81.30005.9038	104091-1	81.30305.9194	170052-35	0032506915	125853
81.30301.0411	1281406	81.30305.9218	170054-35	0032508015	125854
81.30301.0416	128993	81.30305.9219	170055-35	0042504604	170052-35
81.30301.0420	128986	81.30305.9220	170054-35	0042506104	170052-35
81.30301.0448	128993	81.30305.9229	170055-35	0042508704	170052-35
81.30301.0450	1281406	81.30305.9232	164203-15	0042508904	170052-35
81.30301.0460	128986	81.30305-0204	170055-35	0052506204	170052-35
81.30301.0465	128986	81.30305-0214	170055-35	0052506404	180054-38
81.30301.0468	1281406	81.30305-0219	170055-35	0052506604	180054-38
81.30301.0469	1281406	81.30305-0221	170055-35	0052508404	170052-35
81.30301.0470	1281406	81.30305-0229	170055-35	0072502304	162203-12
81.30301.0476	128986	81.30305-0230	170054-35	0072502404	162203-12
81.30301.0478	128993	81.30305-0239	170055-35	0072505704	180058-38
81.30301.0490	1281406	81.30305-9204	170055-35	0072506104	180054-38
81.30301.0491	1281406	81.30305-9221	170055-35	007 2508004	180058-38
81.30301.0492	1281406	81.30305-9230	170054-35	0072508104	180054-38
81.30301.0503	128986	81.30550.0096	125850	0072509704	180054-38
81.30301.0506	128986	81.30550.0101	125850	0082502404	180054-38
81.30301.0507	128986	81.30550.0102	125850	0082502504	180058-38
81.30301.0514	128986	81.30550.0103	125849	0082503004	180054-38
81.30301.0520	1281406	81.30550.0109	125849	0082503204	180058-38
81.30301.0522	128993	81.30550.0113	125853	0082504404	180054-38
81.30301.0529	1281406	81.30550.0117	125853	0092500804	180054-38
81.30301.0533	128986	81.30550.0255	125854	0092500904	180058-38
81.30301.0534	128986	81.30550.0262	125978	0092502204	180054-38
81.30301.0538	128993	81.30550.0264	125854	0092508304	180054-38
81.30301.0548	128986	81.30550-0110	125849	0102500704	180054-38
81.30301.0556	1281406	81.30550-0114	125850	0102501104	180058-38
81.30301.0567	128986	81.30550-0116	125849	0102502104	180054-38
81.30301.0588	128986	81.30550-0251	125854	0102505703	128985
81.30301.0622	128986	82.30005.9004	104091-1	0102505803	128985
81.30301.0623	128986	82.30005.9005	104075-1	0132507403	128985
81.30301.0626	128986	82.30005.9006	1040105-1	0132507903	128985
81.30301.0627	128986	VA.30000.9434	104083-1	0132508703	128985
81.30301.0628	128986	VA.30000.9866	104077-1	0132508803	128985
81.30301.0636	128986	VA.30000.9876	104091-1	0142507603	128985
81.30301.6099	128986	MERCEDES-BENZ		0142507703	128985
81.30301.9465	128986	5001867644	162201-16	0142507803	128985
81.30301.9473	128993	5010452422	162201-16	0142508403	128986
81.30301.9476	128986	7420981951	162201-16	0152502403	128985
81.30301.9492	1281406	0002543008	125850	0152504603	1281404
81.30301.9506	128986	0002543208	125854	0152506303	1281404
81.30301.9514	128986	0012500515	125856	0152507903	1281409
81.30301.9533	128986	0012500615	125855	0152508003	1281409

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
0152508103	1281409	0212502201	1040108-1	0222501601	1040108-1
0152508103	1281409	0212502203	1281409	0222501701	104074-1
0162504003	128985	0212502501	162203-12	0222502001	128991
0162504103	128985	0212502703	128991	0222502301	180058-38
0162504203	128985	0212503003	128991	0222502301	128991
0162505003	128985	0212503401	104681-1	0222502601	1040108-1
0162508103	1281404	0212503501	104681-1	0222503001	104074-1
0162508203	1281404	0212503601	104824-1	0222503601	128991
0162508303	1281404	0212503701	104824-1	0222503801	104074-1
0162508403	1281404	0212503801	104823-1	0222503901	104074-1
0172500303	1281409	0212503901	104823-1	0222504301	104951-1
0172500303	1281409	0212503903	128991	0222504401	104951-1
0172500503	1281412	0212504001	128991	0222504801	104951-1
0172500603	1281412	0212504101	128991	0222504901	1281409
0172500903	1281409	0212504201	104074-1	0222505201	104951-1
0172501103	1281409	0212504301	104074-1	0222505601	104074-1
0182501103	1281409	0212504401	104074-1	0222505701	104074-1
0182501303	1281409	0212504501	104074-1	0222505801	104824-1
0182501803	1281404	0212504601	104074-1	0222505901	104824-1
0182506003	1281409	0212504701	104074-1	0222506201	104823-1
0182509101	104074-1	0212504801	104074-1	0222506301	104823-1
0182509203	1281412	0212504903	128991	0222508101	164202-10
0182509401	104681-1	0212505201	180058-38	0222508103	1281404
0182509501	104824-1	0212505201	128991	0222508203	1281404
0182509601	104823-1	0212505301	180058-38	0222508703	1281404
0182509701	104951-1	0212505301	128991	0222508803	1281404
0182509901	104074-1	0212505401	1040108-1	0242500101	128991
0192500001	104074-1	0212505501	1040108-1	0242500201	128991
0192500101	104074-1	0212505903	1281404	0242500401	128991
0192500201	104074-1	0212506001	104074-1	0242500501	104074-1
0192500501	104074-1	0212506003	1281412	0242500601	104074-1
0192503403	128986	0212506103	1281412	0242500603	1281409
0192504203	1281412	0212506201	104074-1	0242500801	104074-1
0192505203	1281409	0212506301	104074-1	0242500901	104074-1
0192506103	1281409	0212506401	104074-1	0242501001	104074-1
0192506501	104823-1	0212506403	1281404	0242501201	104074-1
0192509103	1281412	0212506501	104074-1	0242501401	104074-1
0192509403	1281404	0212506503	1281404	0242501501	104074-1
0192509503	1281404	0212506601	1281409	0242501701	104074-1
0192509603	1281404	0212506603	1281404	0242501703	1281412
0192509703	1281404	0212506701	1281409	0242502101	180058-38
0192509903	1281404	0212506703	1281404	0242502101	128991
0202500003	1281404	0212506801	104951-1	0242502103	1281412
0202500203	1281404	0212506803	1281404	0242502201	180058-38
0202500303	1281404	0212507201	1040108-1	0242502201	128991
0202503803	1281409	0212507301	1040108-1	0242502204	1040108-1
0202504303	128991	0212507501	104951-1	0242502401	180058-38
0202505001	104072-1	0212507603	1281409	0242502401	128991
0202505101	104099-1	0212508203	128991	0242502501	1040108-1
0202505601	104074-1	0212508303	128991	0242502601	1040108-1
0202508501	104074-1	0212508403	1281409	0242502801	1040108-1
0202508601	104074-1	0212508503	1281409	0242503401	128991
0202508701	104074-1	0212508601	104074-1	0242503701	104074-1
0202508901	104074-1	0212508603	128991	0242503801	104074-1
0202509101	104074-1	0212508703	1281409	0242504001	104074-1
0202509301	104074-1	0212508901	104824-1	0242504101	1281409
0202509401	1040108-1	0212509001	104823-1	0242504201	1281409
0202509403	1281409	0212509401	104074-1	0242504401	1281409
0202509801	1281409	0212509501	104074-1	0242504501	104951-1
0212500601	104074-1	0212509601	104074-1	0242504601	104951-1
0212500701	104951-1	0212509701	104074-1	0242504801	104951-1
0212500801	104074-1	0212509703	1281409	0242504901	104951-1
0212501003	1281404	0212509801	1040108-1	0242505101	104951-1
0212501303	128991	0212509901	1040108-1	0242505201	104951-1
0212501901	1040108-1	0222500901	104074-1	0242505601	104074-1
0212502001	1040108-1	0222501101	104074-1	0242505701	104074-1
0212502003	1281409	0222501401	104074-1	0242507401	128991
0212502101	1040108-1	0222501501	104074-1	0242507501	104074-1
0212502103	1281409	0222501503	1281409	0252502301	104681-1

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
0252502501	104681-1	A 004 250 46 04	170052-35	A 019 250 00 01	104074-1
0252503903	128991	A 004 250 61 04	170052-35	A 019 250 01 01	104074-1
0252504103	128991	A 004 250 87 04	170052-35	A 019 250 02 01	104074-1
0252504203	128991	A 004 250 89 04	170052-35	A 019 250 05 01	104074-1
0252504303	128991	A 005 250 62 04	170052-35	A 019 250 34 03	128986
0252508401	104074-1	A 005 250 64 04	180054-38	A 019 250 42 03	1281412
0252508501	104074-1	A 005 250 66 04	180054-38	A 019 250 52 03	1281409
0252508701	104951-1	A 005 250 84 04	170052-35	A 019 250 61 03	1281409
0262500903	128991	A 007 250 23 04	162203-12	A 019 250 65 01	104823-1
0262501003	128991	A 007 250 24 04	162203-12	A 019 250 91 03	1281412
0262503601	104074-1	A 007 250 57 04	180058-38	A 019 250 94 03	1281404
0262503701	1040108-1	A 007 250 61 04	180054-38	A 019 250 95 03	1281404
0262504101	104074-1	A 007 250 80 04	180058-38	A 019 250 96 03	1281404
0262504201	104074-1	A 007 250 81 04	180054-38	A 019 250 97 03	1281404
0262504301	104074-1	A 007 250 97 04	180054-38	A 019 250 99 03	1281404
0262504401	104074-1	A 008 250 24 04	180054-38	A 020 250 00 03	1281404
0262504501	104074-1	A 008 250 25 04	180058-38	A 020 250 02 03	1281404
0262504701	128991	A 008 250 30 04	180054-38	A 020 250 03 03	1281404
0262504801	104074-1	A 008 250 32 04	180058-38	A 020 250 38 03	1281409
0262504901	104074-1	A 008 250 44 04	180054-38	A 020 250 43 03	128991
0262505001	180058-38	A 009 250 08 04	180054-38	A 020 250 50 01	104072-1
0262505001	128991	A 009 250 09 04	180058-38	A 020 250 51 01	104099-1
0262505101	1040108-1	A 009 250 22 04	180054-38	A 020 250 56 01	104074-1
0262505201	1040108-1	A 009 250 83 04	180054-38	A 020 250 85 01	104074-1
0262505301	104074-1	A 010 250 07 04	180054-38	A 020 250 86 01	104074-1
0262505601	128991	A 010 250 11 04	180058-38	A 020 250 87 01	104074-1
0262505701	128991	A 010 250 21 04	180054-38	A 020 250 89 01	104074-1
0262505801	128991	A 010 250 57 03	128985	A 020 250 91 01	104074-1
0262505901	128991	A 010 250 58 03	128985	A 020 250 93 01	104074-1
0262506401	104074-1	A 013 250 74 03	128985	A 020 250 94 01	1040108-1
0262506501	104074-1	A 013 250 79 03	128985	A 020 250 94 03	1281409
0262506601	128991	A 013 250 87 03	128985	A 020 250 98 01	1281409
0262506701	104074-1	A 013 250 88 03	128985	A 021 250 06 01	104074-1
0262506801	104074-1	A 014 250 76 03	128985	A 021 250 07 01	104951-1
0262506901	104074-1	A 014 250 77 03	128985	A 021 250 08 01	104074-1
0262507001	180058-38	A 014 250 78 03	128985	A 021 250 10 03	1281404
0262507001	128991	A 014 250 84 03	128986	A 021 250 13 03	128991
0262507801	104951-1	A 015 250 24 03	128985	A 021 250 19 01	1040108-1
0262507901	104951-1	A 015 250 46 03	1281404	A 021 250 20 01	1040108-1
0262508101	104951-1	A 015 250 63 03	1281404	A 021 250 20 03	1281409
0262508301	1281409	A 015 250 79 03	1281409	A 021 250 21 01	1040108-1
0262508401	1281409	A 015 250 80 03	1281409	A 021 250 21 03	1281409
0262508501	104951-1	A 015 250 81 03	1281409	A 021 250 22 01	1040108-1
0262509401	104074-1	A 015 250 81 03	1281409	A 021 250 22 03	1281409
0272500001	1040108-1	A 016 250 40 03	128985	A 021 250 25 01	162203-12
0272500201	1040108-1	A 016 250 41 03	128985	A 021 250 27 03	128991
027250020180	1040108-1	A 016 250 42 03	128985	A 021 250 30 03	128991
A 000 254 30 08	125850	A 016 250 50 03	128985	A 021 250 34 01	104681-1
A 000 254 32 08	125854	A 016 250 81 03	1281404	A 021 250 35 01	104681-1
A 001 250 06 15	125855	A 016 250 82 03	1281404	A 021 250 36 01	104824-1
A 001 250 49 15	125855	A 016 250 83 03	1281404	A 021 250 37 01	104824-1
A 001 250 66 15	125855	A 016 250 84 03	1281404	A 021 250 38 01	104823-1
A 001 250 67 15	125855	A 017 250 03 03	1281409	A 021 250 39 01	104823-1
A 001 250 80 15	125855	A 017 250 03 03	1281409	A 021 250 39 03	128991
A 001 250 88 15	125855	A 017 250 05 03	1281412	A 021 250 40 01	128991
A 001 250 97 01	104074-1	A 017 250 06 03	1281412	A 021 250 41 01	128991
A 002 250 08 15	125855	A 017 250 09 03	1281409	A 021 250 42 01	104074-1
A 002 250 34 15	125843K	A 017 250 11 03	1281409	A 021 250 43 01	104074-1
A 002 250 63 15	125853	A 018 250 11 03	1281409	A 021 250 44 01	104074-1
A 002 250 68 15	125961K	A 018 250 13 03	1281409	A 021 250 45 01	104074-1
A 002 250 77 15	125961K	A 018 250 18 03	1281404	A 021 250 46 01	104074-1
A 002 250 82 15	125961K	A 018 250 60 03	1281409	A 021 250 47 01	104074-1
A 002 250 83 15	125853	A 018 250 91 01	104074-1	A 021 250 48 01	104074-1
A 002 250 99 15	125961K	A 018 250 92 03	1281412	A 021 250 49 03	128991
A 003 250 14 15	125853	A 018 250 94 01	104681-1	A 021 250 52 01	180058-38
A 003 250 22 15	125854	A 018 250 95 01	104824-1	A 021 250 52 01	128991
A 003 250 48 15	125853	A 018 250 96 01	104823-1	A 021 250 53 01	180058-38
A 003 250 69 15	125853	A 018 250 97 01	104951-1	A 021 250 53 01	128991
A 003 250 80 15	125854	A 018 250 99 01	104074-1	A 021 250 54 01	1040108-1

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
A 021 250 55 01	1040108-1	A 024 250 02 01	128991	A 026 250 58 01	128991
A 021 250 59 03	1281404	A 024 250 04 01	128991	A 026 250 59 01	128991
A 021 250 60 01	104074-1	A 024 250 05 01	104074-1	A 026 250 64 01	104074-1
A 021 250 60 03	1281412	A 024 250 06 01	104074-1	A 026 250 65 01	104074-1
A 021 250 61 03	1281412	A 024 250 06 03	1281409	A 026 250 66 01	128991
A 021 250 62 01	104074-1	A 024 250 08 01	104074-1	A 026 250 67 01	104074-1
A 021 250 63 01	104074-1	A 024 250 09 01	104074-1	A 026 250 68 01	104074-1
A 021 250 64 01	104074-1	A 024 250 10 01	104074-1	A 026 250 69 01	104074-1
A 021 250 64 03	1281404	A 024 250 12 01	104074-1	A 026 250 70 01	180058-38
A 021 250 65 01	104074-1	A 024 250 14 01	104074-1	A 026 250 70 01	128991
A 021 250 65 03	1281404	A 024 250 15 01	104074-1	A 026 250 78 01	104951-1
A 021 250 66 01	1281409	A 024 250 17 01	104074-1	A 026 250 79 01	104951-1
A 021 250 66 03	1281404	A 024 250 17 03	1281412	A 026 250 81 01	104951-1
A 021 250 67 01	1281409	A 024 250 21 01	180058-38	A 026 250 83 01	1281409
A 021 250 67 03	1281404	A 024 250 21 01	128991	A 026 250 84 01	1281409
A 021 250 68 01	104951-1	A 024 250 21 03	1281412	A 026 250 85 01	104951-1
A 021 250 68 03	1281404	A 024 250 22 01	180058-38	A 026 250 94 01	104074-1
A 021 250 72 01	1040108-1	A 024 250 22 01	128991	A 027 250 00 01	1040108-1
A 021 250 73 01	1040108-1	A 024 250 22 04	1040108-1	A 027 250 02 01	1040108-1
A 021 250 75 01	104951-1	A 024 250 24 01	180058-38	NEOPLAN	
A 021 250 76 03	1281409	A 024 250 24 01	128991	11009985	170052-35
A 021 250 82 03	128991	A 024 250 25 01	1040108-1	11009986	170052-35
A 021 250 83 03	128991	A 024 250 26 01	1040108-1	11079828	128986
A 021 250 84 03	1281409	A 024 250 28 01	1040108-1	11010039	125855
A 021 250 85 03	1281409	A 024 250 34 01	128991	NISSAN	
A 021 250 86 01	104074-1	A 024 250 37 01	104074-1	21173118	160522-33AM
A 021 250 86 03	128991	A 024 250 38 01	104074-1	21173120	160521-33AM
A 021 250 87 03	1281409	A 024 250 40 01	104074-1	RENAULT TRUCKS	
A 021 250 89 01	104824-1	A 024 250 41 01	1281409	5 000 677 165	1281415
A 021 250 90 01	104823-1	A 024 250 42 01	1281409	5 000 677 295	1281415
A 021 250 94 01	104074-1	A 024 250 44 01	1281409	5 001 837 123	170050-35
A 021 250 95 01	104074-1	A 024 250 45 01	104951-1	5 001 850 396	1040109-1
A 021 250 96 01	104074-1	A 024 250 46 01	104951-1	5 001 858 682	125850
A 021 250 97 01	104074-1	A 024 250 48 01	104951-1	5 001 864 270	125850
A 021 250 97 03	1281409	A 024 250 49 01	104951-1	5 001 866 299	104089-1
A 021 250 98 01	1040108-1	A 024 250 51 01	104951-1	5 001 866 891	104084-1
A 021 250 99 01	1040108-1	A 024 250 52 01	104951-1	5 001 867 227	104081-1
A 022 250 09 01	104074-1	A 024 250 56 01	104074-1	5 001 868 537	104460-1
A 022 250 11 01	104074-1	A 024 250 57 01	104074-1	5 001 868 537	128998
A 022 250 14 01	104074-1	A 024 250 74 01	128991	5 001 872 322	104822-1
A 022 250 15 01	104074-1	A 024 250 75 01	104074-1	5 001 872 324	104822-1
A 022 250 15 03	1281409	A 025 250 23 01	104681-1	5 001 873 287	125850
A 022 250 16 01	1040108-1	A 025 250 25 01	104681-1	5001878531	1040104-1
A 022 250 17 01	104074-1	A 025 250 39 03	128991	5 010 244 017	125987
A 022 250 20 01	128991	A 025 250 41 03	128991	5 010 244 097	170050-35
A 022 250 23 01	180058-38	A 025 250 42 03	128991	5 010 244 202	125987
A 022 250 23 01	128991	A 025 250 43 03	128991	5 010 244 203	170050-35
A 022 250 26 01	1040108-1	A 025 250 84 01	104074-1	5 010 244 225	125960
A 022 250 30 01	104074-1	A 025 250 85 01	104074-1	5 010 244 265	170050-35
A 022 250 36 01	128991	A 025 250 87 01	104951-1	5 010 245 457	125857
A 022 250 38 01	104074-1	A 026 250 09 03	128991	5 010 245 921	125857
A 022 250 39 01	104074-1	A 026 250 10 03	128991	5010452533	104097-1
A 022 250 43 01	104951-1	A 026 250 36 01	104074-1	5 010 545 831	1281403
A 022 250 44 01	104951-1	A 026 250 37 01	1040108-1	5 010 545 836	170055-35
A 022 250 48 01	104951-1	A 026 250 41 01	104074-1	5 010 545 851	128992
A 022 250 49 01	1281409	A 026 250 42 01	104074-1	5010545988	125977
A 022 250 52 01	104951-1	A 026 250 43 01	104074-1	5 010 613 151	1281403
A 022 250 56 01	104074-1	A 026 250 44 01	104074-1	5 010 613 658	128992
A 022 250 57 01	104074-1	A 026 250 45 01	104074-1	5 010 837 119	170050-35
A 022 250 58 01	104824-1	A 026 250 47 01	128991	7 420 707 020	180055-34
A 022 250 59 01	104824-1	A 026 250 48 01	104074-1	7 420 707 022	180051-34
A 022 250 62 01	104823-1	A 026 250 49 01	104074-1	7 420 707 024	128989
A 022 250 63 01	104823-1	A 026 250 50 01	180058-38	7 420 725 523	128995
A 022 250 81 01	164202-10	A 026 250 50 01	128991	7 420 725 524	128998
A 022 250 81 03	1281404	A 026 250 51 01	1040108-1	7 420 730 007	125846K
A 022 250 82 03	1281404	A 026 250 52 01	1040108-1	7 420 812 085	160521-33AM
A 022 250 87 03	1281404	A 026 250 53 01	104074-1	7 420 812 086	160522-33AM
A 022 250 88 03	1281404	A 026 250 56 01	128991	7 420 959 262	1281403
A 024 250 01 01	128991	A 026 250 57 01	128991		

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
7 420 998 835	125857	1878002731	128991	3151000278	125856
7 421 134 335	160522-33AM	1878002733	128986	3151000335	125853
7421188863	125977	1878002733	128988	3151000395	125978
7421371759	125848K	1878002735	128985	3151000397	125976
7 421 371 760	125848K	1878003065	128996	3151000493	125854
7 421 593 951	128995	1878003066	128990	3151000547	125855
7 421 916 049	1281403	1878003647	128986	3151000752	125977
7 485 013 741	104460-1	1878003767	128986	3151169332	125849
7 485 013 741	128998	1878003768	1281410	3151225031	125850
7 485 013 826	104822-1	1878003839	1281060	3151241031	125855
7485127008	125854	1878003839	1281401	3151245031	125855
2072 552 5	160522-33AM	1878003867	128998	3151246031	125856
2072 552 6	160521-33AM	1878003868	128995	3151250231	125987
2073 000 7	125846K	1878003968	128992	3151259001	125843K
50 01 854 688	104084-1	1878003969	1281401	3151259031	125843K
50 01 866 297	104066-1	1878004104	128993	3151273431	125849
50 01 868 533	104461-1	1878004132	128992	3151273731	125853
50 10 545 582	170053-38	1878004832	128986	3151274101	125857
50 10 613 659	170055-35	1878005031	1281409	3151274131	125857
74 21 074 314	170055-35	1878005165	128991	3151277531	125848K
74 21 235 561	1281410	1878006129	128995	3151278941	125960
74 85 003 693	1040115-1	1878006370	1281401	3400043032	104085-1
74 85 003 694	1040121-1	1 878006584	128998	3400048031	104082-1
74 85 013 830	104461-1	1878007072	128991	3400117801	104082-1
7420 702 2	180051-34	1878007120	1281401	3400121201	104824-1
SACHS		1878007123	1281402	3400121301	104823-1
1273	170052-35	1878007253	1281060	3400121501	104951-1
1450	170050-38	1878007253	1281401	3400122001	104065-1
1482	180050-35	1878023831	1281404	3400122101	104070-1
1497	180054-38	1878023931	1281404	3400122201	104083-1
1498	180052-34	1878032131	1281413	3400122601	104072-1
1511	170060-35	1878032133	1281413	3400122801	104074-1
1542	170052-35	1878032331	128997	3400122901	104099-1
1555	180053-34	1878037631	128990	3400123701	1040107-1
3308	125848K	1878037834	128986	3400125401	104083-1
3350	125851	1878038041	128993	3400127101	104069-1
3352	125845K	1878047333	1281406	3400127201	1040119-1
3363	125847K	1878048741	1281412	3400127401	104077-1
3366	125850	1878052842	1281412	3400127501	104083-1
3388	125961K	1878054031	128988	3400127701	104681-1
3390	125853	1878054933	128986	3400127901	1040100-1
5523	1281412	1878056331	1281409	3400128001	104073-1
5582	1281409	1878056732	128996	3400700303	104682-1
5583	1281410	1878063231	128990	3400700304	104070-1
5698	128989	1878063531	1281406	3400700307	104680-1
5726	1281404	1878079331	1281406	3400700308	104825-1
5765	1281404	1878080035	128986	3400700314	104077-1
6542	104082-1	1878080037	128986	3400700324	1040106-1
1 862 190 139	1281409	1878085741	128986	3400700332	104097-1
1 862 335 032	1281411	1878634024	128991	3400700333	1040109-1
1862379031	1281415	1878634026	128986	3400700334	104084-1
1862415031	1281417	1878634026	128988	3400700342	104067-1
1862453 031	128985	1878634027	128986	3400700343	104068-1
1862519034	128991	1878634028	128986	3400700350	104066-1
1862519240	128991	1878634034	1281403	3400700351	104089-1
1862530231	1281411	3100000003	125961K	3400700352	104086-1
1878000036	1281405	3100002459	125847K	3400700354	104071-1
1878000116	128985	3100002460	125846K	3400700355	104951-1
1878000300	1281410	3100002464	125848K	3400700356	104071-1
1878000634	128989	3100008101	125845K	3400700357	104088-1
1878000948	128995	3100008201	125845K	3400700358	104460-1
1878001760	1281409	3100026431	125846K	3400700359	104461-1
1878001938	128993	3100026434	125847K	3400700360	104952-1
1878002019	1281409	3100026531	125848K	3400700361	104078-1
1878002024	1281409	3151000034	125849	3400700366	104094-1
1878002139	128993	3151000144	125850	3400700368	104080-1
1878002437	1281413	3151000151	125851	3400700370	1040116-1
1878002504	128988	3151000155	125843K	3400700371	1040116-1
1878002730	128991	3151000217	125848K	3400700372	104096-1

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
3400700373	1040118-1	3482083150	170060-35	323400000299	125850
3400700374	1040117-1	3482083219	170052-35	323400000320	104087-1
3400700380	104077-1	3482083252	170050-35	323400000354	104090-1
3400700381	104076-1	3482123247	170050-35	323400000361	1040108-1
3400700382	104095-1	3482123534	170055-35	323400000362	180058-38
3400700393	104082-1	3482123839	162204-17	323400000362	128991
3400700399	104081-1	3482124731	170061-38	323400000363	104074-1
3400700401	104090-1	3482634003	162201-16	323400000364	104074-1
3400700402	104091-1	3483000258	180058-38	323400000450	104074-1
3400700403	104075-1	3483000348	180057-34	323400000457	128991
3400700404	1040105-1	3483000382	180056-34	323400000485	1040108-1
3400700413	104074-1	3483020036	180050-35	323400000486	104074-1
3400700415	104074-1	3483020037	180052-34	323400000487	104074-1
3400700422	104952-1	3483030032	180054-38	323400000522	128991
3400700435	104080-1	3483034033	180052-34	323400000524	104074-1
3400700438	1040121-1	3483034034	180053-34	323400000536	104088-1
3400700445	104092-1	3483034035	180057-34	323400000538	104088-1
3400700446	1040108-1	3483034042	180051-34	323400000540	104088-1
3400700450	104076-1	3483034043	180055-34	323400000541	104069-1
3400700453	104082-1	3488000024	181202-22	323400000542	104068-1
3400700459	104092-1	3488000158	181201-22	323400000543	104069-1
3400700460	104091-1	3488000159	181202-22	323400000544	104069-1
3400700461	104093-1	3488017439	181204-22	323400000545	104068-1
3400700463	104088-1	3488019031	181205-14	323400000552	104088-1
3400700466	104822-1	3488022253	181203-22	323400000559	104085-1
3400700467	104080-1	3488023031	181201-22	323400000560	104067-1
3400700468	104074-1	9482273000	170052-35	323400000562	180052-34
3400700470	1040104-1	9482277000	170060-35	323400000577	104087-1
3400700478	104087-1	9483014000	180050-35	323400000584	104085-1
3400700479	104460-1	153400000681	104680-1	323400000587	104085-1
3400700488	104080-1	153400000740	104680-1	323400000591	180051-34
3400700489	104080-1	153400000741	104680-1	323400000626	104074-1
3400700491	1040116-1	153400000872	1281406	323400000627	104074-1
3400700495	1040115-1	153400127701	104681-1	323400000628	1040108-1
3400700610	1040116-1	183400000160	1281405	323400000629	1040108-1
3400700611	1040116-1	183400000258	104823-1	323400000630	1040108-1
3400700617	1040108-1	183400000372	104825-1	323400000631	104074-1
3482000096	170054-35	183400000728	104824-1	323400000632	104074-1
3482000195	170055-35	183400000729	104823-1	323400000633	128991
3482000196	170054-35	183400121201	104824-1	323400000634	128991
3482000246	170055-35	183400121301	104823-1	323400000636	104070-1
3482000251	170050-38	183400128101	104824-1	323400000638	1040108-1
3482000257	170051-38	183400128201	104823-1	323400000639	180058-38
3482000282	160521-33AM	323400000019	125850	323400000639	128991
3482000283	160521-33AM	323400000021	104067-1	323400000646	104070-1
3482000355	160521-33AM	323400000023	104067-1	323400000647	104070-1
3482000356	160521-33AM	323400000027	104067-1	323400000660	170052-35
3482000361	170054-35	323400000028	104068-1	323400000660	128986
3482000419	164201-14	323400000029	104088-1	323400000660	125850
3482000461	164203-15	323400000048	104070-1	323400000661	170052-35
3482000462	164202-10	323400000093	104067-1	323400000661	125850
3482000463	162202-16	323400000108	180051-34	323400000682	104074-1
3482000464	162203-12	323400000108	128988	323400000683	104074-1
3482000484	170052-35	323400000113	104088-1	323400000684	128991
3482000552	160522-33AM	323400000127	104072-1	323400000687	128991
3482000553	160521-33AM	323400000128	104099-1	323400000688	104074-1
3482000572	170053-35	323400000140	170055-35	323400000690	104074-1
3482000677	160521-33AM	323400000148	104082-1	323400000692	1040108-1
3482000691	170053-38	323400000167	104074-1	323400000693	1040108-1
3482000794	160521-33AM	323400000169	104074-1	323400000693	128991
3482000999	170101-33	323400000172	104074-1	323400000721	104078-1
3482081231	170052-35	323400000186	1040108-1	323400000727	104070-1
3482081233	170052-35	323400000188	104074-1	323400000730	180054-38
3482083032	170052-35	323400000269	1040108-1	323400000753	104080-1
3482083032	170052-35	323400000271	104070-1	323400000759	170052-35
3482083034	170052-35	323400000289	104068-1	323400000759	128986
3482083038	170052-35	323400000299	170053-35	323400000759	125854
3482083041	170052-35	323400000299	170053-38	323400000802	1040108-1
3482083119	170052-35	323400000299	128992	323400000807	104083-1

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
323400000811	104076-1	323482000214	170055-35	323483000288	180053-34
323400000830	104078-1	323482000226	170054-35	323483000296	180052-34
323400000860	180052-34	323482000237	170052-35	323483000297	180052-34
323400000861	180051-34	323482000246	170055-35	323483000315	180054-38
323400000863	104068-1	323482000251	170050-38	323483000318	180058-38
323400000874	104087-1	323482000257	170051-38	323483000333	180054-38
323400000876	104074-1	323482000301	170052-35	323483000334	180058-38
323400000877	104074-1	323482000318	170053-35	323483000357	180054-38
323400000946	104074-1	323482000318	170053-38	323483000382	180056-34
323400000947	1040108-1	323482000333	170051-38	323483000394	180054-38
323400000950	104074-1	323482000361	170054-35	323483000395	180054-38
323400000951	104074-1	323482000471	170052-35	323483000418	180052-34
323400000952	104074-1	323482000484	170052-35	323483000420	180056-34
323400000953	104074-1	323482000514	170050-35	323483000424	180051-34
323400000954	104074-1	323482000535	170052-35	323483000425	180051-34
323400000955	128991	323482000572	170053-35	323483000448	180054-38
323400000956	128991	323482000572	170053-38	323483000452	180058-38
323400000958	104074-1	323482000675	170054-35	323483000455	180054-38
323400000960	1040108-1	323482000691	170053-38	323483000480	180056-34
323400000961	1040108-1	323482001158	180056-34	323483020006	180050-35
323400000962	104074-1	323482062003	170052-35	323483020007	180052-34
323400000969	128991	323482081201	170052-35	323483020036	180050-35
323400001041	128991	323482081203	170052-35	323483020037	180052-34
323400001042	104074-1	323482081231	170052-35	323483020107	180052-34
323400001043	104074-1	323482081233	170052-35	323483020206	180050-35
323400001044	128991	323482081301	170052-35	323483020207	180052-34
323400001046	104074-1	323482081303	170052-35	323483020307	180052-34
323400001047	180058-38	323482083001	170052-35	323483030032	180054-38
323400001047	128991	323482083032	170052-35	323483030102	180054-38
323400001048	104074-1	323482083038	170052-35	323483030103	180054-38
323400001053	128991	323482083102	170052-35	323483034003	180052-34
323400001055	128991	323482083105	170052-35	323483034004	180053-34
323400001058	1040117-1	323482083108	170052-35	323483034005	180057-34
323400001061	104070-1	323482083120	170060-35	323483034008	180053-34
323400001063	104078-1	323482083150	170060-35	323483034009	180057-34
323400001064	104070-1	323482083222	170050-35	323483034012	180051-34
323400001068	104080-1	323482083252	170050-35	323483034013	180055-34
323400001077	104074-1	323482117002	180054-38	323483034016	180053-34
323400001091	1040108-1	323482117002	180058-38	323483034017	180057-34
323400026001	170052-35	323482123201	180056-34	323483034019	180052-34
323400043032	104085-1	323482123247	170050-35	323483034024	180053-34
323400117801	104082-1	323482123505	170054-35	323483034025	180057-34
323400117901	104082-1	323482123507	170055-35	323483034033	180052-34
323400119501	104082-1	323482123512	170055-35	323483034034	180053-34
323400119601	104082-1	323482129201	170052-35	323483034035	180057-34
323400120301	104082-1	323483000023	180054-38	323483034042	180051-34
323400120601	104090-1	323483000025	180058-38	323483034043	180055-34
323400122001	104065-1	323483000037	180051-34	323483035902	180058-38
323400122101	104070-1	323483000038	180055-34	329483015000	180052-34
323400122201	104083-1	323483000041	180052-34	343100000003	125961K
323400122601	104072-1	323483000076	180055-34	343100000008	125845K
323400122801	104074-1	323483000078	180051-34	343100000010	125848K
323400122901	104099-1	323483000116	180054-38	343100000012	125847K
323400125401	104083-1	323483000137	180056-34	343100000014	125846K
323400127101	104069-1	323483000168	180057-34	343100000021	125846K
323400127501	104083-1	323483000169	180053-34	343100000048	125845K
323400127901	1040100-1	323483000197	180054-38	343100000054	125961K
323400128001	104073-1	323483000199	180058-38	343100000062	125961K
323400700401	104090-1	323483000226	180054-38	343100000079	125961K
323482000004	170055-35	323483000228	180058-38	343100000086	125961K
323482000014	170054-35	323483000233	180054-38	343100000116	125848K
323482000019	170055-35	323483000258	180058-38	343100000117	125848K
323482000020	170055-35	323483000267	180053-34	343100000140	125848K
323482000023	170050-38	323483000269	180052-34	343100002526	125961K
323482000024	170051-38	323483000271	180056-34	343100008201	125845K
323482000048	170053-38	323483000274	180051-34	343100026401	125846K
323482000086	170055-35	323483000275	180051-34	343100026404	125847K
323482000096	170054-35	323483000278	180055-34	343100026431	125846K
323482000196	170054-35	323483000279	180055-34	343100026434	125847K

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
343100026501	125848K	343151000994	125854	391878023912	1281404
343100026531	125848K	343151000995	125854	391878023913	1281404
343151000028	125843K	343151001003	125850	391878023931	1281404
343151000029	125849	343151001058	125850	391878049302	1281405
343151000034	125849	343151001064	125847K	391878049304	1281405
343151000042	125961K	343151001065	125848K	393400000189	1281409
343151000052	125850	343151225103	125850	393400000309	104951-1
343151000053	125849	343151225203	125850	393400000453	104951-1
343151000054	125853	343151225303	125850	393400000455	104951-1
343151000064	125843K	343151260001	125961K	393400000458	1281409
343151000083	125961K	343151260001	125977	393400000488	104952-1
343151000111	125851	343151274101	125857	393400000613	104952-1
343151000118	125848K	343151274131	125857	393400000641	104951-1
343151000141	125853	343151277404	125848K	393400000644	104951-1
343151000144	125850	343151278941	125960	393400000645	1281409
343151000151	125851	343151281101	125851	393400000699	1281409
343151000155	125843K	343151281701	125848K	393400000701	1281409
343151000156	125961K	343151281702	125847K	393400000702	1281409
343151000163	125847K	343400000649	104461-1	393400000702	1281409
343151000185	125851	343400000739	104460-1	393400000736	104951-1
343151000197	125851	343400000851	104461-1	393400000738	104951-1
343151000217	125848K	343400000855	104461-1	393400000856	104951-1
343151000236	125848K	343400000913	104461-1	393400000963	104951-1
343151000278	125856	343482000280	160522-33AM	393400000964	1281409
343151000299	125854	343482000281	160522-33AM	393400000966	104951-1
343151000308	125849	343482000282	160521-33AM	393400000967	1281409
343151000331	125853	343482000283	160521-33AM	393400001049	104951-1
343151000335	125853	343482000352	160522-33AM	393400001051	1281409
343151000339	125849	343482000353	160522-33AM	393400121501	104951-1
343151000356	125854	343482000355	160521-33AM	401862415001	1281417
343151000366	125854	343482000356	160521-33AM	401862415031	1281417
343151000391	125854	343482000552	160522-33AM	421862190109	1281409
343151000408	125850	343482000553	160521-33AM	421862190139	1281409
343151000424	125854	343482000592	160522-33AM	421862379001	1281415
343151000455	125854	343482000594	160522-33AM	421862379031	1281415
343151000466	125853	343482000596	160522-33AM	421878000300	1281410
343151000468	125853	343482000676	160522-33AM	421878000547	1281410
343151000490	125856	343482000677	160521-33AM	421878001263	1281409
343151000493	125854	343482000794	160521-33AM	421878001841	1281409
343151000519	125849	381878000666	1281406	421878001842	1281409
343151000519	125961K	381878000891	1281406	421878001843	1281409
343151000547	125855	381878001621	1281406	421878002019	1281409
343151000548	125855	381878001869	1281406	421878002024	1281409
343151000552	125848K	381878003236	1281406	421878002437	1281413
343151000553	125847K	381878004238	1281406	421878002884	1281409
343151000559	125843K	3818780048741	1281412	421878004019	1281409
343151000560	180058-38	381878049402	1281406	421878004219	1281409
343151000560	125961K	381878052812	1281412	421878004693	1281409
343151000583	125850	381878052842	1281412	421878004962	1281410
343151000590	125843K	381878079301	1281406	421878005001	1281409
343151000609	125843K	381878079302	1281406	421878005031	1281409
343151000610	125961K	381878079305	1281406	421878005578	1281409
343151000642	125848K	381878079331	1281406	421878006527	1281409
343151000679	125854	391861999052	1281404	421878032101	1281413
343151000683	125853	391878000036	1281405	421878032103	1281413
343151000689	125853	391878000152	1281404	421878056301	1281409
343151000690	125854	391878000954	1281404	421878056304	1281409
343151000696	125850	391878002224	1281404	421878056305	1281409
343151000697	125850	391878002523	1281404	421878056331	1281409
343151000731	125851	391878023801	1281404	421878062502	1281410
343151000757	125843K	391878023802	1281404	491862298002	128988
343151000762	125961K	391878023803	1281404	491862298201	128988
343151000819	125847K	391878023813	1281404	491862298504	128988
343151000842	125854	391878023814	1281404	491862326102	128990
343151000844	125854	391878023831	1281404	491862334002	128986
343151000851	125851	391878023901	1281404	491862334003	128986
343151000859	125848K	391878023902	1281404	491862334102	128986
343151000971	125853	391878023910	1281404	491862334202	128986
343151000984	125850	391878023911	1281404	491862334204	128986

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
491862334302	128986	491878004653	128995	491878080011	128986
491862461102	128990	491878004707	128990	491878080037	128986
491862530201	1281411	491878004832	128986	491878085741	128986
491862530202	1281411	491878004940	128998	491878085901	128998
491862530203	1281411	491878004970	128995	491878086001	128995
491862530231	1281411	491878004971	128995	861862298002	128988
491878000197	128986	491878004974	128995	861862379031	1281415
491878000520	128989	491878005165	128991	861862530202	1281411
491878000597	1281401	491878005297	128995	861862530231	1281411
491878000599	1281060	491878005381	128986	861878000036	1281405
491878000599	1281401	491878005433	128986	861878000634	128989
491878000634	128989	491878005476	128995	861878023831	1281404
491878000638	128986	491878005482	128995	861878023931	1281404
491878001194	128991	491878005493	128995	861878032331	128997
491878001251	128986	491878005494	128995	861878048741	1281412
491878001505	128989	491878005495	128995	861878049302	1281405
491878001532	128998	491878005734	128986	861878054001	128988
491878001533	128995	491878005795	1281060	861878054031	128988
491878001546	128991	491878005795	1281401	861878054903	128986
491878001607	128986	491878005797	1281401	861878056301	1281409
491878001616	128993	491878005923	1281402	861878056331	1281409
491878001657	128986	491878005933	128986	861878063201	128990
491878001698	128986	491878005978	128986	861878085741	128986
491878001818	128986	491878005979	128986	863400043032	104085-1
491878001887	128986	491878006043	128986	863400043102	104085-1
491878001957	128998	491878006129	128995	863400043103	104085-1
491878001958	128995	491878006370	1281401	863400120503	104085-1
491878001986	128996	491878006515	128992	863400120601	104090-1
491878002016	128990	491878006525	128991	863400120801	104069-1
491878002086	128986	491878006731	128991	863400700401	104090-1
491878002137	128992	491878006732	128991	863482081201	170052-35
491878002139	128993	491878006733	128991	863482081231	170052-35
491878002226	128986	491878006753	128992	863482081233	170052-35
491878002279	128991	491878006767	128986	863482081301	170052-35
491878002353	128992	491878006792	128986	863482081303	170052-35
491878002354	128992	491878007072	128991	863482083032	170052-35
491878002462	128986	491878007120	1281401	863482083103	170052-35
491878002463	128986	491878007163	128991	863482083150	170060-35
491878002467	128986	491878007164	128991	863483020036	180050-35
491878002534	128991	491878007253	1281060	863483030032	180054-38
491878002535	128991	491878007253	1281401	863483030102	180054-38
491878002731	128991	491878030204	128996	863483034003	180052-34
491878002733	128988	491878032301	128997	863483034007	180052-34
491878002735	128985	491878032303	128997	863483034012	180051-34
491878002788	128986	491878032304	128997	863483034033	180052-34
491878003065	128996	491878032305	128997	863483034034	180053-34
491878003066	128990	491878032306	128997	863483034035	180057-34
491878003229	128992	491878032307	128997	3151000163	125847K
491878003384	128986	491878032331	128997	003180000102	125961K
491878003437	128992	491878037828	128986	1273 03	170052-35
491878003647	128986	491878054001	128988	1498 03	180052-34
491878003767	128986	491878054003	128988	1511 03	170060-35
491878003807	128986	491878054004	128989	1555 03	180053-34
491878003839	1281060	491878054005	128989	186237900142	1281415
491878003839	1281401	491878054009	128989	186241503140	1281417
491878003867	128998	491878054031	128988	186253023149	1281411
491878003868	128995	491878054901	128986	187802393139	1281404
491878003968	128992	491878054903	128986	187803210342	1281413
491878003969	1281401	491878054905	128986	187804874138	1281412
491878004132	128992	491878054933	128986	187806323149	128990
491878004224	128991	491878056732	128996	348208315032	170060-35
491878004242	128986	491878058309	128985	348302003632	180050-35
491878004250	128986	491878061204	128986	5582 03	1281409
491878004285	1281402	491878063201	128990	BA 1878 032 103	1281413
491878004286	128996	491878063231	128990	F8379A	1281415
491878004342	128986	491878066102	128992		
491878004566	128998	491878076501	128988		
491878004605	128986	491878079401	128986		
491878004606	128986	491878080007	128986		
				SCANIA	
				571268	128990
				571269	170061-38
				571270	128996

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
571271	128990	1513718	170051-38	K432-41	1281060
571289	170060-35	1513719	170050-38	k432-44	125851
571300	128990	1513720	170050-38	k432-48	125851
571305	128990	1522424	170051-38	k432-54	170051-38
571310	128996	1527227	1281401	k432-55	170051-38
571315	170051-38	1574912	1281401	K432-62	1281060
571316	1281060	1728165	125851	k432-62	125851
571316	1281401	1749123	128990	k432-7	1040107-1
571317	1281401	1749124	128996	k432-8	1040107-1
571324	170051-38	1749125	125851		
571447	128990	1785010	1281401	SISU	
572943	104096-1	1851631	125851	1302001251	1040109-1
572944	1040116-1	1898019	128996	1302001291	1040110-1
572945	1040116-1	1929397	128990	1302104341	128986
572947	1040118-1	2009984	1281402	1302104371	128992
572948	104096-1	2009987	1281401	1302404351	170053-38
572949	1040116-1	2077903	1281060	1305030321	125960
572950	1040116-1	2077903	1281401	621302404321	170052-35
572953	104086-1	2085861	1281401		
572953	104096-1	2085862	1281401	STEYR	
572954	1040117-1	2085863	1281060	81303050230	170054-35
574903	1281401	2085863	1281401	VALEO	
574905	1281060	2112315	1281401	41420	125967
574905	1281401	2113315	1281401	79 806	125845K
574907	1281401	2164195	125851	805028	104072-1
574908	128996	2274550	125851	805030	104082-1
574911	1281060	2302249	1281401	805034	104099-1
574911	1281401	2302250	1281060	805062	104083-1
574912	1281401	2302250	1281401	805063	104082-1
574913	1281401	k432-10	1040107-1	805073	1040107-1
574914	1040118-1	k432-14	1040107-1	805140	104085-1
574915	104096-1	K432-16	104065-1	805145	104083-1
574916	1040116-1	k432-19	1040106-1	805148	104099-1
574917	1040116-1	k432-19	128996	805160	104085-1
574918	1281402	k432-20	1281060	805164	104070-1
574919	1040116-1	k432-20	125851	805168	104074-1
574926	1281401	K432-25	1281060	805186	104083-1
574927	1281060	k432-26	125851	805201	1040107-1
574927	1281401	k432-27	125851	805232	104074-1
574938	1281401	k432-30	104071-1	805246	104070-1
574981	104096-1	K432-30	170050-38	805291	104074-1
574984	104071-1	K432-31	104071-1	805293	104074-1
1111148	128990	k432-31	170050-38	805297	104824-1
1321253	128990	k432-31	125851	805298	1040100-1
1321258	128990	k432-32	104071-1	805301	104823-1
1322780	180050-35	k432-32	170050-38	805352	1040109-1
1324883	128990	k432-32	125851	805354	1040109-1
1340192	128990	k432-33	104086-1	805356	104084-1
1341687	170060-35	k432-33	170051-38	805358	104084-1
1368697	128990	k432-33	128996	805448	104065-1
1382331	170060-35	k432-33	125851	805449	1040107-1
1386931	128990	k432-35	104086-1	805450	104065-1
1393161	125845K	k432-35	170051-38	805452	104065-1
1393183	180050-35	k432-35	128996	805453	1040107-1
1407430	125845K	k432-35	125851	805483	104073-1
1407912	170061-38	k432-36	104096-1	805484	104072-1
1407913	170051-38	k432-36	170051-38	805514	170052-35
1412319	128990	k432-36	1281060	805600	170052-35
1436695	128996	k432-36	125851	805620	170052-35
1444110	128990	k432-37	104096-1	805642	170052-35
1479575	1281060	k432-37	170051-38	805642	170052-35
1479575	1281401	k432-37	1281060	805711	170052-35
1479576	125851	k432-37	125851	805724	170052-35
1496761	1281401	K432-38	170051-38	805775	170050-35
1496761	1281401	k432-38	125851	805785	170050-35
1499769	1281060	k432-39	104086-1	805786	170060-35
1499769	1281401	k432-39	170051-38	805787	170060-35
1499770	125851	k432-39	128996	805803	170052-35
1510032	128990	k432-39	125851	806151	128990
				806177	128990

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
806197	128990	827176	104094-1	109 458 03	125849
806360	128986	827181	104822-1	109 960 15	125849
806360	128988	827183	104822-1	VOLVO	
806416	128991	827185	104822-1	1069033	1281417
806424	128990	827188	1040116-1	1521712	180053-34
806444	128990	827189	1040116-1	1521713	180057-34
806611	125856	827190	1040116-1	1521716	128997
806616	125849	827191	1040116-1	1521719	180056-34
806661	125847K	827220	1040108-1	1521721	180052-34
806684	125849	827221	104088-1	1524768	1281411
806706	125857	827222	104088-1	1524771	128988
807507	128986	827 223	104066-1	1668537	128986
807520	128990	827257	104951-1	1668537	128988
807522	128986	827259	104681-1	1668671	1281411
807522	128988	827266	104076-1	1668672	128986
807545	128990	827267	104092-1	1668672	128988
807557	128986	827273	104952-1	1668983	128986
807733	128993	827282	104078-1	1668983	128988
807734	128986	827283	104070-1	1669116	180052-34
807736	128986	827283	104078-1	1669141	1281417
809106	1040119-1	827284	104080-1	1669827	180052-34
809107	104069-1	827289	104091-1	1672935	180052-34
809108	1040119-1	827290	104091-1	1673859	1281411
809109	104069-1	827291	104092-1	3191766	128989
809110	104090-1	827293	1040116-1	3191767	128995
809111	104090-1	827294	1040116-1	3191991	128986
809112	104069-1	827319	104089-1	3191991	128988
809113	104069-1	827325	1040115-1	3191993	128988
809127	104082-1	827326	1040115-1	3192200	180052-34
809128	104082-1	827362	104682-1	3192201	180053-34
809131	1040105-1	827363	104680-1	3192202	180057-34
809132	104091-1	827364	104825-1	3192210	180052-34
809133	104091-1	827379	104080-1	3192216	125847K
809134	104075-1	827380	104078-1	3192218	125846K
809135	104077-1	827381	104078-1	3192220	125848K
809136	104077-1	827406	104076-1	3192221	125848K
809140	104074-1	827407	104092-1	3192782	180051-34
809142	104097-1	827408	1040105-1	3192783	180055-34
827025	104074-1	827409	104075-1	8112191	104085-1
827026	104074-1	827415	104093-1	8112194	128986
827032	1040106-1	827417	104094-1	8112194	128988
827033	1040106-1	827426	160521-33AM	8112600	1281417
827052	104071-1	827427	104461-1	8112924	1281411
827053	104071-1	827471	104094-1	8113054	128986
827054	104086-1	827489	104080-1	8113054	128988
827054	104096-1	827490	104080-1	8113225	128986
827054	170051-38	827497	1040108-1	8113225	128988
827055	104086-1	827498	1040108-1	8113257	1281411
827055	104096-1	829067	128989	8113463	180052-34
827055	170051-38	829068	128989	8113467	128997
827069	104067-1	829074	128995	8113512	180053-34
827070	104067-1	830010	125851	8113513	180052-34
827081	1040119-1	830013	125848K	8113514	180057-34
827082	1040119-1	830015	125853	8113525	128986
827087	104068-1	831009	170061-38	8113525	128988
827088	104068-1	831030	170050-38	8113529	180052-34
827095	104088-1	1521717	1281413	8113549	104085-1
827096	104088-1	8113468	1281413	8113551	104085-1
827100	1040118-1	8113468	1281413	8113811	104069-1
827100	170050-35	8113947	1281413	8113812	104085-1
827100	170051-38	8171496	1281413	8113813	104090-1
827101	1040118-1	805454	104065-1	8113824	1040119-1
827101	170050-35	829 075	128995	8113825	1040119-1
827101	170051-38	VAN HOOL		8113894	180051-34
827164	104081-1	518312	170055-35	8171426	128989
827165	104081-1	10996001	125853	8172354	128997
827166	104095-1	11257228	125853	8172402	128997
827167	104095-1	5010545836	170055-35	8172403	128997
827173	104093-1	100.901.513	128993	8172801	128997

CROSS REFERENCE LIST

COMPARE PART NUMBER	EATON PART NUMBER	COMPARE PART NUMBER	EATON PART NUMBER
8172802	128989	85000503	104088-1
8172803	128995	85000510	104087-1
20366591	1281410	85000511	180056-34
20484461	160522-33AM	85000521	180053-34
20484463	160521-33AM	85000522	104088-1
20484467	128998	85000523	180052-34
20484468	128995	85000525	180057-34
20504343	170055-35	85000527	180052-34
20510801	125847K	85000534	128995
20510805	128989	85000542	104090-1
20525015	128995	85000551	104085-1
20525018	128989	85000553	104085-1
20526951	1281410	85000555	1040119-1
20566388	128998	85000558	104088-1
20566389	128995	85000559	104069-1
20569126	180052-34	85000560	104068-1
20569128	180053-34	85000568	104069-1
20569130	180057-34	85000624	160521-33AM
20569134	180051-34	85000625	128995
20569137	180055-34	85000670	128989
20569151	125846K	85000773	104952-1
20569153	125847K	85000775	1281410
20569155	125848K	85000789	162201-16
20569161	125848K	85000790	162201-16
20569174	125847K	85000790	1281403
20575561	180052-34	85000791	104822-1
20577448	128989	85003114	104460-1
20717564	1281410	85003117	160522-33AM
20748154	180056-34	85003118	128998
20806453	160522-33AM	85003119	128989
20806454	160521-33AM	85003903	128995
20812540	162201-16	85003904	128995
20812547	125977	85003972	104461-1
20812550	1281403	85003973	104461-1
20891854	128989	85013742	160522-33AM
20918477	128989	85013744	104460-1
21005310	162201-16	85013744	128998
21134336	160522-33AM	85013766	104461-1
21188868	125977		
21527813	128995		
21539802	128995		
21587950	128995		
21593944	128995		
85000049	128988		
85000053	104085-1		
85000183	104085-1		
85000238	128995		
85000239	128989		
85000240	128995		
85000241	128989		
85000244	1281410		
85000251	180055-34		
85000263	104088-1		
85000265	104088-1		
85000266	104069-1		
85000266	128988		
85000267	104068-1		
85000268	104068-1		
85000272	180053-34		
85000273	104067-1		
85000274	104067-1		
85000275	180052-34		
85000276	180052-34		
85000277	104066-1		
85000278	180051-34		
85000279	104089-1		
85000279	180055-34		
85000382	128989		
85000393	180052-34		

SD CLUTCH SELECTOR				
SD 430 mm clutch ceramic facing	430 mm clutch organic facing	Sachs reference 430 mm	Twin plate 400 mm clutch	Sachs reference 400 mm twin plate clutch
DAF				
104370-1	104070-1	3400122101	-	-
104378-1	104078-1	3400700361	-	-
IVECO				
104382-1	104082-1	3400117801	-	-
MAN				
104377-1	104077-1	3400127401	-	-
104383-1	104083-1	3400122201	-	-
MERCEDES-BENZ				
104374-1	104074-1	3400122801	104951-1	3400121501
RENAULT				
104384-1	104084-1	3400700334	-	3400700311
VOLVO				
104368-1	104068-1	3400700343	104952-1	3400700422
104369-1	104069-1	3400127101	104953-1	3400700406
104385-1	104085-1	3400043032	-	-

EATON

Powering Business Worldwide