

Flexible metallic conduit fittings

Combination couplings

ACC SERIES COMBINATION COUPLINGS – STEEL

Applications:

- ACC combination couplings are used to join EMT conduit to armoured cable, metal-clad cable or flexible metallic conduit

Features:

- Dual gripping saddle design on the coupling safely secures cable or conduit in place and prevents loosening from vibration
- Steel compression ring and nut provide a strong, secure termination point for EMT conduit
- Tri-head set screw may be installed using a slotted, Phillips or Robertson head screwdriver
- Steel combination coupling is zinc electroplated for corrosion resistance

Certifications and compliances:

- UL Listed
- cUL Listed

Standard materials and finishes:


- Body – steel, zinc electroplated
- Saddle – steel, zinc electroplated
- Screw – steel, zinc electroplated

Compression couplings AC/MC, FMC to EMT



Cat. #	Trade size	Cable opening		Unit qty.	Wt. lbs. per 100
		Max.	Min.		
ACC38	3/8" - 1/2"	0.660	0.400	25	10
ACC50	1/2" - 3/4"	0.920	0.520	10	13
ACC75	3/4" - 1"	1.100	0.680	10	16

Dimensions (in inches):

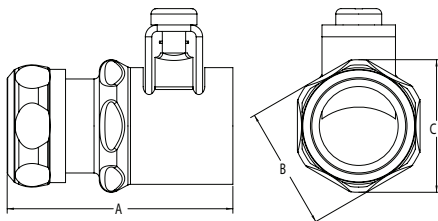

Cat. #	A	B	C
ACC38	1.65	1.05	1.13
ACC50	2.09	1.14	1.23
ACC75	2.15	1.30	1.39


Set screw couplings



Cat. #	Trade size	Unit qty.	Wt. lbs. per 100
ACCSS38	3/8" - 1/2"	25	9
ACCSS50	1/2" - 3/4"	10	12
ACCSS75	3/4" - 1"	10	14

Ⓞ Not UL Listed.

Dimensions (in inches):

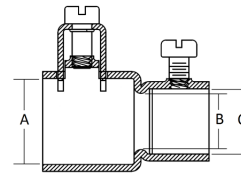

Cat. #	A		B		C	
	Min.	Max.	Min.	Max.	Min.	Max.
ACCSS38	0.615	0.645	N/A	N/A	0.712	0.730
ACCSS50	0.925	0.955	0.560	0.620	0.712	0.730
ACCSS75	1.110	1.140	0.742	0.813	0.930	0.942


Flexible metallic conduit fittings

Combination couplings

COMBINATION COUPLINGS – ZINC DIE CAST

EMT (set screw) to flexible steel (clamp)®

UL File No. E-19189

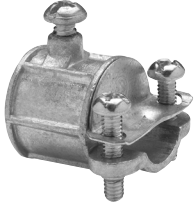

Cat. #	Trade size	Unit qty.	Wt. Lbs. per 100
780DC	1/2" to 3/8"	50	8

®UL Listed flexible metallic conduit fittings are suitable as grounding means under NEC 350-5 and suitable for hazardous location use per Class I, Division 2, NEC 501-4(b).

SCREW-IN TYPE COMPRESSION COMBINATION COUPLINGS – ZINC DIE CAST

UL File No. E-19189




Cat. #	Trade size	Unit qty.	Wt. lbs. per 100
FECC50DC	1/2"	50	41
FECC75DC	3/4"	25	31
FECC100DC	1"	25	46

SET SCREW SQUEEZE TYPE COMBINATION COUPLINGS – ZINC DIE CAST

Set screw squeeze type

UL File No. E-19189

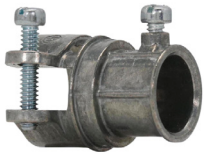

Cat. #	Trade size	Unit qty.	Wt. lbs. per 100
FECS38DC	1/2" to 3/8"	50	34
FECS50DC	1/2" to 1/2"	25	22
FECS75DC	3/4" to 3/4"	25	36

FMC fittings