


Trumpet non-metallic non-armored cable glands

IECEX/ATEX
IP66

1G

Cable type:

- Non-armored cable 

Features:

- Large cable connection area
- Low torque required for tightening
- Integrated sealing lip on thread

Certifications and compliances:



- IP66

ATEX Certificate No.: PTB 00 ATEX 3121

- II 2 G Ex e II / II 2 D Ex tD A21 IP66

IECEX Certificate No.: IECEX BKI 08.0007

- Ex e II / Ex tD A21 IP66 T85°C


Standard material:

- Polyamide



Operating temperature:

- -40°C to +85°C

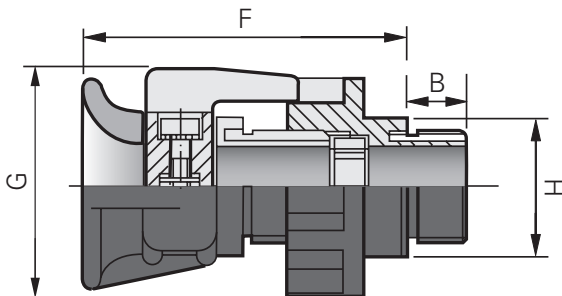

Ordering information:

Gland size	Metric thread size	Cat. #	Thread length (B)	Outer sheath		Gland length (less entry) (F)	Across flats (H)	Across corners (G)
				Min.	Max.			
20	M20	GHG 960 1949 R0111	15.0	8.0	13.0	64.0	27.0	47.0
25	M25	GHG 960 1949 R0112	15.0	11.0	16.0	65.0	32.0	51.0
32	M32	GHG 960 1949 R0113	15.0	15.0	20.0	80.0	41.0	68.0
40	M40	GHG 960 1949 R0114	15.0	19.0	27.0	86.0	50.0	81.0
50	M50	GHG 960 1949 R0115	16.0	28.0	34.0	95.0	60.0	96.0
63	M63	GHG 960 1949 R0116	16.0	38.0	46.0	105.0	75.0	107.0

All dimensions in millimeters.