

# Weatherproof LED luminaires

## WEATHERPROOF LED LUMINAIRES

LED weatherproof luminaires combine the energy efficiency of LED technology with the sharp, sleek design desired for landscaping and outdoor lighting applications. Available in gray, white and bronze, these LED luminaires provide customers with a variety of color options to help match any residential or commercial outdoor landscape.

### Features:

- Durable die cast housing for long life
- Powder paint finish for corrosion resistance and pleasing appearance
- Adjustable mounting arm for directional lighting ability
- Impact-resistant lens
- Fits 1/2" openings of covers in 4" round and rectangular weatherproof boxes
- Voltage – 120V-277V
- Color temperature – 5000K
- Long, dependable life lasting up to 12 years
- Suitable for wet locations

### Certifications and compliances:

- cULus Listed
- UL File No. E-348559

### Standard materials:


- Lamp head and mounting arm - die cast aluminum

### Standard finish:

- Painted powder coat



### Dimensions (in inches):

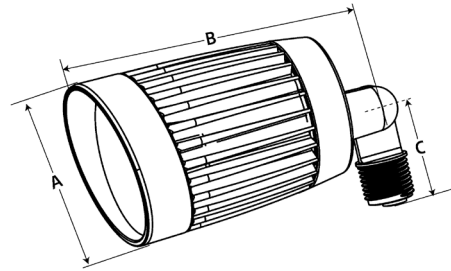

Cat. #	Description	Lumens	Size	Unit qty.	Wt. lbs. per 100
TPLED10B	10W LED lampholder bronze	800	1/2"	4	90
TPLED10W	10W LED lampholder white	800	1/2"	4	90
TPLED10G	10W LED lampholder gray	800	1/2"	4	90

Cat. #	A	B	C
TPLED10B	2.75	4.92	1.57
TPLED10W	2.75	4.92	1.57
TPLED10G	2.75	4.92	1.57

# Weatherproof lampholders

## LAMP HOLDERS & ACCESSORIES

DIE CAST ALUMINUM CONSTRUCTION, UP TO 150 WATTS, WITH LAMP GASKET, UL LISTED



TP7162 - TP7165



TP7166



TP7176

Cat. #	Description	Color	Unit qty.	Wt. lbs. per 100
TP7162 <sup>U</sup>	Universal par lampholder	Natural	36	47.2
TP7163 <sup>U</sup>	Universal par lampholder	Gray	36	47.2
TP7164 <sup>U</sup>	Universal par lampholder	White	36	47.2
TP7165 <sup>U</sup>	Universal par lampholder	Bronze	36	47.2
TP7166 <sup>U</sup>	Universal par lampholder with external gasket	Gray	36	50.0
TP7170	External gasket only	-	100	3.0

<sup>U</sup>Third party certified for use with CFL and LED lamps.

## WEATHERPROOF LAMP HOLDERS & ACCESSORIES

DIE CAST ALUMINUM CONSTRUCTION, UP TO 150 WATTS, WITH LAMP GASKET, UL LISTED



TP7178



TP7186



TP7188 (aluminum)

Cat. #	Description	Color	Unit qty.	Wt. lbs. per 100
TP7178 <sup>U</sup>	Par lampholder with reflector	Gray	6	166.7
TP7186	Portable par lampholder with 6' cord	Gray	12	100.0
TP7188	2 1/2" outside dia. Pole fitter with 1/2" male thread	Gray	24	50.0

<sup>U</sup>Third party certified for use with CFL and LED lamps.

## LAMP HOLDER COMBINATIONS

DIE CAST ALUMINUM CONSTRUCTION, WITH GASKETS, UL LISTED



TP7330 - TP7332

Cat. #	Description	Color	Unit qty.	Wt. lbs. per 100
TP7330 <sup>A</sup>	Two par lampholders and 3-hole round cover	Gray	10	137.5
TP7331 <sup>A</sup>	Two par lampholders and 3-hole round cover	White	10	137.5
TP7332 <sup>A</sup>	Two par lampholders and 3-hole round cover	Bronze	10	137.5

<sup>A</sup>Third party certified for use with CFL and LED lamps.

Weatherproof