

Ruff-IN mounting bracket assemblies with Quick-Lok outlet boxes

Wide-flange telescoping brackets


- Bracket includes an auto height adjustment feature
- Easily adjust to accommodate stud widths of 14½" thru 25"; a secure fit at all stud spacings
- Can be quickly centered at 18" above floor height without additional measuring
- Self-leveling, snap to stud feature frees hands for securing screws
- Continuous hole pattern allows mounting of the box anywhere in the cavity – avoid wall interferences!
- BBT-WF is used for studs wider than 1-3/8"
- UL Listed for U.S. and Canada; CSA certified

Box mounting brackets


- Mounts directly to stud or easily snaps onto BBT telescoping brackets
- Accepts 4", 4-11/16" and 5" box sizes
- Marty Mouse™ ears to retain the box when plaster ring is removed
- Rabbit Ears™ to attach a plaster ring for data devices without using a box
- Available with built-in, snap-off back support extension for studs from 2.5" to 6"
- No need to measure additional box heights – features interlocking brackets to easily and quickly mount boxes side-by-side
- Use with BBT-HF or directly to stud
- UL Listed for U.S. and Canada; CSA certified

Quick-Lok outlet boxes


- Patented pre-installed external connectors with integral insulators maintain all available space within the box
- Ideal for use with BBT brackets and BBA box mounts
- 33 cu. in. capacity for 4" boxes and 44 cu. in. for 4-11/16" boxes
- Ground bump on all models
- Pre-installed pigtail provided as an option on all models
- UL Listed

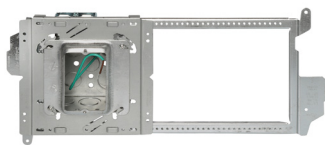


PFTWFA 4Q1075

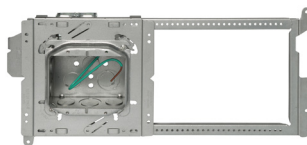


PFTWFA 4Q10275

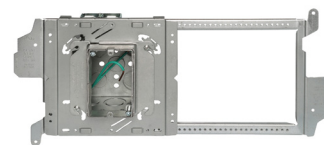


PFTWFA 4Q10AR58

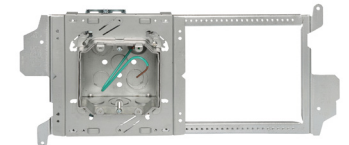


PFTWFA 4Q102AR

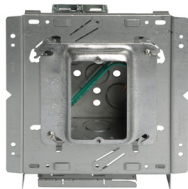


PFTA4 4Q1075

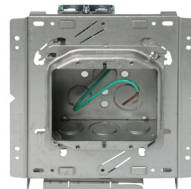

PFTA4 4Q10275

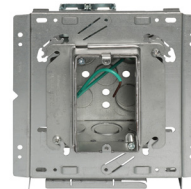

PFTA4 4Q10AR58

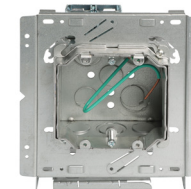

PFTA4 4Q102AR

Catalog	EAN/UPC code	Description
PFTWFA 4Q1075	3066227919215	BBT-WF + BBA - 14.5" - 25" telescoping open bracket w/ alignment plate + TP4Q10PF - 4" SQ. X 2-1/8" D. box with quick-lok connector and ground pigtail + TP486 - 3/4" raised single gang
PFTWFA 4Q10275	3066227919216	BBT-WF + BBA - 14.5" - 25" telescoping open bracket w/ alignment plate + TP4Q10PF - 4" SQ. X 2-1/8" D. box w/ quick-lok connector and ground pigtail + TP500 - 3/4" raised two gang
PFTWFA 4Q10AR58	3066227919217	BBT-WF + BBA - 14.5" - 25" telescoping open bracket w/ alignment plate + TP4Q10PF - 4" SQ. X 2-1/8" D. box w/ quick-lok connector and ground pigtail + ARM158 - adjustable depth single gang
PFTWFA 4Q102AR	3066227919218	BBT-WF + BBA - 14.5" - 25" telescoping open bracket w/ alignment plate + TP4Q10PF - 4" SQ. X 2-1/8" D. Box w/ quick-lok connector and ground pigtail + AMR2 - adjustable depth two gang
PFTA4 4Q1075	3066227918264	BBA-4 - double sided stud mount bracket w/ backside support+ TP4Q10PF - 4" SQ. X 2-1/8" D. box w/ quick-lok connector and ground pigtail + TP486 - 3/4" raised single gang
PFTA4 4Q10275	3066227712612	BBA-4 - double sided stud mount bracket w/ backside support+ TP4Q10PF - 4" SQ. X 2-1/8" D. box w/ quick-lok connector and ground pigtail + TP500 - 3/4" raised two gang
PFTA4 4Q10AR58	3066227919224	BBA-4 - double sided stud mount bracket w/ backside support+ TP4Q10PF - 4" SQ. X 2-1/8" D. box w/ quick-lok connector and ground pigtail + ARM158 - adjustable depth single gang
PFTA4 4Q102AR	3066227918263	BBA-4 - double sided stud mount bracket w/ backside support+ TP4Q10PF - 4" SQ. X 2-1/8" D. box w/ quick-lok connector and ground pigtail + AMR2 - adjustable depth two gang



Eaton
1000 Eaton Boulevard
Cleveland, OH 44122
United States
Eaton.com

© 2023 Eaton
All Rights Reserved
Printed in USA
Publication No. SA406014EN
July 2023

Eaton is a registered trademark.

All other trademarks are property of their respective owners.

Follow us on social media to get the latest product and support information.

