

BS – for non-armoured & marine round cables

Technical specifications

IP66



Suitable for the following cable types



Non-armoured cable

Cable with insulated conductors, with no layer of mechanical (metallic) protection.



Marine shipboard cable

Non-armoured cable designed specially for marine applications.



Braided marine shipboard cable

Cable designed for marine applications.

Certifications

MN 823 C

Temperature range

-20 °C to +80 °C


Material

Steel body with natural brass cap

Perfectly adapted to industrial environments

Supplied with neoprene sealing ring

Dimensions

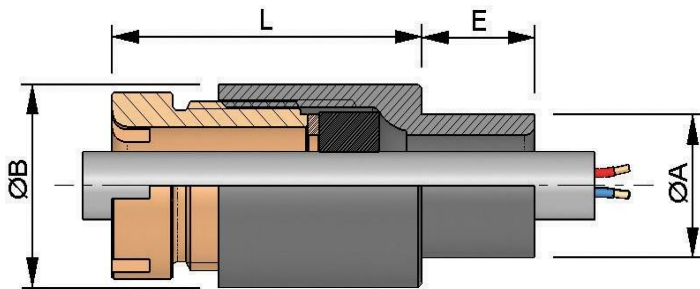

Our range of BS cable glands is a specific French Navy cable management solutions as per MN823C standards.

These IP66 tight cable glands allow the connection of non-armoured or marine cables without the coupling of the armour.

Made of a steel body with natural brass cap, the BS cable glands accommodate a neoprene sealing and achieves an IP66 tightness on the outer sheath of the cable as well as a perfect tensile strength.

With an operating temperature range starting from -20°C up to +80°C, the BS range meets the requirement for cable entries management in marine environments.

Ordering codes

Size	External Cable Diameter		Ø A	Ø B	L	E	Catalog Number
	Min	Max					
1	6.0	12.0	17.0	24.0	41.0	15.0	CAP530100
1 bis	2.0	8.0	17.0	24.0	41.0	15.0	CAP532100
2	8.5	14.5	20.0	27.0	44.0	15.0	CAP530200
3	13.5	19.0	24.0	32.0	44.0	15.0	CAP530300
4	16.5	22.6	28.0	36.0	57.0	15.0	CAP530400
5	22.0	28.0	35.0	42.0	57.0	15.0	CAP530500
5 bis	18.0	24.0	35.0	42.0	57.0	15.0	CAP532500
6	30.0	36.0	44.0	55.0	57.0	15.0	CAP530600
6 bis	25.0	31.0	50.0	60.0	57.0	15.0	CAP532600
7	36.5	42.5	64.0	75.0	57.0	15.0	CAP530700
7 bis	33.0	39.0	64.0	75.0	57.0	15.0	CAP532700

All dimensions in mm.