

Safeguard your loved ones with the advanced Eaton MCB

Safe | Reliable | Affordable


 With effect from 1st June, 2023



SP



DP

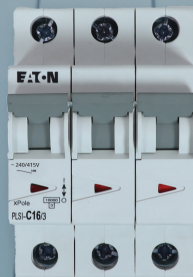

TP



FP



Powering Business Worldwide

Miniature Circuit Breaker Type PLSI, 10kA

- Rated Current : 6 A to 63 A
- Rated voltage : 240/415 V, 50 Hz
- ISI Mark and CE Mark
- Tripping Characteristics : B & C Curves
- Energy Limiting Class 3
- Bi-connect terminal on both line and load side
- 2 Position DIN Rail clamp
- Finger proof IP20 terminals
- Combi-head Screw
- Trip Free Mechanism
- True Contact Position Indicator



B Curve

Rated Current (A)	1 P			2 P			3 P			4 P		
	Part No.	Article No.	Unit MRP	Part No.	Article No.	Unit MRP	Part No.	Article No.	Unit MRP	Part No.	Article No.	Unit MRP
6	EIN-810101	PLSI-B6-GI	265	EIN-810109	PLSI-B6/2-GI	850	EIN-810117	PLSI-B6/3-GI	1325	EIN-810125	PLSI-B6/4-GI	1800
10	EIN-810102	PLSI-B10-GI	265	EIN-810110	PLSI-B10/2-GI	850	EIN-810118	PLSI-B10/3-GI	1325	EIN-810126	PLSI-B10/4-GI	1800
16	EIN-810103	PLSI-B16-GI	265	EIN-810111	PLSI-B16/2-GI	850	EIN-810119	PLSI-B16/3-GI	1325	EIN-810127	PLSI-B16/4-GI	1800
20	EIN-810104	PLSI-B20-GI	265	EIN-810112	PLSI-B20/2-GI	850	EIN-810120	PLSI-B20/3-GI	1325	EIN-810128	PLSI-B20/4-GI	1800
25	EIN-810105	PLSI-B25-GI	265	EIN-810113	PLSI-B25/2-GI	850	EIN-810121	PLSI-B25/3-GI	1325	EIN-810129	PLSI-B25/4-GI	1800
32	EIN-810106	PLSI-B32-GI	265	EIN-810114	PLSI-B32/2-GI	850	EIN-810122	PLSI-B32/3-GI	1325	EIN-810130	PLSI-B32/4-GI	1800
40	EIN-810107	PLSI-B40-GI	600	EIN-810115	PLSI-B40/2-GI	1335	EIN-810123	PLSI-B40/3-GI	2120	EIN-810131	PLSI-B40/4-GI	2710
63	EIN-810108	PLSI-B63-GI	600	EIN-810116	PLSI-B63/2-GI	1335	EIN-810124	PLSI-B63/3-GI	2120	EIN-810132	PLSI-B63/4-GI	2710

C Curve

Rated Current (A)	1 P			2 P			3 P			4 P		
	Part No.	Article No.	Unit MRP	Part No.	Article No.	Unit MRP	Part No.	Article No.	Unit MRP	Part No.	Article No.	Unit MRP
6	EIN-810140	PLSI-C6-GI	265	EIN-810148	PLSI-C6/2-GI	850	EIN-810156	PLSI-C6/3-GI	1325	EIN-810164	PLSI-C6/4-GI	1800
10	EIN-810141	PLSI-C10-GI	265	EIN-810149	PLSI-C10/2-GI	850	EIN-810157	PLSI-C10/3-GI	1325	EIN-810165	PLSI-C10/4-GI	1800
16	EIN-810142	PLSI-C16-GI	265	EIN-810150	PLSI-C16/2-GI	850	EIN-810158	PLSI-C16/3-GI	1325	EIN-810166	PLSI-C16/4-GI	1800
20	EIN-810143	PLSI-C20-GI	265	EIN-810151	PLSI-C20/2-GI	850	EIN-810159	PLSI-C20/3-GI	1325	EIN-810167	PLSI-C20/4-GI	1800
25	EIN-810144	PLSI-C25-GI	265	EIN-810152	PLSI-C25/2-GI	850	EIN-810160	PLSI-C25/3-GI	1325	EIN-810168	PLSI-C25/4-GI	1800
32	EIN-810145	PLSI-C32-GI	265	EIN-810153	PLSI-C32/2-GI	850	EIN-810161	PLSI-C32/3-GI	1325	EIN-810169	PLSI-C32/4-GI	1800
40	EIN-810146	PLSI-C40-GI	600	EIN-810154	PLSI-C40/2-GI	1335	EIN-810162	PLSI-C40/3-GI	2120	EIN-810170	PLSI-C40/4-GI	2710
63	EIN-810147	PLSI-C63-GI	600	EIN-810155	PLSI-C63/2-GI	1335	EIN-810163	PLSI-C63/3-GI	2120	EIN-810171	PLSI-C63/4-GI	2710

India Head Office
 Eaton Power Quality Pvt. Ltd.
 2, EVR Street, Sedarpet
 Industrial Estate
 Pondicherry - 605111
 Tel: +91 413 2672000
 Toll free: 1800 425 5758, 1800 102 4620
 Enquiries - EatonElectricalIndia@eaton.com

Eaton is a registered trademark.



Eaton.com/in
 © 2023 Eaton All Rights Reserved

All other trademarks are property of their respective owners.