HLD

1/4" x 1 1/4" (6.3 mm x 32 mm) Visual indicating fuse holder

Product features

- For use with GBA and GLD fuses.
- Bayonet-type transparent knob permits visual indication of "opened" pin indicating fuses.
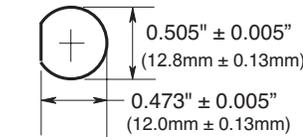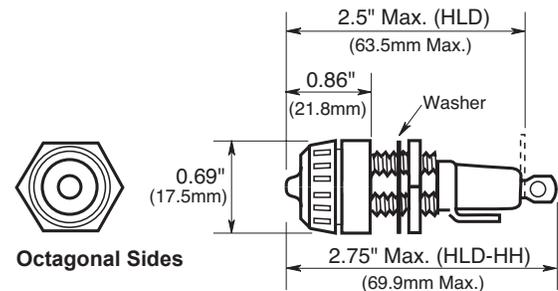
Environmental Data:

Temperature Rating (RTI): +130 °C

Agency information

- *UL Recognized, Guide IZLT2, File E14853

Dimensions - in (mm)

2.5" Max. (HLD)
(63.5mm Max.)

0.86"
(21.8mm)

Washer

0.69"
(17.5mm)

Octagonal Sides

2.75" Max. (HLD-HH)
(69.9mm Max.)

0.505" ± 0.005"
(12.8mm ± 0.13mm)

0.473" ± 0.005"
(12.0mm ± 0.13mm)

Punched Mounting Hole

Electrical Ratings

Symbol	Amps	Volts AC	Features
*HLD	15	250	Solder terminals
HLD-HH	15	250	¼″ quick-connect terminals

C€ CE logo denotes compliance with European Union Low Voltage Directive (50-1000Vac, 75-1500Vdc). Refer to Data Sheet: 8002

FAT•N
Powering Business Worldwide