


Series EM3583

EuroMag Terminal Blocks

IDC Pluggable Block

(Mates with EM3593 Series); 3.81 Centers

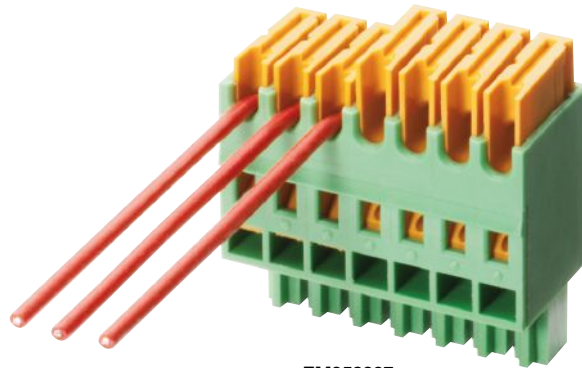

EM358307

SPECIFICATIONS

Ratings: 10A, 160V

Center Spacing: 0.15" (3.81mm)

Wire Range: #18-20 AWG

Housing Material: UL rated 94V0 Thermoplastic

Contact Material: Brass, Tin-Plated


Operating Temperature: 105°C (221°F) max., -49°C (-40°F) min.

Construction: Mold-to-length.

Agency Information: cULus File E62622; CE Certified

Poles	L1 (mm)	L2 (mm)	Poles	L1 (mm)	L2 (mm)
02	3.81	8.40	08	26.67	31.26
03	7.62	12.21	09	30.48	35.07
04	11.43	16.02	10	34.29	38.88
05	15.24	19.83	11	38.10	42.69
06	19.05	23.64	12	41.91	46.50
07	22.86	27.45			

Dimensions - mm (in)

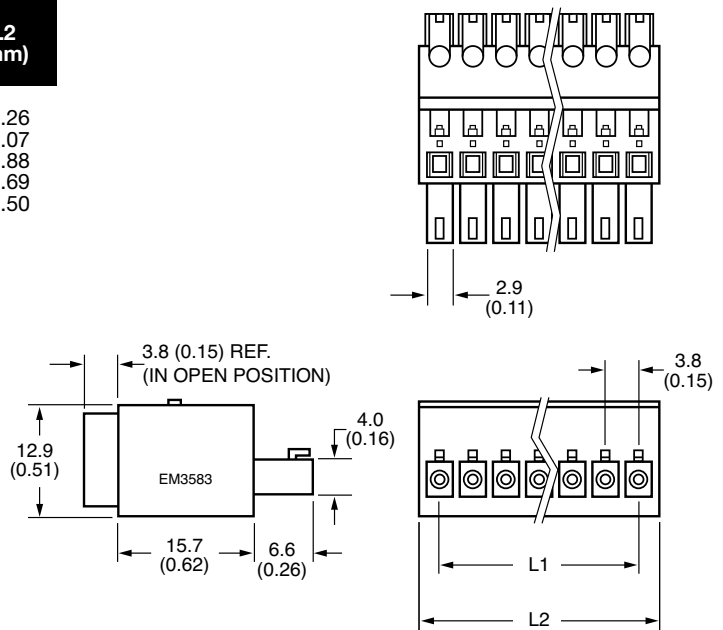

Part Numbering System

Inches (Millimeters)

Series

EM3583

of Positions

02 to 12

Mating Header: EM3593 pg. 81

Terminal Blocks:
Single Row

EuroMag Series
Plug & Header

Edge Connectors,
One-Sided Boards

Compliance
References