


# EV Charging Panelboard

Whether you're enabling charging for a multi-family dwelling, commercial application, educational campus or a parking garage, charge up to 10 electric vehicles (EVs) with Eaton's Pow-R-Line 3X panelboard.

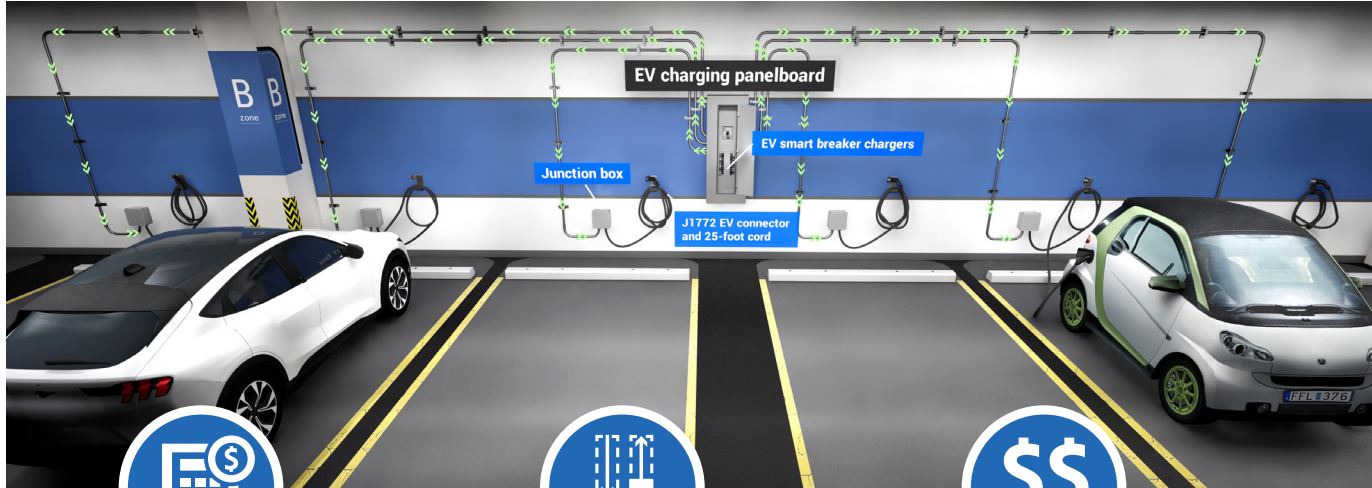

**Cost-effective\*** and easy to service compared to traditional EVSE installation



**Highly scalable solution:** adding new EV chargers is as easy as adding a new circuit breaker




**Up to 16% savings\*** in labor and **24% savings\*** in material

\*Per quotes from independent contractors

- AC Level 2 charging at 7.7 kW, 240 Vac (up to 10)
- Restricted access to EV panel provides protection against vandalism
- Wi-Fi connectivity to facilitate CPO connection
- OCPP 1.6j certification enables integration with your preferred charge management solution
- Access control (QR code)
- SAE J1772 EV connector and 25-foot cord
- 0.2% energy metering accuracy
- Wi-Fi connectivity
- UL/FCC/IC
- Energy Star rated
- NEMA 3R/4/4X/12
- 10kA Interruption rating

Charging Network Management software to manage access control, payments and load management

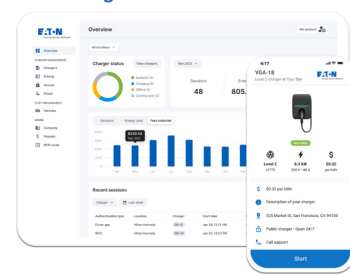

Contact your local sales representative or visit [Eaton.com/evchargers](https://Eaton.com/evchargers) for more information.

Eaton  
1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
Eaton.com

© 2023 Eaton  
All Rights Reserved  
SA191006EN / GG  
Rev.03  
November 2023

Eaton is a registered trademark.

All other trademarks are property of their respective owners.

Follow us on social media to get the latest product and support information.

