


Premier series enclosures

The competitive edge for wall mount panel applications

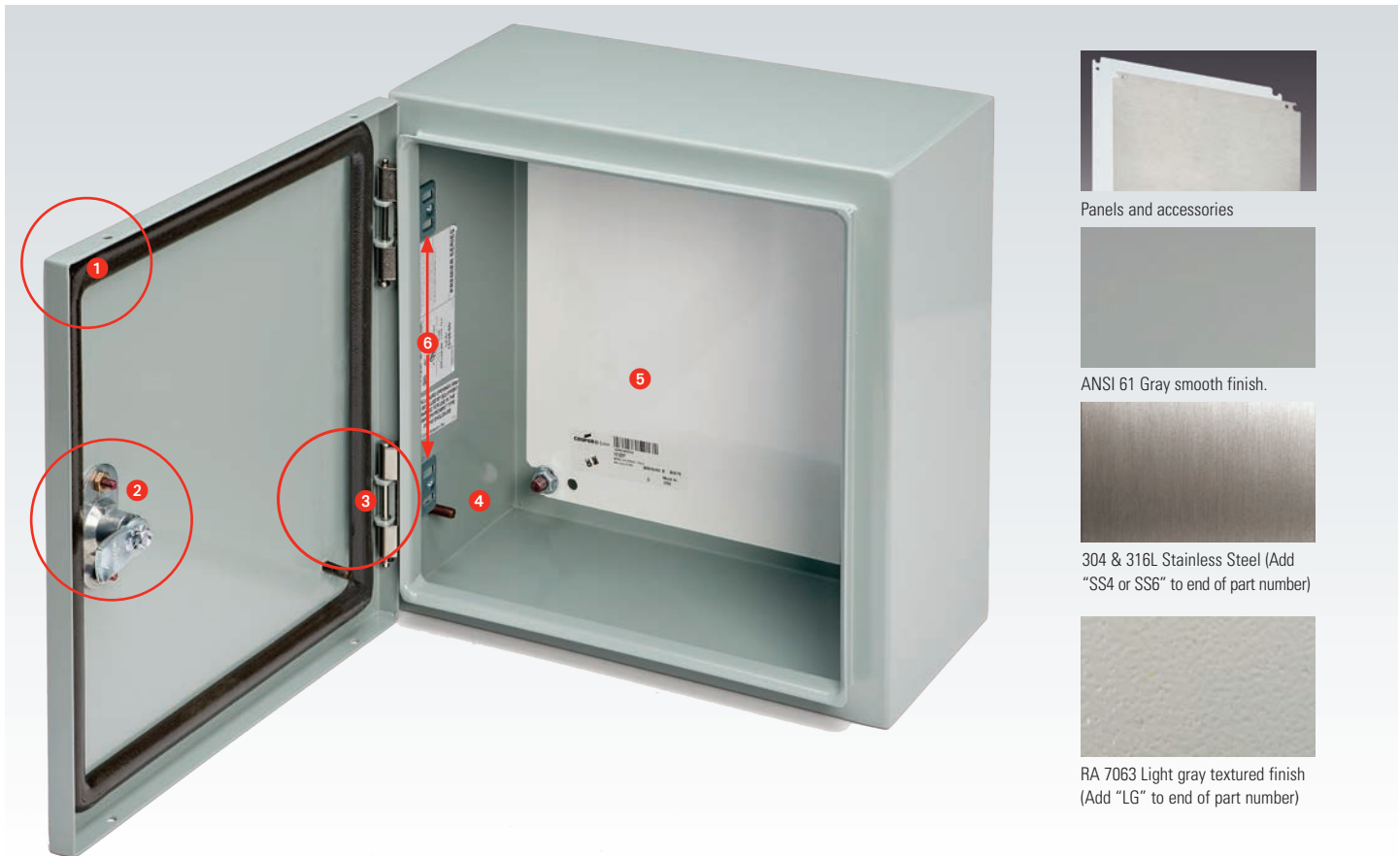

Panels and accessories

ANSI 61 Gray smooth finish.

304 & 316L Stainless Steel (Add "SS4 or SS6" to end of part number)

RA 7063 Light gray textured finish (Add "LG" to end of part number)

Manufactured in Sherman, Texas and locally stocked by distribution partners, leverage B-Line series enclosures to get the product you want, in the time you need them.

- ① Robotically applied seamless foam-in-place gasket helps assure high performance in environmental conditions.
 - ② Robust ¼ turn latches for easy access and closure, with stainless inserts on stainless type 4X products.
 - ③ Concealed hinges providing aesthetics and easy door removal.
 - ④ Ground provisions provided on all doors, bodies and back panels.
 - ⑤ Three back panel options are offered. White paint for improved equipment visibility, galvanized for improved equipment grounding, and stainless for use when corrosion is of concern. (Panel ordered separately).
 - ⑥ Mounting brackets for swing panel and other miscellaneous premier series accessory items.
- Other options:**
- Three-point latching system on Type 4 enclosures when the height is equal to or greater than 42" and on all double door units. The three-point mechanism is a quarter turn, slotted latch.
 - Extra ¼ turns on top and bottom are provided on larger Type 4X stainless enclosures.
 - Flush mounted clear polycarbonate windows are offered to provide visibility into the enclosure.*
 - Premier wall mount platform is provided in a broad range of sizes including an expanded range of 10", 16", and 20" depths.*
- Discount schedule: C2
Subclass: TC0, TD0, TE0, TDP, & TED.

* Reference ENC-17 product catalog or other side for sizes, options, and additional services available.

EATON

Powering Business Worldwide

Competitive cross reference and available options†.

Enclosure Size (H"xW"xD")	Eaton's B-Line Series			Hoffman®† Enclosure	Rittal®† Enclosure [§]	Saginaw®† Enclosure
	Enclosure	White Panel	Zinc Panel			
10x8x6	1086-SD ^{2,4}	108P	108GP	108PSS4	N/A	N/A
12x12x6	12126-SD ^{1,2,3,4,5,6}	1212P	1212GP	1212PSS4	CSD12126	WM121206NC
16x12x6	16126-SD ^{1,2,3,4,5,6}	1612P	1612GP	1612PSS4	CSD16126	WM161206NC
16x16x6	16166-SD ^{2,4,6}	1616P	1616GP	1616PSS4	CSD16166	WM161606NC
20x16x6	20166-SD ^{1,2,3,4,5,6}	2016P	2016GP	2016PSS4	CSD20166	WM201606NC
20x20x6	20206-SD ^{1,2,3,4,5,6}	2020P	2020GP	2020PSS4	CSD20206	WM202006NC
24x24x6	24246-SD ^{1,2,3}	2424P	2424GP	2424PSS4	CSD24246	WM242406NC
16x12x8	16128-SD ^{1,2,3,4,6}	1612P	1612GP	1612PSS4	CSD16128	WM161208NC
16x16x8	16168-SD ^{2,4,6}	1616P	1616GP	1616PSS4	CSD16168	WM161608NC
16x20x8	16208-SD ^{2,4,6}	2016P	1620GP	1620PSS4	CSD16208	WM162008NC
20x16x8	20168-SD ^{1,2,3,4,5,6}	2016P	2016GP	2016PSS4	CSD20168	WM201608NC
20x20x8	20208-SD ^{1,2,3,4,5,6}	2020P	2020GP	2020PSS4	CSD20208	WM202008NC
20x24x8	20248-SD ²	2420P	2024GP	2024PSS4	CSD20248	WM202408NC
24x16x8	24168-SD ^{2,4,6}	2416P	2416GP	2416PSS4	CSD24168	WM241608NC
24x20x8	24208-SD ^{1,2,4,5,6}	2420P	2420GP	2420PSS4	CSD24208	WM242008NC
24x24x8	24248-SD ^{1,2,3,4,5,6}	2424P	2424GP	2424PSS4	CSD24248	WM242408NC
30x24x8	30248-SD ^{1,2,3,4,5,6}	3024P	3024GP	3024PSS4	CSD30248	WM302408NC
30x30x8	30308-SD ^{2,4,6}	3030P	3030GP	3030PSS4	CSD30308	WM303008NC
36x36x8	36368-SD ^{1,2,3}	3636P	3636GP	3636PSS4	CSD36368	WM363608NC
20x16x10	201610-SD ^{1,2,3,4}	2016P	2016GP	2016PSS4	CSD201610	N/A
24x24x10	242410-SD ^{1,2,3}	2424P	2424GP	2424PSS4	CSD242410	WM242410NC
30x24x10	302410-SD ^{1,2,3}	3024P	3024GP	3024PSS4	CSD302410	WM302410NC
30x30x10	303010-SD ²	3030P	3030GP	3030PSS4	CSD303010	N/A
36x36x10	363610-SD ²	3636P	3636GP	3636PSS4	CSD363610	N/A
20x20x12	202012-SD ^{1,2,3,4,5,6}	2020P	2020GP	2020PSS4	CSD202012	WM202012NC
24x24x12	242412-SD ^{1,2,3,4,6}	2424P	2424GP	2424PSS4	CSD242412	WM242412NC
30x24x12	302412-SD ^{1,2,3,4,5,6}	3024P	3024GP	3024PSS4	CSD302412	WM302412NC
30x30x12	303012-SD ^{2,4,6}	3030P	3030GP	3030PSS4	CSD303012	WM303012NC
36x24x12	362412-SD ^{2,4}	3624P	3624GP	3624PSS4	CSD362412	WM362412NC
36x36x12	363612-SD ^{2,4}	3636P	3636GP	3636PSS4	CSD363612	WM363612NC
48x36x12	483612-SD ^{2,4,6}	4836P	4836GP	4836PSS4	CSD483612	WM483612NC
24x20x16	242016-SD	2420P	2420GP	2420PSS4	CSD242016	N/A
24x24x16	242416-SD ^{1,2,3,4}	2424P	2424GP	2424PSS4	CSD242416	N/A
48x36x16	483616-SD ^{2,4,6}	4836P	4836GP	4836PSS4	CSD483616	WM483616NC

Part Numbering

H x W x D - SD (Suffix Options)
ANSI 61 Gray Paint

(Suffix Options)

-SD ¹	-SDW	Flush-Mounted Polycarbonate Window
-SD ²	-SDLG	RAL 7035 Light Textured Paint
-SD ³	-SDWLG	RAL 7035 with Window
-SD ⁴	-SDSS4	304 Stainless Steel
-SD ⁵	-SDWSS4	304 Stainless Steel with Window
-SD ⁶	-SDSS6	316 Stainless Steel

Description

‡ Eaton has made every effort to ensure the integrity of the contents of this document. However, we cannot accept responsibility for errors, that may have been caused by changing part numbers, typographical or clerical errors in the preparation of this document.

Chart provides a cross reference to determine equivalent products.

† All other trademarks are property of their respective owners.

§ Mounting panel included.

Modification services



Modification capabilities to provide special sizes, painted finishes, added holes and cut-outs, pre-installed accessories, and much more.

Eaton.com/modified

Eaton

1000 Eaton Boulevard
Cleveland, OH 44122
United States
Eaton.com

© 2020 Eaton
All Rights Reserved
Printed in USA
Publication No. BR304001EN
February 2020 PREMENC-20

Disconnect provisions



Also available from B-Line series enclosures are type 4 and 4X Premier™ disconnects provided with door locking hardware and interlock latches.

Eaton.com/enc

Eaton is a registered trademark.

All other trademarks are property of their respective owners.

Follow us on social media to get the latest product and support information.



Powering Business Worldwide

B-Line Division
509 West Monroe Street
Highland, IL 62249
United States
Phone: 800-851-2415
Eaton.com/enc