





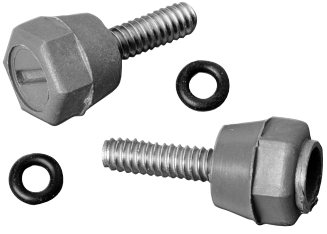
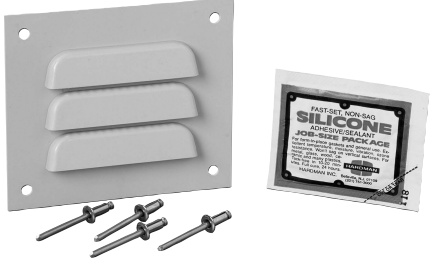

Drain & Breather Vent

| | | | |
|---|---|--|---|
|  |  |  |  |
| CHDV Drain Vent | CHDVKIT Drain Vent Kit | CHDVKIT4X Drain Vent Kit 4X | CHBVKIT4X Breather Vent Kit 4X |

Encapsulated Screws

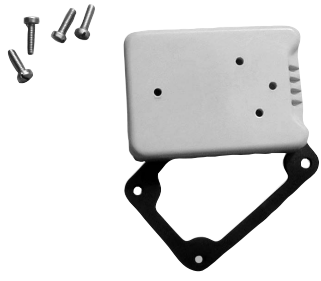

Louver Plate Vent

Carrying Handle

| | | |
|---|---|---|
|  |  |  |
| CHENCAP2PK CHENCAP4PK | CHLP1 CHLPKIT | CHHANDLE |

Stainless Steel Screws

Corrosion Inhibitor

| | |
|---|--|
|  |  |
| CHSS2PK | CHCI21 |
| CHSS4PK | Radius of Protection: 2 ft. Normal Life Span: 1 yr. |

5E Fiberglass Enclosure Accessories

Fiberglass Hole Plug Assembly



| Catalog Number | Fits | Hole Dia. Range |
|----------------|-----------------------|-----------------|
| FPLG1KIT | 1/2" Dia. Hole | .50" - .56" |
| | 5/8" Dia. Hole | .63" - .69" |
| | 3/4" Dia. Hole | .75" - .81" |
| FPLG2KIT | 22mm PB, 1/2" Conduit | .88" - 1.00" |
| | 3/4" Conduit | 1.06" - 1.12" |
| | 30mm PB | 1.22" - 1.28" |
| FPLG3KIT | 1" Conduit | 1.38" - 1.50" |
| | 1 1/4" Conduit | 1.69" - 1.75" |
| FPLG4KIT | 1 1/2" Conduit | 2.00" - 2.12" |
| FPLG5KIT | 2" Conduit | 2.50" - 2.56" |
| FPLG6KIT | 2 1/2" Conduit | 3.00" |
| FPLG7KIT | 3" Conduit | 3.62" |
| FPLG8KIT | 3 1/2" Conduit | 4.12" |
| | 4" Conduit | 4.62" |

Fiberglass Enclosure Mounting Plate Options

Aluminum (SA)
Back Panels
Grade Aluminum
3003 H14 - No Finish

Fiberglass (FG)
Back Panels
All FG Back Panels
UL 94 V-0 Rated

Stainless Steel (SS)
Back Panels
Stainless Steel
Grade 304

Carbon Steel (C)
Back Panels
Carbon Steel
Grade 1010 HRS -
Painted White Enamel

Mounting Plates for Disconnect & Circuit Breaker Dimensions

Only Available
in Carbon
Steel (C)

| | BA | BB | BK | BL | Panel Thickness BT | Panel Type | Hole Dia. | # of Holes | Weight (Carbon Steel) Suffix: C | Fits Typical Enclosure Size |
|-----------------|----------------|----------------|----------------|----------------|--------------------------|---------------|--------------|---------------|---------------------------------------|------------------------------------|
| FMPC2016 | 16.88 (429) | 13.38 (340) | 15.25 (387) | 11.25 (286) | 0.13 (2) | Formed | 0.31 (8) | 4 | 7.3 lbs. | 20 x 16 Disconnect enclosure |
| FMPC2412 | 20.88 (530) | 9.38 (238) | 19.25 (489) | 7.25 (184) | 0.13 (2) | Formed | 0.50 (13) | 4 | 6.5 lbs. | 24 x 12 Disconnect enclosure |
| FMPC2424 | 20.88 (530) | 21.38 (543) | 19.25 (489) | 19.25 (489) | 0.13 (2) | Formed | 0.50 (13) | 4 | 14 lbs. | 24 x 24 Disconnect enclosure |
| FMPC3024 | 26.88 (683) | 21.38 (543) | 25.25 (641) | 19.25 (489) | 0.13 (2) | Formed | 0.50 (13) | 4 | 19 lbs. | 30 x 24 Disconnect enclosure |
| FMPC3630 | 32.88 (835) | 27.38 (695) | 31.25 (794) | 25.25 (641) | 0.13 (2) | Formed | 0.50 (13) | 5 | 27 lbs. | 36 x 30 Disconnect enclosure |

Mounting Plates for NEMA 3R, NEMA 4X & Large Fiberglass Enclosure Dimensions

| Catalog Number | BA | BB | BK | BL | BT (SA) | BT (C) | Panel Type | Hole Dia. | # of Holes | Weight (Aluminum) Suffix: SA | Weight (Carbon Steel) Suffix: C |
|---------------------------|-----------------|----------------|-----------------|----------------|--------------|--------------|------------|--------------|------------|------------------------------|---------------------------------|
| FMPWM1610SA FMPWM1610C | 13.00 (330) | 8.50 (216) | 12.00 (305) | 7.50 (191) | 0.090 (2) | 0.105 (3) | Flat | 0.31 (8) | 4 | 1 lb. | 3.3 lbs. |
| FMPWM2016SA FMPWM2016C | 17.00 (432) | 13.00 (330) | 15.25 (387) | 11.25 (286) | 0.090 (2) | 0.105 (3) | Flat | 0.50 (13) | 4 | 2 lbs. | 6.7 lbs. |
| FMPWM2412SA FMPWM2412C | 21.00 (533) | 9.00 (229) | 19.25 (489) | 7.25 (184) | 0.090 (2) | 0.105 (3) | Flat | 0.50 (13) | 4 | 4.5 lbs. | 8.7 lbs. |
| FMPWM2420SA FMPWM2420C | 21.00 (533) | 17.00 (432) | 19.25 (489) | 15.25 (387) | 0.13 (3) | 0.105 (3) | Flat | 0.50 (13) | 4 | 5 lbs. | 10.8 lbs. |
| FMPWM2424SA FMPWM2424C | 21.00 (533) | 21.00 (533) | 19.25 (489) | 19.25 (489) | 0.13 (3) | 0.105 (3) | Flat | 0.50 (13) | 4 | 5.5 lbs. | 13.4 lbs. |
| FMPWM3020SA FMPWM3020C | 27.00 (686) | 17.00 (432) | 25.25 (641) | 15.25 (387) | 0.13 (3) | 0.105 (3) | Flat | 0.50 (13) | 4 | 5.8 lbs. | 14 lbs. |
| FMPWM3024SA FMPWM3024C | 27.00 (686) | 21.00 (533) | 25.25 (641) | 19.25 (489) | 0.13 (3) | 0.105 (3) | Flat | 0.50 (13) | 4 | 7 lbs. | 17 lbs. |
| FMPWM3630SA FMPWM3630C | 33.00 (838) | 27.00 (686) | 31.25 (794) | 25.25 (641) | 0.13 (3) | 0.105 (3) | Flat | 0.50 (13) | 4 | 11 lbs. | 27 lbs. |
| FMPWM3636SA FMPWM3636C | 31.00 (787) | 33.00 (838) | 29.00 (737) | 31.00 (787) | 0.13 (3) | 0.105 (3) | Formed | 0.50 (13) | 6 | 13 lbs. | 33 lbs. |
| FMPWM3648C | 31.00 (787) | 22.00 (559) | 29.00 (737) | 20.00 (508) | 0.13 (3) | 0.105 (3) | Flat | 0.50 (13) | 8 | 22 lbs. | 41 lbs. |
| FMPWM4836SA FMPWM4836C | 45.00 (1143) | 33.00 (838) | 43.25 (1099) | 31.25 (794) | 0.13 (3) | 0.105 (3) | Formed | 0.50 (13) | 8 | 22 lbs. | 47 lbs. |
| FMPWM6036SA FMPWM6036C | 57.00 (1448) | 33.00 (838) | 55.25 (1403) | 31.25 (794) | 0.13 (3) | 0.105 (3) | Formed | 0.50 (13) | 8 | 23 lbs. | 60 lbs. |
| FMPWM7225C | 64.00 (1626) | 21.00 (533) | 62.00 (1575) | 19.00 (483) | 0.13 (3) | 0.105 (3) | Formed | 0.50 (13) | 10 | 30 lbs. | 43 lbs. |
| FMPWM7249C | 64.00 (1626) | 22.00 (559) | 62.00 (1575) | 20.00 (508) | 0.13 (3) | 0.105 (3) | Formed | 0.50 (13) | 10 | 38 lbs. | 91 lbs. |



Mounting Plates for FSJ, FPB, FJ, FRCJ, FXDJ, FA Series Enclosures

| Catalog Number | BA | BB | BK | BL | BT (SA) | BT (FG) | BT (SS) | BT (C) | Panel Type | Hole Dia. | # of Holes | Weight (Aluminum) Suffix: SA | Weight (Fiberglass) Suffix: FG | Weight (Stainless) Suffix: SS | Weight (Carbon Steel) Suffix: C |
|---|---------------|---------------|---------------|---------------|--------------|--------------|--------------|--------------|------------|-------------|------------|------------------------------|--------------------------------|-------------------------------|---------------------------------|
| FMP0604SA FMP0604FG FMP0604SS FMP0604C | 4.88 (124) | 2.88 (73) | 4.25 (108) | 2.25 (57) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 2 oz. | 2 oz. | 5 oz. | 5 oz. |
| FMP0606SA FMP0606FG FMP0606SS FMP0606C | 4.88 (124) | 4.88 (124) | 4.25 (108) | 4.25 (108) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 3 oz. | 3 oz. | 8 oz. | 8 oz. |
| FMP0706SA FMP0706FG FMP0706SS FMP0706C | 6.00 (152) | 4.88 (124) | 5.38 (137) | 4.25 (108) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 4 oz. | n/a | n/a | 10 oz. |
| FMP0806SA FMP0806FG FMP0806SS FMP0806C | 6.88 (175) | 4.88 (124) | 6.25 (159) | 4.25 (108) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 4 oz. | 4 oz. | 12 oz. | 12 oz. |
| FMP0808SA FMP0808FG FMP0808SS FMP0808C | 6.88 (175) | 6.88 (175) | 6.25 (159) | 6.25 (159) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 5 oz. | 5 oz. | 15 oz. | 15 oz. |
| FMP0906SA FMP0906FG FMP0906SS FMP0906C | 8.25 (210) | 4.88 (124) | 7.63 (194) | 4.25 (108) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 5 oz. | n/a | n/a | 14 oz. |

5E Fiberglass Enclosure Accessories


Mounting Plates for FSJ, FPB, FJ, FRCJ, FXDJ, FA Series Enclosures

| Catalog Number | BA | BB | BK | BL | BT (SA) | BT (FG) | BT (SS) | BT (C) | Panel Type | Hole Dia. | # of Holes | Weight (Aluminum) Suffix: SA | Weight (Fiberglass) Suffix: FG | Weight (Stainless) Suffix: SS | Weight (Carbon Steel) Suffix: C |
|---|----------------|----------------|----------------|----------------|--------------|--------------|--------------|--------------|------------|-------------|------------|------------------------------|--------------------------------|-------------------------------|---------------------------------|
| FMP1008SA FMP1008FG FMP1008SS FMP1008C | 8.88 (225) | 6.88 (175) | 8.25 (210) | 6.25 (159) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 8 oz. | 8 oz. | 19 oz. | 21 oz. |
| FMP1210SA FMP1210FG FMP1210SS FMP1210C | 10.88 (276) | 8.88 (225) | 10.25 (260) | 8.25 (210) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 12 oz. | 14 oz. | 30 oz. | 33 oz. |
| FMP1212SA FMP1212FG FMP1212SS FMP1212C | 10.88 (276) | 10.88 (276) | 10.25 (260) | 10.25 (260) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 16 oz. | 18 oz. | 37 oz. | 38 oz. |
| FMP1407SA FMP1407FG FMP1407SS FMP1407C | 12.88 (327) | 5.88 (149) | 12.25 (311) | 5.25 (133) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 14 oz. | 14 oz. | 32 oz. | 34 oz. |
| FMP1412SA FMP1412FG FMP1412SS FMP1412C | 12.88 (327) | 10.88 (276) | 12.25 (311) | 10.25 (260) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 18 oz. | 20 oz. | 45 oz. | 48 oz. |
| FMP1614SA FMP1614FG FMP1614SS FMP1614C | 14.88 (378) | 12.88 (327) | 14.25 (362) | 12.25 (311) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 24 oz. | 23 oz. | 60 oz. | 66 oz. |
| FMP1816SA FMP1816FG FMP1816SS FMP1816C | 16.88 (429) | 14.88 (378) | 16.25 (413) | 14.25 (362) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 31 oz. | 32 oz. | 88 oz. | 87 oz. |
| FMP2016SA FMP2016FG FMP2016SS FMP2016C | 18.88 (479) | 14.88 (378) | 18.25 (463) | 14.25 (362) | 0.080 (2) | 0.125 (3) | 0.060 (2) | 0.075 (2) | Flat | 0.25 (6) | 4 | 36 oz. | 34 oz. | 98 oz. | 97 oz. |

5E

Cover Panel Dimensions

| Catalog Number | A | B | C | D | Panel Thk. | Panel Type | Hole Dia. | # of Holes |
|----------------|----------------|----------------|----------------|----------------|--------------|------------|-------------|------------|
| FACP0606SA | 5.64 (143) | 5.64 (143) | 5.02 (127) | 5.02 (127) | 0.080 (2) | Flat | 0.25 (6) | 4 |
| FACP0806SA | 7.68 (195) | 5.64 (143) | 7.05 (179) | 5.02 (127) | 0.080 (2) | Flat | 0.25 (6) | 4 |
| FACP0808SA | 7.68 (195) | 7.68 (195) | 7.05 (179) | 7.05 (179) | 0.080 (2) | Flat | 0.25 (6) | 4 |
| FACP1008SA | 9.71 (247) | 7.71 (196) | 9.08 (231) | 7.08 (180) | 0.080 (2) | Flat | 0.25 (6) | 4 |
| FACP1210SA | 11.74 (298) | 9.74 (247) | 11.12 (282) | 9.12 (232) | 0.080 (2) | Flat | 0.25 (6) | 4 |
| FACP1412SA | 13.78 (350) | 11.78 (299) | 13.15 (334) | 11.15 (283) | 0.080 (2) | Flat | 0.25 (6) | 4 |
| FACP1614SA | 15.81 (402) | 13.81 (351) | 15.18 (386) | 13.18 (334) | 0.080 (2) | Flat | 0.25 (6) | 4 |
| FACP1816SA | 17.94 (456) | 15.94 (405) | 17.31 (440) | 15.31 (389) | 0.080 (2) | Flat | 0.25 (6) | 4 |
| FACP2016SA | 19.76 (502) | 15.76 (400) | 19.13 (486) | 15.13 (384) | 0.080 (2) | Flat | 0.25 (6) | 4 |

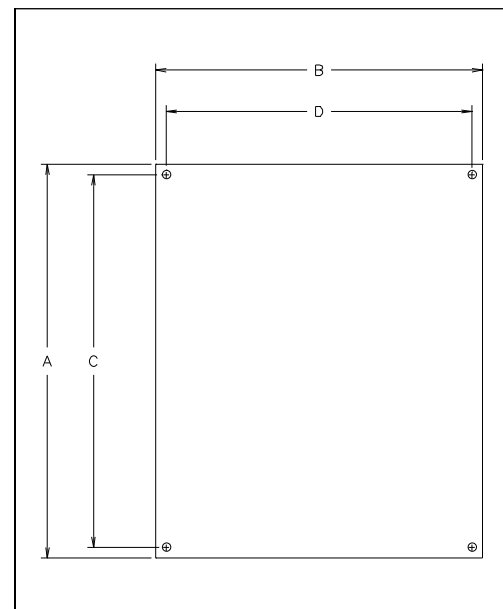

Note: Cover panel kit includes cover panel and mounting hardware.