

# Type 4X Panel Enclosures

## Wall-Mount Enclosures Type 4X Single-Door Data and Illustration Sheet



### Application

- Houses electrical controls and instruments
- Intended for indoor or outdoor use where a corrosive environment exists
- Protects against corrosion, windblown dust and rain, splashing water and hose directed water

### Standards

- UL 508 Listed, Type 4, Type 4X, Type 12 and Type 13
- CSA C22.2 No. 94 Certified, Type 4, Type 4X, Type 12 and Type 13
- Conforms to NEMA Standard for Type 4, Type 4X, Type 12 and Type 13

### Construction




- Enclosure and door are fabricated from (14) gauge, Type 304 or Type 316L stainless steel
- All continuous welded seams are finished smooth
- Doors are secured to the body with a heavy duty stainless steel continuous hinge and pin on one side and easy-to-release stainless steel door clamps mounted to the other three sides
- Each door has a padlock hasp with sealing hole provision
- Print pocket provided
- Door has a seamless poured in place gasket
- Ground stud provided on door
- Formed lip around enclosure opening diverts liquids and contaminants
- .375-16 collar studs are provided for mounting optional panel
- External mounting feet are provided for secure wall mounting

### Finish

- Door and sides of body have a smooth #4 brushed finish

### Accessories

- Panels
- NEMA terminal strap kit
- Terminal blocks
- Floor stand kit
- See Accessories section

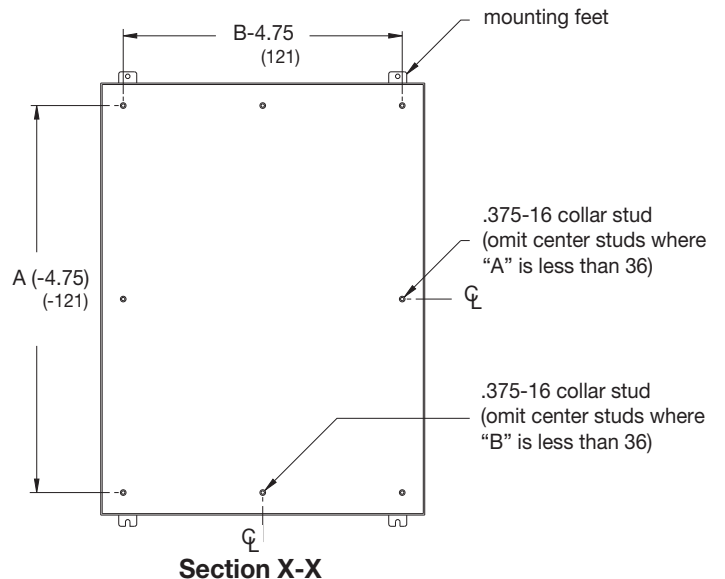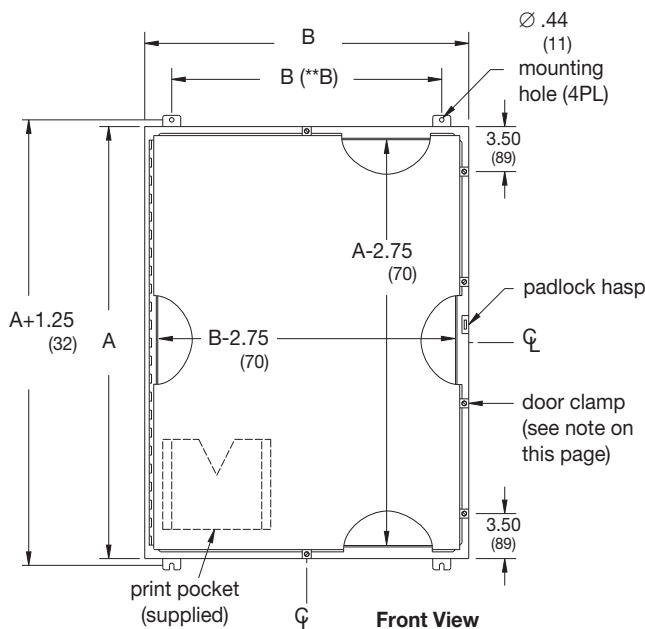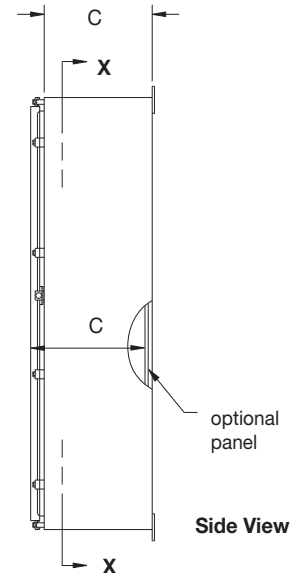

Notes: Dimensions: \*\*B = (-2.50) if 12 inches wide; (-6.00) if wider than 12 inches.

# Type 4X Panel Enclosures

## Wall-Mount Enclosures Type 4X Single-Door Catalog Number

Enclosure Catalog #		Enclosure Size Height x Width x Depth AxBxC		Panel Catalog #		Panel Size Height x Width	
		in.	mm.	Steel	Conductive	in.	mm.
CH16126-4XS	CH16126-4XSS6	16.00 x 12.00 x 6.00	406 x 305 x 152	CHAW1612P	CHAW1612GP	13.00 x 9.00	330 x 229
CH16166-4XS	CH16166-4XSS6	16.00 x 16.00 x 6.00	406 x 406 x 152	CHAW1616P	CHAW1616GP	13.00 x 13.00	330 x 330
CH16206-4XS	CH16206-4XSS6	16.00 x 20.00 x 6.00	406 x 508 x 152	CHAW2016P	CHAW2016GP	17.00 x 13.00	432 x 330
CH20166-4XS	CH20166-4XSS6	20.00 x 16.00 x 6.00	508 x 406 x 152	CHAW2016P	CHAW2016GP	17.00 x 13.00	432 x 330
CH20206-4XS	CH20206-4XSS6	20.00 x 20.00 x 6.00	508 x 508 x 152	CHAW2020P	CHAW2020GP	17.00 x 17.00	432 x 432
CH24126-4XS	CH24126-4XSS6	24.00 x 12.00 x 6.00	610 x 305 x 152	CHAW2412P	--	21.00 x 9.00	533 x 229
CH24166-4XS	CH24166-4XSS6	24.00 x 16.00 x 6.00	610 x 406 x 152	CHAW2416P	CHAW2416GP	21.00 x 13.00	533 x 330
CH24206-4XS	CH24206-4XSS6	24.00 x 20.00 x 6.00	610 x 508 x 152	CHAW2420P	CHAW2420GP	20.87 x 16.87	530 x 428
CH24246-4XS	CH24246-4XSS6	24.00 x 24.00 x 6.00	610 x 610 x 152	CHAW2424P	CHAW2424GP	20.87 x 20.87	530 x 530
CH30246-4XS	CH30246-4XSS6	30.00 x 24.00 x 6.00	762 x 610 x 152	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH36246-4XS	CH36246-4XSS6	36.00 x 24.00 x 6.00	914 x 610 x 152	CHAW3624P	CHAW3624GP	32.87 x 20.87	835 x 530
CH16128-4XS	CH16128-4XSS6	16.00 x 12.00 x 8.00	406 x 305 x 203	CHAW1612P	CHAW1612GP	13.00 x 9.00	330 x 229
CH20168-4XS	CH20168-4XSS6	20.00 x 16.00 x 8.00	508 x 406 x 203	CHAW2016P	CHAW2016GP	17.00 x 13.00	432 x 330
CH20208-4XS	CH20208-4XSS6	20.00 x 20.00 x 8.00	508 x 508 x 203	CHAW2020P	CHAW2020GP	17.00 x 17.00	432 x 432
CH20248-4XS	CH20248-4XSS6	20.00 x 24.00 x 8.00	508 x 610 x 203	CHAW2420P	CHAW2420GP	32.87 x 26.87	835 x 682
CH24168-4XS	CH24168-4XSS6	24.00 x 16.00 x 8.00	610 x 406 x 203	CHAW2416P	CHAW2416GP	21.00 x 13.00	533 x 330
CH24208-4XS	CH24208-4XSS6	24.00 x 20.00 x 8.00	610 x 508 x 203	CHAW2420P	CHAW2420GP	20.87 x 16.87	530 x 428
CH24248-4XS	CH24248-4XSS6	24.00 x 24.00 x 8.00	610 x 610 x 203	CHAW2424P	CHAW2424GP	20.87 x 20.87	530 x 530
CH24308-4XS	CH24308-4XSS6	24.00 x 30.00 x 8.00	610 x 762 x 203	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH30208-4XS	CH30208-4XSS6	30.00 x 20.00 x 8.00	762 x 508 x 203	CHAW3020P	CHAW3020GP	26.87 x 16.87	682 x 428
CH30248-4XS	CH30248-4XSS6	30.00 x 24.00 x 8.00	762 x 610 x 203	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH30308-4XS	CH30308-4XSS6	30.00 x 30.00 x 8.00	762 x 762 x 203	CHAW3030P	CHAW3030GP	26.87 x 26.87	682 x 682
CH36248-4XS	CH36248-4XSS6	36.00 x 24.00 x 8.00	914 x 610 x 203	CHAW3624P	CHAW3624GP	32.87 x 20.87	835 x 530
CH36308-4XS	CH36308-4XSS6	36.00 x 30.00 x 8.00	914 x 762 x 203	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH42308-4XS	CH42308-4XSS6	42.00 x 30.00 x 8.00	1067 x 762 x 203	CHAW4230P	CHAW4230GP	38.87 x 26.87	987 x 682
CH42368-4XS	CH42368-4XSS6	42.00 x 36.00 x 8.00	1067 x 914 x 203	CHAW4236P	CHAW4236GP	38.87 x 32.87	987 x 835
CH48368-4XS	CH48368-4XSS6	48.00 x 36.00 x 8.00	1219 x 914 x 203	CHAW4836P	CHAW4836GP	44.87 x 32.87	1140 x 835
CH201610-4XS	CH201610-4XSS6	20.00 x 16.00 x 10.00	508 x 406 x 254	CHAW2016P	CHAW2016GP	17.00 x 13.00	432 x 330
CH242010-4XS	CH242010-4XSS6	24.00 x 20.00 x 10.00	610 x 508 x 254	CHAW2420P	CHAW2420GP	20.87 x 16.87	530 x 428
CH302410-4XS	CH302410-4XSS6	30.00 x 24.00 x 10.00	762 x 610 x 254	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH362410-4XS	CH362410-4XSS6	36.00 x 24.00 x 10.00	914 x 610 x 254	CHAW3624P	CHAW3624GP	32.87 x 20.87	835 x 530
CH363010-4XS	CH363010-4XSS6	36.00 x 30.00 x 10.00	914 x 762 x 254	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH423010-4XS	CH423010-4XSS6	42.00 x 30.00 x 10.00	1067 x 762 x 254	CHAW4230P	CHAW4230GP	38.87 x 26.87	987 x 682
CH483010-4XS	CH483010-4XSS6	48.00 x 30.00 x 10.00	1219 x 762 x 254	CHAW4830P	CHAW4830GP	44.87 x 26.87	1140 x 682
CH483610-4XS	CH483610-4XSS6	48.00 x 36.00 x 10.00	1219 x 914 x 254	CHAW4836P	CHAW4836GP	44.87 x 32.87	1140 x 835
CH603610-4XS	CH603610-4XSS6	60.00 x 36.00 x 10.00	1524 x 914 x 254	CHAW6036P	CHAW6036GP	56.87 x 32.87	1444 x 835
CH242412-4XS	CH242412-4XSS6	24.00 x 24.00 x 12.00	610 x 610 x 305	CHAW2424P	CHAW2424GP	20.87 x 20.87	530 x 530
CH302412-4XS	CH302412-4XSS6	30.00 x 24.00 x 12.00	762 x 610 x 305	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH363012-4XS	CH363012-4XSS6	36.00 x 30.00 x 12.00	914 x 762 x 305	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH363612-4XS	CH363612-4XSS6	36.00 x 36.00 x 12.00	914 x 914 x 305	CHAW3636P	--	32.87 x 32.87	835 x 835
CH483612-4XS	CH483612-4XSS6	48.00 x 36.00 x 12.00	1219 x 914 x 305	CHAW4836P	CHAW4836GP	44.87 x 32.87	1140 x 835
CH603612-4XS	CH603612-4XSS6	60.00 x 36.00 x 12.00	1524 x 914 x 305	CHAW6036P	CHAW6036GP	56.87 x 32.87	1444 x 835
CH302416-4XS	CH302416-4XSS6	30.00 x 24.00 x 16.00	762 x 610 x 406	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH363016-4XS	CH363016-4XSS6	36.00 x 30.00 x 16.00	914 x 762 x 406	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH483616-4XS	CH483616-4XSS6	48.00 x 36.00 x 16.00	1219 x 914 x 406	CHAW4836P	CHAW4836GP	44.87 x 32.87	1140 x 835
CH603616-4XS	CH603616-4XSS6	60.00 x 36.00 x 16.00	1524 x 914 x 406	CHAW6036P	CHAW6036GP	56.87 x 32.87	1444 x 835

**Notes:** Clamps are mounted along three sides of the enclosure door. Spacing between clamps along side opposite the hinge does not exceed 15 inches. Dimensions are in inches. Millimeters shown are for reference only. Data subject to change without notice.

# Type 4X Panel Enclosures

## Wall-Mount Enclosures Type 4X Single-Door, Aluminum Data Sheet and Catalog Number



### Application

- Houses electrical controls and instruments
- Intended for indoor or outdoor use where a corrosive environment exists
- Protects against corrosion, windblown dust and rain, splashing water and hose directed water

### Standards

- UL 508 Listed, Type 4, Type 4X, Type 12 and Type 13
- CSA C22.2 No. 94 Certified, Type 4, Type 4X, Type 12 and Type 13
- Conforms to NEMA Standard for Type 4, Type 4X, Type 12 and Type 13

### Finish

- Door and sides of body have a smooth #4 brushed finish

### Accessories

- Panels
- NEMA terminal strap kit
- Terminal blocks
- Floor stand kit
- See Accessories section

### Construction


- Enclosure and door are fabricated from (14) gauge, Type 5052-H32 aluminum
- All continuous welded seams are finished smooth
- Doors are secured to the body with a heavy duty aluminum continuous hinge and pin on one side and easy to operate stainless steel door clamps mounted to the other three sides
- Each door has a padlock hasp with sealing hole provision
- Print pocket provided
- Door has a seamless poured in place gasket
- Formed lip around enclosure opening diverts liquids and contaminants
- .375-16 collar studs are provided for mounting optional panel
- External mounting feet are provided for secure wall mounting

Enclosure Catalog #	Enclosure Size Height x Width x Depth AxBxC		Panel Catalog #		Panel Size Height x Width	
	in.	mm.	Steel	Conductive	in.	mm.
CH16126-4XA	16.00 x 12.00 x 6.00	406 x 305 x 152	CHAW1612P	CHAW1612GP	13.00 x 9.00	330 x 229
CH16166-4XA	16.00 x 16.00 x 6.00	406 x 406 x 152	CHAW1616P	CHAW1616GP	13.00 x 13.00	330 x 330
CH20166-4XA	20.00 x 16.00 x 6.00	508 x 406 x 152	CHAW2016P	CHAW2016GP	17.00 x 13.00	432 x 330
CH20206-4XA	20.00 x 20.00 x 6.00	508 x 508 x 152	CHAW2020P	CHAW2020GP	17.00 x 17.00	432 x 432
CH24206-4XA	24.00 x 20.00 x 6.00	610 x 508 x 152	CHAW2420P	CHAW2420GP	20.87 x 16.87	530 x 428
CH16128-4XA	16.00 x 12.00 x 8.00	406 x 305 x 203	CHAW1612P	CHAW1612GP	13.00 x 9.00	330 x 229
CH20168-4XA	20.00 x 16.00 x 8.00	508 x 406 x 203	CHAW2016P	CHAW2016GP	17.00 x 13.00	432 x 330
CH24168-4XA	24.00 x 16.00 x 8.00	610 x 406 x 203	CHAW2416P	CHAW2416GP	21.00 x 13.00	533 x 330
CH24208-4XA	24.00 x 20.00 x 8.00	610 x 508 x 203	CHAW2420P	CHAW2420GP	20.87 x 16.87	530 x 428
CH24248-4XA	24.00 x 24.00 x 8.00	610 x 610 x 203	CHAW2424P	CHAW2424GP	20.87 x 20.87	530 x 530
CH24308-4XA	24.00 x 30.00 x 8.00	610 x 762 x 203	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH30208-4XA	30.00 x 20.00 x 8.00	762 x 508 x 203	CHAW3020P	CHAW3020GP	26.87 x 16.87	682 x 428
CH30248-4XA	30.00 x 24.00 x 8.00	762 x 610 x 203	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH30308-4XA	30.00 x 30.00 x 8.00	762 x 762 x 203	CHAW3030P	CHAW3030GP	26.87 x 26.87	682 x 682
CH36248-4XA	36.00 x 24.00 x 8.00	914 x 610 x 203	CHAW3624P	CHAW3624GP	32.87 x 20.87	835 x 530
CH36308-4XA	36.00 x 30.00 x 8.00	914 x 762 x 203	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH42368-4XA	42.00 x 36.00 x 8.00	1067 x 914 x 203	CHAW4236P	CHAW4236GP	38.87 x 32.87	987 x 835
CH48368-4XA	48.00 x 36.00 x 8.00	1219 x 914 x 203	CHAW4836P	CHAW4836GP	44.87 x 32.87	1140 x 835

# Type 4X Panel Enclosures

## Wall-Mount Enclosures Type 4X Single-Door, Aluminum Data Sheet and Catalog Number

Enclosure Catalog #	Enclosure Size Height x Width x Depth AxBxC		Panel Catalog #		Panel Size Height x Width	
	in.	mm.	Steel	Conductive	in.	mm.
CH201610-4XA	20.00 x 16.00 x 10.00	508 x 406 x 254	CHAW2016P	CHAW2016GP	17.00 x 13.00	432 x 330
CH242010-4XA	24.00 x 20.00 x 10.00	610 x 508 x 254	CHAW2420P	CHAW2420GP	20.87 x 16.87	530 x 428
CH362410-4XA	36.00 x 24.00 x 10.00	914 x 610 x 254	CHAW3624P	CHAW3624GP	32.87 x 20.87	835 x 530
CH363010-4XA	36.00 x 30.00 x 10.00	914 x 762 x 254	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH423010-4XA	42.00 x 30.00 x 10.00	1067 x 762 x 254	CHAW4230P	CHAW4230GP	38.87 x 26.87	987 x 682
CH242412-4XA	24.00 x 24.00 x 12.00	610 x 610 x 305	CHAW2424P	CHAW2424GP	20.87 x 20.87	530 x 530
CH302412-4XA	30.00 x 24.00 x 12.00	762 x 610 x 305	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH363012-4XA	36.00 x 30.00 x 12.00	914 x 762 x 305	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH483612-4XA	48.00 x 36.00 x 12.00	1219 x 914 x 305	CHAW4836P	CHAW4836GP	44.87 x 32.87	1140 x 835
CH603612-4XA	60.00 x 36.00 x 12.00	1524 x 914 x 305	CHAW6036P	CHAW6036GP	56.87 x 32.87	1444 x 835
CH362416-4XA	36.00 x 24.00 x 16.00	914 x 610 x 406	CHAW3624P	CHAW3624GP	32.87 x 20.87	835 x 530
CH363016-4XA	36.00 x 30.00 x 16.00	914 x 762 x 406	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH483616-4XA	48.00 x 36.00 x 16.00	1219 x 914 x 406	CHAW4836P	CHAW4836GP	44.87 x 32.87	1140 x 835

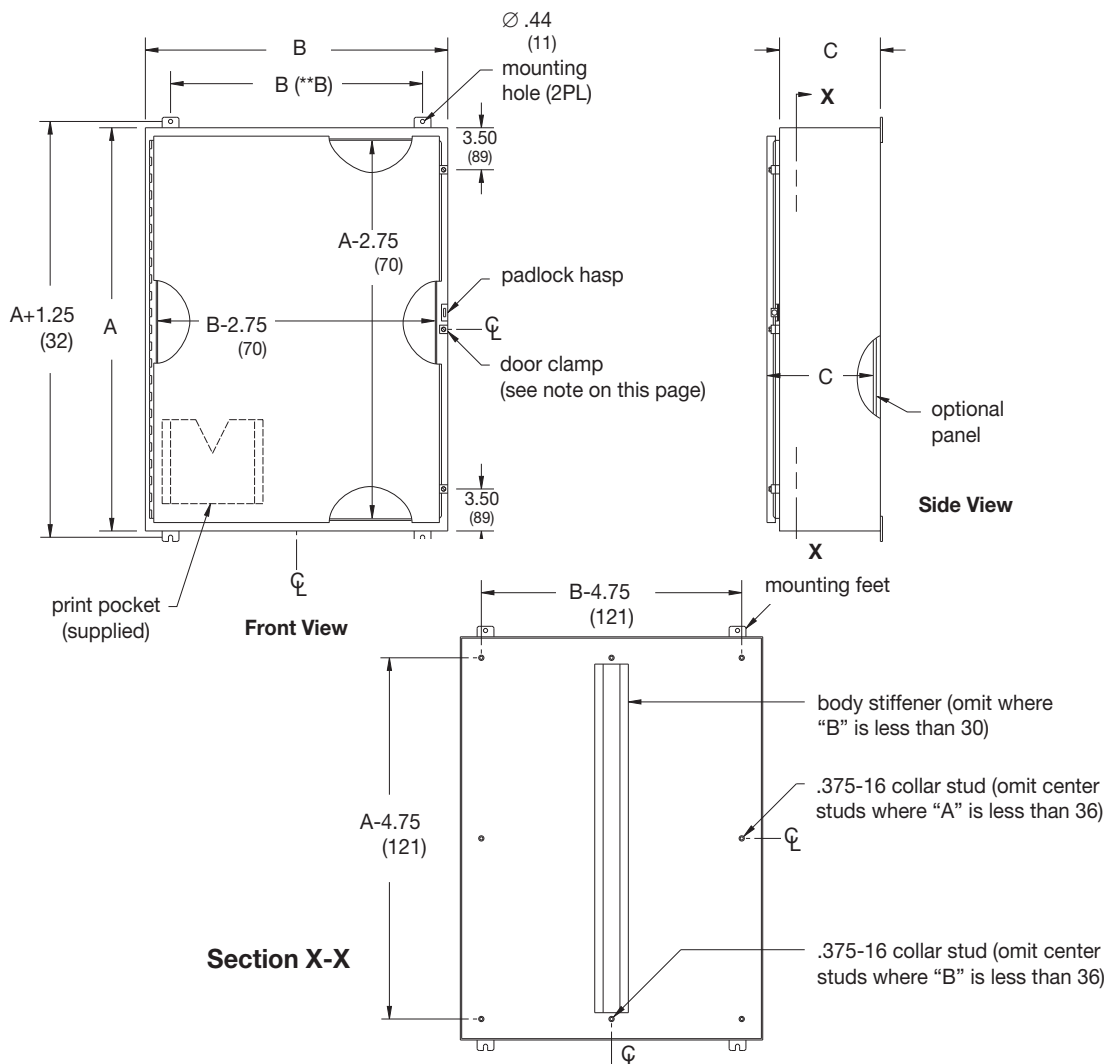

**Notes:** Dimensions: \*\*B = (-2.50) if 12 inches wide; (-6.00) if wider than 12 inches. Clamps are mounted along three sides of the enclosure door. Spacing between clamps along side opposite the hinge does not exceed 15 inches. Dimensions are in inches. Millimeters shown are for reference only. Data subject to change without notice.

# Type 4X Panel Enclosures

## Wall-Mount Enclosures Type 4X Single-Door with 3-Point Locking Data Sheet and Catalog Number



### Finish

- Door and sides of body have a smooth #4 brushed finish

### Accessories

- Panels
- Swing-out panel kits
- NEMA terminal kits
- Window kits
- Floor stand kit
- Replacement handle

### Application

- Houses electrical controls and instruments
- Intended for indoor or outdoor use where a corrosive environment exists
- Protects against windblown dust and rain, splashing water and hose directed water

### Standards

- UL 508 Listed, Type 3R, Type 4, Type 4X and Type 12
- CSA C22.2 No. 94 Certified, Type 3R, Type 4, Type 4X and Type 12
- Conforms to NEMA Standards for Type 3, Type 3R, Type 4, Type 4X and Type 12
- Meets NEMA Type 3R requirements

### Construction

- Enclosure and door are fabricated from (14) gauge stainless steel
- All continuous welded seams are finished smooth
- Stainless steel continuous hinge and pin
- Internal 3-point latching with a stainless padlocking handle
- Door has a seamless poured in place gasket
- Formed lip around enclosure opening diverts liquids and contaminants
- Ground stud provided on door
- Print pocket provided
- .375-16 collar studs are provided for mounting optional panel
- External mounting feet

Enclosure Catalog #		Enclosure Size Height x Width x Depth AxBxC		Panel	Conductive	Panel Size Height x Width	
Type 304	Type 316L	in.	mm.	Catalog #	Catalog #	in.	mm.
CH24206-4XS3PT	CH24206-4XSS63PT	24.00 x 20.00 x 6.00	609 x 508 x 152	CHAW2420P	CHAW2420GP	20.87 x 16.87	530 x 428
CH24208-4XS3PT	CH24208-4XSS63PT	24.00 x 20.00 x 8.00	609 x 508 x 203	CHAW2420P	CHAW2420GP	20.87 x 16.87	530 x 428
CH24248-4XS3PT	CH24248-4XSS63PT	24.00 x 24.00 x 8.00	609 x 609 x 203	CHAW2424P	CHAW2424GP	20.87 x 20.87	530 x 530
CH30248-4XS3PT	CH30248-4XSS63PT	30.00 x 24.00 x 8.00	762 x 609 x 203	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH30308-4XS3PT	CH30308-4XSS63PT	30.00 x 30.00 x 8.00	762 x 762 x 203	CHAW3030P	CHAW3030GP	26.87 x 26.87	682 x 682
CH36248-4XS3PT	CH36248-4XSS63PT	36.00 x 24.00 x 8.00	914 x 609 x 203	CHAW3624P	CHAW3624GP	32.87 x 20.87	835 x 530
CH36308-4XS3PT	CH36308-4XSS63PT	36.00 x 30.00 x 8.00	914 x 762 x 203	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH48368-4XS3PT	CH48368-4XSS63PT	48.00 x 36.00 x 8.00	1219 x 914 x 203	CHAW4836P	CHAW4836GP	44.87 x 32.87	1139 x 835
CH242010-4XS3PT	CH242010-4XSS63PT	24.00 x 20.00 x 10.00	609 x 508 x 254	CHAW2420P	CHAW2420GP	20.87 x 16.87	530 x 428
CH363010-4XS3PT	CH363010-4XSS63PT	36.00 x 30.00 x 10.00	914 x 762 x 254	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH423010-4XS3PT	CH423010-4XSS63PT	42.00 x 30.00 x 10.00	1067 x 762 x 254	CHAW4230P	CHAW4230GP	38.87 x 26.87	987 x 682
CH483610-4XS3PT	CH483610-4XSS63PT	48.00 x 36.00 x 10.00	1219 x 914 x 254	CHAW4836P	CHAW4836GP	44.87 x 32.87	1139 x 835


# Type 4X Panel Enclosures

## Wall-Mount Enclosures

### Type 4X Single-Door with 3-Point Locking

#### Illustration Sheet and Catalog Number

Enclosure Catalog #		Enclosure Size Height x Width x Depth AxBxC		Panel	Conductive	Panel Size Height x Width	
Type 304	Type 316L	in.	mm.	Catalog #	Catalog #	in.	mm.
CH242412-4XS3PT	CH242412-4XSS63PT	24.00 x 24.00 x 12.00	609 x 609 x 305	CHAW2424P	CHAW2424GP	20.87 x 20.87	530 x 530
CH302412-4XS3PT	CH302412-4XSS63PT	30.00 x 24.00 x 12.00	762 x 609 x 305	CHAW3024P	CHAW3024GP	26.87 x 20.87	682 x 530
CH363012-4XS3PT	CH363012-4XSS63PT	36.00 x 30.00 x 12.00	914 x 762 x 305	CHAW3630P	CHAW3630GP	32.87 x 26.87	835 x 682
CH363612-4XS3PT	CH363612-4XSS63PT	36.00 x 36.00 x 12.00	914 x 914 x 305	CHAW3636P	CHAW3636GP	32.87 x 32.87	835 x 835
CH423612-4XS3PT	CH423612-4XSS63PT	42.00 x 36.00 x 12.00	1067 x 914 x 305	CHAW4236P	CHAW4236GP	38.87 x 32.87	987 x 835
CH483612-4XS3PT	CH483612-4XSS63PT	48.00 x 36.00 x 12.00	1219 x 914 x 305	CHAW4836P	CHAW4836GP	44.87 x 32.87	1139 x 835
CH603612-4XS3PT	CH603612-4XSS63PT	60.00 x 36.00 x 12.00	1524 x 914 x 305	CHAW6036P	CHAW6036GP	56.87 x 32.87	1444 x 835
CH483616-4XS3PT	CH483616-4XSS63PT	48.00 x 36.00 x 16.00	1219 x 914 x 406	CHAW4836P	CHAW4836GP	44.87 x 32.87	1139 x 835
CH603616-4XS3PT	CH603616-4XSS63PT	60.00 x 36.00 x 16.00	1524 x 914 x 406	CHAW6036P	CHAW6036GP	56.87 x 32.87	1444 x 835

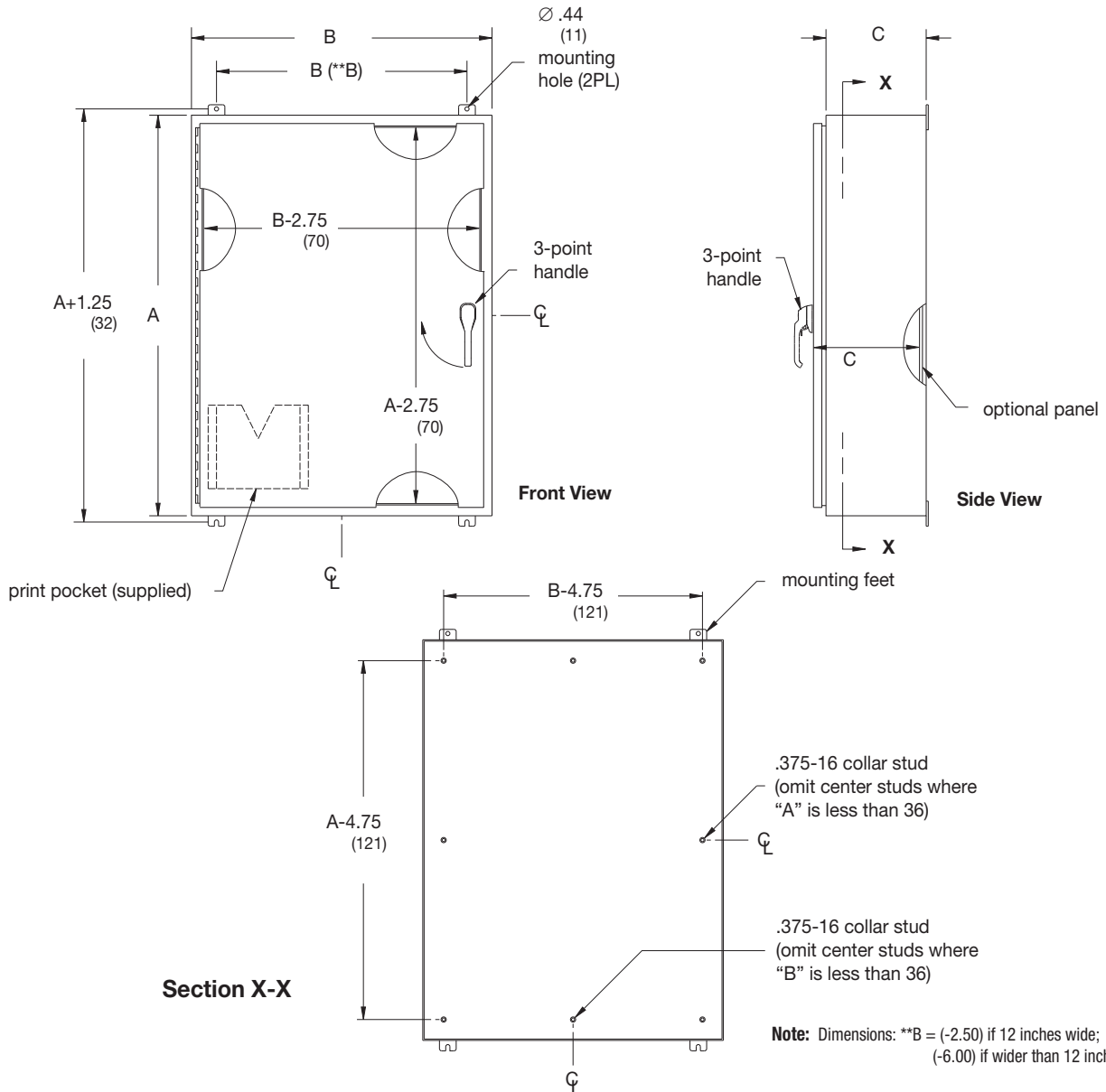

**Notes:** Dimensions are in inches. Millimeters shown are for reference only. Data subject to change without notice.

# Type 4X Panel Enclosures

## Wall-Mount Enclosures Type 4X Double-Door with 3-Point Locking Data Sheet and Catalog Number



### Application

- Houses electrical controls and instruments
- Intended for indoor or outdoor use where a corrosive environment exists
- Protects against corrosion, windblown dust and rain, splashing water and hose directed water

### Standards

- UL 508 Listed, Type 3R, Type 4, Type 4X and Type 12
- CSA C22.2 No. 94 Certified, Type 3R, Type 4, Type 4X and Type 12
- Conforms to NEMA Standards for Type 3, Type 3R, Type 4, Type 4X and Type 12
- Meets NEMA Type 3R requirements

### Finish

- Door and sides of body have a smooth #4 brushed finish

### Accessories

- Panels
- Swing-out panel kits
- Window kits
- Floor stand kit
- Lights
- Replacement handle

### Construction

- Enclosure and cover are fabricated from (14) gauge stainless steel
- All continuous welded seams are finished smooth
- Stainless steel continuous hinge and pin
- Internal 3-point latching with stainless padlocking handles
- Removable center post for easy panel installation
- Doors have a seamless poured in place gasket
- Formed lip around enclosure opening diverts liquids and contaminants
- Ground stud provided on door
- Print pocket provided
- .375-16 collar studs are provided for mounting optional panel
- External mounting feet

Enclosure Catalog #	Enclosure Size Height x Width x Depth AxBxC		Panel Catalog #	Conductive Catalog #	Panel Size Height x Width	
	in.	mm.			in.	mm.
CH24428-4XSD3PT	24.00 x 42.00 x 8.00	609 x 1067 x 203	CHAW4224P	--	38.87 x 20.87	987 x 530
CH24488-4XSD3PT	24.00 x 48.00 x 8.00	609 x 1219 x 203	CHAW4824P	--	44.87 x 20.87	1139 x 530
CH304210-4XSD3PT	30.00 x 42.00 x 10.00	762 x 1067 x 254	CHAW4230P	CHAW4230GP	38.87 x 26.87	987 x 682
CH304810-4XSD3PT	30.00 x 48.00 x 10.00	762 x 1219 x 254	CHAW4830P	CHAW4830GP	44.87 x 26.87	1139 x 682
CH306010-4XSD3PT	30.00 x 60.00 x 10.00	762 x 1524 x 254	CHAW6030P	--	56.87 x 26.87	1444 x 682
CH364212-4XSD3PT	36.00 x 42.00 x 12.00	914 x 1067 x 305	CHAW4236P	CHAW4236GP	38.87 x 32.87	987 x 835
CH364812-4XSD3PT	36.00 x 48.00 x 12.00	914 x 1219 x 305	CHAW4836P	CHAW4836GP	44.87 x 32.87	1139 x 835
CH366012-4XSD3PT	36.00 x 60.00 x 12.00	914 x 1524 x 305	CHAW6036P	CHAW6036GP	56.87 x 32.87	1444 x 835
CH424212-4XSD3PT	42.00 x 42.00 x 12.00	1067 x 1067 x 305	CHAW4242P	--	38.87 x 38.87	987 x 987
CH424812-4XSD3PT	42.00 x 48.00 x 12.00	1067 x 1219 x 305	CHAW4842P	CHAW4824GP	44.87 x 38.87	1139 x 987
CH426012-4XSD3PT	42.00 x 60.00 x 12.00	1067 x 1524 x 305	CHAW6042P	--	56.87 x 38.87	1444 x 987
CH484812-4XSD3PT	48.00 x 48.00 x 12.00	1219 x 1219 x 305	CHAW4848P	--	44.87 x 44.87	1139 x 1139




# Type 4X Panel Enclosures

## Wall-Mount Enclosures

### Type 4X Double-Door with 3-Point Locking

#### Illustration Sheet

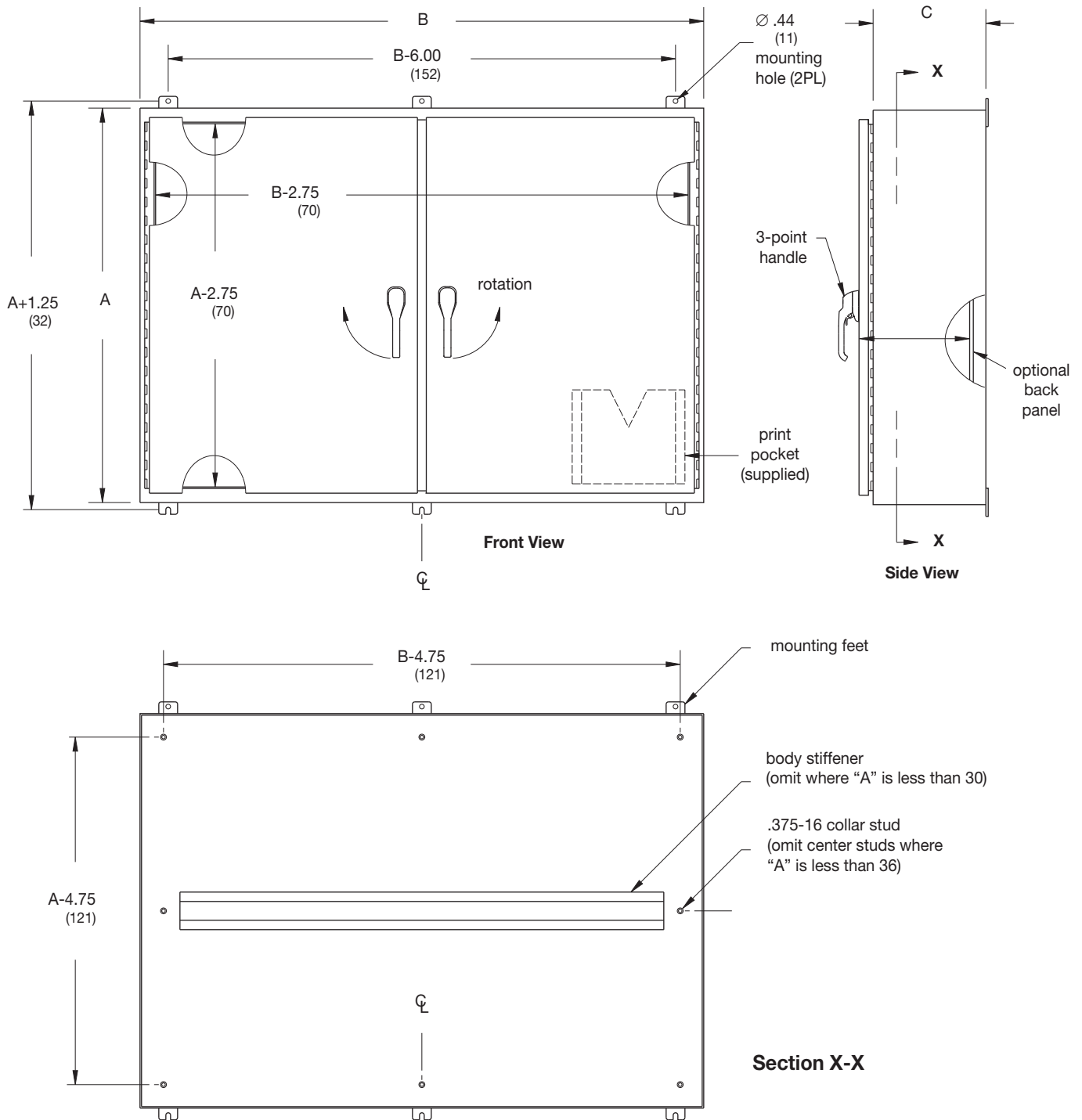

**Notes:** Dimensions are in inches. Millimeters shown are for reference only. Data subject to change without notice.