



Ergonomic Articulating Arms for Flat Panel Monitors



Powering Business Worldwide


Single/Dual Monitor Slatwall Solutions



KONWL9D
Dual arm, height-adjustable slatwall mount adjusts up to 13".




KONWL3B
Direct slatwall mount.

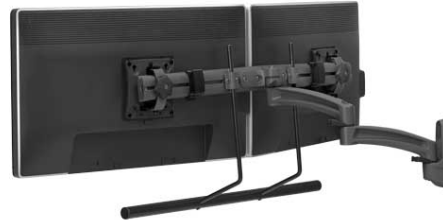

KONWL4B
Dual arm, dual monitor lateral adjustment slatwall mount.



KONWL10D
Dual arm, dual monitor, height-adjustable slatwall mount includes two independent arms. Adjusts up to 13".

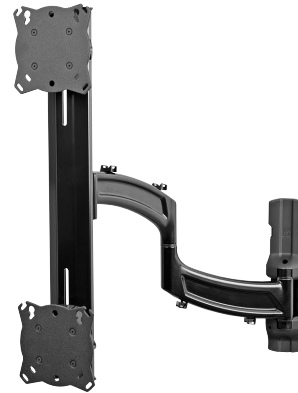

KONWL2B
Dual arm, vertical dual monitor mount includes slight height adjustment.



KONWL13D
Dual arm, height-adjustable slatwall mount adjusts up to 13", with Extreme Tilt range.

Eaton Item #	KONWL2B	KONWL3B	KONWL4B	KONWL9D	KONWL10D	KONWL13D
Dynamic Height Adjustment	-	-	-	13" (330.2mm)	13" (330.2mm)	13" (330.2mm)
Maximum Extension	16.2" (411.5mm)	-	18.6" (472.4mm)	21.0" (533.4mm)	16.5" (418.6mm)	21.0" (533.4mm)
Minimum Depth	8.1" (205.5mm)	2.9" (74.7mm)	5.9" (150.6mm)	2.1" (53.1mm)	3.0" (75.7mm)	2.1" (53.1mm)
Tilt	+/- 10°	+/- 15°	+/- 15°	+/- 15°	+/- 15°	+ 75° / - 10°
Typical Screen Sizes (diagonal)	10 - 30"	10 - 30"	10 - 30"	10 - 30"	10 - 30"	10 - 30"
Monitor Width Range	-	10 - 34" (254 - 864mm)	10 - 34" (254 - 864mm)	10 - 34" (254 - 864mm)	10 - 34" (254 - 864mm)	10 - 34" (254 - 864mm)
Monitor Height Range	10 - 17.7" (254 - 450mm)	-	-	-	-	-
Wall Stud Compatibility (inches)	Slatwall	Slatwall	Slatwall	Slatwall	Slatwall	Slatwall
MAX Weight Capacity (per monitor)	15 lbs (6.8kg)	40 lbs (18.1kg)	17 lbs (7.5kg)	25 lbs (11.3kg)	25 lbs (11.3kg)	25 lbs (11.3kg)

Single/Dual Monitor Grommet Solutions




KONWL6B

Dual monitor grommet mounts. Includes 32" pole mount with slight height adjustment. Includes decorative snap-on cable cover.



KONWL8B

Dual monitor grommet mounts. Includes 28" pole mount with generous height adjustment. Decorative snap-on cable cover.

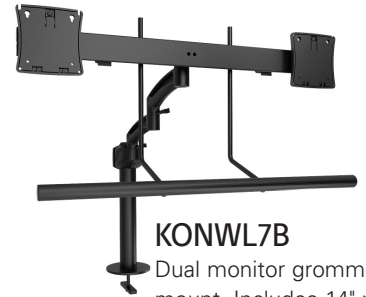

KONWL7B

Dual monitor grommet mount. Includes 14" pole mount and decorative snap-on cable cover.

Eaton Item #	KONWL6B	KONWL7B	KONWL8B	KONWL11D	KONWL12D
Dynamic Height Adjustment	-	-	-	13" (330.2mm)	13" (330.2mm)
Maximum Extension	-	20.0" (508mm)	20.0" (508mm)	19.9" (505.5mm)	-
Minimum Depth	-	7.0" (177.8mm)	7.0" (177.8mm)	2.1" (53.1mm)	-
Tilt	+/- 10°	+/- 15°	+/- 15°	+/- 15°	+/- 15°
Typical Screen Sizes (diagonal)	Up to 30"	10-24"	10-24"	10 - 30"	10 - 30"
Monitor Width Range	-	22.7"	22.7"	10 - 34" (254 - 864mm)	10 - 34" (254 - 864mm)
Wall Stud Compatibility (inches)	Pole	Pole	Pole	Clamp	Clamp
MAX Weight Capacity (per monitor)	15.0 lbs (6.8 kg)	15.0 lbs (6.8 kg)	15.0 lbs (6.8 kg)	25.0 lbs (11.3kg)	25.0 lbs (11.3kg)

Single/Dual Monitor Desk Mount Solutions



KONWL11D

Dual arm, single monitor, height-adjustable desk clamp. Includes clamp, grommet or bolt-through mounting options.



KONWL12D

Dual arm, dual monitor, desk clamp. Includes independent arms for larger monitor sizes.


Advanced Monitor Column Solutions




KONWLK0B
Pitch/pivot column head kit



KONWLK1B
Dynamic height adjustable column arm kit

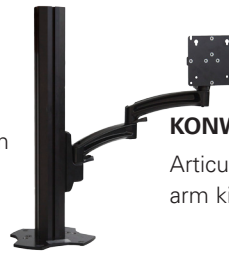

KONWLK2B
Articulating column arm kit

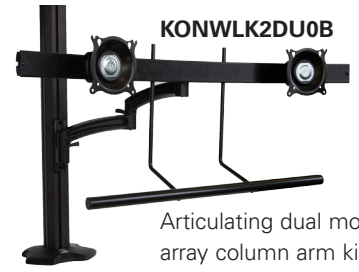

KONWLK2DU0B
Articulating dual monitor array column arm kit



KONWLC20B
20" Monitor mounting column & base plate kit



KONWLC30B
30" Monitor mounting column & base plate kit



TOACJSBUB
Universal flat panel interface bracket, black (26-45" displays)



KONRA300B
Laptop tray accessory with quick connect plate and hardware allows any dynamic height adjust arm to hold a laptop and docking station.

Eaton Item #	KONWLK0B	KONWLK1B	KONWLK2B	KONWLK2DU0B	KONWLC20B	KONWLC30B	TOACJSBUB
Dynamic Height Adjustment	-	13" (330 mm)	-	-	-	-	-
Maximum Extension	-	20.67" (525.0 mm)	17.7" (449.6 mm)	17.7" (449.6 mm)	-	-	-
Minimum Depth	3.71" (94.2 mm)	3.71" (94.2 mm)	4.2" (106.7 mm)	3.71" (94.2 mm)	-	-	0.24" (6.1 mm)
Tilt	+ 75° / - 10°	+ 75° / - 10°	+ 75° / - 10°	+/- 15°	-	-	-
Typical Screen Sizes (diagonal)	10 - 32" diagonals	10 - 32" diagonals	10 - 32" diagonals	10 - 32" diagonals	-	-	32" - 55" diagonals
Monitor Width Range	-	-	-	Up to 30.0" (762 mm)	-	-	-
MAX Weight Capacity (per monitor)	40 lbs (18.1 kg)	25 lbs (11.3 kg)	40 lbs (18.1 kg)	15 lbs (6.8 kg)	80 lbs (36.2 kg)	80 lbs (36.2 kg)	75 lbs. (34 kg)

Features



Sleek, solidly-constructed forged aluminum arms accommodate larger and heavier monitors.



Dynamic height adjustment feature uses gas-spring technology. Tool-free cable management covers create a clean, professional look.



Simple 3-step installation and integrated quick-connect interface for easy mounting and maintenance.



Patented Centris Extreme Tilt adjusts -75°/+10° for an ultimate ergonomic solution (available on select models).

Eaton
Electrical Sector
1111 Superior Avenue
Cleveland, OH 44114
United States
877-ETN-CARE (877-386-2273)
Eaton.com

© 2017 Eaton
All Rights Reserved
Publication No. BR210005EN