




**Unlock USB XC-104-..., XC-204-...**

→ PC admin rights required!

**1 + 2 Plug in Ethernet cable, ETH0!**

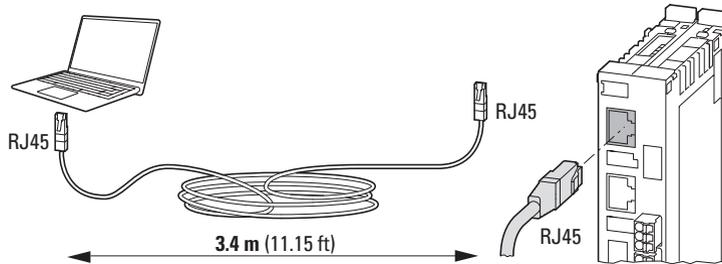

PC ETH IP address  
**192.168.119.xxx**  
255.255.255.0

	ETH0 default IP address	Subnet mask
XC-104-...	192.168.119.104	255.255.255.0
XC-204-...	192.168.119.204	255.255.255.0

 
**3 Set PC ETH IP address**

- → Settings [Einstellungen]
- 
- Change adapter options  
View network adapters and change connection settings
- Ethernet
- Internet Protocol Version 4 (TCP/IPv4)
- Use the following IP address

	PC ETH IP address	Subnet mask
XC-104-...	192.168.119.xxx    xxx ≠ 104	255.255.255.0
XC-204-...	192.168.119.xxx    xxx ≠ 204	255.255.255.0

- OK

**4 XControl: POW ON**




**5 Open browser Internet Explorer**



**6 Connect XControl**

 - XC-104-... <https://192.168.119.104:8375/#/login>
- XC-204-... <https://192.168.119.204:8375/#/login>



**7 Login config tool XControl**



New password

- ✓ At least 8 characters in length
- ✓ At least 1 digit
- ✓ At least 1 uppercase letter
- ✓ At least 1 lowercase letter
- ✓ At least 1 special character: (valid: !@#\$%^&)

Confirm new password

Set password



**USB**

Enable USB  Enable USB autostart

Enable USB factory reset

Reset changes Apply

**8 Note the password**

**9 Enable USB + 10 Apply**

**System configuration** English

**Device information**

Model number  
XC-204-C11-003

---

Serial number  
100000001098

---

Image name  
eaton-image

---

Image version  
v1.0.0-rc4

---

Bootloader version  
2020.04.1.0

---

OS version  
v3.2.0.0-rc2

---

change password

**Power management**

Reboot Shutdown

---

**Factory reset**

Factory reset

---

**Powerfail**

Power down resources are in good condition.  
Current power fail reserves are 71ms.

Minimal power fail time (ms)  
0

---

Maximal power fail time (ms)  
128

**USB**

Enable USB  Enable USB autostart

Enable USB factory reset

Reset changes Apply

02/23 MZ050017ZU