



Champ Pro PVM with occupancy sensor and photocell

Features:

- Fully customizable settings
 - High and low dimmed light levels, time delay and cut off
 - Motion sensitivity levels, photocell and hold off set points
 - Light fade up and down when transitioning light levels
- Wireless configuration tool for customizing fixture settings
- Cable options (non-armoured) include TECK, P Type, metal-clad and SD cable
- Mounting kits include wall, pendant and stanchion

Certifications and compliances:

NEC and CEC

- Wet Locations, Type 4X, IP66

UL Standard

- UL1598 Luminaires

CSA Standard

- cUL Listed to CSA Standard CSA C22.2 No. 250

Temperature ratings:

- Operating ambient: -40°C to 65°C (PVM3L-PVM11L/UNV1 models); -40°C to 55°C (PVM3L-PVM11L/UNV34 and PVM13L-PVM25L models)




ORDC/UNV1



REMOTE CONTROL 1

Occupancy sensor and remote (ordered separately)

Ordering information:

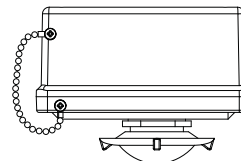

Occupancy sensors

ORDC/UNV1	¾" NPT entry, 100-277 VAC
347/480 K1	Step down transformer for 347-480 VAC applications

Occupancy sensor accessories (ordered separately)

CABLE KIT ORD 1	TECK armoured cable (5ft) with TECK glands (¾")
CABLE KIT ORD 2	P Type non-armoured cable (5ft) with ADE1F glands (¾")
CABLE KIT ORD 3	Metal-clad armoured cable (5ft) with TMC glands (¾")
CABLE KIT ORD 4	SO cable (5ft) with ADE1F glands (¾")
ORDC WKIT	Wall mount kit
ORDC PKIT	Pendant mount kit
ORDC SKIT	Stanchion mount kit
REMOTE CONTROL 1	Remote control for programming sensor



Powering Business Worldwide