



Selecting a luminaire that complements both the straight lines and curves of an installation can be difficult. But often the simplest design is the most effective. SVN uses clean lines to define its outer shape and subtly brings in a curved detail between the body and diffuser, making it blend with many different features within a space.

- Ultra slim 56mm wide profile
- High quality extruded aluminium body
- End to end or individually mounted
- Surface or suspended options
- Opal polycarbonate diffuser
- High efficiency or high output T5 lamps

Lamp and Control Gear Options

- 24W, 39W (HO) T5 fluorescent - G5 cap 
- 18W, 24W, 36W TC-L compact fluorescent - 2G11 cap 
- High frequency control gear as standard
- Dimming options including DSI and DALI


Materials

- Body - steel, RAL9006 finish
- Diffuser - UV stable acrylic

Installation Notes

- Suitable for wall or ceiling mount
- Back plate mounts direct to surface
- Diffuser retained with tool-less fixing screws
- Supplied excluding lamps

Dimensions

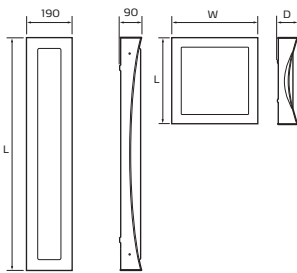


Lamp	L (mm)	Lamp	L (mm)	W (mm)	D (mm)
1 x 24W TC-L	370	2 x 18W TC-L	350	350	90
2 x 24W T5	650	3 x 24W TC-L	450	450	95
2 x 39W T5	950	4 x 36W TC-L	550	550	100

Specification

To specify state: Square/rectangular surface mount luminaire with steel body construction, UV stable acrylic diffuser and tool-less access as Eaton's SVN range, part no. _____

Photometric Data

Cat. No. SVN-R224Z

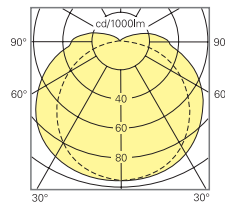

LOR: 39.1
ULOR: 3.9
DLOR: 35.2

Catalogue Numbers

Lamp Rating	Cat No	Weight (kg)
Rectangular		
1 x 24W TC-L	SVN-R124Z	2.5
2 x 24W T5	SVN-R224Z	4.1
2 x 39W T5	SVN-R239Z	5.8
Square		
2 x 18W TC-L	SVN-S218Z	4.6
3 x 24W TC-L	SVN-S324Z	5.9
4 x 36W TC-L	SVN-S436Z	8.4

