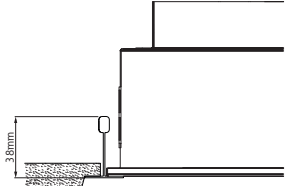
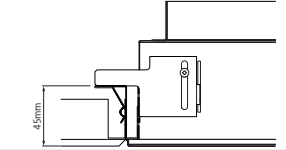
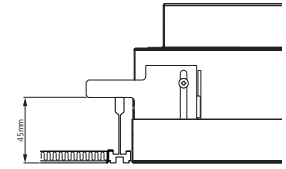
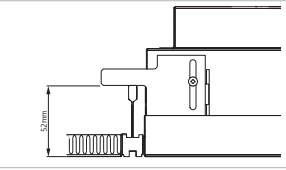
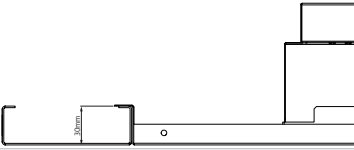
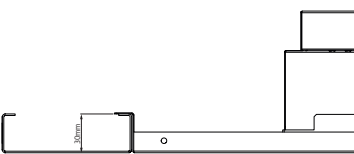


## Mains Lighting

### Recessed - Priam Ceiling Compatibility

Priam ceiling type	Manufacturers reference	Installation method	Body size	Bearer bracket	Note
	Exposed 'T' 15mm	Lay in only	1197 x 297 x 113	N/A	Not suitable for draw-up applications
	Exposed 'T' 24mm	Lay in only	1197 x 297 x 113	N/A	Not suitable for draw-up applications
	Burgess half tee clip in	Draw up only	1197 x 297 x 113	PRMBHTBS	Set of 4 brackets - suitable for one luminaire
<b>A</b> 	Alugrid 15/08	Draw up only	1183 x 285 x 113	Included with the luminaire	Set of 4 brackets - suitable for one luminaire
<b>A</b> 	Alugrid 15/16	Draw up only	1183 x 285 x 113	Included with the luminaire	Set of 4 brackets - suitable for one luminaire
<b>B</b> 	SAS 330 1350 x 300	Lay in only	1348* x 298 x 113	N/A	Not suitable for draw-up applications
	150mm C-Profile		*Dimension within the tile aperture		
<b>C</b> 	SAS 330 1400 x 300	Lay in only	1398* x 298 x 113	N/A	Not suitable for draw-up applications
	100mm C-Profile		*Dimension within the tile aperture		