


MIGHT LIGHT TM



LED Powered Worklights

Cooper Lighting's LED Worklights are great tools to have around your house, garage, workshop or automobile. We offer several multi-functional worklights for handling almost any type of project or job.

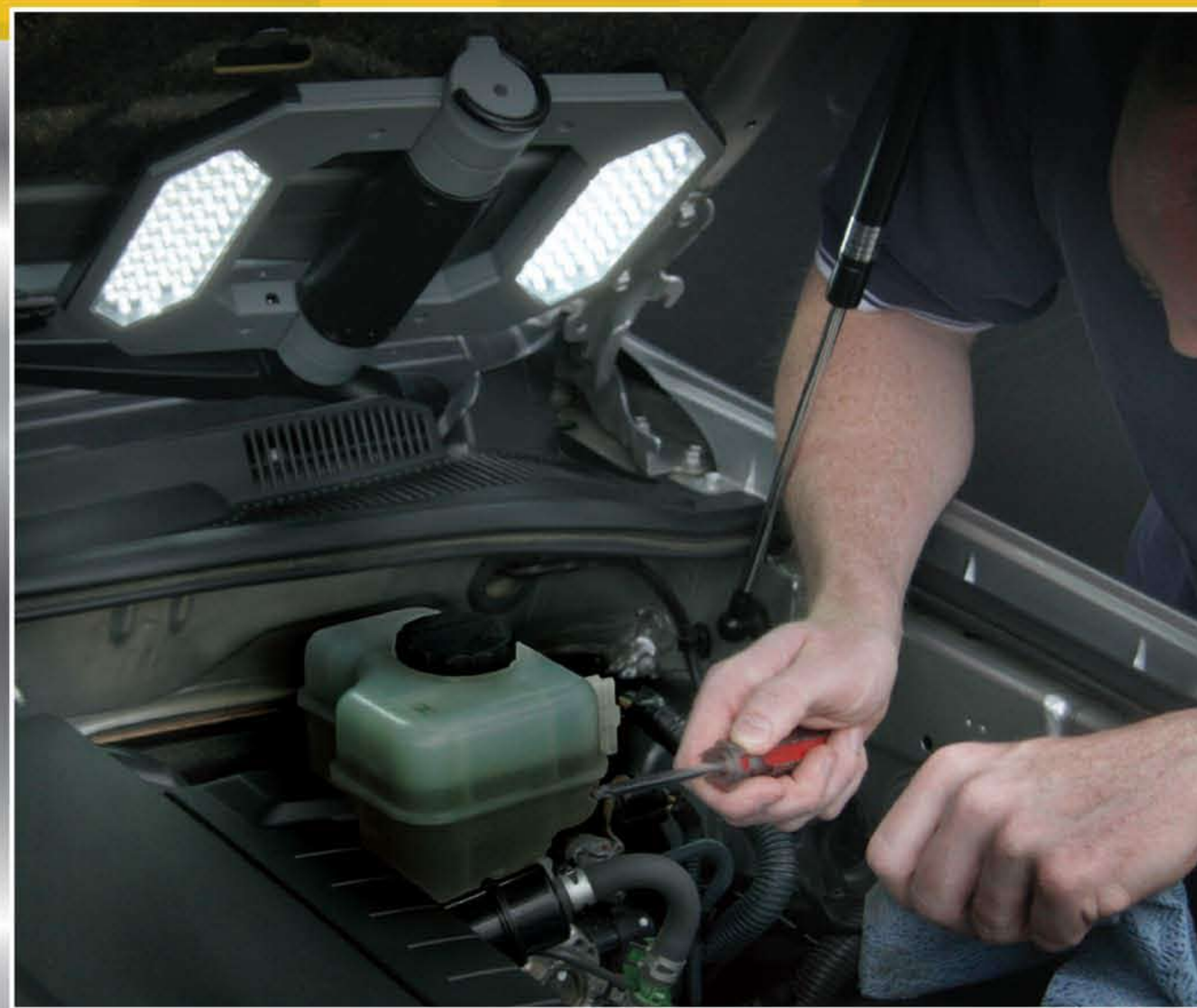

LED Powered Worklights



LED130

- 80 Long life LED lights
- Cordless rechargeable unit with AC & DC charging adapters included
- Patent pending design
- Durable polycarbonate lens
- Nylon swivel hook
- Easy grip cushioned handle
- Convenient ON/OFF switch
- Reflective strips for increased visibility during roadside applications
- Integrated neodymium magnets for securing to metal doors, tool boxes, car hoods, etc.
- 2 Hour battery life



LED120

- 35 Long life LED lights
- Cordless rechargeable unit with AC & DC charging adapters included
- End of light doubles as a spotlight/flashlight
- Durable plastic construction with polycarbonate lens
- 360° Rotating swivel hook
- Cushioned grip with convenient instant-ON switch
- Magnetic clamp
- Up to 12 hour battery life (when used only as a flashlight)



LED110

- 60 Long life LED lights
- 15 ft. 18 Gauge power cord
- Durable plastic construction with polycarbonate lens
- Cushioned grip with instant-ON switch
- 360° Rotating swivel hook
- 120 volts (standard household supply)



LED105

- 30 Ultra bright LED lights
- Cordless rechargeable unit with AC charging adaptor included
- Durable plastic body with polycarbonate lens
- 3-way rocker switch for high or low light output
- Octagonal body design allows you to direct light where needed most
- 360° Rotating swivel hook
- Up to 3 hour battery life



LED100

- 30 Ultra bright LED lights
- 15 ft. Light weight power cord
- Durable plastic body with tapered polycarbonate lens
- Easy ON/OFF rocker switch
- Octagonal body design allows you to direct light where needed most
- 360° Rotating swivel hook
- 120 volts (standard household supply)

Model#	Product Description	UPC#	Unit Carton Dimensions (in.)	Master Carton	Master Carton Dimensions (in.)	I2 of 5
LED130	80 LED fold-up rechargeable worklight with AC/DC adapters	0 80083 51204 1	7.5W x 10.5H x 7.3D	2Pk	15.5W x 10.9H x 7.8D	1 00 80083 51204 8
LED120	35 LED rechargeable worklight with AC/DC adapters	0 80083 50895 2	4.0W x 17.4H x 4.0D	4Pk	8.8W x 18.1H x 8.8D	1 00 80083 50895 9
LED110	60 LED plug-in worklight	0 80083 50894 5	4.0W x 18.1H x 5.0D	4Pk	10.8W x 18.9H x 8.8D	1 00 80083 50894 2
LED105	30 LED rechargeable sticklight	0 80083 53095 3	6.25W x 20.63H x 3.0D	4Pk	8.27W x 6.89H x 21.26D	1 00 80083 53095 0
LED100	30 LED plug-in sticklight	0 80083 53096 0	6.25W x 20.63H x 3.0D	4Pk	8.27W x 6.89H x 21.26D	1 00 80083 53096 7