

ALL-PRO™

LED | Outdoor Security Lighting



Superior Outdoor Security with the sustainability of LED Technology

Designed for performance in a sleek, low profile die cast housing, these innovative LED light fixtures illuminate outdoor spaces creating unmatched safety and reliability.

Choose from Motion-Activated, Dusk-to-Dawn, or Floodlights in a range of lumen options to fit any application. These patent pending products are available in bronze and white and can be wall or eave mounted for entry ways, garages and corners.

ALL-PRO™ LED outdoor security lighting provides the safety of super bright lighting, energy savings up to 90%, and the convenience of one-time installation without re-lamping.

SAVES up to
90%
energy
vs. traditional light sources



Floodlight

Light turns on when switch is manually turned on



Shown: Large Single Head Floodlight



Dusk to dawn

Light turns on automatically at night and off during the day



Shown: Small Single Head Dusk to Dawn Floodlight



Motion Activated

Light turns on only when motion is detected at night



Shown: Twin Head Motion Activated Floodlight



Innovation you can rely on™

Floodlights



- 1900 Lumens; up to 64 Lumens per watt
- Maintenance-free LEDs with 35,000 hours of life
- Heavy duty die-cast aluminum construction
- Perfect for wall or eave mount applications



Model Number	Description	ENERGY STAR®	Lumens
FSL2030L	Large Single Head LED Floodlight - Bronze	No	1900
FSL2030LW	Large Single Head LED Floodlight - White	No	1900

Dusk to Dawn




- 1350 - 1410 Lumens; up to 65 Lumens per watt
- Maintenance-free LEDs with 35,000 hours of life
- Integral photo control automatically turns lights on at night and off during the day
- Heavy duty die-cast aluminum construction
- Perfect for wall or eave mount applications



Model Number	Description	ENERGY STAR®	Lumens
FSS1530LPCW	Small Single Head LED Floodlight - White	No	1410
FSS1530LPCES	Small Single Head LED Floodlight - Bronze	Yes	1350

Motion Activated

- 1350 - 2300 Lumens; up to 74 Lumens per watt
- Maintenance-free LEDs with 35,000 hours of life
- Motion sensor turns light on automatically when motion is detected and off after a preselected time delay (up to 12 minutes)
- Motion sensor detects motion in 110°, 180° and 270° of coverage up to 70 ft.
- Manual override feature allows fixture to be operated as a floodlight for up to 6 hours
- Integral photocell ensure lights are only activated with motion at nighttime
- Heavy duty die-cast aluminum construction
- Perfect for wall or eave mount applications

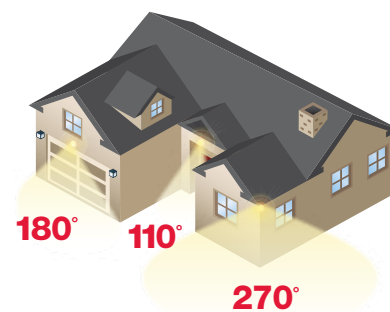

Model Number	Description	ENERGY STAR®	Lumens
MSS11315LES	110° Small Single Head LED Floodlight - Bronze	Yes	1350
MST18920L	180° Twin Head LED Floodlight - Bronze	No	1840
MST18920LW	180° Twin Head LED Floodlight - White	No	1980
MST18920LES	180° Twin Head LED Floodlight - Bronze	Yes	2240
MST18920WES	180° Twin Head LED Floodlight - White	Yes	2300
MST27920LES	270° Twin Head LED Floodlight - Bronze	Yes	2240

Innovation you can rely on™