

DESCRIPTION

The new Might D Light™ Mini Folding LED worklight utilizes LED technology to offer a versatile and portable lighting solution in a compact design. Ideal for camping, automotive repair, home improvement projects, and emergencies.

Catalog #		Type
Project		
Comments		Date
Prepared by		

SPECIFICATION FEATURES

Construction

- Durable Polycarbonate housing with TPE over mold
- Splash resistant
- Hinge adjusts up to 230°
- (3) Neodymium Magnets: One magnet per panel and one magnet on the center handle
- Concealed 2 mm thick metal "D" Ring hooks on each end

Optical

- Precision optics with up to 350 lumens (both panels on 350 lumens; single panel 180 lumens)
- Patent pending Pass Thru feature providing light when operating in closed position

Electrical

- White Maintenance-free LEDs
- Three-way integrated switch: Both panels ON/single panel ON/OFF
- A LONG switch press in any mode will turn the fixture OFF

Warranty

- One-year limited warranty

LED225 Features

- 2400 mA-H Lithium ion battery
- Micro USB port with recharging indicator LED
- Up to 7 hour battery life
- USB Power supply cord to Micro-B USB; 1 m length

LED226 Features

- 3 Alkaline batteries (AA) included
- Up to 3.5 hour battery life




MINI FOLDING LED


Worklight

DIMENSIONS

Open Front View

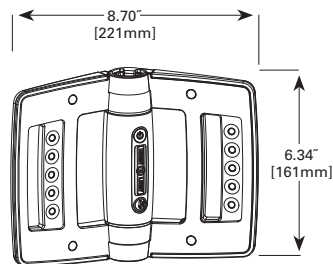

Closed View and Side Depth

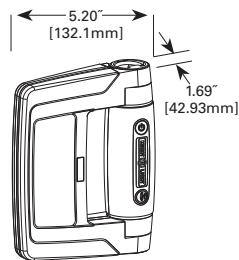

TECHNICAL INFORMATION

Model	Description	Delivered Lumens	LED Color Temperature (K)	CRI	Battery
LED225	Might D Light Mini Rechargeable Worklight	350	5000K	70	Integrated Lithium ion
LED226	Might D Light Mini Worklight	350	5000K	70	Replaceable (AA)x3