

Applications:

- Damp or wet locations

Features:

- Weatherproof toggle switch
- Cover may be locked closed to limit accessibility
- Wide range of switch types in single-pole, two-pole, three-way or four-way units
- Heavy duty mounting pads
- Neoprene gasket resists petroleum and provides a watertight seal
- Silicone lubricant provided for cover screws and flange
- Switches rated at 15, 20 or 30 amperes

Certifications and compliances:

- Conforms to IP52
- ABS

Standard materials:

- Box – cast copper-free aluminum
- Cover – die cast aluminum, powder coated
- Hardware – stainless steel
- Gasket – one-piece neoprene

Technical specifications:

- Entries – standard units undrilled; up to four 1" NPT outlets available

Voltage and current ratings:

Switch

- 15 amperes, 277 VAC
- 20 amperes, 250 VAC
- 30 amperes, 250 VAC

Mounting option:

- Surface mount, via two maximum 1/4" mounting bolts (not included)

Entry options:

NPT trade size	Dead end	Through feed	X positions
1/2"	E1	C1	X1
3/4"	E2	C2	X2
1"	E3	C3	X3





Ordering information:

Cat. #	Description	Voltage and current	Weight (lbs.)
2420A	Single-pole	15A, 277 VAC	1.8
2430A	Single-pole	20A, 250 VAC	1.8
2440A	Single-pole	30A, 250 VAC	1.8
2422A	Two-pole	15A, 277 VAC	1.8
2432A	Two-pole	20A, 250 VAC	1.8
2442A	Two-pole	30A, 250 VAC	1.8
2423A	Three-way	15A, 277 VAC	1.8
2433A	Three-way	20A, 250 VAC	1.8
2443A	Three-way	30A, 250 VAC	1.8
2424A	Four-way	15A, 277 VAC	1.8

12P

Dimensions (in inches):

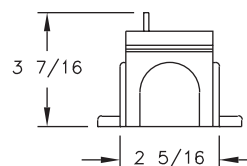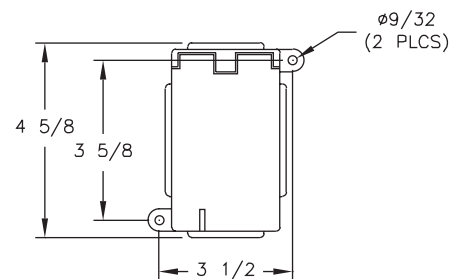

2420A–2424A / 2430A–2433A
2440A–2443A