

Pro

ProXchange 2482/mw



FEATURES

- Internal industrial breaker provides thermal overload and short circuit protection.
- Full load circuit interruption for added safety.
- Corrosion resistant cast marine brass construction.
- Neoprene gasket resists petroleum and provides a watertight seal.
- Heavy duty mounting pads.
- Silicone lubricant provided for cover screws and flange.
- External control handle has provision for padlocking in the OFF position.
- Available from 15 to 100 Amp.
- 2P3W or 3P4W units available.

APPLICATIONS

- Emergency disconnect
- Marine and watertight requirements

APPROVALS

- Conforms to IP66
- ABS

TECHNICAL SPECIFICATIONS

BOX/COVER/HANDLE

Cast marine brass.

HARDWARE

Stainless steel.

GASKET

One piece neoprene.

ENTRIES

Standard units undrilled. One outlet each end up to 1½" NPT or two outlets each end up to 1¼" NPT available. Please state requirements on application.

VOLTAGE

Two pole breakers rated for 480v AC or 250v DC.

Three pole breakers rated for 480v AC only.

MOUNTING

Surface, via four maximum ¾" mounting bolts (not included).


ORDERING REFERENCES

PART NUMBER	DESCRIPTION	WEIGHT LBS
2482B	2 Pole, Enclosure Only	28.0
2482B-215	2 Pole, 15 Amp Breaker	30.5
2482B-220	2 Pole, 20 Amp Breaker	30.5
2482B-230	2 Pole, 30 Amp Breaker	30.5
2482B-240	2 Pole, 40 Amp Breaker	30.5
2482B-250	2 Pole, 50 Amp Breaker	30.5
2482B-260	2 Pole, 60 Amp Breaker	30.5
2482B-2100	2 Pole, 100 Amp Breaker	30.5
2482B-315	3 Pole, 15 Amp Breaker	30.5
2482B-320	3 Pole, 20 Amp Breaker	30.5
2482B-330	3 Pole, 30 Amp Breaker	30.5
2482B-340	3 Pole, 40 Amp Breaker	30.5
2482B-350	3 Pole, 50 Amp Breaker	30.5
2482B-360	3 Pole, 60 Amp Breaker	30.5
2482B-3100	3 Pole, 100 Amp Breaker	30.5

SPARE PARTS

Part No.	Description	Part No.	Description
INX6575B	COVER WITH HANDLE	INX3092	2 POLE BREAKER, 100 Amp
INX6041B	BOX	INX8018B	HANDLE ASSEMBLY
GKT5005	GASKET	INX3093	3 POLE BREAKER, 15 Amp
INX3086	2 POLE BREAKER, 15 Amp	INX3094	3 POLE BREAKER, 20 Amp
INX3087	2 POLE BREAKER, 20 Amp	INX3095	3 POLE BREAKER, 30 Amp
INX3088	2 POLE BREAKER, 30 Amp	INX3096	3 POLE BREAKER, 40 Amp
INX3089	2 POLE BREAKER, 40 Amp	INX3097	3 POLE BREAKER, 50 Amp
INX3090	2 POLE BREAKER, 50 Amp	INX3098	3 POLE BREAKER, 60 Amp
INX3091	2 POLE BREAKER, 60 Amp	INX3099	3 POLE BREAKER, 100 Amp

DIMENSIONS

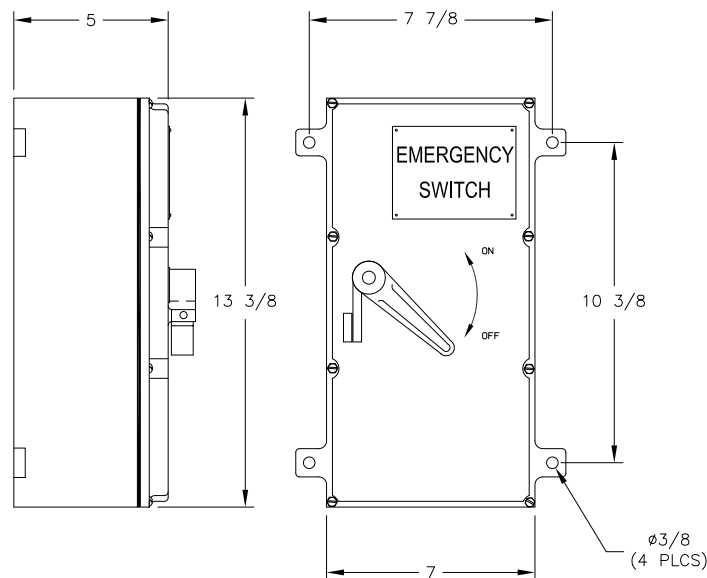

Dimensions in inches