

# Pauluhn ProXchange 833 and 834 wiring devices

Conforms to IP66

12P

## Applications:

- Alarm/warning indication
- Marine and watertight requirements

## Features:

- Single throw two-pole snap switch
- Cast marine brass construction
- Neoprene gasket resists petroleum and provides a watertight seal
- Heavy duty mounting pads
- Silicone lubricant provided for cover screws and flange
- Available in 15 or 20 ampere units

## Certifications and compliances:

- Conforms to IP66
- ABS

## Standard materials:

- Box and cover – cast marine brass
- Switch stem – free machining brass
- Hardware – stainless steel
- Gasket – one-piece neoprene

## Technical specifications:

- Entries – standard units undrilled; up to four 3/4" NPT outlets available
- Switch – spring loaded two-pole single throw


### Voltage and current ratings:

#### 833 models

- 15 amperes, 125 VAC
- 10 amperes, 24 VDC
- 2 amperes, 125 VDC

#### 834 models

- 20 amperes, 600 VAC
- 15 amperes, 24 VDC
- 5 amperes, 125 VDC

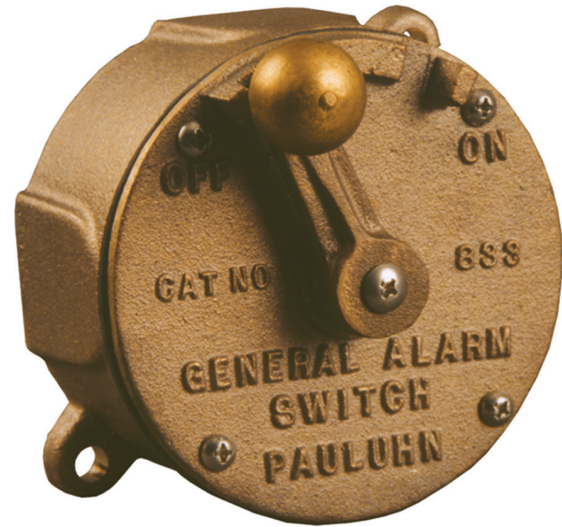

## Mounting options:

- Surface mount (via two 11/32") or flush mount (via four 5/16") mounting bolts (not included)

## Entry options:

| NPT trade size | Dead end | Through feed | 90° | X positions |
|----------------|----------|--------------|-----|-------------|
| 1/2"           | E1       | C1           | L1  | X1          |
| 3/4"           | E2       | C2           | L2  | X2          |

## Ordering information:

| Cat. # | Description                 | Weight (lbs.) |
|--------|-----------------------------|---------------|
| 833    | 15A, 120 VAC, surface mount | 5.0           |
| 834    | 20A, 600 VAC, surface mount | 6.0           |
| 833F   | 15A, 120 VAC, flush mount   | 5.0           |
| 834F   | 20A, 600 VAC, flush mount   | 6.0           |

## Dimensions (in inches):

