

Group Meter Main - Without Bypass

200 Amp Vertical

Multiple Metering



2222 (closed)



2222 (open)

Application

- For vertical multi-meter/mains installations - 4 position maximum
- 400A main buss
- Factory installed breakers
- Receive ANSI C12.10 watt-hour meters
- Overhead or underground feed (see chart)
- Surface mount

Construction

- Ring type
- NEMA Type 3R
- ANSI 61 gray E-coat finish
- Aluminum snap ring included

Standards

- UL 67 Listed
- ANSI C12.7

Accessories

- 5th Jaw Kit - 50365
- Screw Type Ring - 26016D



Part/UPC Number	Catalog Number	Number of Positions	Buss Amps	Amp Rating	Jaws	Service Type	Access	Main Breaker		
								Voltage	AIC	Main
78205161519	2222	2	400	200	4	1Ø/3W	OH/UG	120/240	10K	(2) 200A, 2P
79903854901	2223	3	800	200	4	1Ø/3W	OH/UG	120/240	10K	(3) 200A, 2P
79903854902	2224	4	800	200	4	1Ø/3W	OH/UG	120/240	10K	(4) 200A, 2P

Part/UPC Number	Catalog Number	Connections			Overall Dimensions			Top Provision	Knockout Layout
		Line	Load	Neutral	Height	Width	Depth		
78205161519	2222	Studs	MCB	#6 - 250 MCM	48"	26 ⁵ / ₈ "	6"	None	Fig. 1
79903854901	2223	Studs	MCB	#6 - 250 MCM	48"	40 ³ / ₄ "	6"	None	Fig. 2
79903854902	2224	Studs	MCB	#6 - 250 MCM	48"	40 ³ / ₄ "	6"	None	Fig. 2

MCB - Main Circuit Breaker


Group Meter Main - Without Bypass

200 Amp Vertical

Style #	Suffixes
2222	SS - Stainless Steel
2223	
2224	

Multiple Metering

Layouts

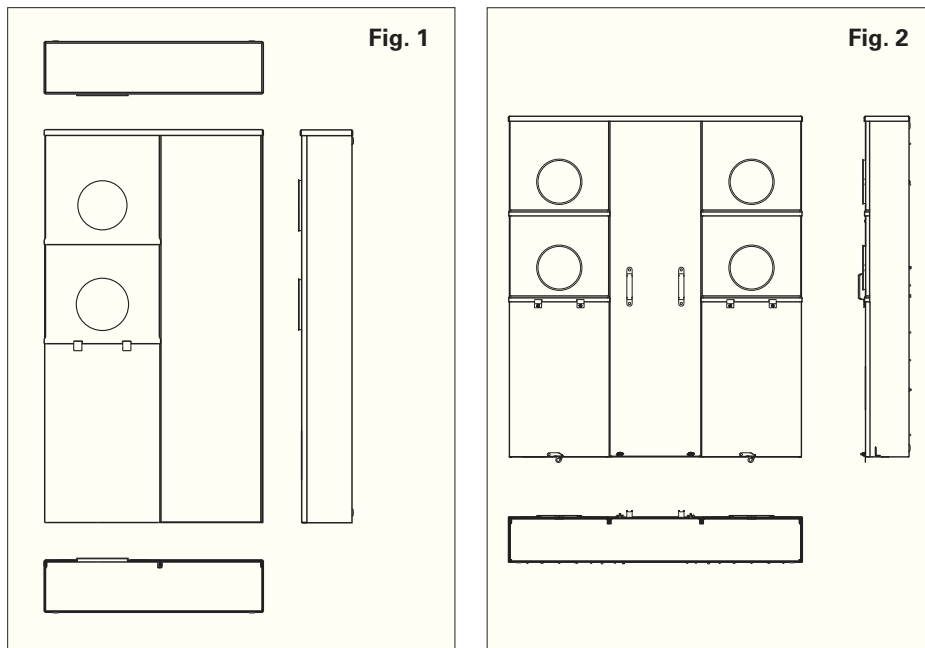

Data subject to change without notice. Consult local utility for area acceptance. All dimensions are in inches.