

Commercial Meter Pedestals - Post/Wall Mounted



CMP4111M

Application

- Utility meter, main disconnect and distribution panel
- Receive ANSI C12.10 watthour meters

Construction

- Ring type
- NEMA Type 3R
- ANSI 61 gray E-coat finish
- Separate sealable utility termination and meter compartments
- Padlockable disconnect and distribution section
- Underground feed


Standards

- UL Listed
- ANSI C12.7

Accessories

- 5th jaw kit - 50365 (single phase)
- Filler plate kit - 25139
- Class T fusible pullouts
- Controls, see page 109

Catalog Number	Amp Rating	Jaws	Service Type	Bypass	Voltage	Distribution		Type	Dimensions		
						Main Breaker	Branches		Width	Depth	Height
CMP4111M	100	4	1Ø,3W	--	240	100A,2P	12	Plug-In	32"	8"	32"
CMP4111MC	100	4	1Ø,3W	TB	240	100A,2P	12	Plug-In	32"	8"	32"
CMP4111MCH	100	4	1Ø,3W	TB	480	100A,2P	14	Bolt-On	32"	8"	38"
CMP4121M	200	4	1Ø,3W	--	240	200A,2P	12	Plug-In	32"	8"	38"
CMP4121MC	200	4	1Ø,3W	TB	240	200A,2P	12	Plug-In	32"	8"	38"
CMP4121MCH	200	4	1Ø,3W	TB	480	200A,2P	18	Bolt-On	32"	8"	38"
CMP4411M	100	7	3Ø,4W	--	240	100A,3P	12	Plug-In	32"	8"	32"
CMP4411MC	100	7	3Ø,4W	TB	240	100A,3P	12	Plug-In	32"	8"	32"
CMP4411MCH	100	7	3Ø,4W	TB	480	100A,3P	12	Bolt-On	32"	8"	32"
CMP4421M	200	7	3Ø,4W	--	240	200A,3P	12	Plug-In	32"	8"	32"
CMP4421MC	200	7	3Ø,4W	TB	240	200A,3P	12	Plug-In	32"	8"	32"
CMP4421MCH	200	7	3Ø,4W	--	480	200A,3P	18	Bolt-On	32"	8"	38"

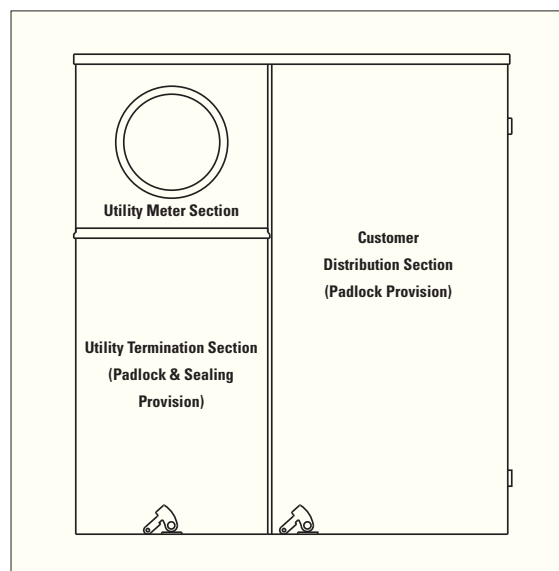

Data subject to change without notice. Consult local utility for area acceptance. All dimensions are in inches.