

CT Enclosures With Lift Off Covers



18249 RTCT (closed)



18249 RTCT (open)



Application

- Designed to house ANSI C12.11 current transformers
- Includes provision to install model 6019/6067 CT mounts
- Surface mount

Construction

- Enclosure has mounting holes on back of body
- Covers include padlock provision, utility sealing provisions, wing nuts, and lifting handles
- Enclosures over 36" wide and 42" tall have two overlapping covers
- NEMA Type 3R
- ANSI 61 gray E-coat finish

Standards


- UL 414 Listed
- EUSERC 316

Part/UPC Number	Catalog Number	Service Type	Use With Mounting Base	Overall Dimensions			Knockout Layout
				Height	Width	Depth	
78205137005	18249 RTCT	1Ø	6019	24"	18"	9"	Fig. 1
78205137020	242411 RTCT	1Ø	6019	24"	24"	11"	Fig. 1
78205137030	243011 RTCT	1Ø	6019	30"	24"	11"	Fig. 1
78205137025	24329 RTCT	1Ø	6019	32"	24"	9"	Fig. 1
78205137070	243611 RTCT	1Ø	6019	36"	24"	11"	Fig. 1
78205144811	244811 RTCT	1Ø	6019	48"	24"	11"	Fig. 1
78205137070	303011 RTCT	1Ø or 3Ø	6019 or 6067	30"	30"	11"	Fig. 1
78205137080	303611 RTCT	1Ø or 3Ø	6019 or 6067	36"	30"	11"	Fig. 1
78205130113	303614 RTCT	1Ø or 3Ø	6019 or 6067	36"	30"	14"	Fig. 1
78205137090	363611 RTCT	1Ø or 3Ø	6019 or 6067	36"	36"	11"	Fig. 1
78205137100	364211 RTCT	1Ø or 3Ø	6019 or 6067	42"	36"	11"	Fig. 1
78205137110	364811 RTCT	1Ø or 3Ø	6019 or 6067	48"	36"	11"	Fig. 1
78205137200	364814 RTCT	1Ø or 3Ø	6019 or 6067	48"	36"	14"	Fig. 1
78205124211	424211 RTCT	1Ø or 3Ø	6019 or 6067	42"	42"	11"	Fig. 1
78205140872	484811 RTCT	1Ø or 3Ø	6019 or 6067	48"	48"	11"	Fig. 1


Part/UPC Number	Catalog Number	A	B	C	E
78205137005	18249 RTCT	--	--	--	--
78205137020	242411 RTCT	9"	8"	8"	--
78205137030	243011 RTCT	12"	8"	8"	--
78205137025	24329 RTCT	--	--	--	--
78205137070	243611 RTCT	15"	8"	8"	--
78205144811	244811 RTCT	21"	8"	8"	--
78205137070	303011 RTCT	12"	7"	8"	8"
78205137080	303611 RTCT	15"	7"	8"	8"
78205130113	303614 RTCT	15"	7"	8"	8"
78205137090	363611 RTCT	15"	10"	8"	8"
78205137100	364211 RTCT	18"	10"	8"	8"
78205137110	364811 RTCT	21"	10"	8"	8"
78205137200	364814 RTCT	21"	10"	8"	8"
78205124211	424211 RTCT	18"	13"	8"	8"
78205140872	484811 RTCT	--	--	--	--

CT Enclosures With Lift Off Covers

Style #	Suffixes
xxxxxx RTCT	MS40 - Mounting studs for 415 H - Universal CT Rack
	SS - Stainless Steel

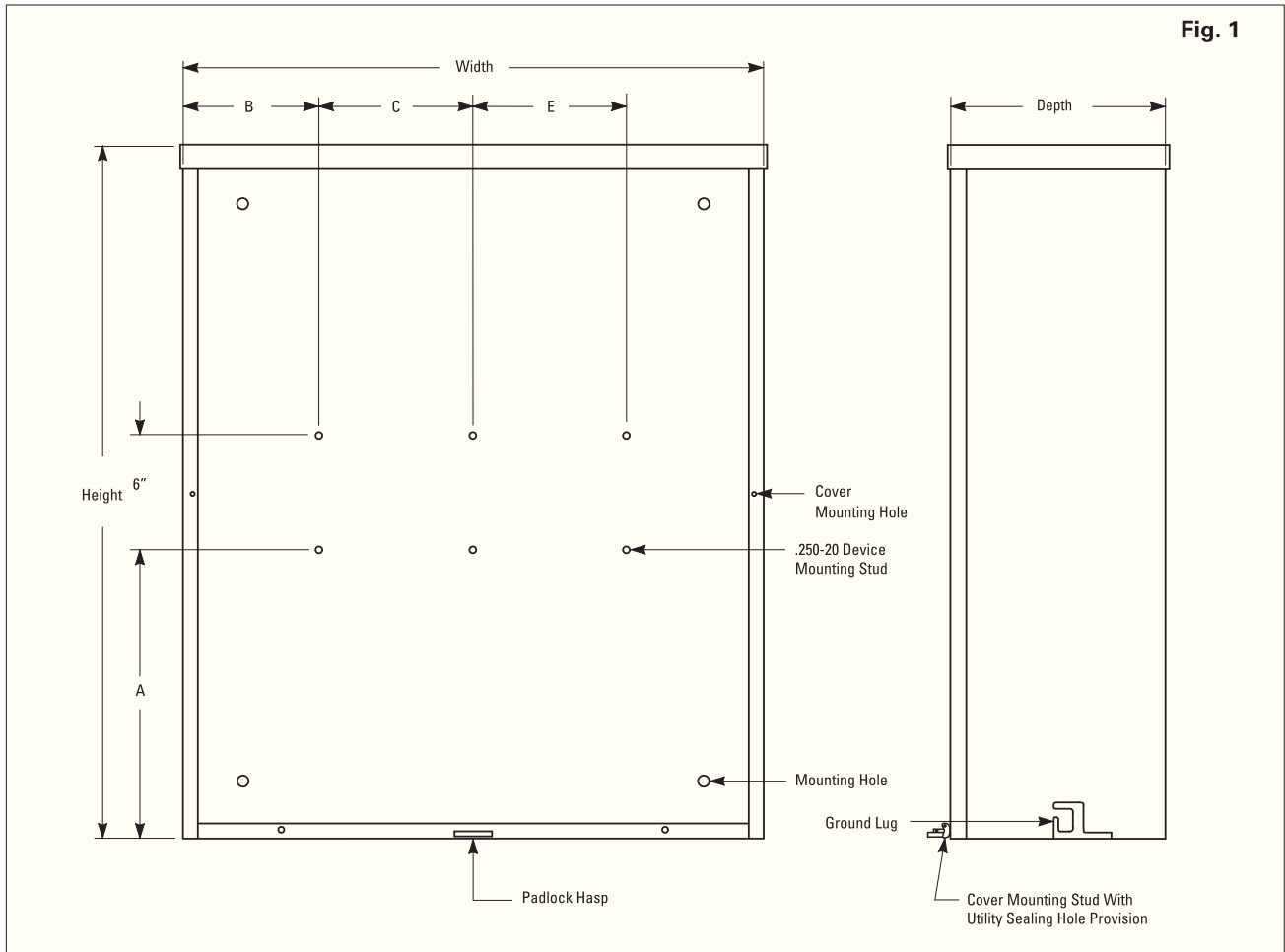

415 H
Universal CT Rack

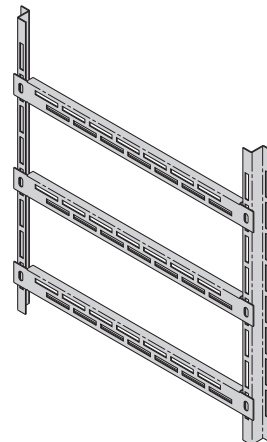

CT Metering

Data subject to change without notice. Consult local utility for area acceptance. All dimensions are in inches.

CT Enclosures With Hinged, Lift Off Doors



363611 HRTCT (closed)



363611 HRTCT (open)



Application

- Designed to house ANSI C12.11 current transformers
- Includes provision to install model 6019/6067 CT mounts
- Surface mount

Construction

- Enclosure has mounting holes on back of body
- Covers include utility sealing provisions, wing nuts, and lifting handles
- DD parts include master/slave style overlapping doors
- NEMA Type 3R
- Wash and phosphate undercoat
- ANSI 61 gray E-coat finish

Standards



- UL 414 Listed
- EUSERC 316

Part/UPC Number	Catalog Number	Service Type	Use With Mounting Base	Height	Overall Dimensions Width	Depth	Knockout Layout
78205180295	203611 HRTCT	1Ø	6019	36"	20"	11"	Fig. 1
78205180435	243011 HRTCT	1Ø	6019	30"	24"	11"	Fig. 1
78205180436	244811 HRTCT	1Ø or 3Ø	6019 or 6067	48"	24"	11"	Fig. 1
78205180445	303611 HRTCT	1Ø or 3Ø	6019 or 6067	36"	30"	11"	Fig. 1
78205180446	304811 HRTCT	1Ø or 3Ø	6019 or 6067	48"	30"	11"	Fig. 1
78205180455	363611 HRTCT	1Ø or 3Ø	6019 or 6067	36"	36"	11"	Fig. 1
78205180456	364811 HRTCT	1Ø or 3Ø	6019 or 6067	48"	36"	11"	Fig. 1
78205105532	484814 DDHRTCT	1Ø or 3Ø	6019 or 6067	48"	48"	11"	Fig. 2

Part/UPC Number	Catalog Number	A	B	C	E
78205180295	203611 HRTCT	--	--	--	--
78205180435	243011 HRTCT	12"	8"	8"	--
78205180436	244811 HRTCT	21"	8"	8"	--
78205180445	303611 HRTCT	15"	7"	8"	8"
78205180446	304811 HRTCT	21"	7"	8"	8"
78205180455	363611 HRTCT	15"	10"	8"	8"
78205180456	364811 HRTCT	21"	10"	8"	8"
78205105532	484814 DDHRTCT	16"	21"	8"	8"

CT Enclosures With Hinged, Lift Off Doors

Style #	Suffixes
xxxxxx HRTCT	MS40 - Mounting studs for
xxxxxx DDHRTCT	415 H - Universal CT Rack
	SS - Stainless Steel

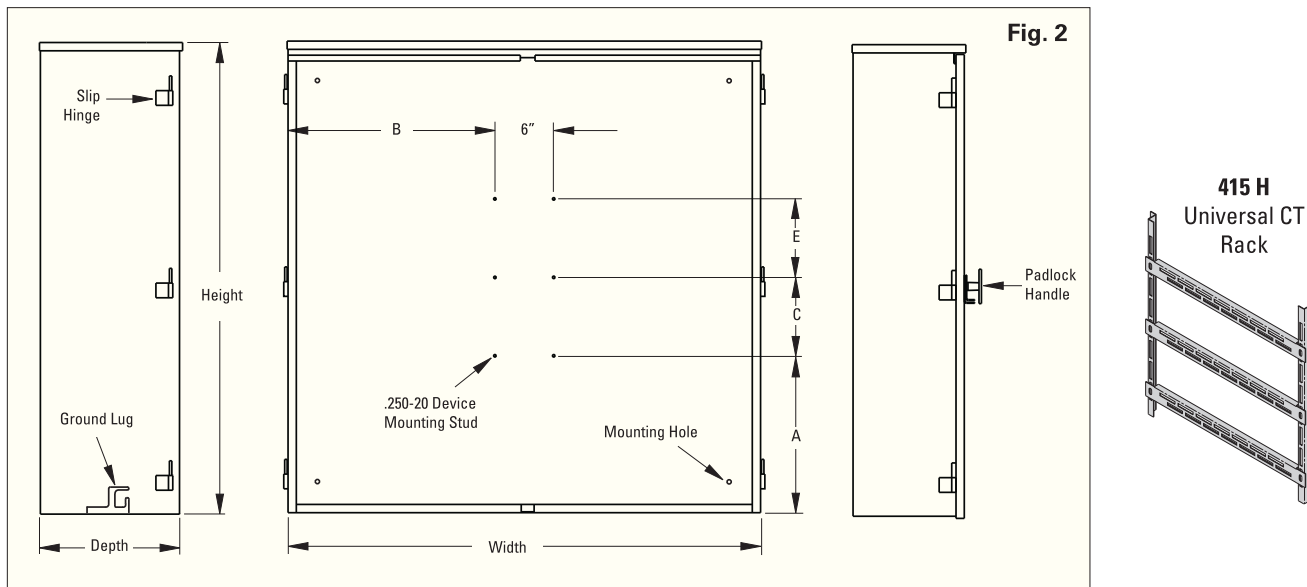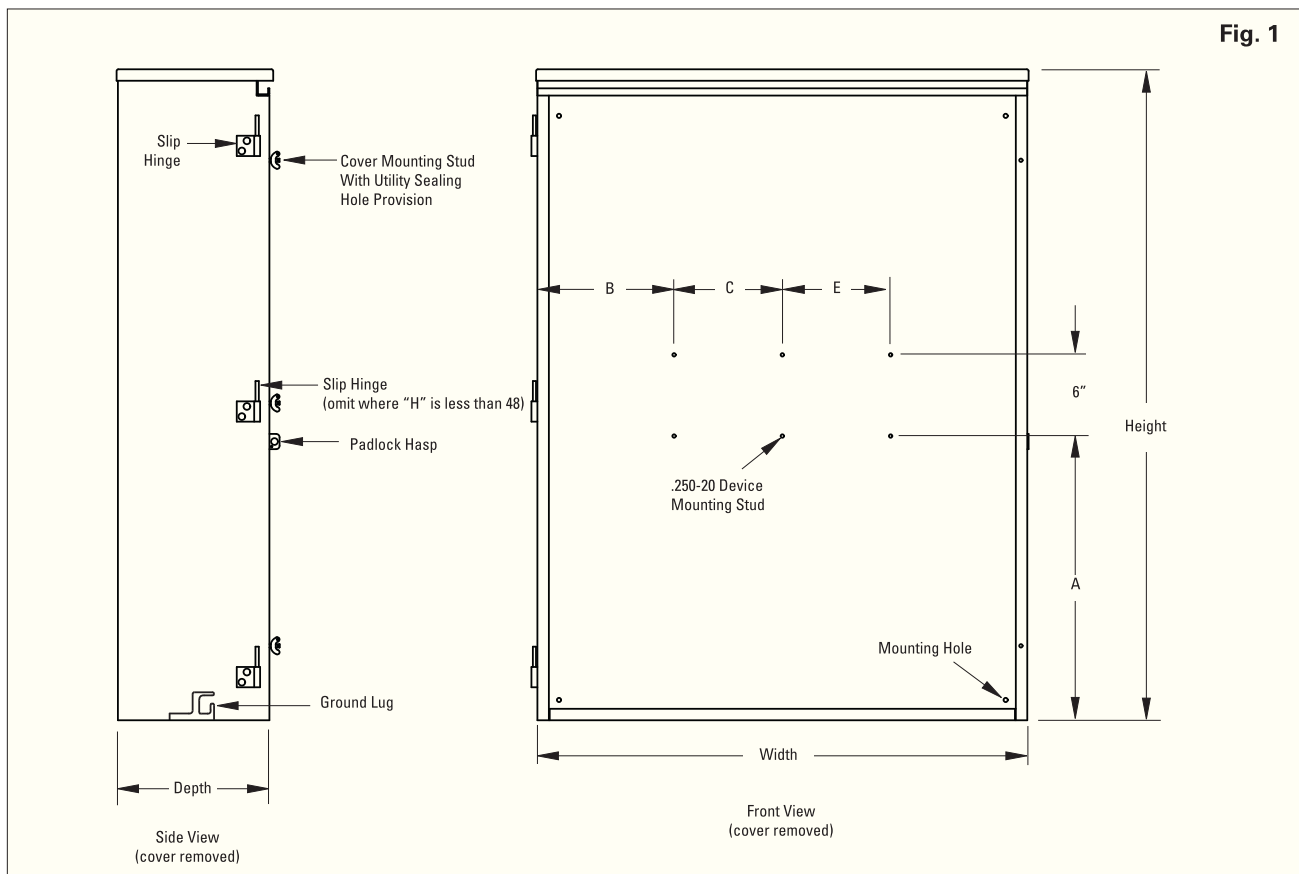

Data subject to change without notice. Consult local utility for area acceptance. All dimensions are in inches.