



Parts Information

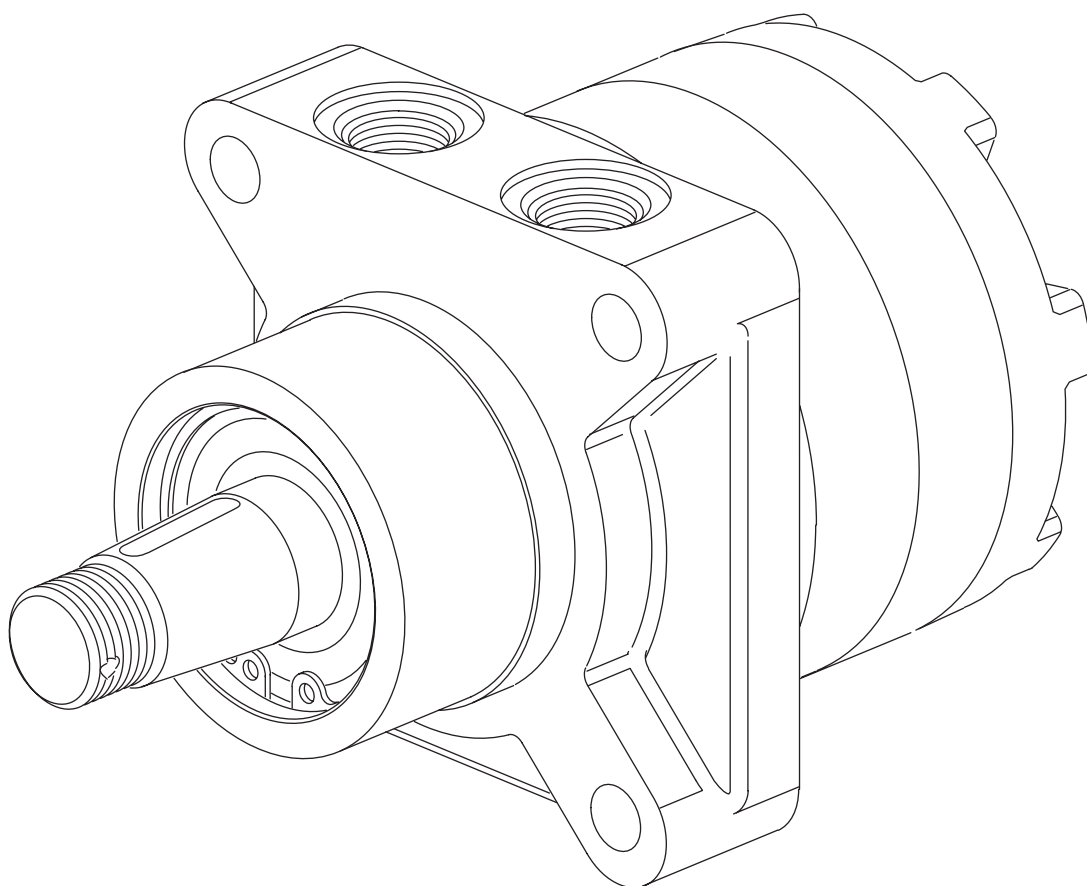

W Series
Geroler® Motors

002

W Series

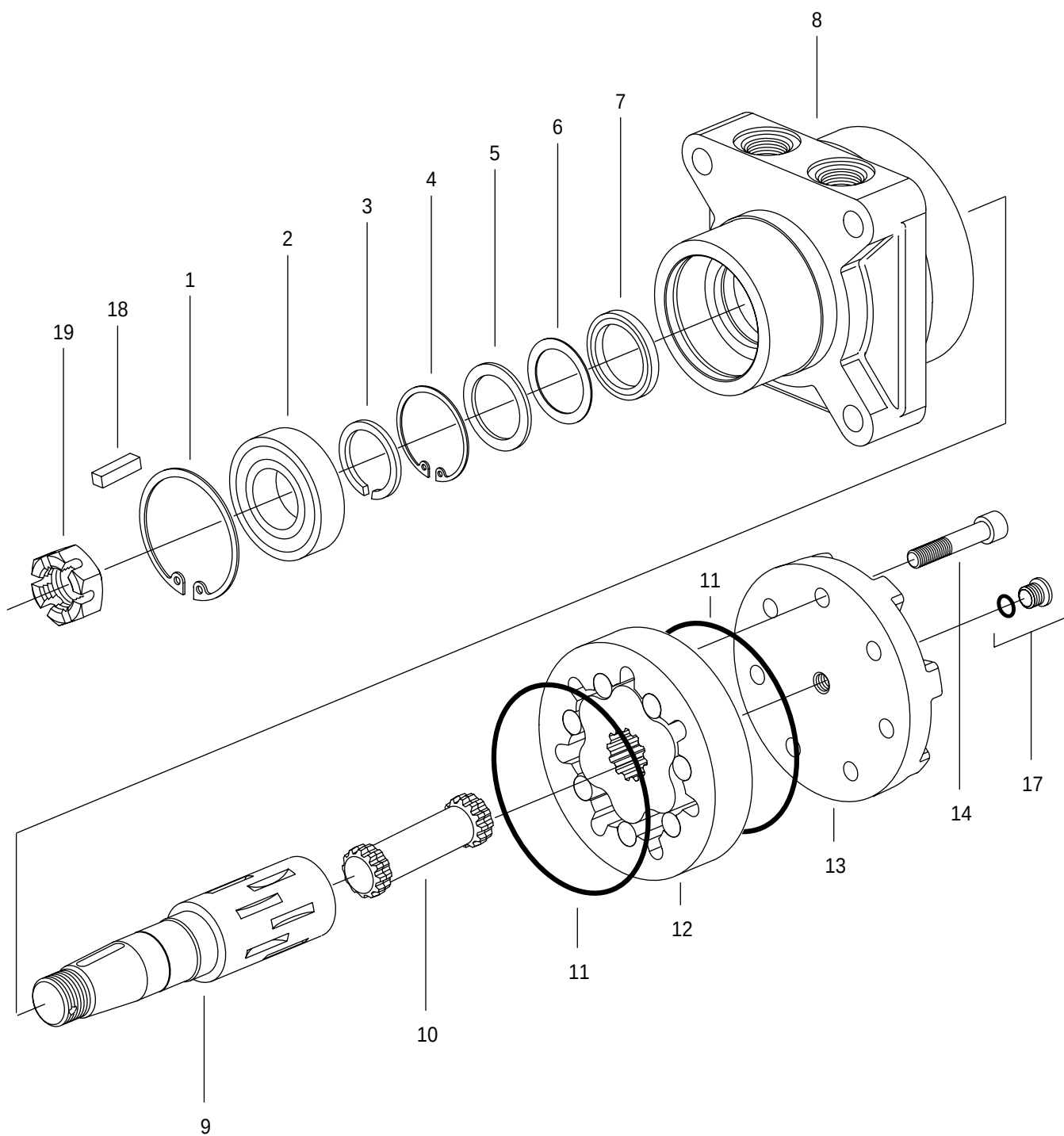

W Series

Ref. No.	Part Number	Description	Quantity
X 1	14731-001	Ring, Retaining	1
X 2	14730-001	Bearing, Ball	1
X 3	14734-001	Ring, Retaining	1
X 4	14733-001	Ring, Retaining	1
X 5	201977-001	Washer	1
X 6	7382-000	Washer, Backup	1
X 7	9057-009	Seal, Pressure	1
8	201954-001	Housing — 7/8-14 UNF O-ring Port	1
	—	Housing — G 1/2 (BSP) Straight Thread	1
9	201966-053	Shaft, Output	1
	201953-053	Shaft, Output — with Internal Check Valve seats (Poppets (2) not included)	1
	201971-001	Poppet (for Shaft, Output — with Internal Check Valve seats)	2
10	*	Drive	1
X 11	9086-006	Seal	2
12	*	Geroler®	1
13	201960-001	End Cap	1
	201960-002	End Cap — 7/16-20 UNF O-ring Port	1
	—	End Cap — G 1/4 (BSP) Straight Thread	1
14	*	Cap Screw, Internal Hex Head	7
17	9072-003	Plug/O-ring S/A — 7/16-20 UNF	1
X	250003-905	O-ring	1
	—	Plug/O-ring S/A — G 1/4 (BSP)	1
	—	O-ring	1
18	14392-005	Key	1
19	14163-000	Hex Nut	1
	60569-000	Seal Kit — Contains Parts Indicated by X	

*See Chart Below

Displacement cm ³ /r [in ³ /r]	Item Ref. No. 14 Screw, Cap Internal Hex	Length mm [inch]	Ref. No. 12 Geroler®	Width mm [inch]	Ref. No. 10 Drive	Length mm [inch]
80 [4.9]	16319-616	44,4 [1.75]	201974-001	9,1 [.36]	201979-003	81,0 [3.19]
126 [7.7]	16319-622	57,1 [2.25]	201974-002	11,9 [.47]	201979-001	83,7 [3.30]
154 [9.4]	16319-624	63,5 [2.50]	201974-003	14,7 [.58]	201979-002	86,4 [3.40]
195 [11.9]	16319-624	63,5 [2.50]	201974-004	18,5 [.73]	22252-000	90,0 [3.54]
251 [15.3]	16319-626	69,8 [2.75]	201974-005	23,9 [.94]	22189-000	95,8 [3.77]
303 [18.5]	16319-630	76,2 [3.00]	201974-006	29,0 [1.14]	201979-005	100,8 [3.97]
374 [22.8]	16319-632	82,5 [3.25]	201974-007	35,6 [1.40]	201979-006	106,9 [4.21]

W Series


How to Order Replacement Parts

Each Order Must Include the Following:

1. Product Number
2. Date Code
3. Part Name
4. Part Number
5. Quantity of Parts

For More Detailed Information Contact Eaton Corp. Hydraulics Division 15151 Highway 5 Eden Prairie, MN 55344.

- Specifications and performance data, Catalog No. 11-111
- When servicing W Series refer to Repair Information No. 7-157. This repair manual lists tools required, and step by step disassembly and reassembly procedures.

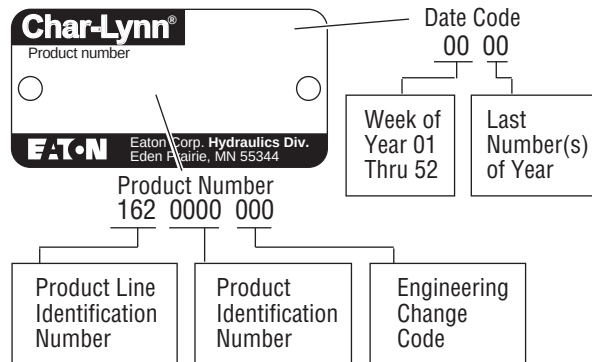

Eaton
Fluid Power Group
Hydraulics Business USA
14615 Lone Oak Road
Eden Prairie, MN 55344
USA
Tel: 952-937-9800
Fax: 952-294-7722
www.eaton.com/hydraulics

Eaton
Fluid Power Group
Hydraulics Business Europe
Route de la Longeraie 7
1110 Morges
Switzerland
Tel: +41 (0) 21 811 4600
Fax: +41 (0) 21 811 4601

Eaton
Fluid Power Group
Hydraulics Business Asia Pacific
11th Floor Hong Kong New World Tower
300 Huaihai Zhong Road
Shanghai 200021
China
Tel: 86-21-6387-9988
Fax: 86-21-6335-3912