

CGLine+ Touchscreen Controller



CGLine+ Touchscreen Controllers

- 10,1 inch Touchscreen IPS display with WIN10
- For connecting up to 800 luminaires in max. 4 lines
- Unique ID per luminaire assigned by the manufacturer
- Automatic luminaire search function requiring no manual addressing
- Simple sorting using unrestricted short address assignment
- Unrestricted entry of target location names for the luminaires with up to 20 characters
- Clearly-shown allocation of luminaires to up to 16 zones per line
- Automatic function and duration test of luminaires, with customisable time/date settings
- Up to 8 test groups per luminaire can be defined for the function test (FT) and duration test (DT)
- Electronic log book storage for a period of minimum 4 years
- Blocking the emergency lighting function during non-operational periods (all / per bus line/ per zone / per luminaire)
- Luminaires in maintained mode switchable (all / per bus line / per zone / per luminaire)
- Password protected access as an administrator or user
- Visualisation of luminaires in up to 30 different building layouts
- Efficient and convenient analysis of the log book using the CGLine+ PC software

10

CGL+ CGVision Touchscreen S/Controller - Specific features :

- CGVision Touchscreen Software allows full configuration and visualisation of the integrated CGLine+ Web Controller.


CGL+ CGVision Touchscreen G/Controller - Specific features :

- Ethernet connection
- CGVision Touchscreen Software allows full configuration and visualisation of the integrated CGLine+ Web Controller and up to 9 external controllers/installations via ethernet.
- E-mail service for sending automatic e-mail in case of malfunctions to up to 10 e-mail addresses, assignable and 2 escalation groups

CGLine+ Web Touchscreen Controller - Specific features :

- Ethernet connection
- Web-browser allows a visualisation of the integrated CGLine+ Web Controller and up to 9 external connected CGLine+ Web Controller via ethernet.
- Easy access web-based visualisation
- Building layouts could be loaded and used to localized faulty luminaires.
- Compatible with central CGVision software.
- E-mail service for sending automatic e-mail in case of malfunctions to up to 10 e-mail addresses, assignable and 2 escalation groups

Dimensional drawing Controller, data in mm

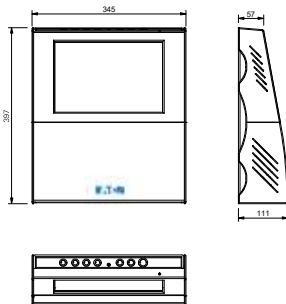

Dimensions in mm (H x W x D)	345 x 397 x 111
Housing type	Plastic, wall-mounted housing
Power supply	230 V AC, 50/60 Hz
Power consumption	< 12 watts standby < 38 watts full load
Connection terminals	max. 2.5 mm ² flexible
Permissible Ambient temperature	0 ° to 35 °C
Storage temperature	0 ° to 35 °C
Degree of protection	IP 20

Ordering details

Type	Scope of supply	Order No.
CGLine+ Web Touchscreen Controller	Web-based visualisation via integrated web-browser of any no. of networked CGL+ Web Touchscreen Controller or CGLine+ Web Controller. A networked CGVision PC allows a full configuration and monitoring of up to 32 CGLine+ Controllers	40071361056
CGL+ CGVision Touchscreen S/Controller	CGL+ CGVision Touchscreen S/Controller: Stand alone operation with full configuration and monitoring	40071361083
CGL+ CGVision Touchscreen G/Controller	CGL+ CGVision Touchscreen G/Controller: Group visualisation with full configuration and monitoring of up to 9 external CGL+ Controllers	40071361084

Accessory

Type	Scope of supply	Order No.
CGLine+ PC software	on CD-ROM	40071361178