

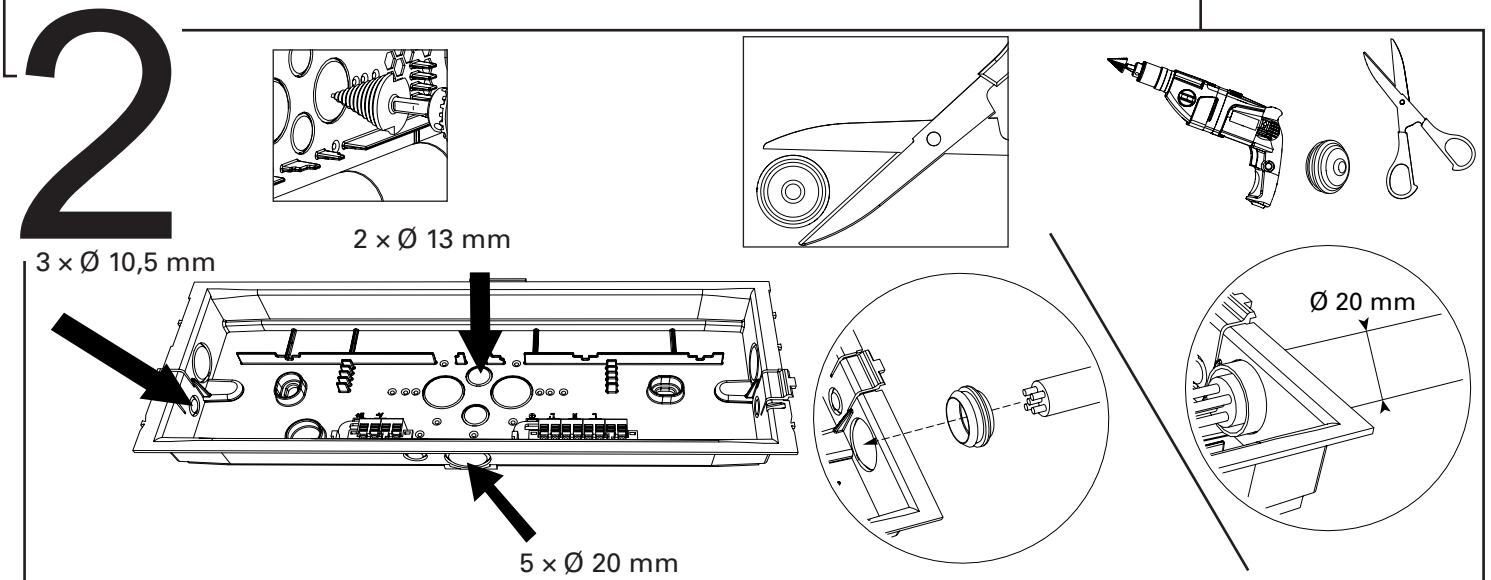
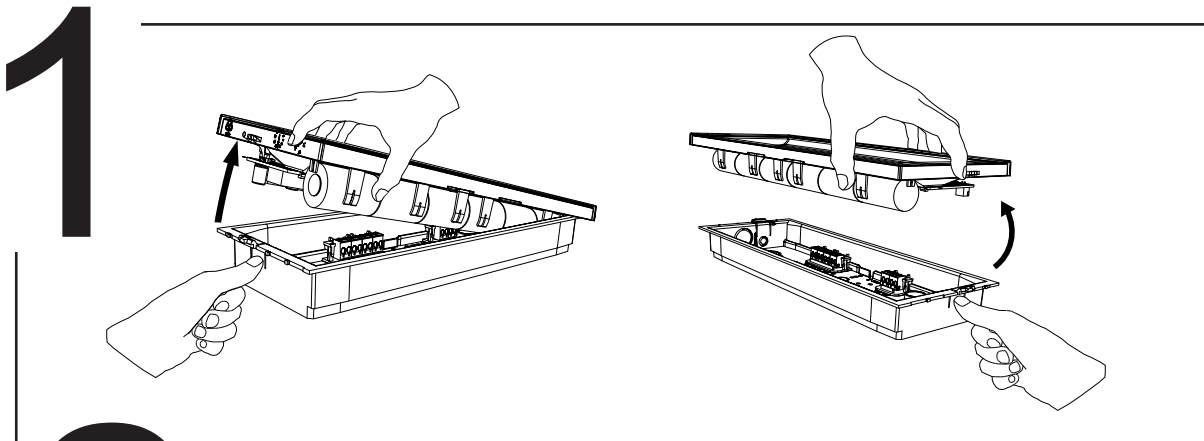
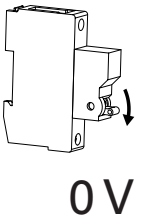
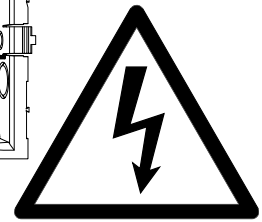
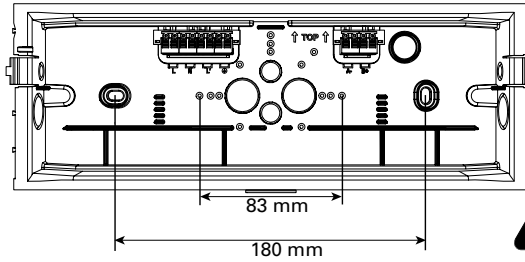
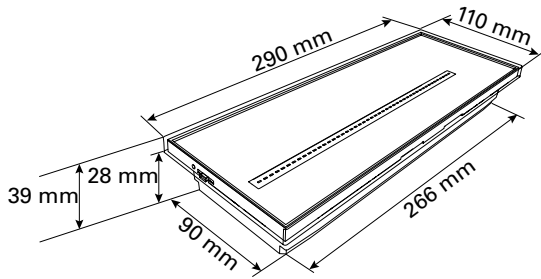



NexiLite

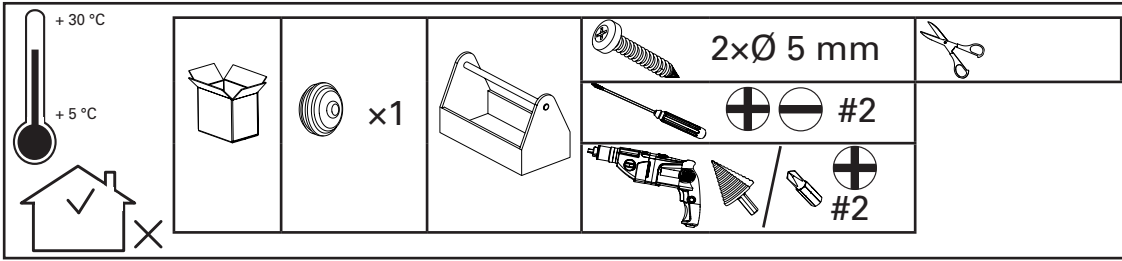

2


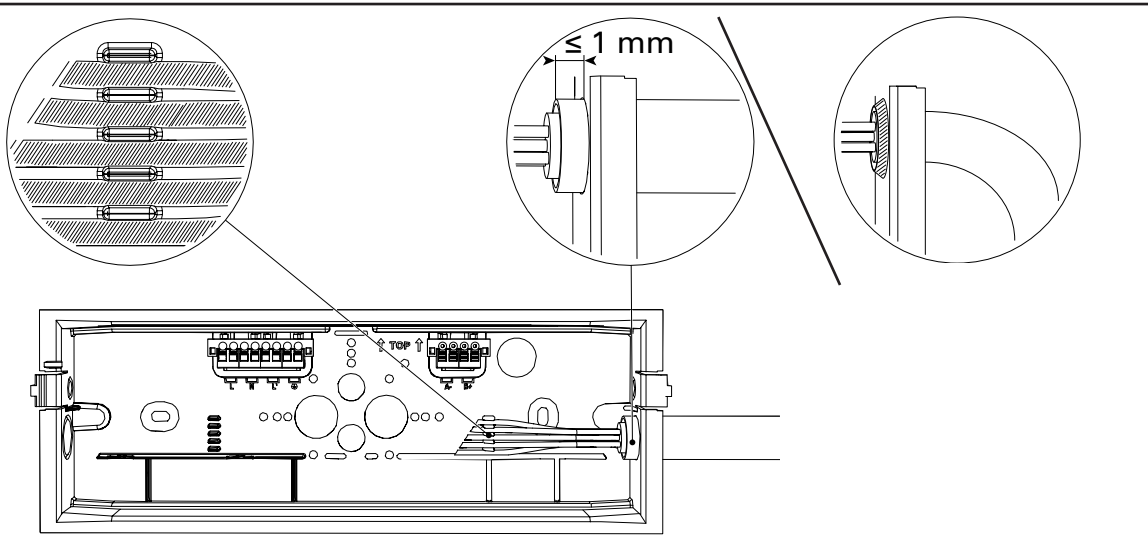


3


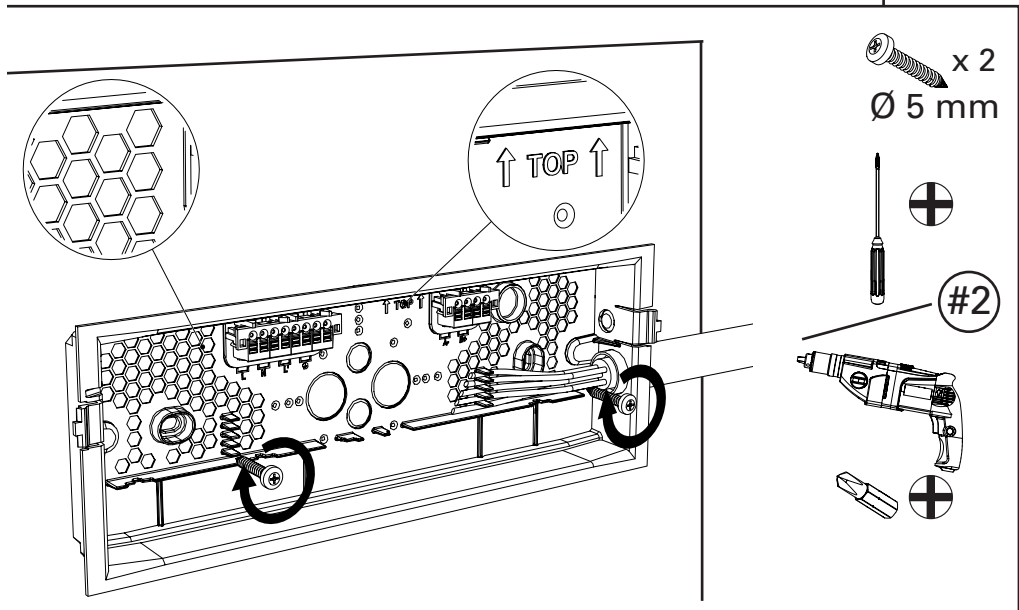


4


 
NXL100
NXL150
NXL250

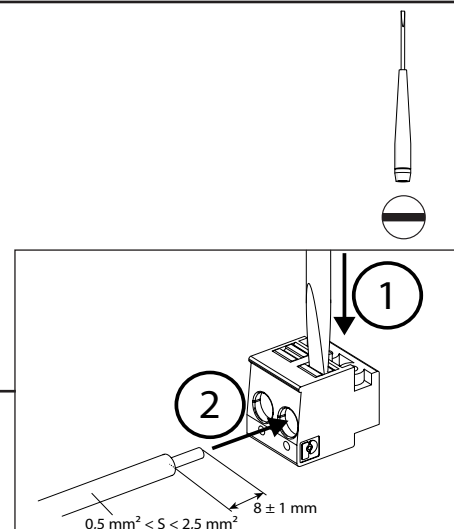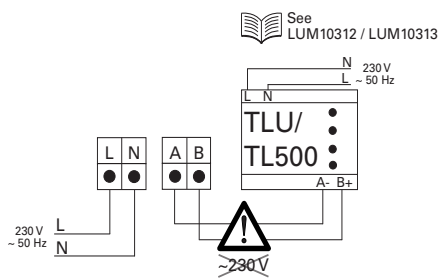



NXL150-3H
NXL250-3H

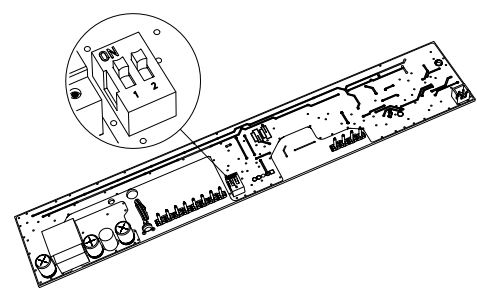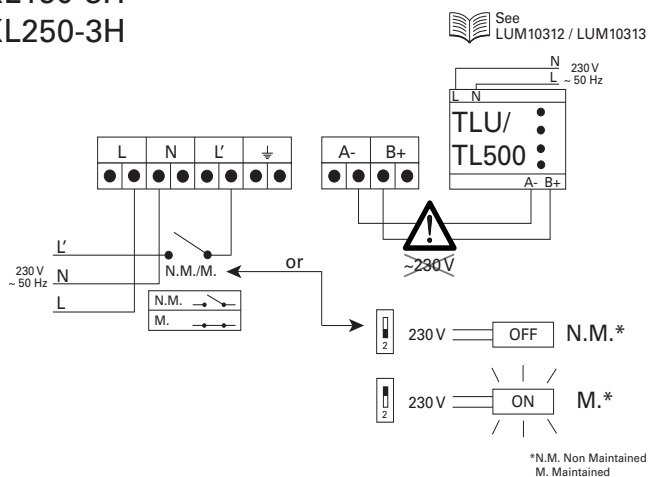




5 option

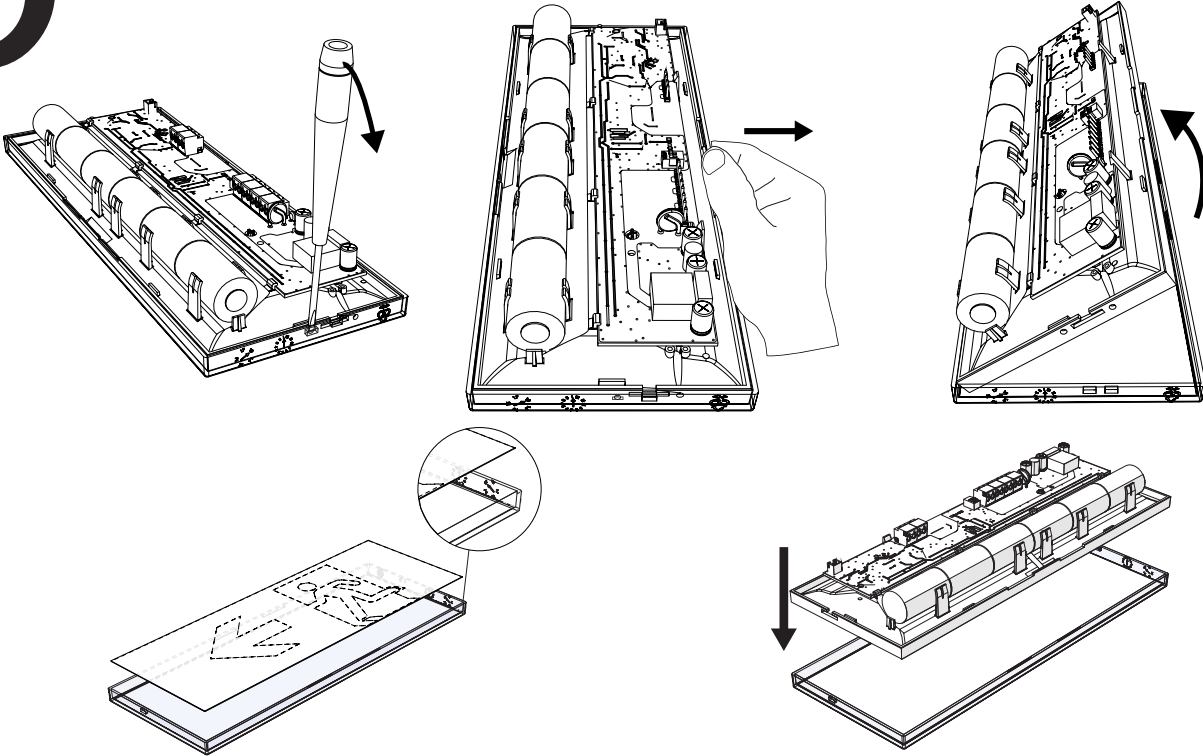

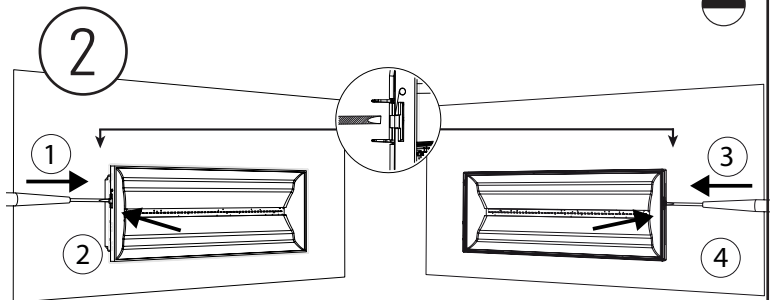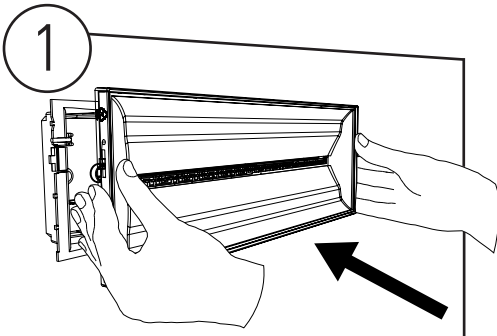


6

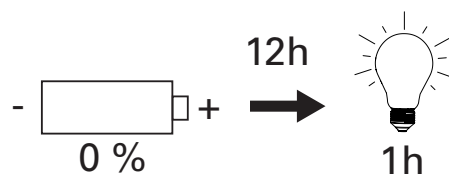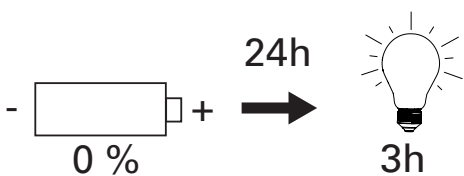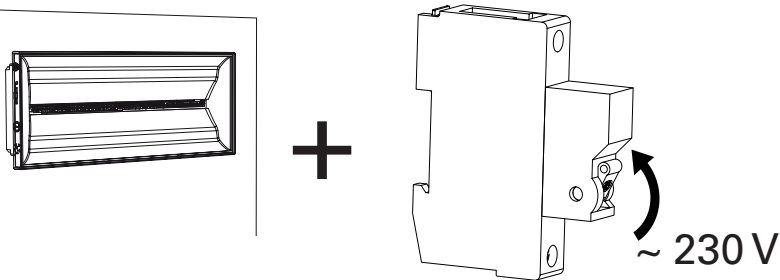

7



	IP/IK				N.M.	M.
			min	lm	W	W
NXL100	IP40/IK03	3,6 V 0,8 Ah NiCd	60	100	1,2	
NXL150	IP40/IK03	3,6 V 0,8 Ah NiCd	60	150	1,2	
NXL250	IP40/IK03	3,6 V 1,7 Ah NiCd	60	250	1,4	
NXL150-3H	IP40/IK03	3,6 V 2,0 Ah NiCd	180	150	1,3	3,1
NXL250-3H	IP40/IK03	7,2 V 1,7 Ah NiCd	180	250	2,25	3,6

