

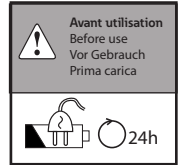
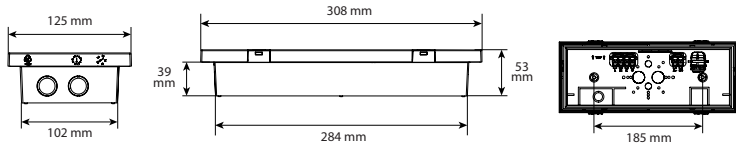


NexiTech LED 1h/3h IA CGLine+ IP65


+ web-controller CGLine+ (et variantes / and variants / und Varianten / e varianti)

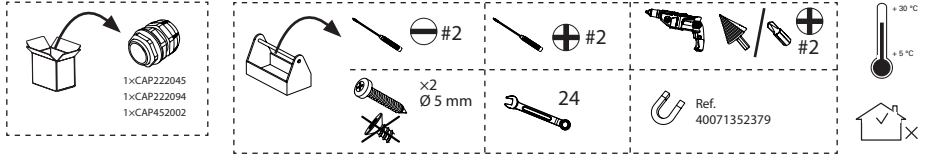

1

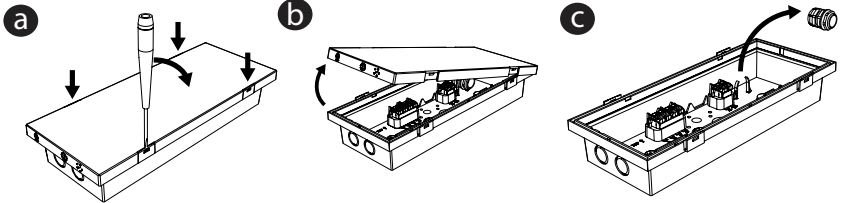

2

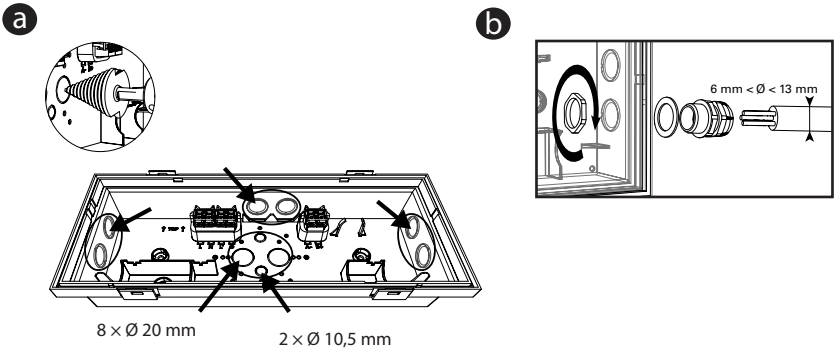


EATON

Powering Business Worldwide

3

× 2
Ø 5 mm


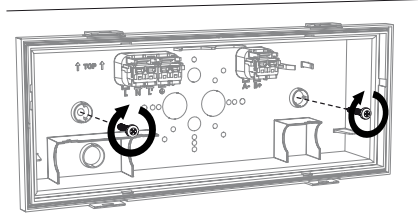


4

Fil rigide ou souple / Rigid or flexible wire / Starre oder flexible Leitung / Cavo rigido o flessibile
0,5 < S < 2,5 mm²




Si fil rigide / If rigid wire / Wenn starre Leitung /
Si cavo flessibile
1,5 < S < 2,5 mm²

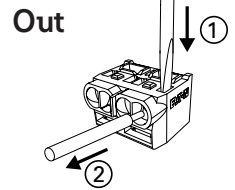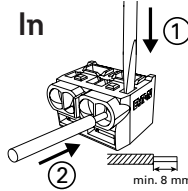

a

Web-controller CGLine+
(et variantes / and variants / und Varianten / e varianti)


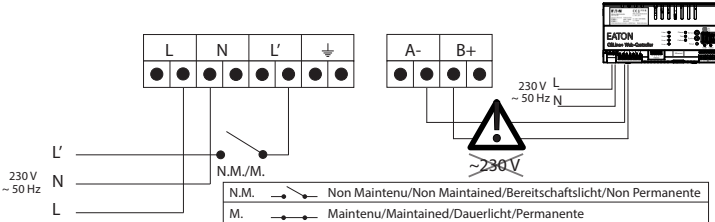


Web-controller CGLine+
40071361055
(Firmware: Z1000.G)

TL CGLine+
LUM10319 A

b






Réglage de l'intensité lumineuse sur secteur / Light intensity setting (230V ON) / Einstellung der Lichtintensität (230V ON) / Regolazione dell'intensità luminosa (con alimentazione)

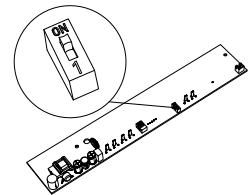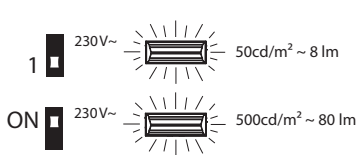

5

Pour changer le pictogramme

For changing the pictogram
Um das Piktogramm zu ändern
Per cambiare il pittogramma

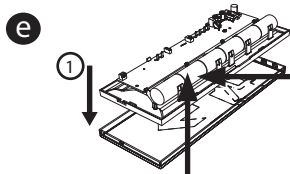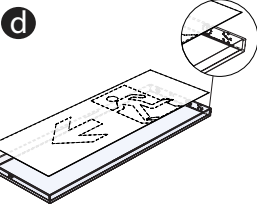
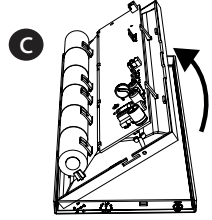
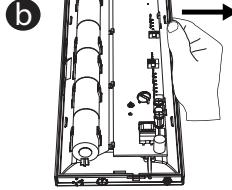
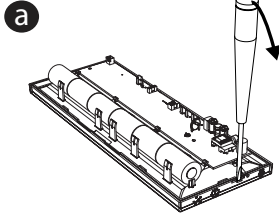


AASS/YYWW/JJWW/AASS
ex./ex./B./es.: 1536


Date de fabrication/Manufacturing date/
Herstellungsdatum/Data di fabbricazione

Date installation	jj/mm/aaaa
Installation date	dd/mm/yyyy
Installationsdatum	TT/MM/JJJJ
Data installazione	gg/mm/aaaa

   

6

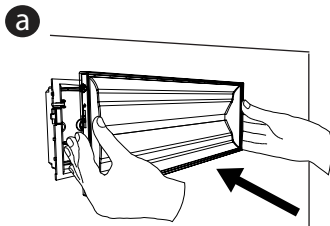



7 Affichage dynamique / Increase Affordance / Visibilità aumentata

 See PC Software CGLine+ manual for IA configurations/
 Se référer au manuel PC Software CGLine+ pour configurer l'affichage dynamique /
 Siehe Betriebsanleitung PC Software CGLine+ für IA/
 Cfr. manuale PC Software CGLine+ per la configurazione di la visibilità aumentata.

 Web-controller CGLine+ (et variantes / and variants / und Varianten / e varianti)

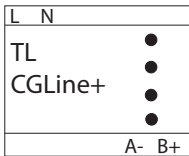

 
Contact sec
 Dry contact
 Schaltkontakt
 Contatto secco

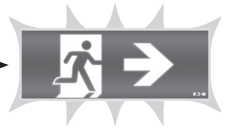





30 min

Affichage dynamique
 Increase Affordance
 Visibilità aumentata

 Web-controller CGLine+
 40071361055
 (Firmware: Z1000.G)

 TL CGLine+
 LUM10319 A

8 Test

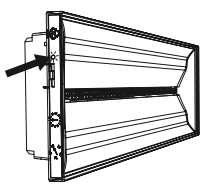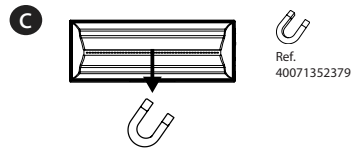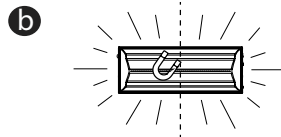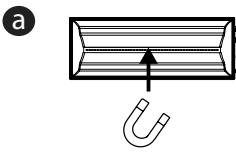

Vert/Green/ Grün/Verde		OK		Fixe Continuous Andauernd Fisso
Vert/Green/ Grün/Verde		Test		Clignotant Blinking Blinker Lampeggiante
Vert-Jaune/Green-Yellow/ Grün-Gelbe/Verde-Giallo		•))) com/kom		
Jaune/Yellow/Gelbe/Giallo		2 s		
Jaune/Yellow/Gelbe/Giallo		0,5 s		



N.M.

M.

EN



NEXITECH LED 1H IA CGLine+ IP65	NEXI1HIACGLIP	IP65//IK07	7,2 V 1,7 AH Ni-Cd	60 min	500cd/m ² 48 x LED Nichia 3V	1,8 W	3,9 W	EN 60598.1 EN 60598.2.22 EN 1838/ISO 30061 EN 62034
NEXITECH LED 3H IA CGLine+ IP65	NEXI3HIACGLIP			180 min				



**Remplacer la batterie si autonomie insuffisante/
Battery to replace if insufficient autonomy/
Ersetzen des Akkus wenn Autonomie ungenügend/
Sostituire la batteria se la autonomia è insufficiente.**



**Remplaçable
Replaceable
Auswechselbare
Sostituibile**



**Non remplaçable
Not replaceable
Nicht auswechselbar
Non sostituibili**

→ NEXI-BAT2



NEXI-PICTO-D



NEXI-PICTO-L



NEXI-PICTO-R



NEXI-PICTO-U

Eaton
Cooper Sécurité SAS
PEE II - Rue Beethoven - BP10184
63204 RIOM CEDEX FRANCE
+33 (0) 825 826 212
www.cooperfrance.com
www.eaton.com

© 2017 Eaton
All Rights Reserved

ZNO2040400B - 11/2017

Eaton is a registered trademark.

All trademarks are property of their respective owners.



EATON

Powering Business Worldwide

