

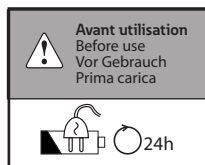
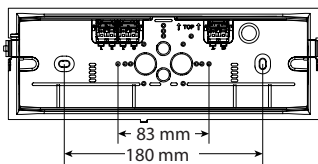


# NexiTech LED 1h/3h IA CGLine+


+ web-controller CGLine+ (et variantes / and variants / und Varianten / e varianti)

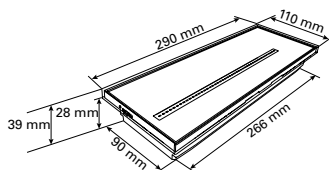


1

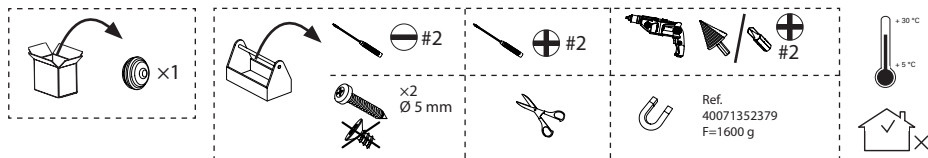

a

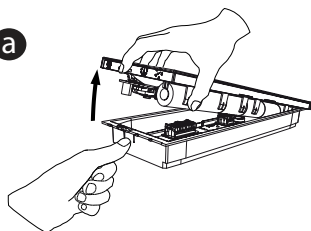


b

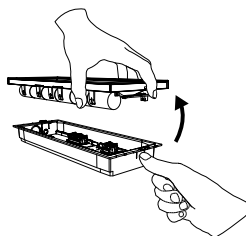


2

 a






2 × Ø 13 mm

3 × Ø 10,5 mm

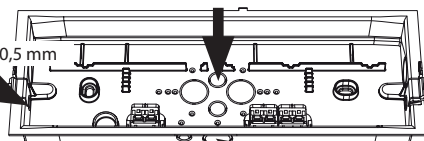

5 × Ø 20 mm


b

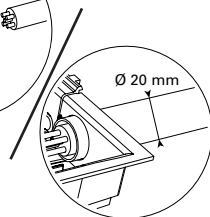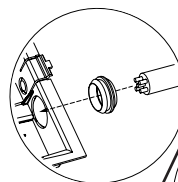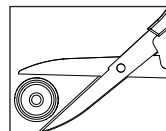

# EATON


Powering Business Worldwide

2

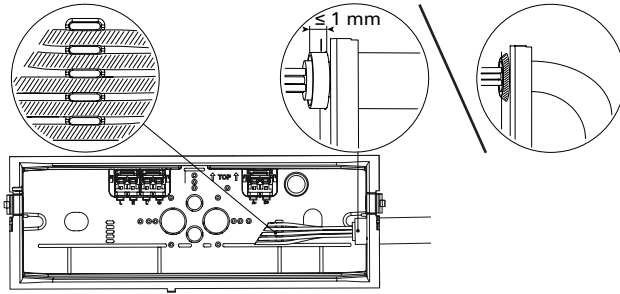

3

× 2  
Ø 5 mm


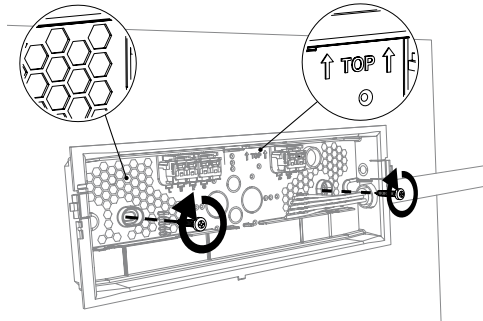


4

**Fil rigide ou souple / Rigid or flexible wire / Starre oder flexible Leitung / Cavo rigido o flessibile**  
 $0,5 < S < 2,5 \text{ mm}^2$




**Si fil rigide / If rigid wire / Wenn starre Leitung / Si cavo flessibile**  
 $1,5 < S < 2,5 \text{ mm}^2$

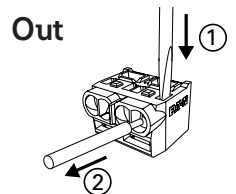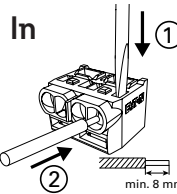

a



**Web-controller CGLine+**  
 (et variantes / and variants / und Varianten / e varianti)

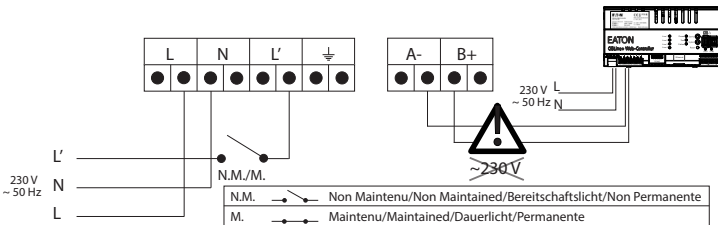

Web-controller CGLine+  
 40071361055  
 (Firmware: Z1000.G)

TL CGLine+  
 LUM10319 A

**b** Réglage de l'intensité lumineuse sur secteur / Light intensity setting (230V ON) / Einstellung der Lichtintensität (230V ON) / Regolazione dell'intensità luminosa (con alimentazione)

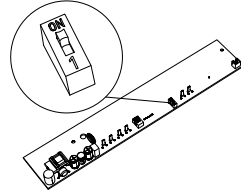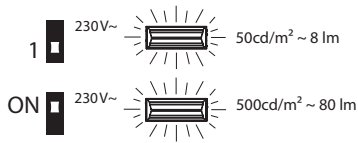


**5**


**Pour changer le pictogramme**  
 For changing the pictogram  
 Um das Piktogramm zu ändern  
 Per cambiare il pittogramma




**a**

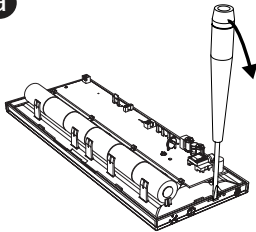


**b**

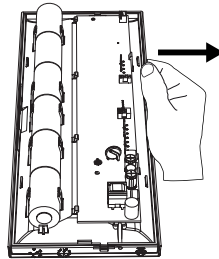


**c**

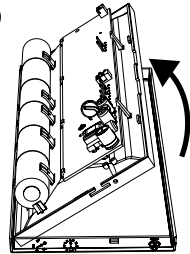

**d**

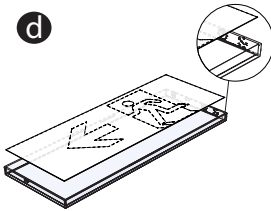

**e**

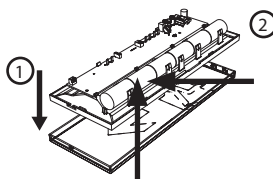


Date installation	jj/mm/aaaa
Installation date	dd/mm/yyyy
Installationsdatum	TT/MM/JJJJ
Data installazione	gg/mm/aaaa


AASS/YYWW/JJWW/AASS  
 ex./ex./B./es.: 1536  
 Date de fabrication/Manufacturing date/  
 Herstellungsdatum/Data di fabbricazione

**6**


**a**

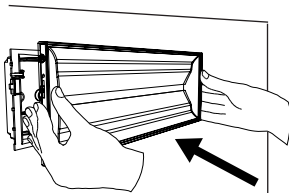

**b**

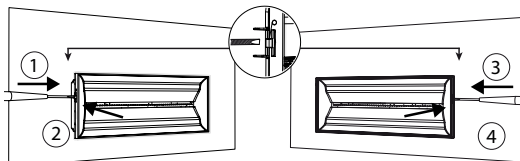

7

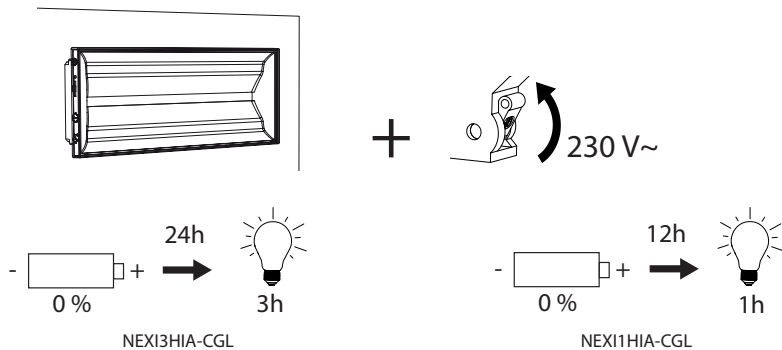

8

## Affichage dynamique / Increase Affordance / Visibilità aumentata



See PC Software CGLine+ manual for IA configurations/


 
Se référer au manuel PC Software CGLine+ pour configurer l'affichage dynamique /

Siehe Betriebsanleitung PC Software CGLine+ für IA/

Cfr. manuale PC Software CGLine+ per la configurazione di la visibilità aumentata.

### Web-controller CGLine+

(et variantes / and variants / und Varianten / e varianti)

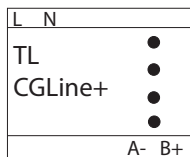

Contact sec  
Dry contact  
Schaltkontakt  
Contatto secco



30 min

Affichage dynamique  
Increase Affordance  
Visibilità aumentata




Web-controller CGLine+  
40071361055  
(Firmware: Z1000.G)




TL CGLine+  
LUM10319 A

# 9 Test


a

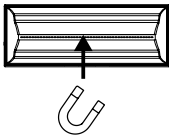


b

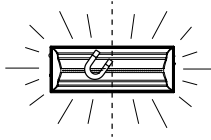

c

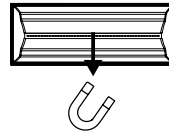

Ref.  
40071352379

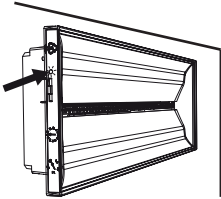

Vert/Green/  
Grün/Verde



OK

Vert/Green/  
Grün/Verde



Test

Vert-Jaune/Green-Yellow/  
Grün-Gelbe/Verde-Giallo



•) ) ) ) ) com/kom

Jaune/Yellow/Gelbe/Giallo



2 s



Jaune/Yellow/Gelbe/Giallo










0,5 s





**Fixe**  
Continuous  
Andauernd  
Fisso




**Clignotant**  
Blinking  
Blinker  
Lampeggiante

							N.M.	M.	EN	
NEXITECH LED 1H IA CGLine+	NEXI1HIA-CGL	IP40/IK03		7,2 V, 1,7 Ah Ni-Cd	60 min	500cd/m <sup>2</sup> 48 x LED Nichia 3V	1,8 W	3,9 W		
NEXITECH LED 3H IA CGLine+	NEXI3HIA-CGL				180 min				EN 60598.1 EN 60598.2.22 EN 1838/ISO 30061 EN 62034	

 Remplacer la batterie si autonomie insuffisante/  
 Battery to replace if insufficient autonomy/  
 Ersetzen des Akkus wenn Autonomie ungenügend/  
 Sostituire la batteria se la autonomia è insufficiente.

 Non remplaçable  
 Not replaceable  
 Nicht auswechselbar  
 Non sostituibili

 Remplaçable  
 Replaceable  
 Auswechselbare  
 Sostituibile

➔ NEXI-BAT2

