

CERTIFICATE

Issued to:
Applicant:
Cooper Securite SAS
Parc Européen d'Entreprise RII Rue Beethoven -
BP 10184
63204 Riom, France

Licensee:
COOPER CSA S.R.L.
Via San Bovio 3 - Edificio Y
20090 Segrate (MI), Italy

Product : Luminaire for emergency lighting with LED light source
Trade name(s) : EATON
Type(s)/model(s) : NEXI600-AT and NEXI600-AT-IP

The product and any acceptable variation thereto is specified in the Annex to this certificate and the documents therein referred to.

DEKRA hereby declares that the above-mentioned product has been certified on the basis of:

- a type test according to the standard EN 60598-2-22:2014, EN 60598-2-22:2014/AC:2015, EN 60598-2-22:2014/AC:2016-05, EN 60598-1:2015, EN 60598-1:2015/AC:2016, EN 60598-1:2015/AC:2015 and EN 60598-1:2015/A1:2018
- an inspection of the production location according to CENELEC Operational Document CIG 021
- a certification agreement with the number 3504272

DEKRA hereby grants the right to use the ENEC certification mark.


Compliance with the requirements of this Standard carries a presumption of conformity with the essential safety requirements of the Low voltage directive (LVD) 2014/35/EU.

The ENEC certification mark may be applied to the product as specified in this certificate for the duration of the ENEC certification agreement and under the conditions of the ENEC certification agreement.

This certificate is issued on 11 February 2019 and expires upon withdrawal of one of the above mentioned standards.

Certificate number: 81-107406

DEKRA Certification B.V.

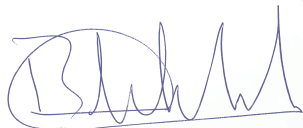

B.T.M. Holtus
Managing Director



RZH Zhou
Certification Manager

© Integral publication of this certificate is allowed

ACCREDITED BY THE
DUTCH ACCREDITATION
COUNCIL



SPECIFICATION OF THE CERTIFIED PRODUCT**Product data**

Product	: Luminaire for emergency lighting with LED light source
Trade name(s)	: EATON
Type(s)/model(s)	: NEXI600-AT and NEXI600-AT-IP
Supply voltage	: 220-240 V
Rated frequency	: 50/60 Hz
Ambient temperature	: 5..30 °C
Battery	: NiCd 7,2 V 1,7 Ah
Type installation	: Ceiling / Wall / Recessed ceiling / Wall
Rated duration of emergency operation	: 90 minutes
Type	: Maintained / Non maintained

Product data – type NEXI600-AT

Degree of protection	: IP40
Degrees of protection against	: IK03

Product data – type NEXI600-AT-IP

Degree of protection	: IP65
Degrees of protection against	: IK07

TESTS**Test requirements**

EN 60598-2-22:2014
EN 60598-2-22:2014/AC:2015
EN 60598-2-22:2014/AC:2016-05
EN 60598-1:2015
EN 60598-1:2015/AC:2016
EN 60598-1:2015/AC:2015
EN 60598-1:2015/A1:2018

Test result

The test results are laid down in DEKRA test file 350627200.

Additional information

The test results list are laid down in DEKRA test report No. 3506272.50

The list of components is laid down at test report 3506272.50

Note with the accessory

NEXI-RB Recessed wall box (dimension 277 x 100 mm)
NEXI- FC Kit Recessed ceiling (dimension 272 x 95 mm)

Conclusion

The examination proved that all requirements were met.

Factory location

SC Cooper Industries Romania SRL
Zona Industrială Vest Str. III, Nr. 12
310510 Arad, Romania