


Askari Panel - process sounder

A compact sounder, designed to fit through the fascias of control panels or equipment housings. The single nut fixing ensures simple installation and maximum audibility, while the high IP rating allows installation in most process and industrial environments.



Technical specification

Voltage	9-28Vdc, 24Vac
Current	18mA (Typical Tone 3)
Sound output	92dB(A)
Tones	32
Alarm stages	2
Temperature	- 25°C to + 70°C
Protection	IP65
Construction	ABS
Weight	0.09kg
Colour	Red or white

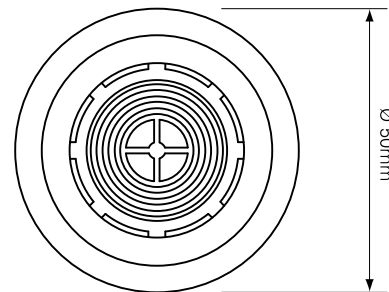


Features

- Small size
- Dedicated panel fixing
- 9Vdc to 28Vdc
- IP65 protection

Benefits

- Easily accommodated
- Easy to fit into control equipment enclosures
- Accepts most common DC supplies
- Can be used in internal and external equipment

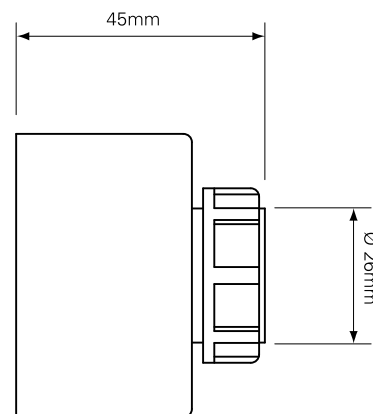

Reference	Catalogue no.	Description
AP/W/S/VC	560002FULL-0072	Askari Panel Mounting Sounder, White, Tone Select Switch, Volume Control
AP/R/S VC	560013FULL-0021	Askari Panel Mounting Sounder, Red, Tone Select Switch, Volume Control
AP/SV/W/S/VC/24VAC	562002FULL-0076	Askari Panel, 24V, White Base, Switch, Volume Control