



The 111dB (A) IP66 rated Asserta Midi Sounder is a versatile, compact unit that has been designed for industrial environments or areas where there is a requirement for a physically robust alarm.


Features

- 111dB(A) output
- 32 Alarm tones
- 2 stage alarm
- Robust design with IP66 protection

Benefits

- Large range of tone options
- Alert and alarm function
- For demanding environments in non-hazardous area

Dimensions

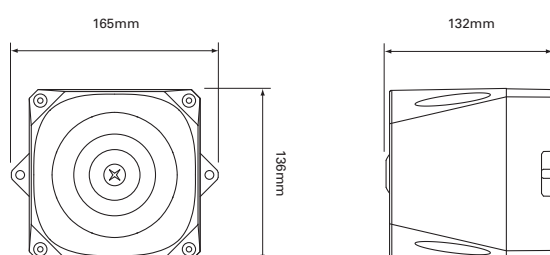

Technical Specification

Voltage	9 - 60Vdc
Current	24mA @ 24Vdc (Typical Tone 3)
Sound Output	108dB(A) @ 24Vdc (Typical Tone 3)
Tones	32
Alarm Stages	2
Monitoring	Reverse polarity (dc only)
Temperature	- 25°C to + 70°C
Protection	IP66
Construction	ABS
Weight	0.5Kg (dc version) 0.7Kg (mains version)
Colour	Red or grey

Asserta Midi Grey



Catalogue Numbers

Reference	Cat No	Description
AS/M/S/9-60V/R	7041134FUL-0020X	Asserta MIDI Sounder, Red, 9 to 60Vdc
AS/M/S/9-60/G	7041214FUL-0176X	Asserta MIDI Sounder, Grey, 9 to 60Vdc

