

Remote LED Indicator REM/C

Cable Size	0.5 - 2.5mm ²
Recommended cable types	FIRETUF,FP200 or MICC
Mounting Hole Centres	60.3mm
Temperature Range	-10°C to +60°C
Material	Body(PC/ABS) Lense (PMMA)





Llantarnam Park
Cwmbran
Gwent
Wales
U.K.
NP44 3AW

Connection	1 & 3	1 & 3	2 & 3
Link JP1	Out	In	n/a
Supply	5-35Vdc	3-16Vdc	25mA max
Resistance	3k6	1k5	0



WIRING DETAILS

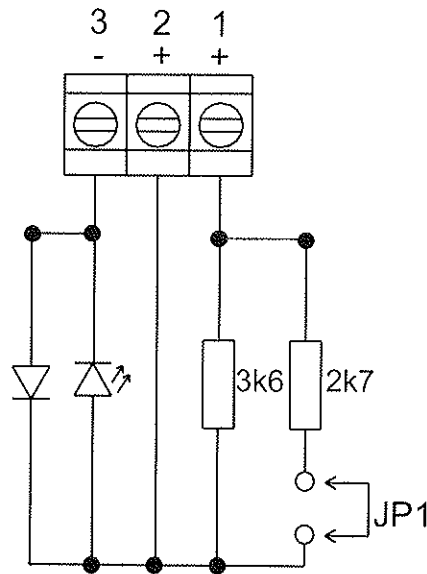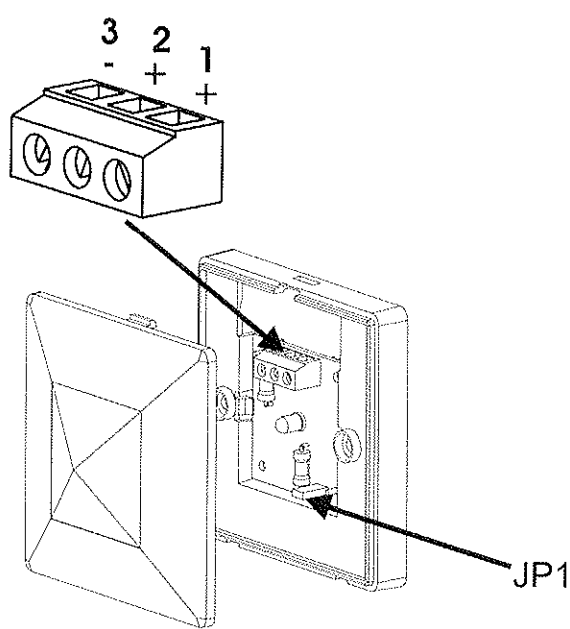

DIMENSIONS

