


**Kwiksplice™ cable tray and  
FLEXTRAY™ wire basket**

CANSTKCT

**B-LINE  
SERIES**

**Ready. Set. Ship.**

B-Line series KwikSplice™ cable tray & FLEXTRAY™ stocked in Mississauga for faster delivery!

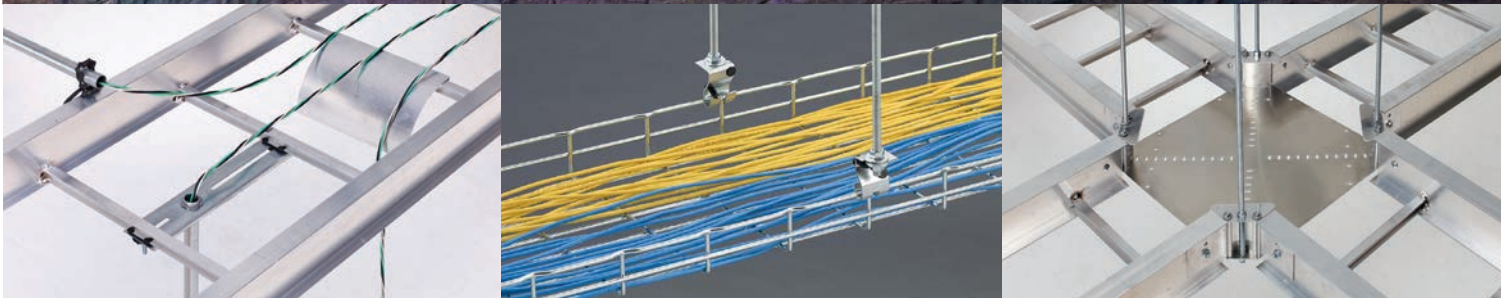

**Now stocked in Mississauga**

- KwikSplice™ Aluminum Cable Tray
  - 4 different width options
  - Class C-3m and D-3m
  - 12" rung spacing and 10' lengths
  - Horizontal & vertical bends
  - Horizontal tees
  - Universal Fitting
  - Covers and accessories
- FLEXTRAY™ Wire Basket
  - 2" and 4" deep straight sections
  - Splices, supports and popular accessories also available



**EATON**

*Powering Business Worldwide*

B-Line Part #	Competitors Part #		
---------------	--------------------	--	--

### Straight Sections

<input type="checkbox"/>	KSA4A12-06-120	AH1-4-06-L12-3	LCA43-06-12	CI40LASL3126
<input type="checkbox"/>	KSA4A12-12-120	AH1-4-12-L12-3	LCA43-12-12	CI40LASL31212
<input type="checkbox"/>	KSA4A12-18-120	AH1-4-18-L12-3	LCA43-18-12	CI40LASL31218
<input type="checkbox"/>	KSA4A12-24-120	AH1-4-18-L12-3	LCA43-24-12	CI40LASL31224
<input type="checkbox"/>	KSB4A12-06-120	AH24-06-L12-120	LDA43-06-12	DI45LASL3126
<input type="checkbox"/>	KSB4A12-12-120	AH24-12-L12-120	LDA43-12-12	DI45LASL31212
<input type="checkbox"/>	KSB4A12-18-120	AH24-18-L12-120	LDA43-18-12	DI45LASL31218
<input type="checkbox"/>	KSB4A12-24-120	AH24-24-L12-120	LDA43-24-12	DI45LASL31224

### Horizontal Bends

<input type="checkbox"/>	KS4A09-06-90HB12	AUF4-06-LHB90-12	LCA43-06-H90, 12R	CI40LAHL90126
<input type="checkbox"/>	KS4A09-12-90HB12	AUF4-12-LHB90-12	LCA43-12-H90, 12R	CI40LAHL901212
<input type="checkbox"/>	KS4A09-18-90HB12	AUF4-18-LHB90-12	LCA43-18-H90, 12R	CI40LAHL901218
<input type="checkbox"/>	KS4A09-24-90HB12	AUF4-24-LHB90-12	LCA43-24-H90, 12R	CI40LAHL901224
<input type="checkbox"/>	KS4A09-12-90HB24	AUF4-12-LHB90-24	LCA43-12-H90, 24R	CI40LAHL902412
<input type="checkbox"/>	KS4A09-18-90HB24	AUF4-18-LHB90-24	LCA43-18-H90, 24R	CI40LAHL902418
<input type="checkbox"/>	KS4A09-24-90HB24	AUF4-24-LHB90-24	LCA43-24-H90, 24R	CI40LAHL902424

### Horizontal Tees

<input type="checkbox"/>	KS4A09-06-HT12	AUF4-06-LHT-12	LCA43-06-TEE, 12R	CI40LAHT126
<input type="checkbox"/>	KS4A09-12-HT12	AUF4-12-LHT-12	LCA43-12-TEE, 12R	CI40LAHT1212
<input type="checkbox"/>	KS4A09-18-HT12	AUF4-18-LHT-12	LCA43-18-TEE, 12R	CI40LAHT1218
<input type="checkbox"/>	KS4A09-24-HT12	AUF4-24-LHT-12	LCA43-24-TEE, 12R	CI40LAHT1224
<input type="checkbox"/>	KS4A09-12-HT24	AUF4-12-LHT-24	LCA43-12-TEE, 24R	CI40LAHT2412
<input type="checkbox"/>	KS4A09-18-HT24	AUF4-18-LHT-24	LCA43-18-TEE, 24R	CI40LAHT2418
<input type="checkbox"/>	KS4A09-24-HT24	AUF4-24-LHT-24	LCA43-24-TEE, 24R	CI40LAH2424

### Vertical Inside/Vertical Outside Bends

<input type="checkbox"/>	KS4A09-06-90VI12	AUF4-06-LVI90-12	LCA43-06-VI90, 12R	CI40LAVI90126
<input type="checkbox"/>	KS4A09-12-90VI12	AUF4-12-LVI90-12	LCA43-12-VI90, 12R	CI40LAVI901212
<input type="checkbox"/>	KS4A09-18-90VI12	AUF4-18-LVI90-12	LCA43-18-VI90, 12R	CI40LAVI901218
<input type="checkbox"/>	KS4A09-24-90VI12	AUF4-24-LVI90-12	LCA43-24-VI90, 12R	CI40LAVI901224
<input type="checkbox"/>	KS4A09-12-90VI24	AUF4-12-LVI90-24	LCA43-12-VI90, 24R	CI40LAVI902412
<input type="checkbox"/>	KS4A09-18-90VI24	AUF4-18-LVI90-24	LCA43-18-VI90, 24R	CI40LAVI902418
<input type="checkbox"/>	KS4A09-24-90VI24	AUF4-24-LVI90-24	LCA43-24-VI90, 24R	CI40LAVI902424
<input type="checkbox"/>	KS4A09-06-90VO12	AUF4-06-LVO90-12	LCA43-06-VO90, 12R	CI40LAVO90126
<input type="checkbox"/>	KS4A09-12-90VO12	AUF4-12-LVO90-12	LCA43-12-VO90, 12R	CI40LAVO901212
<input type="checkbox"/>	KS4A09-18-90VO12	AUF4-18-LVO90-12	LCA43-18-VO90, 12R	CI40LAVO901218
<input type="checkbox"/>	KS4A09-24-90VO12	AUF4-24-LVO90-12	LCA43-24-VO90, 12R	CI40LAVO901224
<input type="checkbox"/>	KS4A09-12-90VO24	AUF4-12-LVO90-24	LCA43-12-VO90, 24R	CI40LAVO902412
<input type="checkbox"/>	KS4A09-18-90VO24	AUF4-18-LVO90-24	LCA43-18-VO90, 24R	CI40LAVO902418
<input type="checkbox"/>	KS4A09-24-90VO24	AUF4-24-LVO90-24	LCA43-24-VO90, 24R	CI40LAVO902424

### Universal Fitting

<input type="checkbox"/>	KS4A-UF-06	6" Universal fitting with cable tie provisions
<input type="checkbox"/>	KS4A-UF-12	12" Universal fitting with cable tie provisions
<input type="checkbox"/>	KS4A-UF-18	18" Universal fitting with cable tie provisions
<input type="checkbox"/>	KS4A-UF-24	24" Universal fitting with cable tie provisions


B-Line Part #	Description
---------------	-------------

### Tab and Lock Trapeze Support

<input type="checkbox"/>	KSA-06CT	6" Tab and Lock Trapeze Hanger
<input type="checkbox"/>	KSA-12CT	12" Tab and Lock Trapeze Hanger
<input type="checkbox"/>	KSA-18CT	18" Tab and Lock Trapeze Hanger
<input type="checkbox"/>	KSA-24CT	24" Tab and Lock Trapeze Hanger

### Accessories

<input type="checkbox"/>	KS4A-SSP	4" Splice Plate
<input type="checkbox"/>	KSA-SDO-12	12" Side Rail Drop Out
<input type="checkbox"/>	KSA-OUT-06	6" Rung Drop Out
<input type="checkbox"/>	KSA-OUT-12	12" Rung Drop Out
<input type="checkbox"/>	KSA-OUT-18	18" Rung Drop Out
<input type="checkbox"/>	KSA-OUT-24	24" Rung Drop Out
<input type="checkbox"/>	KS4A-FSP	4" Flexmount Splice Plate
<input type="checkbox"/>	807A-06-120	6" Solid Flange Cover
<input type="checkbox"/>	807A-12-120	12" Solid Flange Cover
<input type="checkbox"/>	807A-18-120	18" Solid Flange Cover
<input type="checkbox"/>	807A-24-120	24" Solid Flange Cover
<input type="checkbox"/>	9A-9012	Standard Indoor Cover Clamp
<input type="checkbox"/>	KS4A-HDCC-06	6" Heavy Duty Wrap Around Cover Clamp
<input type="checkbox"/>	KS4A-HDCC-12	12" Heavy Duty Wrap Around Cover Clamp
<input type="checkbox"/>	KS4A-HDCC-18	18" Heavy Duty Wrap Around Cover Clamp
<input type="checkbox"/>	KS4A-HDCC-24	24" Heavy Duty Wrap Around Cover Clamp
<input type="checkbox"/>	KS4A-VSP	4" Vertical Adjustable Splice Plate
<input type="checkbox"/>	KS4A-RSP-S3	3" Offset Side Reducing Splice Plate
<input type="checkbox"/>	KS4A-RSP-S6	6" Offset Side Reduction Splice Plate
<input type="checkbox"/>	KS4A-RSP-S9	9" Offset Side Reduction Splice Plate
<input type="checkbox"/>	R4A-DSL-120	4" Side Rail Straight Section Barrier Strip
<input type="checkbox"/>	R4A-DHB	Hold Down Clamp/Guide
<input type="checkbox"/>	99-30	Bonding Jumping
<input type="checkbox"/>	9A-2130	Grounding Clamp - UL
<input type="checkbox"/>	9G-1158-1 & 1 1/4	Conduit to Tray Adapter - UL
<input type="checkbox"/>	BG-8-12-W2	Guide-Rite Conduit to Tray Adapter (1/2" and 3/4")
<input type="checkbox"/>	BG-16-W2	Guide-Rite Conduit to Tray Adapter (1")
<input type="checkbox"/>	9ZN-1241	Heavy Duty Hold Down Bracket
<input type="checkbox"/>	KSA-VCH-0.5	Vertical Conduit Hanger for 1/2" Conduit
<input type="checkbox"/>	KSA-VCH-0.75	Vertical Conduit Hanger for 3/4" Conduit
<input type="checkbox"/>	KSA-VCH-1	Vertical Conduit Hanger for 1" Conduit
<input type="checkbox"/>	KS4A-CP	4" Universal Fitting Corner Post

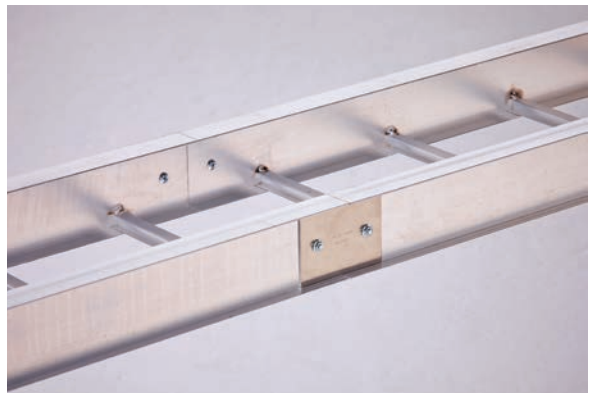

\* Splice plate included with all straight sections and fittings

# FLEXTRAY™ wire basket cable tray

## B-Line Part # Description

### Straight Sections

<input type="checkbox"/>	FT2X4X10 ELG	2' Deep X 4" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X6X10 ELG	2' Deep X 6" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X8X10 ELG	2' Deep X 8" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X12X10 ELG	2' Deep X 12" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X16X10 ELG	2' Deep X 16" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X18X10 ELG	2' Deep X 18" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X20X10 ELG	2' Deep X 20" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X6X10 ELG	4" Deep X 6" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X8X10 ELG	4" Deep X 8" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X12X10 ELG	4" Deep X 12" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X16X10 ELG	4" Deep X 16" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X18X10 ELG	4" Deep X 18" Wide X 3m Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X24X10 ELG	4" Deep X 24" Wide X 3m long Electroplated Zinc Galvanized Finish

### Splicing Accessories

<input type="checkbox"/>	WASHER SPL KIT	Connector Assembly of Staked Washer Stud/Washer & Finned Nut
<input type="checkbox"/>	FTHDWE 1/4	1/4" x 1" Carriage Bolt & Finned Nut
<input type="checkbox"/>	TOP WASHER	1" Square Splice Washer
<input type="checkbox"/>	BTM WASHER	1 3/16" Square Splice Washer
<input type="checkbox"/>	FTSCH	Connecting Hardware
<input type="checkbox"/>	FTSWN	Wing Splice
<input type="checkbox"/>	FTS3SP	Splice Plate
<input type="checkbox"/>	FLEXMATE2	Flexmate Splice Clips
<input type="checkbox"/>	FLEXMATE TOOL	Flexmate Splice Tool
<input type="checkbox"/>	FTSTLC	Tab-Loc Connectors
<input type="checkbox"/>	SPLICE BAR	10 13/16" Long Bar
<input type="checkbox"/>	SUPT WASHER	Hold Down Plate
<input type="checkbox"/>	FTA6HD	Hold Down Plate
<input type="checkbox"/>	FTSHAK	Horizontal Adjustable Kit
<input type="checkbox"/>	90 DEGREE KIT	90 Degree Splice Bar & Hardware


### Accessories

<input type="checkbox"/>	2 IN DIVIDER	2" Divider
<input type="checkbox"/>	4 IN DIVIDER	4" Divider
<input type="checkbox"/>	CABLE ROLLER	Cable Roller
<input type="checkbox"/>	DROP OUT	Drop out Fitting
<input type="checkbox"/>	FTA2DO	2" Plenum-rated Plastic Cable Drop Out
<input type="checkbox"/>	B719EB	Rubber Cap for Wire Ends
<input type="checkbox"/>	LABEL CLIP	Label Clip
<input type="checkbox"/>	GROUND BOLT	Ground Bolt
<input type="checkbox"/>	GROUND SUPT GL	Ground Wire Support
<input type="checkbox"/>	CLEANSHEAR™	Flextray Cutter
<input type="checkbox"/>	CLEANSHEAR™ BEND	Flextray Cutter/Bender

## B-Line Part # Description

### Supports

<input type="checkbox"/>	WB46H	Flip Clip
<input type="checkbox"/>	TRAPEZE SUPT2	Trapeze Support Clip
<input type="checkbox"/>	FTB06CT	6" Center/Trapeze Hanger
<input type="checkbox"/>	FTB08CT	8" Center/Trapeze Hanger
<input type="checkbox"/>	FTB12CT	12" Center/Trapeze Hanger
<input type="checkbox"/>	FTB18CT	18" Center/Trapeze Hanger
<input type="checkbox"/>	FTB24CT	24" Center/Trapeze Hanger
<input type="checkbox"/>	4 L BRKT	4" L Bracket
<input type="checkbox"/>	8 L BRKT	8" L Bracket
<input type="checkbox"/>	12 L BRKT	12" L Bracket
<input type="checkbox"/>	20 L BRKT	20" L Bracket
<input type="checkbox"/>	24 L BRKT	24" L Bracket
<input type="checkbox"/>	FTA9WTK	Wall Termination Kit

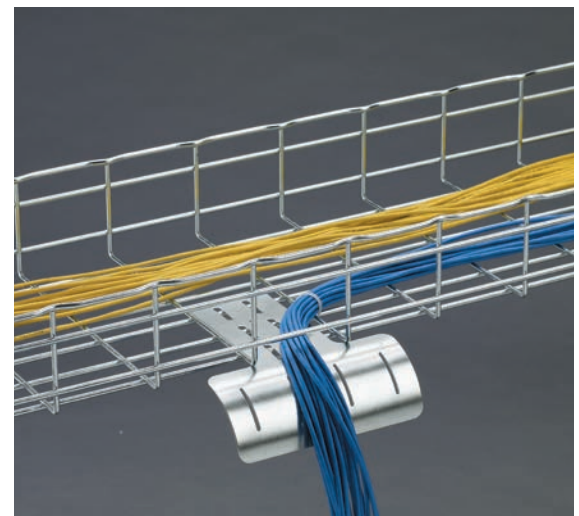





**Eaton**  
1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
Eaton.com

© 2015 Eaton  
All Rights Reserved  
Printed in USA  
Publication No. SA302003EN  
August 2015 CANSTKCT

B-Line Division  
509 West Monroe Street  
Highland, IL 62249  
United States  
Phone: 800-851-7415

[www.cooperblineline.com/contactus](http://www.cooperblineline.com/contactus)

Eaton is a registered trademark.

All other trademarks are property  
of their respective owners.

**Follow us on social media to get the  
latest product and support information.**

