
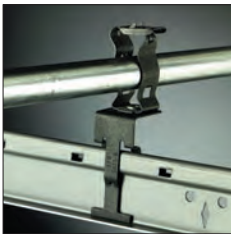



# Acoustical tee

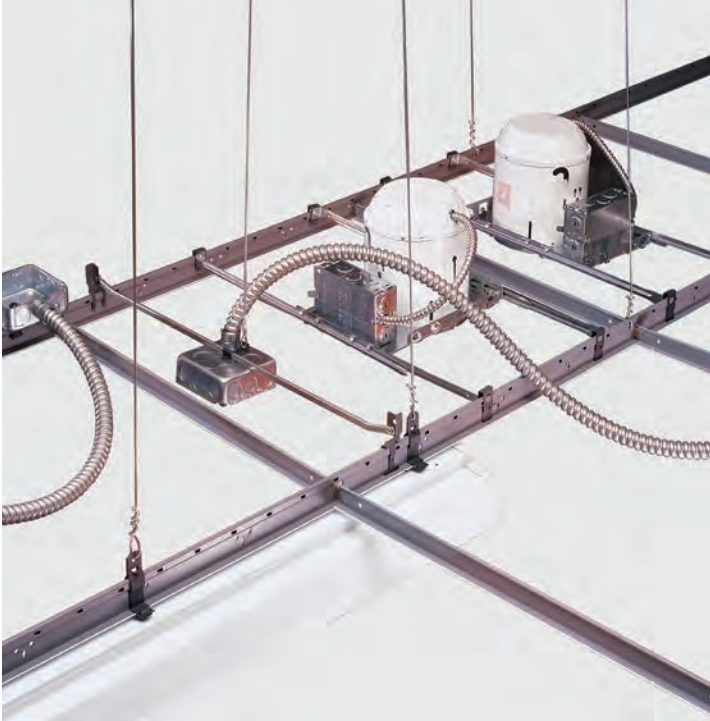

Acoustical Tee

*Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.*

# Acoustical tee

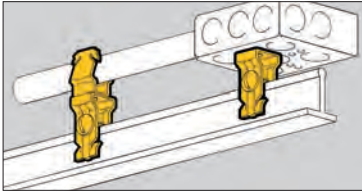


- Attaches to top of acoustical T-Bar with 1/4"-20 screw.
- Has 1/4"-20 thread impression for attachment to box or conduit fastener.
- **WARNING** Do not use for hanging acoustical tee.

## T-Bar Support Fasteners



| UPC/Part Number | Catalog Number | Description        | Box Qty. |
|-----------------|----------------|--------------------|----------|
| 78101118090     | BA14           | T-Bar Support Clip | 100      |

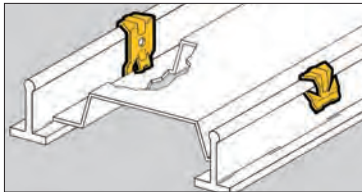


- Gives positive support for troffers and lay-in fixtures.
- Complies with NEC Article 410.16(C) for fixtures supported by suspended ceilings.
- Fits rectangular or round head T-Bars.
- Commonly known as "Hurricane Clip".

## Troffer Fasteners



| UPC/Part Number | Catalog Number | Description                                      | Box Qty. |
|-----------------|----------------|--|----------|
| 78101118095     | BA15           | For Straight Lip or Upturned Lip Fixtures        | 100      |
| 78205118209     | BA15W          | White, For Straight Lip or Upturned Lip Fixtures | 100      |

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

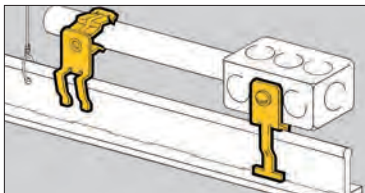

## Side Mount T-Bar Fasteners

- A positive method for supporting vertical boxes, conduit or cable above T-Bar.
- Allows conduit to clear drop wires.
- **WARNING** Do not use for hanging acoustical tee.



BA5-4T

| UPC/Part Number | Catalog Number | Description                    | Box Qty. |
|-----------------|----------------|--------------------------------|----------|
| 78101118095     | <b>BA5-4T</b>  | With 1/4"-20 Thread Impression | 100      |

BG Series



BP Series



| UPC/Part Number | Catalog Number    | Conduit Size | Box Qty. |
|-----------------|-------------------|--------------|----------|
| 78101118410     | <b>BG-6-A5 *</b>  | 3/8"         | 100      |
| 78101118465     | <b>BG-8-12-A5</b> | 1/2", 3/4"   | 100      |
| 78101118545     | <b>BG-16-A5</b>   | 1"           | 100      |


Patent #4958792

|             |                 |                             |     |
|-------------|-----------------|-----------------------------|-----|
| 78101119235 | <b>BP-8-A5</b>  | 1/2" EMT                    | 100 |
| 78101119335 | <b>BP-12-A5</b> | 3/4" EMT<br>1/2" IMC, Rigid | 100 |
| 78101118545 | <b>BP-16-A5</b> | 1"EMT<br>3/4" IMC, Rigid    | 100 |

\* BG-6 will accept the following range  $\varnothing.420 - \varnothing.675$ : 14/2 thru 10/4 MC/AC cable and 5/16" or 3/8" flexible conduit

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

# Acoustical tee

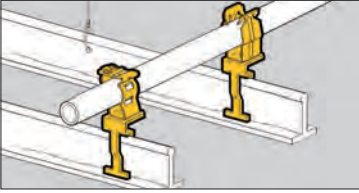

- A positive method for supporting horizontal boxes or conduit above T-Bar.
- Allows conduit to clear drop wires.
- **WARNING** Do not use for hanging acoustical tee.

## Top Mount T-Bar Fasteners



| UPC/Part Number | Catalog Number | Description                    | Box Qty. |
|-----------------|----------------|--------------------------------|----------|
| 78101118125     | <b>BA6-4T</b>  | With 1/4"-20 Thread Impression | 100      |


Acoustical Tee



| UPC/Part Number | Catalog Number    | Conduit Size                | Box Qty. |
|-----------------|-------------------|-----------------------------|----------|
| 781011188540    | <b>BG-6-A6 *</b>  | 3/8"                        | 100      |
| 78101118470     | <b>BG-8-12-A6</b> | 1/2", 3/4"                  | 100      |
| 78101118550     | <b>BG-16-A6</b>   | 1"                          | 100      |
| Patent #4958792 |                   |                             |          |
| 78101119240     | <b>BP-8-A6</b>    | 1/2" EMT                    | 100      |
| 78101119340     | <b>BP-12-A6</b>   | 3/4" EMT<br>1/2" IMC, Rigid | 100      |
| 78101119435     | <b>BP-16-A6</b>   | 1"EMT<br>3/4" IMC, Rigid    | 100      |

\* BG-6 will accept the following range  $\varnothing.420 - \varnothing.675$ : 14/2 thru 10/4 MC/AC cable and 5/16" or 3/8" flexible conduit

*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*

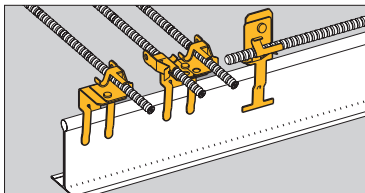

- A positive method for supporting cable or flexible conduit above T-Bar.
- Assemblies support MC, AC, sizes 14/2 through 10/3 or 3/8" FMC.

## Top Mount T-Bar Fasteners



BX4-A6



BX4M-A6

| UPC/Part Number | Catalog Number | Description | Box Qty. |
|-----------------|----------------|-------------|----------|
| 78101101220     | <b>BX4-A6</b>  | Single Runs | 100      |
| 78101101216     | <b>BX4M-A6</b> | Double Runs | 100      |

Note: Fasteners will rotate 360°.



BX4-A5




BX4M-A5

| UPC/Part Number | Catalog Number | Description | Box Qty. |
|-----------------|----------------|-------------|----------|
| 78101101187     | <b>BX4-A5</b>  | Single Runs | 100      |
| 78101101211     | <b>BX4M-A5</b> | Double Runs | 100      |

Note: Fasteners will rotate 360°.


*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*

# Acoustical tee

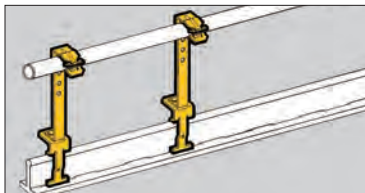

- Supports conduit and electrical boxes above T-Bar.
- Height adjusts from 4¼" to 7¼".
- Conduit fasteners can be attached at ¾" increments.
- BX4M-A28 supports cable or FMC above T-Bar.

## Support Fasteners

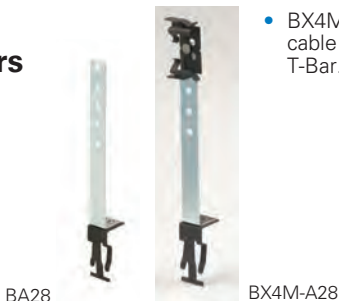

BA28

BX4M-A28

| UPC/Part Number | Catalog Number  | Description  | Box Qty. |
|-----------------|-----------------|--|----------|
| 78101118115     | <b>BA28</b>     | ½" Holes Allow for Adjustment Between 4¼" and 7¼" at ¾" Increments | 50       |
| 78101101211     | <b>BX4M-A28</b> | Double Runs MC, AC, or FMC   | 25       |

Acoustical Tee




BP-12-A28

| UPC/Part Number | Catalog Number   | Conduit Size            | Box Qty. |
|-----------------|------------------|-------------------------|----------|
| 78101119230     | <b>BP-8-A28</b>  | ½" EMT                  | 100      |
| 78101119330     | <b>BP-12-A28</b> | ¾" EMT<br>½" IMC, Rigid | 100      |
| 78101119425     | <b>BP-16-A28</b> | 1" EMT<br>¾" IMC, Rigid | 100      |

Note: Adjustable BP Conduit Fastener is attached with screw in 7¼" top hole position.

*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*

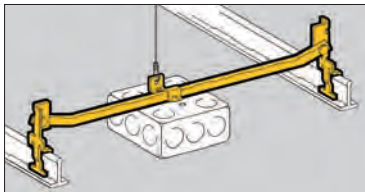

## Electrical Box T-Bar Fasteners



BA12-20



- See BA50 for a stronger, more cost effective solution.
- Supports octagonal or square boxes.
- Allows for flush mounting or 3/4" offset for plaster ring.
- One BB27 box mounting clip with screw included with each hanger.
- Load Capacity: 20 lbs.
- For additional support, attach dropwire to BB27 box mounting clip.
- **WARNING** Do not use for hanging acoustical tee.


| UPC/Part Number | Catalog Number | Description            | Box Qty. |
|-----------------|----------------|------------------------|----------|
| 78101118080     | <b>BA12</b>    | Box Hanger<br>24" Span | 50       |
| 78101118082     | <b>BA12-12</b> | Box Hanger<br>12" Span | 50       |
| 78101118085     | <b>BA12-20</b> | Box Hanger<br>20" Span | 50       |
| 78101118087     | <b>BA12-30</b> | Box Hanger<br>30" Span | 50       |



| UPC/Part Number | Catalog Number         | Description  | Box Qty. |
|-----------------|------------------------|--|----------|
| 78101118170     | <b>BB27</b>            | Box Mounting<br>Clip (with Screw)                        | 100      |
| 78101101673     | <b>SRHMS 1/4 x 3/8</b> | 1/4"-20 x 3/8"<br>Slotted Round<br>Head Machine<br>Screw | 50       |

Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.

# Acoustical tee

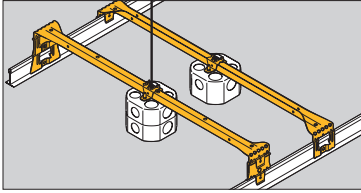

## Heavy Duty Electrical Box Hanger



BA50 &  
BA50CAN



BA50D &  
BA50DCAN



BA50E



BA50C3T & BA50C4T


- Supports octagonal or square boxes on 24" span.
- Bendable ends mount 1½" or 2⅞" deep boxes without tools.
- Self-centering feature positions box on center.
- Includes BA50C4T Box Mounting Clip.
- Ultimate Static Load Capacity: 50 Lbs. (without dedicated dropwire)
- Static Load Capacity: 70 Lbs. (with dedicated dropwire) 35 Lbs. Canada
- Finish: Pre-Galvanized
- Consult factory for pre-fab box assemblies.
- Not for use with fans. See BA50F.

| UPC/Part Number | Catalog Number    | Description                         | Box Qty. |
|-----------------|-------------------|-------------------------------------|----------|
| 78101196490     | <b>BA50</b>       | Box Hanger                          | 25       |
| 78205135905     | <b>BA50CAN</b> *  | Box Hanger                          | 25       |
| 78101196491     | <b>BA50D</b>      | Box Hanger for Box w/ 1½" Extension | 25       |
| 78205135906     | <b>BA50DCAN</b> * | Box Hanger for Box w/ 1½" Extension | 25       |
| 78205136570     | <b>BA50C4T</b>    | Box Mounting Clip with Hardware     | 25       |
| 78205136571     | <b>BA50C3T</b> *  | Box Mounting Clip with Hardware     | 25       |
| 78101196489     | <b>BA50E</b>      | Extender Brackets with Hardware     | 10 pair  |

\* Canada Only

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.



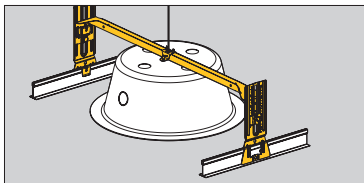

- Adjustable box support for suspended ceilings.
- Accommodates heights up to 8¾".
- Integral ruler enables height adjustments without measuring.


## Adjustable Box Support



- Ideal for installation of speaker cases, emergency light fixtures, etc. in suspended ceilings.
- Static Load Capacity: 25 Lbs. without dedicated dropwire 70 Lbs. with dedicated dropwire 35 Lbs. (Canada) with dedicated dropwire
- Consult factory for pre-fab box assemblies.



| UPC/Part Number | Catalog Number | Description                 | Box Qty. |
|-----------------|----------------|-----------------------------|----------|
| 78205118460     | <b>BA50A</b>   | Adjustable Box Hanger T-Bar | 10       |

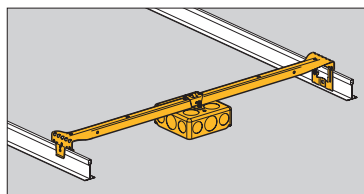

- Pre-assembled T-Bar fasteners speed installation.
- Boxes have ½" and ¾" knockouts.
- Loading not to exceed 50 lbs. in U.S.A. without independent support. 35 Lbs. in Canada
- 24" span

## Electrical Box T-Bar Fasteners



BA50-OB




BA50-SB


| UPC/Part Number | Catalog Number    | Description                    | Box Qty. |
|-----------------|-------------------|--------------------------------|----------|
| 78205124855     | <b>BA50-OB-24</b> | 1½" Deep Box to T-Bar Fastener | 10       |
| 78205124856     | <b>BA50-OB-34</b> | 2⅛" Deep Box to T-Bar Fastener | 10       |
| 78205124857     | <b>BA50-SB-24</b> | 1½" Deep Box to T-Bar Fastener | 10       |
| 78205150954     | <b>BA50-SB-34</b> | 2⅛" Deep Box to T-Bar Fastener | 10       |

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

# Acoustical tee

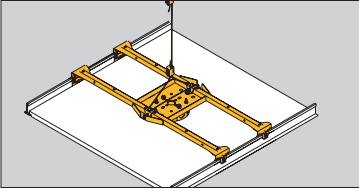


## RediMount Fan Hanger

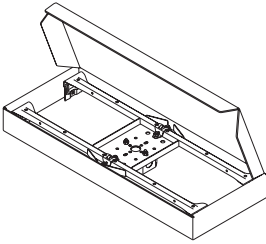


- Redi-mount™ features pre-assembled fan/fixture hanger installs on T-Bar in less than 30 seconds.
- Positions and secures fans and fixtures in suspended ceilings.
- Includes KwikWire™ cable and clamps which attach to mounting clips for easy installation.
- Recommended for use in seismic areas.
- UL Listed for fan support up to 70 lbs. or fixture support up to 90 lbs. 35 Lbs. Canada
- Finish: Pre-Galvanized.



| UPC/Part Number | Catalog Number | Description   | Box Qty. |
|-----------------|----------------|---|----------|
| 78101196492     | BA50F          | Fan/Fixture Hanger Includes 4" x 1½" Deep Octagon Box | 1        |

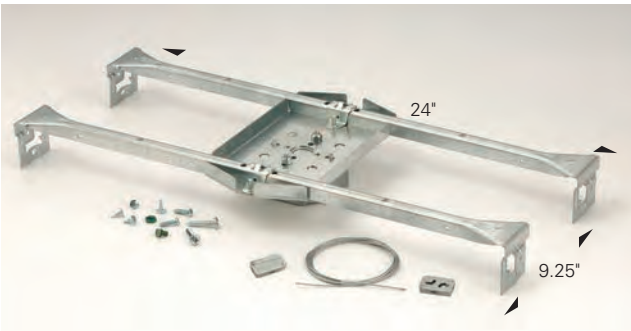

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

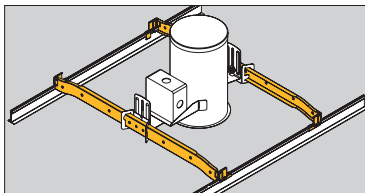

## QuikFix Fastening System




- New QuikFix™ Fastening System mounts spec grade downlights 50% faster than "wire bound" installation methods.
- QuikFix System is pre-sized for 24" spacing.
- No tools required.
- Recommended for use in seismic areas.
- UL listed for fixture support up to 50 lbs.

| UPC/Part Number | Catalog Number | Description | Box Qty. |
|-----------------|----------------|-------------|----------|
| 78205199873     | BA40           | Fixture Bar | 20 pair  |


Patent # 6286265

- Innovative design features offset bar hangers with integral locking tabs that secure downlights to T-Bar and prevent lifting or sliding.

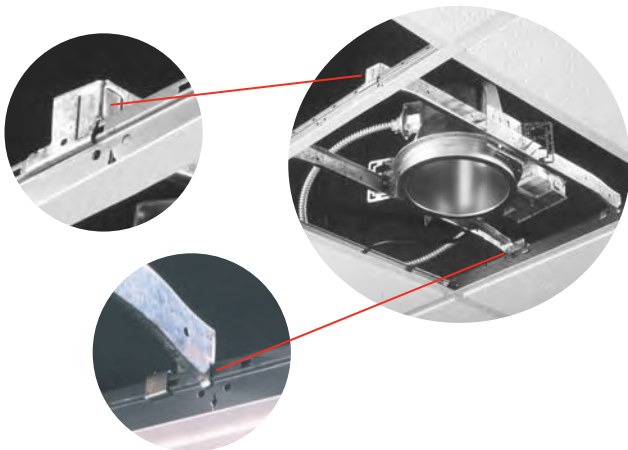


*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*

# Acoustical tee

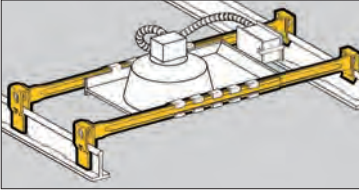


- Adjustable span from 20" to 30".
- Fits horizontal and vertical flanges.
- Fixture position is adjustable.
- No center clips or tools required.
- One set completes one fixture installation (four bars per set).

## Light Fixture T-Bar Fasteners

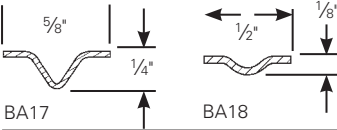

| UPC/Part Number | Catalog Number              | "High Hat" Fixtures   | Box Qty. |
|-----------------|-----------------------------|---|----------|
| 78101118100     | <b>BA17</b><br>(Wide Bar)   | CAPRI <sup>†</sup> R-9X, R-10C<br>CAPRI <sup>†</sup> R-10X<br>CAPRI <sup>†</sup> PR-751CX<br>HALO <sup>®†</sup> H7, HALO <sup>®†</sup> H17<br>JUNO <sup>®†</sup> AP, APT<br>JUNO <sup>®†</sup> IC, ICT, J, SC, TC<br>THOMAS <sup>®†</sup> RI-IC | 10 sets  |
| 78101118105     | <b>BA18</b><br>(Narrow Bar) | CAPRI <sup>†</sup> HSG<br>LIGHTOLIER <sup>®†</sup> 711  | 10 sets  |

Acoustical Tee

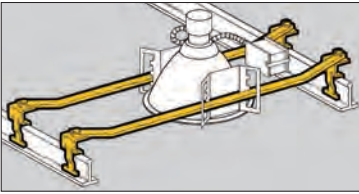

- Fixture position is adjustable within the span of the hanger.
- Fixed span of 24 inches for T-Bar applications.
- Requires only a screwdriver to install.
- One set completes one fixture installation (four bars per set).

## Light Fixture T-Bar Fasteners



| UPC/Part Number | Catalog Number            | "High Hat" Fixtures  | Box Qty. |
|-----------------|---------------------------|--|----------|
| 78101118110     | <b>BA20</b><br>(Wide Bar) | Fits LIGHTOLIER <sup>®†</sup><br>CALCULITE <sup>®†</sup><br>Fixtures | 10 sets  |

† All other trademarks are property of their respective owners.

*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*



- Allows for independent suspension of fixtures.
- Fits most acoustical T-Bars.
- BA-4-WN wing nut included with all 1/4"-20 suspension hangers.
- Static Load Capacity: 65 Lbs.

## Suspension Fasteners



BA1                      BA1-T                      BA1-T-BN



| UPC/Part Number | Catalog Number  | T-Bar Size | Stud Size                      | Box Qty. |
|-----------------|-----------------|------------|--------------------------------|----------|
| 78101118065     | <b>BA1</b>      | 15/16"     | 1/4"-20 x 5/8"                 | 100      |
| 78101118070     | <b>BA1-24</b>   | 15/16"     | 1/4"-20 x 1 1/2"               | 100      |
| 78101118075     | <b>BA1-32</b>   | 15/16"     | 1/4"-20 x 2"                   | 100      |
| 78101102891     | <b>BA1-T</b>    | 15/16"     | #8-32 x 5/8"<br>with Pal Nut   | 100      |
| 78101102897     | <b>BA1-T-BN</b> | 15/16"     | #8-32 x 5/8"<br>with Brass Nut | 100      |



BA1-9


BA1-95



| UPC/Part Number | Catalog Number | T-Bar Size | Stud Size      | Box Qty. |
|-----------------|----------------|------------|----------------|----------|
| 78205125585     | <b>BA1-9</b>   | 9/16"      | 1/4"-20 x 5/8" | 100      |
| 78205125587     | <b>BA1-95</b>  | 9/16"      | 1/4"-20 x 5/8" | 100      |

Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.

# Acoustical tee

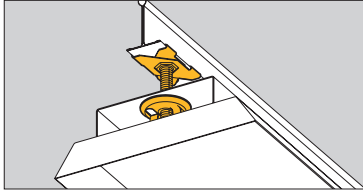


- Supports electrical fixtures from standard  $1\frac{5}{16}$ " T-Bars.
- BA-4-WN wing nut included.
- $\frac{1}{4}$ "-20 stud available in varying lengths.
- Static Load Capacity: 50 Lbs.

## T-Bar Scissor Fasteners



| UPC/Part Number | Catalog Number     | Stud Length      | Box Qty. |
|-----------------|--------------------|------------------|----------|
| 78101104258     | <b>BAX-4-16</b>    | $\frac{5}{8}$ "  | 100      |
| 78101104262     | <b>BAX-4-16-24</b> | $1\frac{1}{2}$ " | 100      |
| 78101104263     | <b>BAX-4-16-32</b> | 2"               | 100      |
| 78101104264     | <b>BAX-4-16-48</b> | 3"               | 100      |

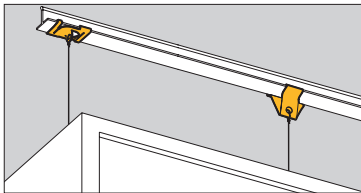

- BA-4-16-H supports signs from  $1\frac{5}{16}$ " T-Bar.
- BA-4-16-H1 supports signs from  $\frac{9}{16}$ " or  $1\frac{5}{16}$ " T-Bar.
- Static Load Capacity: 40 Lbs.

## Sign Hangers




BA-4-16-H



BA-4-16-H1

| UPC/Part Number | Catalog Number    | Stud Length                         | Box Qty. |
|-----------------|-------------------|-------------------------------------|----------|
| 78101118040     | <b>BA-4-16-H</b>  | Sign Hanger with White Finish       | 100      |
| 78101104449     | <b>BA-4-16-H1</b> | Sign Hanger with Zinc Plated Finish | 100      |

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

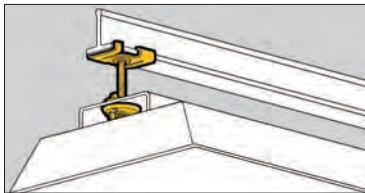


## 15/16" Twist Fasteners



BA-4-WN

- Supports electrical fixtures from 15/16" T-Bar.
- 1/4"-20 stud available in varying lengths.
- Includes BA-4-WN wing nut with impression.
- Static Load Capacity:  
BA4-16 Series = 50 lbs.  
BA4-WN Series = 100 lbs.

| UPC/Part Number | Catalog Number    | Finish | Stud Length | Box Qty. |
|-----------------|-------------------|--------|-------------|----------|
| 78101118020     | <b>BA-4-16</b>    | Black  | 5/8"        | 100      |
| 78101118055     | <b>BA-4-16-W</b>  | White  | 5/8"        | 100      |
| 78101118025     | <b>BA-4-16-24</b> | White  | 1 1/2"      | 100      |
| 78101118030     | <b>BA-4-16-32</b> | White  | 2"          | 100      |
| 78101118035     | <b>BA-4-16-48</b> | White  | 3"          | 100      |
| 78101118060     | <b>BA-4-WN</b>    | Black  |             | 100      |

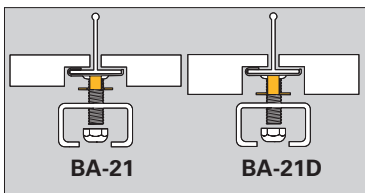

BA-21

BA-21D

## T-Bar Spacers



BA-21




BA-21D

- T-Bar spacer provides flush mounting surface for tegular tile installations.
- Spacer must be used in combination with our BA-4-16 or BA-2-16 series fasteners.
- Finish: Zinc Plated

| UPC/Part Number | Catalog Number | Description | Box Qty. |
|-----------------|----------------|-------------|----------|
| 78101195575     | <b>BA-21</b>   | 1/4" Spacer | 100      |
| 78101199567     | <b>BA-21D</b>  | 3/8" Spacer | 100      |

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

# Acoustical tee

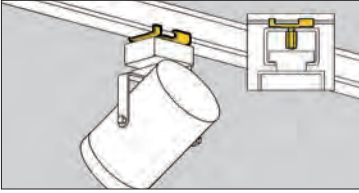

- Supports electrical fixtures from 1<sup>5</sup>/<sub>16</sub>" T-Bar.
- #8-32 stud available in varying lengths.
- Static Load Capacity: 25 Lbs.

## 1<sup>5</sup>/<sub>16</sub>" Twist Fasteners




| UPC/Part Number | Catalog Number     | Finish             | Stud Length | Box Qty. |
|-----------------|--------------------|--------------------|-------------|----------|
| 78101118000     | <b>BA-2-16</b>     | Black with Pal Nut | 5/8"        | 100      |
| 78101104259     | <b>BA-2-16-7</b>   | Black with Pal Nut | 7/16"       | 100      |
| 78101118010     | <b>BA-2-16-W</b>   | White with Pal Nut | 5/8"        | 100      |
| 78101104261     | <b>BA-2-16-7-W</b> | White with Pal Nut | 7/16"       | 100      |



| UPC/Part Number | Catalog Number       | Finish               | Stud Length | Box Qty. |
|-----------------|----------------------|----------------------|-------------|----------|
| 78101118015     | <b>BA-2-16-BN</b>    | Black with Brass Nut | 5/8"        | 100      |
| 78101104260     | <b>BA-2-16-7-BN</b>  | Black with Brass Nut | 7/16"       | 100      |
| 78101118015     | <b>BA-2-16-WBN</b>   | White with Brass Nut | 5/8"        | 100      |
| 78101199566     | <b>BA-2-16-7-WBN</b> | White with Brass Nut | 7/16"       | 100      |

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.



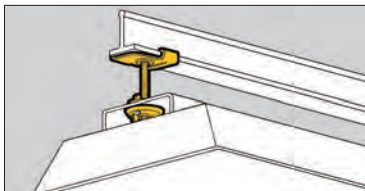


- Supports electrical fixtures from 9/16" T-Bar.
- Stud size: 1/4"-20 x 5/8".
- Static Load Capacity: 40 Lbs.

## 9/16" Twist Fasteners



| UPC/Part Number | Catalog Number  | Finish | Stud Length | Box Qty. |
|-----------------|-----------------|--------|-------------|----------|
| 78101103458     | <b>BA-4-9</b>   | Black  | 5/8"        | 100      |
| 78101103461     | <b>BA-4-9-W</b> | White  | 5/8"        | 100      |

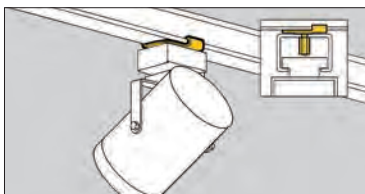

- Supports electrical fixtures and track lighting from 9/16" T-Bar.
- Stud size: #8-32 x length.
- Static Load Capacity: 25 Lbs.

## 9/16" Twist Fasteners



BA-2-9 Series with Pal Nut




BA-2-9-BN Series with Brass Nut

| UPC/Part Number | Catalog Number     | Finish | Stud Length | Box Qty. |
|-----------------|--------------------|--------|-------------|----------|
| 78101103467     | <b>BA-2-9</b>      | Black  | 5/8"        | 100      |
| 78101103466     | <b>BA-2-9-7</b>    | Black  | 7/16"       | 100      |
| 78101103459     | <b>BA-2-9-W</b>    | White  | 5/8"        | 100      |
| 78101103465     | <b>BA-2-9-BN</b>   | Black  | 5/8"        | 100      |
| 78101103464     | <b>BA-2-9-7-BN</b> | Black  | 7/16"       | 100      |
| 78101103460     | <b>BA-2-9-WBN</b>  | White  | 5/8"        | 100      |

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

# Acoustical tee

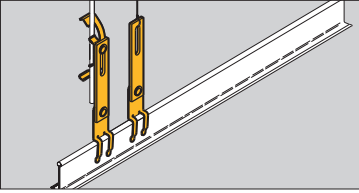

- Secures independent support wires to ceiling grid as required by NEC Article 300.11.
- Slotted design permits adjustment when securing rods.
- Bright yellow color, Per NEC 300.11 (A), is easily identified by inspectors.

## Drop Wire/Rod Securing Clip



BA-311



BA-311-W2 Shown

| UPC/Part Number | Catalog Number  | Description                | Box Qty. |
|-----------------|-----------------|----------------------------|----------|
| 78101199569     | <b>BA311</b>    | #12 thru #8 Wire           | 100      |
| 78101199570     | <b>BA311-W2</b> | #12 thru 1/4" Plain or     | 100      |
| 78101199571     | <b>BA311-W6</b> | 3/8" Plain or Threaded Rod | 100      |

*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*



## Seismic Fixture Clamps

- BA-SFC Series provides seismic restraint for light fixtures within a suspended ceiling.
- BA-SFC reduces labor by attaching light fixtures to the T-bar frame and eliminating extra drop wires or chains.
- Load rating: 200 lbs.
- Provides positive attachment of fixtures to ceiling grid members, in compliance with ICBO Acceptance Criteria 184 (AC 184).
- Satisfies NEC 410.16(C) which requires positive attachment for secure fastening of luminaries.

| UPC/Part Number | Catalog Number    | Description   | Box Qty.                   |
|-----------------|-------------------|---|----------------------------|
| 78205145911     | <b>BA-SFC</b>     | Seismic Fixture Clamp attaches one standard 2' x 4' light fixture to T-Bar ceiling    | 25 sets (4 clamps per set) |
| 78205145912     | <b>BA-SFC-E*</b>  | For attachment of two standard 2' x 4' light fixtures end-to-end onto T-Bar ceiling   | 25 sets (4 clamps per set) |
| 78205145913     | <b>BA-SFC-S*</b>  | For attachment of two standard 2' x 4' light fixtures side-by-side onto T-Bar ceiling | 25 sets (4 clamps per set) |
| 78205145914     | <b>BA-SFC-CF*</b> | For attachment of standard 2' x 2' light fixtures onto T-Bar                          | 50 sets (2 clamps per set) |
| 78205145915     | <b>BA-SFC-CFS</b> | Seismic Fixture Clamp for reinforcement of main runner connection points              | 50 sets (2 clamps per set) |

\* BASFC is required to complete installation.

*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*

# Acoustical tee

## Seismic Fixture Clamps cont.



**BA-SFC**



**BA-SFC-E**



**BA-SFC-S**




**BA-SFC-CF**




**BA-SFC-CFS**

### Single Fixture Installation

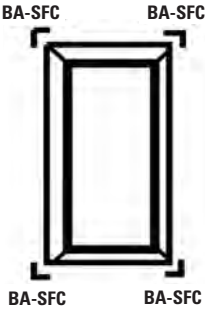


Parts Required:  
1 pc. BA-SFC Installation Kit

### Two Fixtures (Side by Side)

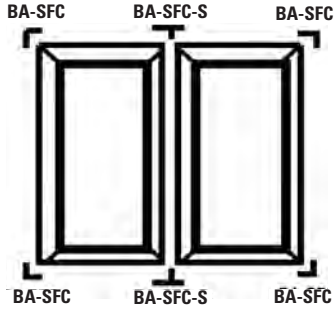

Parts Required:  
1 pc. BA-SFC Installation Kit  
1 pc. BA-SFC-S Installation Kit

### Two Fixtures (End to End)

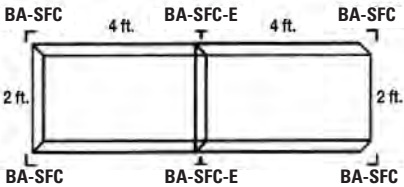

Parts Required:  
1 pc. BA-SFC Installation Kit  
1 pc. BA-SFC-E Installation Kit



*Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.*