


*Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.*

# Beams

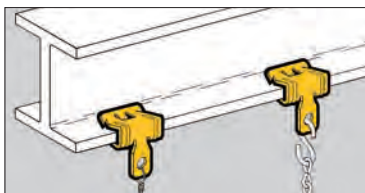

- Permits fast and easy installation on bulb tees and beams.
- Clearance hole for 1/4" bolt in tab.
- Simply installed with a hammer.

## Flange Beam Fasteners




UPC/Part Number	Catalog Number	Flange Thickness	Static Load Cap.	Box Qty.
78101118290	<b>BE-1-2</b>	3/32" - 9/64"	160 lbs.	100



BE-2-4

UPC/Part Number	Catalog Number	Flange Thickness	Static Load Cap.	Box Qty.
78101118295	<b>BE-2-4</b>	1/8" - 1/4"	200 lbs.	100
78101118300	<b>BE-5-8</b>	5/16" - 1/2"	200 lbs.	100
78101118305	<b>BE-9-12</b>	9/16" - 3/4"	200 lbs.	100

*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*

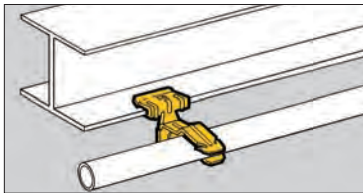


- Quickly attaches conduit to beams.
- Fasteners will rotate 360°.
- Simply installed with a hammer.

## Push-Type Conduit To Beam Fasteners




UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
78101119275	<b>BP-8-E-2-4</b>	1/2" EMT	1/8" - 1/4"	100
78101119280	<b>BP-8-E-5-8</b>	1/2" EMT	5/16" - 1/2"	100
78101119285	<b>BP-8-E-9-12</b>	1/2" EMT	9/16" - 3/4"	100
78101119375	<b>BP-12-E-2-4</b>	1/2" EMT 1/2" IMC, Rigid	1/8" - 1/4"	100
78101119380	<b>BP-12-E-5-8</b>	1/2" EMT 1/2" IMC, Rigid	5/16" - 1/2"	100
78101119385	<b>BP-12-E-9-12</b>	1/2" EMT 1/2" IMC, Rigid	9/16" - 3/4"	100
78101119465	<b>BP-16-E-2-4</b>	1" EMT 3/4" IMC, Rigid	1/8" - 1/4"	100
78101119470	<b>BP-16-E-5-8</b>	1" EMT 3/4" IMC, Rigid	5/16" - 1/2"	100
78101119475	<b>BP-16-E-9-12</b>	1" EMT 3/4" IMC, Rigid	9/16" - 3/4"	100

**Ultimate  
Static Load  
Capacity**

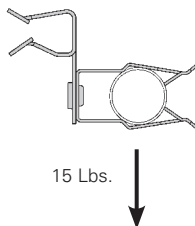

*Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.*

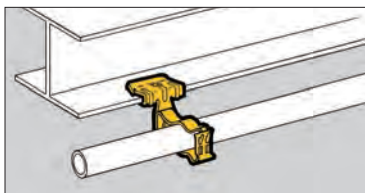

- Unique Guide-Rite™ fastener provides for fast and easy installation.
- Fasteners will rotate 360°.
- Simply installed with a hammer and pliers.


## Guide-Rite Conduit To Beam Fasteners




UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
78101118430	<b>BG-6-E-2-4*</b>	3/8"	1/8" - 1/4"	100
78101118435	<b>BG-6-E-5-8*</b>	3/8"	5/16" - 1/2"	100
78101118440	<b>BG-6-E-9-12*</b>	3/8"	9/16" - 3/4"	100
78101118505	<b>BG-8-12-E-2-4</b>	1/2", 3/4"	1/8" - 1/4"	100
78101118510	<b>BG-8-12-E-5-8</b>	1/2", 3/4"	5/16" - 1/2"	100
78101118515	<b>BG-8-12-E-9-12</b>	1/2", 3/4"	9/16" - 3/4"	100
78101118575	<b>BG-16-E-2-4</b>	1"	1/8" - 1/4"	100
78101118580	<b>BG-16-E-5-8</b>	1"	5/16" - 1/2"	100
78101118585	<b>BG-16-E-9-12</b>	1"	9/16" - 3/4"	100
78101118660	<b>BG-20-E-2-4</b>	1 1/4"	1/8" - 1/4"	100
78101118665	<b>BG-20-E-5-8</b>	1 1/4"	5/16" - 1/2"	100
78101118670	<b>BG-20-E-9-12</b>	1 1/4"	9/16" - 3/4"	100
78101118705	<b>BG-24-E-2-4</b>	1 1/2"	1/8" - 1/4"	50
78101118710	<b>BG-24-E-5-8</b>	1 1/2"	5/16" - 1/2"	50
78101118715	<b>BG-24-E-9-12</b>	1 1/2"	9/16" - 3/4"	50
78101118745	<b>BG-32-E-2-4</b>	2"	1/8" - 1/4"	50
78101118750	<b>BG-32-E-5-8</b>	2"	5/16" - 1/2"	50
78101118755	<b>BG-32-E-9-12</b>	2"	9/16" - 3/4"	50

Patent #4958792

\* BG-6 will accept the following range Ø.420 - Ø.675: 14/2 thru 10/4 MC/AC cable and 5/16" or 3/8" flexible conduit

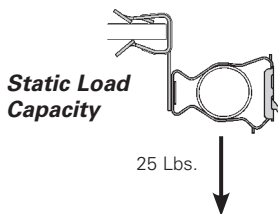

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

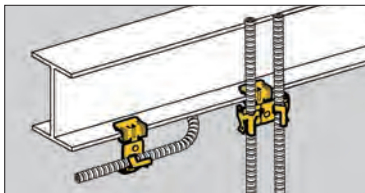

- Attaches MC, AC, sizes 14/2 through 10/3 or 3/8" FMC to beam flanges 1/8" to 3/4" thick.
- Fasteners will rotate 360°.
- Simply installed with a hammer.

## Cable To Beam Fasteners




UPC/Part Number	Catalog Number	Types Of Runs	Flange Thickness	Box Qty.
78101101192	<b>BX4-E-2-4</b>	Single	1/8" - 1/4"	100
78101101193	<b>BX4-E-5-8</b>	Single	5/16" - 1/2"	100
78101101194	<b>BX4-E-9-12</b>	Single	9/16" - 3/4"	100



UPC/Part Number	Catalog Number	Types Of Runs	Flange Thickness	Box Qty.
78101101213	<b>BX4M-E-2-4</b>	Double	1/8" - 1/4"	100
78101101214	<b>BX4M-E-5-8</b>	Double	5/16" - 1/2"	100
78101101215	<b>BX4M-E-9-12</b>	Double	5/16" - 3/4"	100

Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.

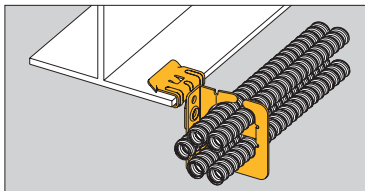


## MC/AC Cable Carrier to Beam Fastener



BRC5-2-E24

- Secures and supports MC/AC cables as required by the NEC.
- Effectively organizes cables and eliminates derating issues.
- BRC5-1 secures up to four (4) runs of .430 to .560 diameter cable.
- BRC5-2 secures up to nine (9) runs of .430 to .560 diameter cable.
- BRC5-3 secures up to seven (7) runs of .560 to .690 diameter cable.
- Load Capacity: 50 lbs.


UPC/Part Number	Catalog Number	Flange Thickness	Box Qty.
78205144093	<b>BRC51-E12</b>	3/32" - 9/64"	25
78205144096	<b>BRC51-E24</b>	1/8" - 1/4"	25
78205144099	<b>BRC51-E58</b>	5/16" - 1/2"	25
78205144102	<b>BRC51-E912</b>	9/16" - 3/4"	25
78205144094	<b>BRC52-E12</b>	3/32" - 9/64"	25
78205144097	<b>BRC52-E24</b>	1/8" - 1/4"	25
78205144100	<b>BRC52-E58</b>	5/16" - 1/2"	25
78205144103	<b>BRC52-E912</b>	9/16" - 3/4"	25
78205144095	<b>BRC53-E12</b>	3/32" - 9/64"	25
78205144098	<b>BRC53-E24</b>	1/8" - 1/4"	25
78205144101	<b>BRC53-E58</b>	5/16" - 1/2"	25
78205144104	<b>BRC53-E912</b>	9/16" - 3/4"	25

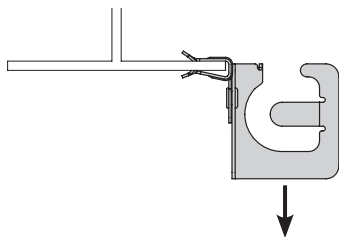

**Static Load Capacity**

50 Lbs.

*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*

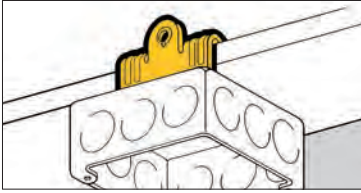

- Suspend boxes or fixtures from beam flanges  $\frac{1}{8}$ " to  $\frac{3}{4}$ " thick.
- Provided with  $\frac{1}{4}$ "-20 thread impression for quick and secure attachment.
- Simply installed with a hammer.

## Universal Beam Fasteners




UPC/Part Number	Catalog Number	Flange Thickness	Box Qty.
78101119600	<b>BU-2-4</b>	$\frac{1}{8}$ " - $\frac{1}{4}$ "	100
78101119605	<b>BU-5-8</b>	$\frac{5}{16}$ " - $\frac{1}{2}$ "	100
78101119610	<b>BU-9-12</b>	$\frac{9}{16}$ " - $\frac{3}{4}$ "	100




20 x  $\frac{3}{8}$ "  
Threaded Stud

UPC/Part Number	Catalog Number	Flange Thickness	Box Qty.
78101119615	<b>BU-2-4-S</b>	$\frac{1}{8}$ " - $\frac{1}{4}$ "	100
78101119620	<b>BU-5-8-S</b>	$\frac{5}{16}$ " - $\frac{1}{2}$ "	100
78101119625	<b>BU-9-12-S</b>	$\frac{9}{16}$ " - $\frac{3}{4}$ "	100

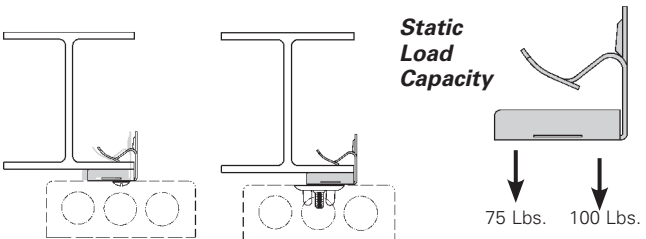

Note: Indicated loads are static load capacity and should not be combined.

Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.

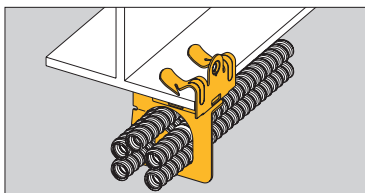


## MC/AC Cable Carrier to Beam Fastener



- Secures and supports MC/AC cables as required by the NEC.
- Effectively organizes cables and eliminates derating issues.
- BRC5-1 secures up to four (4) runs of .430 to .560 diameter cable.
- BRC5-2 secures up to nine (9) runs of .430 to .560 diameter cable.
- BRC5-3 secures up to seven (7) runs of .560 to .690 diameter cable.
- Load Capacity: 50 lbs.

UPC/Part Number	Catalog Number	Flange Thickness	Box Qty.
78205144066	<b>BRC51-U24</b>	1/8" - 1/4"	25
78205144069	<b>BRC51-U58</b>	5/16" - 1/2"	25
78205144072	<b>BRC51-U912</b>	9/16" - 3/4"	25
78205144067	<b>BRC52-U24</b>	1/8" - 1/4"	25
78205144070	<b>BRC52-U58</b>	5/16" - 1/2"	25
78205144073	<b>BRC52-U912</b>	9/16" - 3/4"	25
78205144068	<b>BRC53-U24</b>	1/8" - 1/4"	25
78205144071	<b>BRC53-U58</b>	5/16" - 1/2"	25
78205144074	<b>BRC53-U912</b>	9/16" - 3/4"	25

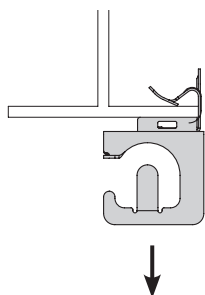


**Static Load Capacity**

75 Lbs.

*Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.*



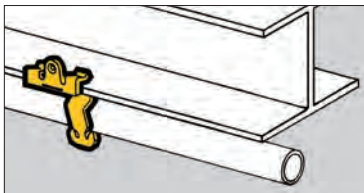


- Quickly attaches conduit to beams.
- Fasteners will rotate 360°.
- Simply installed with a hammer.

## Push-Type Conduit To Beam Fasteners




UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
78101119310	<b>BP-8-U-2-4</b>	1/2" EMT	1/8" - 1/4"	100
78101119315	<b>BP-8-U-5-8</b>	1/2" EMT	5/16" - 1/2"	100
78101119320	<b>BP-8-U-9-12</b>	1/2" EMT	9/16" - 3/4"	100
78101119405	<b>BP-12-U-2-4</b>	3/4" EMT 1/2" IMC, Rigid	1/8" - 1/4"	100
78101119410	<b>BP-12-U-5-8</b>	3/4" EMT 1/2" IMC, Rigid	5/16" - 1/2"	100
78101119415	<b>BP-12-U-9-12</b>	3/4" EMT 1/2" IMC, Rigid	9/16" - 3/4"	100
78101119490	<b>BP-16-U-2-4</b>	1" EMT 3/4" IMC, Rigid	1/8" - 1/4"	100
78101119495	<b>BP-16-U-5-8</b>	1" EMT 3/4" IMC, Rigid	5/16" - 1/2"	100
78101119500	<b>BP-16-U-9-12</b>	1" EMT 3/4" IMC, Rigid	9/16" - 3/4"	100

**Ultimate  
Static Load  
Capacity**

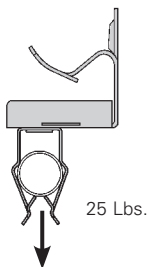

*Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.*

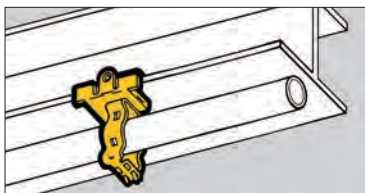

- Unique Guide-Rite™ Fastener provides for fast and easy installation.
- Fasteners will rotate 360°.
- Simply installed with a hammer and pliers.

## Guide-Rite Conduit To Beam Fasteners



UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
78101118450	<b>BG-6-U-2-4*</b>	3/8"	1/8" - 1/4"	100
78101118455	<b>BG-6-U-5-8*</b>	3/8"	5/16" - 1/2"	100
78101118460	<b>BG-6-U-9-12*</b>	3/8"	9/16" - 3/4"	100
78101118525	<b>BG-8-12-U-2-4</b>	1/2", 3/4"	1/8" - 1/4"	100
78101118530	<b>BG-8-12-U-5-8</b>	1/2", 3/4"	5/16" - 1/2"	100
78101118535	<b>BG-8-12-U-9-12</b>	1/2", 3/4"	9/16" - 3/4"	100
78101118625	<b>BG-16-U-2-4</b>	1"	1/8" - 1/4"	100
78101118630	<b>BG-16-U-5-8</b>	1"	5/16" - 1/2"	100
78101118635	<b>BG-16-U-9-12</b>	1"	9/16" - 3/4"	100
78101118680	<b>BG-20-U-2-4</b>	1 1/4"	1/8" - 1/4"	100
78101118685	<b>BG-20-U-5-8</b>	1 1/4"	5/16" - 1/2"	100
78101118690	<b>BG-20-U-9-12</b>	1 1/4"	9/16" - 3/4"	100
78101118720	<b>BG-24-U-2-4</b>	1 1/2"	1/8" - 1/4"	50
78101118725	<b>BG-24-U-5-8</b>	1 1/2"	5/16" - 1/2"	50
78101118730	<b>BG-24-U-9-12</b>	1 1/2"	9/16" - 3/4"	50
78101118760	<b>BG-32-U-2-4</b>	2"	1/8" - 1/4"	50
78101118765	<b>BG-32-U-5-8</b>	2"	5/16" - 1/2"	50
78101118770	<b>BG-32-U-9-12</b>	2"	9/16" - 3/4"	50

Patent #4958792


\* BG-6 will accept the following range  $\varnothing.420 - \varnothing.675$ : 14/2 thru 10/4 MC/AC cable and 5/16" or 3/8" flexible conduit



**Static Load Capacity**

75 Lbs.

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

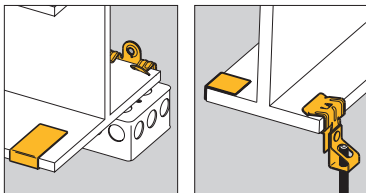

## Beam Fasteners With Anchor Straps

- Anchor strap provides secure attachment to beam flanges.
- Suspends threaded rod from beam flanges.
- 8" anchor straps are provided for  $\frac{1}{8}$ " to  $\frac{1}{4}$ " thick flanges.
- 13" anchor straps are provided for  $\frac{5}{16}$ " to  $\frac{3}{4}$ " thick flanges.



**Static Load  
Capacity**

75 Lbs.



UPC/Part Number	Catalog Number	Stud Size	Flange Thickness	Box Qty.
78101104942	<b>BU-2-4-S-AS</b>	$\frac{1}{4}$ "-20 x $\frac{3}{8}$ "	$\frac{1}{8}$ " - $\frac{1}{4}$ "	50
78101104943	<b>BU-5-8-S-AS</b>	$\frac{1}{4}$ "-20 x $\frac{3}{8}$ "	$\frac{5}{16}$ " - $\frac{1}{2}$ "	50
78101104944	<b>BU-9-12-S-AS</b>	$\frac{1}{4}$ "-20 x $\frac{3}{8}$ "	$\frac{9}{16}$ " - $\frac{3}{4}$ "	50




**Static Load  
Capacity**

160 Lbs.



UPC/Part Number	Catalog Number	Threaded Rod Size	Flange Thickness	Box Qty.
78101104948	<b>BH4-E-2-4-AS</b>	$\frac{1}{4}$ "-20	$\frac{1}{8}$ " - $\frac{1}{4}$ "	50
78101104949	<b>BH4-E-5-8-AS</b>	$\frac{1}{4}$ "-20	$\frac{5}{16}$ " - $\frac{1}{2}$ "	50
78101104950	<b>BH4-E-9-12-AS</b>	$\frac{1}{4}$ "-20	$\frac{9}{16}$ " - $\frac{3}{4}$ "	50
78101104951	<b>BH6-E-2-4-AS</b>	$\frac{3}{8}$ "-16	$\frac{1}{8}$ " - $\frac{1}{4}$ "	50
78101104952	<b>BH6-E-5-8-AS</b>	$\frac{3}{8}$ "-16	$\frac{5}{16}$ " - $\frac{1}{2}$ "	50
78101104953	<b>BH6-E-9-12-AS</b>	$\frac{3}{8}$ "-16	$\frac{9}{16}$ " - $\frac{3}{4}$ "	50

Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.

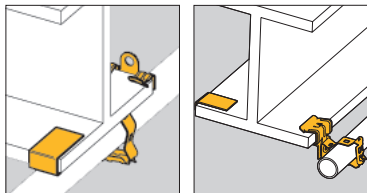

- Anchor strap provides secure attachment to beam flanges.
- Unique Guide-Rite™ Fastener provides for fast and easy installation.
- 8" anchor straps are provided for 1/8" to 1/4" thick flanges.
- 13" anchor straps are provided for 5/16" to 3/4" thick flanges.

## Conduit To Beam Fasteners With Anchor Straps



**Static Load Capacity**

75 Lbs.

UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
78101104966	<b>BG-8-12-U-2-4-AS</b>	1/2", 3/4"	1/8" - 1/4"	50
78101104967	<b>BG-8-12-U-5-8-AS</b>	1/2", 3/4"	5/16" - 1/2"	50
78101104968	<b>BG-8-12-U-9-12-AS</b>	1/2", 3/4"	9/16" - 3/4"	50
78101104969	<b>BG-16-U-2-4-AS</b>	1"	1/8" - 1/4"	50
78101104970	<b>BG-16-U-5-8-AS</b>	1"	5/16" - 1/2"	50
78101104971	<b>BG-16-U-9-12-AS</b>	1"	9/16" - 3/4"	50




**Static Load Capacity**

25 Lbs.

UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
78101104972	<b>BG-8-12-E-2-4-AS</b>	1/2", 3/4"	1/8" - 1/4"	50
78101104973	<b>BG-8-12-E-5-8-AS</b>	1/2", 3/4"	5/16" - 1/2"	50
78101104974	<b>BG-8-12-E-9-12-AS</b>	1/2", 3/4"	9/16" - 3/4"	50
78101104975	<b>BG-16-E-2-4-AS</b>	1"	1/8" - 1/4"	50
78101104976	<b>BG-16-E-5-8-AS</b>	1"	5/16" - 1/2"	50
78101104977	<b>BG-16-E-9-12-AS</b>	1"	9/16" - 3/4"	50

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

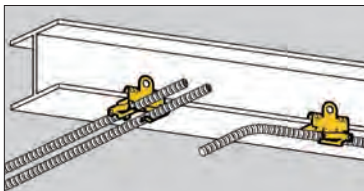

- Attaches MC, AC, sizes 14/2 through 10/3 or 3/8" FMC to flanges 1/8" to 3/4" thick.
- Fasteners will rotate 360°.

## Cable To Beam Fasteners




UPC/Part Number	Catalog Number	Description	Flange Thickness	Box Qty.
78101101197	<b>BX4-U-2-4</b>	Single Runs	1/8" - 1/4"	100
78101101198	<b>BX4-U-5-8</b>	Single Runs	5/16" - 1/2"	100
78101101199	<b>BX4-U-9-12</b>	Single Runs	9/16" - 3/4"	100



UPC/Part Number	Catalog Number	Description	Flange Thickness	Box Qty.
78101101206	<b>BX4M-U-2-4</b>	Double Runs	1/8" - 1/4"	100
78101101207	<b>BX4M-U-5-8</b>	Double Runs	5/16" - 1/2"	100
78101101208	<b>BX4M-U-9-12</b>	Double Runs	9/16" - 3/4"	100

Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.

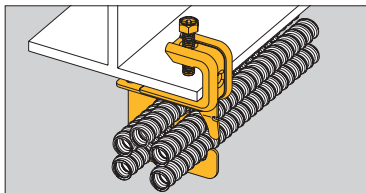


- Secures and supports MC/AC cables as required by the NEC.
- Effectively organizes cables and eliminates derating issues.
- Fits beam flanges from 1/8" thru 5/8" thick.
- Load Capacity: 50 lbs.

## MC/AC Cable Carrier to Beam Fastener



BRC5-1-C442

UPC/Part Number	Catalog Number	Cable Diameter & Number of Runs	Box Qty.
78205144087	<b>BRC51-C442</b>	.430" to .560" Up to 4 Runs	25
78205144088	<b>BRC52-C442</b>	.430" to .560" Up to 9 Runs	25
78205144089	<b>BRC53-C442</b>	.560" to .690" Up to 7 Runs	25

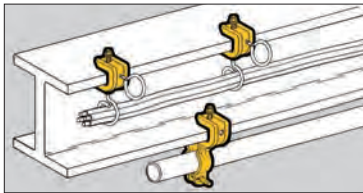

- BC442 fits beam flanges  $\frac{1}{8}$ " to  $\frac{5}{8}$ ". BC442-6 fits beam flanges up to  $\frac{3}{4}$ ".
- Finish: Zinc Plated.
- Static Load Capacity:  
BC442 = 100 Lbs.  
BC442-6 = 200 Lbs.

## Beam Fasteners




UPC/Part Number	Catalog Number	Description	Box Qty.
78101118278	<b>BC442</b>	Accepts $\frac{1}{4}$ "-20 Threaded Rod or $\frac{1}{4}$ "-20 Threaded Bridle Rings	50
78101104283	<b>BC442-6</b>	Accepts $\frac{3}{8}$ "-16 Threaded Rod	25



UPC/Part Number	Catalog Number	Conduit Size Rigid	EMT	Box Qty.
78101119850	<b>BL1400-C442</b>	$\frac{1}{2}$ "	$\frac{1}{2}$ "	50
78101119851	<b>BL1410-C442</b>	$\frac{3}{4}$ "	$\frac{3}{4}$ "	50
78101119852	<b>BL1420-C442</b>	1"	1"	50
78101119853	<b>BL1425-C442</b>	--	1 $\frac{1}{4}$ "	50
78101119854	<b>BL1430-C442</b>	1 $\frac{1}{4}$ "	1 $\frac{1}{2}$ "	50
78101119855	<b>BL1440-C442</b>	1 $\frac{1}{2}$ "	--	25
78101119856	<b>BL1450-C442</b>	2"	2"	25

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

# Beams

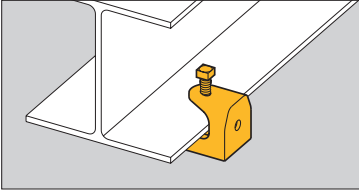


- Can be used with 1/4"-20 and 3/8"-16 threaded rod or bridle rings.
- Fits beam flanges through 1/2" thick.
- Safety Factor of 5.
- Finish: Zinc-Plated.

## Beam Fasteners



UPC/Part Number	Catalog Number	Rod Size	Static Load Cap.	Box Qty.
78101155333	<b>B444-1/4</b>	1/4"-20	150 lbs.	50
78101155333	<b>B444-5/16</b>	5/16"-18	150 lbs.	50
78101155333	<b>B444-3/8</b>	3/8"-16	150 lbs.	50



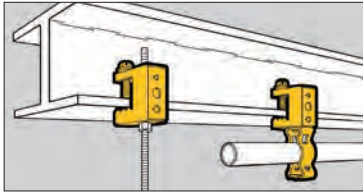

- Fits beam flanges thru 1/2" thick.
- Accepts "S" hooks, 1/4" and 3/8" threaded rod, 1/4"-20 or #10-24 threaded bridle rings.
- Supports conduit and electrical boxes.

## Conduit To Beam Fasteners



UPC/Part Number	Catalog Number	Flange Thickness	Static Load Cap.	Box Qty.
78101118275	<b>BC1</b>	Thru 1/2"	100 lbs.	100



**Guide-Rite™**  
Fastener

UPC/Part Number	Catalog Number	Conduit Size EMT & Rigid	Static Load Cap.	Box Qty.
78101118490	<b>BG-8-12-C2</b>	1/2", 3/4"	100 lbs.	100
78101118570	<b>BG-16-C2</b>	1"	100 lbs.	100
78101118655	<b>BG-20-C2</b>	1 1/4"	100 lbs.	100
78101118700	<b>BG-24-C2</b>	1 1/2"	100 lbs.	100
78101118740	<b>BG-32-C2</b>	2"	100 lbs.	100

Read safety/installation instruction sheets in packages before use.

## Conduit To Beam Fasteners



Guide-Rite™  
Fastener

UPC/Part Number	Catalog Number	Conduit Size EMT & Rigid	Static Load Cap.	Box Qty.
78101118485	<b>BG-8-12-C1</b>	½", ¾"	25 lbs.	100
78101118565	<b>BG-16-C1</b>	1"	25 lbs.	100
78101118650	<b>BG-20-C1</b>	1¼"	25 lbs.	100
78101118695	<b>BG-24-C1</b>	1½"	25 lbs.	50
78101118735	<b>BG-32-C1</b>	2"	25 lbs.	50



Push-Type


UPC/Part Number	Catalog Number	Conduit Size	Ultimate Static Load Cap.	Box Qty.
78101119260	<b>BP-8-C2</b>	½" EMT	25 lbs.	100
78101119360	<b>BP-12-C2</b>	¾" EMT ½" IMC, Rigid	25 lbs.	100
78101119455	<b>BP-16-C2</b>	1" EMT ¾" IMC, Rigid	25 lbs.	100



Push-Type

UPC/Part Number	Catalog Number	Conduit Size	Ultimate Static Load Cap.	Box Qty.
78101119255	<b>BP-8-C1</b>	½" EMT	25 lbs.	100
78101119355	<b>BP-12-C1</b>	¾" EMT ½" IMC, Rigid	25 lbs.	100
78101119450	<b>BP-16-C1</b>	1" EMT ¾" IMC, Rigid	25 lbs.	100

Read safety/installation instruction sheets in packages before use.

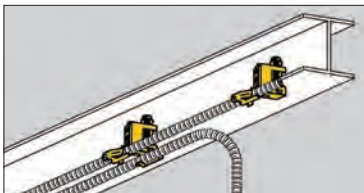

## Cable To Beam Fasteners




BX4-C2



BX4M-C2

- Attaches MC, AC, sizes 14/2 through 10/3 or 3/8" FMC to beam flanges thru 1/2" thick.
- Fasteners will rotate 360°.
- Requires only a screwdriver to install.

UPC/Part Number	Catalog Number	Flange Thickness	Box Qty.
78101101190	<b>BX4-C2</b>	Single Runs	100
78101101210	<b>BX4M-C2</b>	Double Runs	100

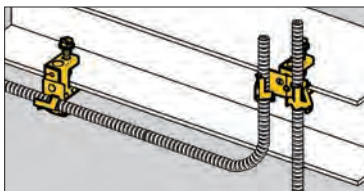

## Cable To Beam Fasteners



BX4-C1




BX4M-C1

- Attaches MC, AC, sizes 14/2 through 10/3 or 3/8" FMC to beam flanges thru 1/2" thick.
- Fasteners will rotate 360°.
- Requires only a screwdriver to install.

UPC/Part Number	Catalog Number	Flange Thickness	Box Qty.
78101101191	<b>BX4-C1</b>	Single Runs	100
78101101209	<b>BX4M-C1</b>	Double Runs	100

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.

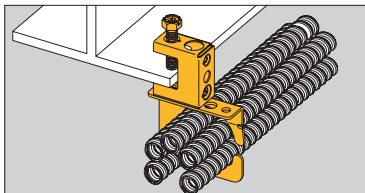


- Secures and supports MC/AC cables as required by the NEC.
- Effectively organizes cables and eliminates derating issues.
- Fits beam flanges thru 1/2" thick.
- Load Capacity: 50 lbs.

## MC/AC Cable Carrier to Beam Fastener



BRC5-x-C2

UPC/Part Number	Catalog Number	Cable Diameter & Number of Runs	Box Qty.
78205144090	<b>BRC51-C2</b>	.430" to .560" Up to 4 Runs	25
78205144091	<b>BRC52-C2</b>	.430" to .560" Up to 9 Runs	25
78205144092	<b>BRC53-C2</b>	.560" to .690" Up to 7 Runs	25

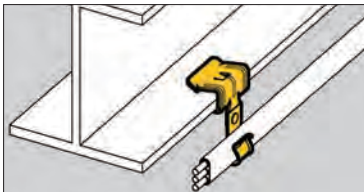


- Attaches type NM cable to beam flanges  $\frac{1}{8}$ " to  $\frac{1}{2}$ " thick.
- Supports cable sizes 14/2 and 12/2 with ground wire.
- Simply installed with a hammer.

## Cable To Beam Fasteners



UPC/Part Number	Catalog Number	Flange Thickness	Box Qty.
78101103550	<b>BRC3-E-2-4</b>	$\frac{1}{8}$ " to $\frac{1}{4}$ "	100
78101103551	<b>BRC3-E-5-8</b>	$\frac{5}{16}$ " to $\frac{1}{2}$ "	100
78101103552	<b>BRC3-E-9-12</b>	$\frac{9}{16}$ " to $\frac{3}{4}$ "	100

*Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.*

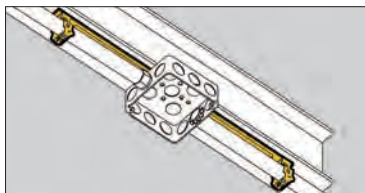

## Guide-Rite Conduit & Box Support Fasteners



- Consult factory for pre-fab box assemblies.

- BMC3 plate is available to support multiple conduit runs.
- Guide-Rite™ Riveted assembly secures electrical boxes and conduit runs to beam flanges 1/8" to 1/2" thick.
- Provides support for conduit on either side of electrical box.
- Assemblies using BMC3 plate include center conduit clamp. Additional conduit clamps may be purchased separately.



BG\_-S18-U\_



BG\_-S18-U\_-MC3

UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
78101103583	<b>BG6-S18-U24 *</b>	3/8"	1/8" to 1/4"	25
78101103584	<b>BG6-S18-U58 *</b>	3/8"	5/16" to 1/2"	25
78101103579	<b>BG812-S18-U24</b>	1/2", 3/4"	1/8" to 1/4"	25
78101103580	<b>BG812-S18-U58</b>	1/2", 3/4"	5/16" to 1/2"	25
78101103581	<b>BG16-S18-U24</b>	1"	1/8" to 1/4"	25
78101103582	<b>BG16-S18-U58</b>	1"	5/16" to 1/2"	25


Patent #4958792

### With Multiple Conduit Plate

78205152813	<b>BG6-S18-U24-MC3 *</b>	3/8"	1/8" to 1/4"	25
78205152814	<b>BG6-S18-U58-MC3 *</b>	3/8"	5/16" to 1/2"	25
78205152815	<b>BG812-S18-U24-MC3</b>	1/2", 3/4"	1/8" to 1/4"	25
78205152816	<b>BG812-S18-U58-MC3</b>	1/2", 3/4"	5/16" to 1/2"	25
78205152817	<b>BG16-S18-U24-MC3</b>	1"	1/8" to 1/4"	25
78205152823	<b>BG16-S18-U58-MC3</b>	1"	5/16" to 1/2"	25

\* BG-6 will accept the following range  $\varnothing.420 - \varnothing.675$ : 14/2 thru 10/4 MC/ AC cable and 5/16" or 3/8" flexible conduit

Read safety/installation instruction sheets in packages before use.

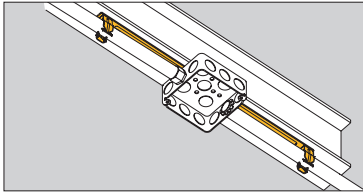

## Push-Type Conduit & Box Support Fasteners

- Consult factory for pre-fab box assemblies.

- BMC3 plate is available to support multiple conduit runs.
- Riveted assembly secures electrical boxes and conduit runs to beam flanges  $\frac{1}{8}$ " to  $\frac{1}{2}$ " thick.
- Provides support for conduit on either side of electrical box.
- Assemblies using BMC3 plate include center conduit clamp. Additional conduit clamps may be purchased separately.



BP\_\_-S18-U\_\_



BP\_\_-S18-U\_\_-MC3


UPC/Part Number	Catalog Number	Conduit Size EMT, IMC, Rigid	Flange Thickness	Box Qty.
78205123635	<b>BP8-S18-U24</b>	$\frac{3}{8}$ "	$\frac{1}{8}$ " to $\frac{1}{4}$ "	25
78205123638	<b>BP8-S18-U58</b>	$\frac{3}{8}$ "	$\frac{5}{16}$ " to $\frac{1}{2}$ "	25
78205123636	<b>BP12-S18-U24</b>	$\frac{1}{2}$ ", $\frac{3}{4}$ "	$\frac{1}{8}$ " to $\frac{1}{4}$ "	25
78205123639	<b>BP12-S18-U58</b>	$\frac{1}{2}$ ", $\frac{3}{4}$ "	$\frac{5}{16}$ " to $\frac{1}{2}$ "	25
78205123637	<b>BP16-S18-U24</b>	1"	$\frac{1}{8}$ " to $\frac{1}{4}$ "	25
78205123640	<b>BP16-S18-U58</b>	1"	$\frac{5}{16}$ " to $\frac{1}{2}$ "	25

Patent #4958792

### With Multiple Conduit Plate

78205152824	<b>BP8-S18-U24-MC3</b>	$\frac{3}{8}$ "	$\frac{1}{8}$ " to $\frac{1}{4}$ "	25
78205152825	<b>BP8-S18-U58-MC3</b>	$\frac{3}{8}$ "	$\frac{5}{16}$ " to $\frac{1}{2}$ "	25
78205152827	<b>BP12-S18-U24-MC3</b>	$\frac{1}{2}$ ", $\frac{3}{4}$ "	$\frac{1}{8}$ " to $\frac{1}{4}$ "	25
78205152828	<b>BP12-S18-U58-MC3</b>	$\frac{1}{2}$ ", $\frac{3}{4}$ "	$\frac{5}{16}$ " to $\frac{1}{2}$ "	25
78205152825	<b>BP16-S18-U24-MC3</b>	1"	$\frac{1}{8}$ " to $\frac{1}{4}$ "	25
78205152964	<b>BP16-S18-U58-MC3</b>	1"	$\frac{5}{16}$ " to $\frac{1}{2}$ "	25

Read safety/installation instruction sheets in packages before use.  
These products are designed for positioning only. No load rating.

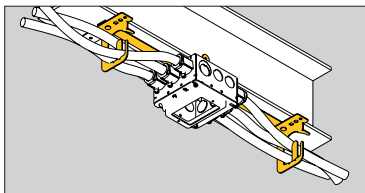

- Riveted assembly provides support for electrical box and cable run on either side of box.
- Cable retention tab is open for easy loading and contains cable when bent in place.

## Multi-Run Cable Carrier & Box Support Fastener



BRC5\_-S18-U\_\_

UPC/Part Number	Catalog Number	Conduit Size Number of Runs	Flange Thickness	Box Qty.
78205152829	<b>BRC51-S18-U24</b>	.430" - .560" Up to 4 Runs	1/8" to 1/4"	25
78205152830	<b>BRC51-S18-U58</b>	.560" - .690" Up to 7 Runs	5/16" to 1/2"	25
78205152834	<b>BRC53-S18-U24</b>	.430" - .560" Up to 4 Runs	1/8" to 1/4"	25
78205152835	<b>BRC53-S18-U58</b>	.560" - .690" Up to 7 Runs	5/16" to 1/2"	25