

# Eaton's Fuller Reman is second only to a new transmission.



FLEX Reman Transmission



Standard Reman Transmission

You have many options for rebuilt transmissions, but only Eaton's Reman Transmission gives you the quality and content of a genuine, new Eaton transmission. Other advantages include:

- Industry's best warranty in the U.S. and Canada – 2 years for linehaul and vocational applications.
- Receive an enhanced 3-year total warranty on your transmission and clutch when you bundle a standard or FLEX Reman transmission, Advantage/EverTough clutch and Eaton-approved lubricant. Registration required. Form TCWY0760 available at [www.roadranger.com/warranty](http://www.roadranger.com/warranty)
- 100% genuine Eaton content.
- Backed by the Roadranger Network – the nation's leading support system for drivetrain components – providing unequalled protection, support, and training from experienced professionals.
- Expertly remanufactured using Eaton technology.
- Dyno performance tested to meet Eaton standards.

## Benefits of FLEX Reman

When faced with a truck down situation, you need immediate access to quality Reman units. But you also need to keep inventory low and focus on turns to keep your dealership profitable. The FLEX transmission increase your *flexibility* to do both.

- The FLEX portfolio covers over 85% of the reman market demand.
- Truck-down orders will ship same day or next day with no additional fee.

**Units will ship the same day when an order is received by 2:00 PM local time of the delivering Eaton Logistics Center.**

## Increase sales with FLEX Reman Transmissions


Components	FLEX Reman Transmissions	Standard Reman Transmissions
<b>100% Genuine Eaton Content</b>	Yes	Yes
<b>Warranty: 2 yrs. Linehaul and Vocational*</b>	Yes	Yes
<b>Clutch Housing</b>	Shipped with new gasket only – recycle housing from existing unit or replace with new	Shipped with complete clutch housing
<b>Torque Coverage</b>	Range of torque covers multiple models, increasing availability and decreasing dealer stock	Model-specific torque limits unit to single model coverage

9 Series 13- and 18-speed FLEX transmissions are shipped with the HALO tube installed. Older clutch housings without HALO tube provisions will need to be replaced.

\* Can be upgraded to a three-year warranty. See form TCWY0760.

## Roadranger® Logistic Centers

These facilities offer customer pick-up options which save you time and money. The Logistic Centers are set up to meet same or next day criteria to almost anywhere in the United States. Look for one near you. Or contact your Roadranger Parts Representative. **To order, please call 1-800-826-4357.**

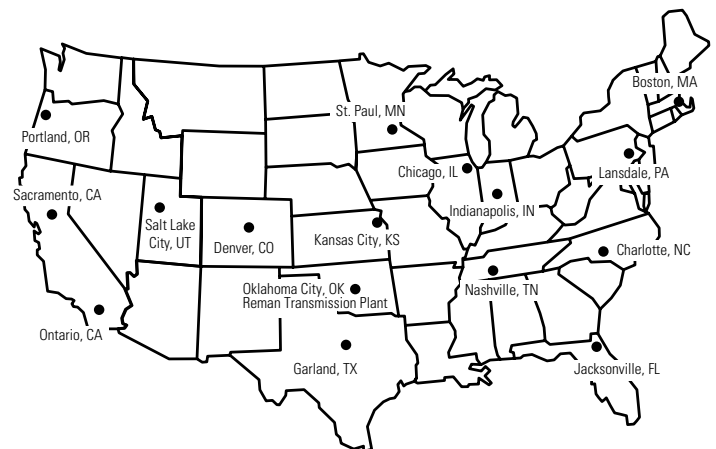

Powering Business Worldwide

BACKED BY

**Roadranger**

SUPPORT

# Standard Reman and FLEX Reman Transmissions

Manual Models	Standard Shift Bar Housing		Forward Shift Bar Housing	
	Without Internal Oil Pump	With Internal Oil Pump (-12) Cooler (-10) Forced Lube (-50)	Without Internal Oil Pump	With Internal Oil Pump (-12) Cooler (-10) Forced Lube (-50)
<b>7-SPEEDS</b>				
T-14607A	TA-862-11R			
T-14607B	TA-874-11R			
<b>9-SPEEDS</b>				
RT/F-8709	TA-E34-11R		TA-E53-11R	
RT-11709A	TA-718-11R			
RT-12709A				
RT-14709A		TA-720-12R		
RT/F-11709H	TA-A41-11R		TA-A42-11R	
RT/F-12709H				
RT/F-13709H				
RT/F-14709H		TA-A19-12R		TA-A20-12R
RTX-11709A	TA-719-11R			
RTX-12709A				
RTX/F-11709H	TA-A43-11R		TA-A44-11R	
RTX/F-12709H				
RTX/F-13709H				
RTX/F-14609B		TA-809-12R		TA-999-12R
RTX-14709A		TA-721-12R		
RTX-16709B		TA-A45-12R		TA-A47-125
RTX/14709H		TA-A46-12R		TA-A48-12R
RTX/16709H				
<b>CONVERTIBLE 9-SPEEDS</b>				
RTOC/F-16709A		TA-E97-12R		TA-E98-12R
RTOC/F-16909A		TA-F83-12R		TA-F84-12R
RTOCM-16909A		TA-D96-12R		
RTLQC-16909A-T2		TA-F81-12R		TA-F82-12R
RTOC/F-18909A		TA-G07-12R		TA-G08-12R
<b>10-SPEEDS</b>				
FR/F-9210B	TA-D67-11R		TA-D68-11R	
FR/F-11210B	TA-D40-11R		TA-D41-11R	TA-D47-12R
FR/F-12210B		TA-D46-12R		
FR/F-13210B				
FR/F-14210B		TA-D46-12R		TA-D47-12R
FR/F-15210B		TA-D64-12R		TA-D65-12R
		TA-D64-10R		TA-D65-10R
FRO/F-11210B	TA-D42-11R	TA-D48-12R	TA-D43-11R	TA-D49-12R
FRO/F-12210B				
FRO/F-13210B				
FRO/F-14210B		TA-D48-12R		TA-D49-12R
FRO/F-15210B		TA-D54-12R		TA-D55-12R
FRO/F-16210B		TA-D58-12R		TA-D59-12R
		TA-D58-10R		
FRW-15210B	TA-D98-11R			
FRO/F-11210C	TA-D44-11R	TA-D50-12R	TA-D45-12R	TA-D51-12R
FRO/F-12210C				
FRO/F-13210C				
FRO/F-14210C		TA-D50-12R		TA-D51-12R
FRO/F-15210C		TA-D56-12R		TA-D57-12R
FRO/F-16210C		TA-D60-12R		TA-D61-12R
		TA-D60-10R		TA-D61-10R
		TA-D73-12R		TA-D74-12R
FRO/F-17210C		TA-D73-10R		TA-D74-10R
		TA-D69-12R		TA-D70-12R
FRO/F-18210C		TA-D69-10R		TA-D70-10R
RT/F-9710B	TA-A81-11R	TA-A81-12R	TA-A96-11R	TA-A96-12R
RT/F-11710B				
RT/F-12710B				
RT/F-13710B				
RT/F-14710B		TA-A52-12R		TA-A53-12R
RTX/F-11710B	TA-A82-11R	TA-A82-12R	TA-A97-11R	TA-A97-12R
RTX/F-12710B				
RTX/F-13710B				

Manual Models	Standard Shift Bar Housing		Forward Shift Bar Housing	
	Without Internal Oil Pump	With Internal Oil Pump (-12) Cooler (-10) Forced Lube (-50)	Without Internal Oil Pump	With Internal Oil Pump (-12) Cooler (-10) Forced Lube (-50)
<b>10-SPEEDS</b>				
RTX/F-14710B		TA-A54-12R		TA-A55-12R
RTX/F-15710B		TA-B50-12R		TA-B54-12R
RTX/F-16710B				
RTX/F-11710C	TA-B12-11R	TA-B12-12R	TA-B21-11R	TA-B21-12R
RTX/F-12710C				
RTX/F-13710C				
RTX/F-14710C		TA-B14-12R		TA-B22-12R
RTX/F-15710C		TA-B51-12R		TA-B55-12R
RTX/F-16710C				
RTO/F-14708LL		TA-758-12R		TA-797-12R
RTX/F-14708LL		TA-893-12R		TA-897-12R
RT/F-8908LL	TA-E35-11R		TA-E36-11R	
RTO/F-11908LL		TA-E37-12R		TA-E38-12R
RTO/F-14908LL		TA-E39-12R		TA-E40-12R
RTO/F-16908LL		TA-E41-12R		TA-E42-12R
RTLQ/F-14610B		TA-B45-12R		TA-B46-12R
RTLQ/F-15610B				
RTLQ/F-16610B				
<b>11-SPEEDS</b>				
RTO/F-11909ALL	TA-F26-11R		TA-F27-11R	
RTO/F-11909MLL				
RTO/F-14909ALL		TA-F68-12R		TA-F69-12R
RTO/F-14909MLL				
RTO/F-16909ALL		TA-F28-12R		TA-F29-12R
<b>13-SPEEDS</b>				
RTLQ/F-14713A		TA-B09-12R		TA-B28-12R
RTLQ/F-16713A		TA-B56-12R		TA-B57-12R
RTLQ/F-14913A		TA-F02-50R		TA-F03-50R
RTLQ/F-16913A		TA-F04-50R		TA-F05-50R
RTLQ/F-18913A		TA-E59-50R		TA-E60-50R
RTLQ/F-20913A		TA-F43-50R		TA-F44-50R
<b>15-SPEEDS</b>				
RT/F-14915		TA-E47-12R		TA-E48-12R
RTO/F-14715		TA-789-12R		TA-790-12R
RTO/F-15715				
RTX/F-14715		TA-871-12R		TA-899-12R
RTX/F-15715				
RTO/F-14915		TA-E51-12R		TA-E52-12R
RTO/F-16915				
<b>18-SPEEDS</b>				
RTLQ/F-14718B		TA-B25-12R		TA-B26-12R
RTLQ/F-16718B		TA-B29-12R		TA-B30-12R
RTLQ/F-18718B		TA-B77-12R		TA-B78-12R
RTLQ/F-20718B		TA-E61-12R		TA-E62-12R
RTLQ/F-14918B		TA-F06-50R		TA-F07-50R
RTLQ/F-16918B		TA-F08-50R		TA-F09-50R
RTLQ/F-18918B		TA-F10-50R		TA-F11-50R
RTLQ/F-20918B		TA-E63-50R		TA-E64-50R
RTLQ/F-22918B		TA-F48-50R		TA-F49-50R

Manual Models	Standard Shift Tower Opening	Forward Shift Tower Opening	Clutch Housing
<b>LIGHTNING 10-SPEEDS</b>			
FRLO/F-16410C-T2	TN-D66-HA-10R	TN-D75-HA-10R	Hydraulic clutch release
	TN-D66-SAU-10R	TN-D75-SAU-10R	Upper clutch release shafts
	TN-D66-NAL-10R	TN-D75-NAL-10R	Nodal mount, lower clutch release shafts
	TN-D66-NAU-10R	TN-D75-NAU-10R	Nodal mount, upper clutch release shafts
FRLO-16410C-T2	TN-D84-SAL-10R		Upper clutch release shafts


# Standard Reman and FLEX Reman Transmissions

Gen 2 Automated Models	Without Internal Oil Pump (-11) With Internal Oil Pump (-12)
<b>10-SPEED AUTOSHIFT</b>	
RT-14710B-AS2	TB-F65-12R
RT-14910B-AS2	TB-F78-12R
RTO-10710B-AS2	TB-F56-12R
RTO-10710C-AS2	TN-F57-11R
RTO-10910B-AS2	TB-F74-12R
RTO-12710B-AS2	TB-F58-12R
RTO-12710C-AS2	TN-F59-11R
RTO-12910B-AS2	TB-F75-12R
RTO-14710B-AS2	TB-F52-12R
RTO-14710C-AS2	TB-F54-12R
RTO-14910B-AS2	TB-F76-12R
RTO-14910C-AS2	TB-F77-12R
RTO-16710B-AS2	TB-F53-12R
RTO-16710C-AS2	TB-F55-12R
RTO-16910B-AS2	TB-F79-12R
RTO-16910C-AS2	TB-F80-12R
RTO-18910B-AS2	TB-F70-12R
<b>10-SPEED ULTRASHIFT</b>	
RTO-10910B-DM2	TN-F86-11R
RTO-12910B-DM2	TN-F87-11R
RTO-14910B-DM2	TN-F88-12R
RTO-16910B-DM2	TN-F89-12R
<b>18-SPEED AUTOSHIFT</b>	
RTLO-14918A-AS2	TB-F61-12R
RTLO-16918A-AS2	TB-F62-12R
RTLO-18918A-AS2	TB-F63-12R
RTLO-20918A-AS2	TB-F64-12R
RTLO-22918A-AS2	TB-F73-12R

Gen 3 Automated Models	With Internal Oil Pump
<b>10-SPEED AUTOSHIFT</b>	
RTO-16910C-AS3	TN-F97-12R
<b>18-SPEED AUTOSHIFT</b>	
RTLO-18918A-AS3	TN-G18-12R
RTLO-20918A-AS3	TN-G19-12R
RTLO-22918A-AS3	TN-G20-12R
<b>10-SPEED ULTRASHIFT</b>	
FM-14D310B-LST	TN-G22-12R
FM-15D310B-LST	TN-G25-12R
RTO-16910B-DM3	TN-G03-12R
RTOM-16910B-DM3	TN-D86-12R
<b>13-SPEED ULTRASHIFT</b>	
FO-16D313E-LEP	TN-G12-12R
FOM-16D313E-LEP	TN-G13-12R
RTLO-16913L-DM3	TN-G14-12R
RTLOM-16913L-DM3	TN-G15-12R

UltraShift PLUS Automated Models	With Internal Oil Pump
<b>10-SPEED</b>	
FM-14E310B-LAS	TN-J00-12R
FM-15E310B-LAS	TN-J01-12R
FO-10E310C-VAS	TN-J53-12R
FO-14E308LL-VCS	TN-G34-12R
FO-14E310C-LAS	TN-J05-12R
FO-16E308LL-VCS	TN-G26-12R
FO-16E310C-LAS	TN-J06-12R
FO-16E310C-VAS	TN-J51-12R
FO-17E308LL-VCS	TN-G44-12R
FOM-14E310C-LAS	TN-J02-12R
FOM-15E310C-LAS	TN-J03-12R
FOM-16E310C-LAS	TN-J04-12R
FOM-16E310C-VAS	TN-J52-12R
<b>11-SPEED</b>	
FO-12E309ALL-VMS	TN-J58-12R
FO-14E309ALL-VMS	TN-G35-12R
FO-16E309ALL-VMS	TN-G27-12R
FO-17E309ALL-VMS	TN-G45-12R
<b>13-SPEED</b>	
FO-14E313A-MHP	TN-G42-12R
FO-16E313A-MHP	TN-G43-12R
FO-16E313A-VHP	TN-G47-12R
FO-18E313A-MHP	TN-G30-12R
FO-18E313A-VHP	TN-G48-12R
FO-20E313A-MHP	TN-G31-12R
FO-20E313A-VHP	TN-G49-12R
<b>18-SPEED</b>	
FO-14E318B-MXP	TN-G39-12R
FO-14E318B-VXP	TN-G36-12R
FO-16E318B-MXP	TN-G40-12R
FO-16E318B-VXP	TN-G37-12R
FO-18E318B-MXP	TN-G32-12R
FO-18E318B-VXP	TN-G28-12R
FO-20E318B-MXP	TN-G33-12R
FO-20E318B-VXP	TN-G29-12R
FO-22E318B-MXP	TN-G41-12R
FO-22E318B-VXP	TN-G38-12R


## Part Number Nomenclature:

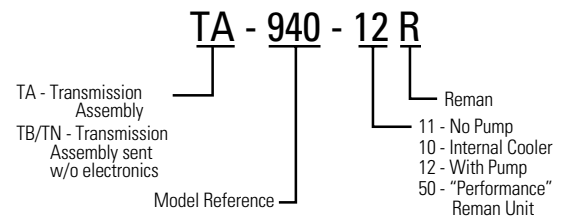

## Transmission Model Nomenclature:


 
## FLEX Part Number Nomenclature:





# Stop Searching & Start Selling

Eaton® FLEX Reman™ transmissions offer the flexibility of stocking several Genuine Eaton Fuller units to cover a wide range of models.

**Units will ship the same day when an order is received by 2:00 PM local time of the delivering Eaton Logistics Center.**

The FLEX portfolio cover over 85% of the reman market demand. Stock several different FLEX Reman transmissions for immediate coverage of dozens of Eaton Fuller units. Greater coverage and access = more business.

## What makes FLEX Reman flexible?

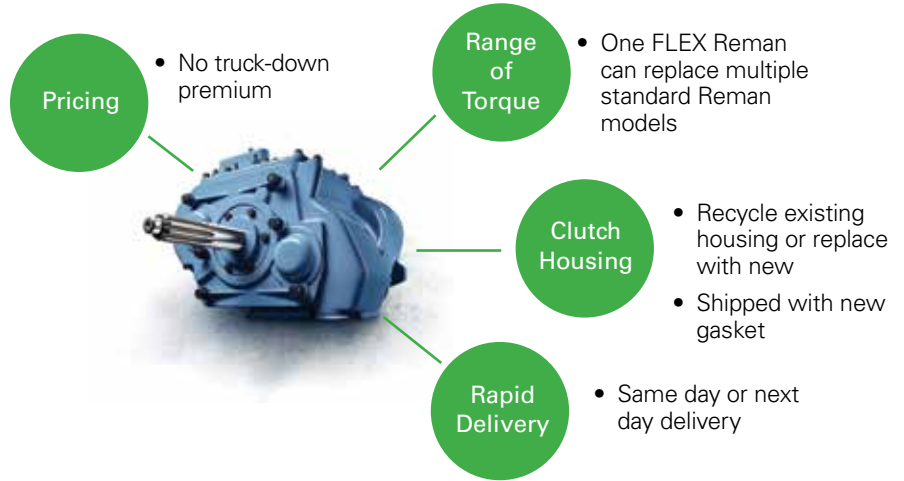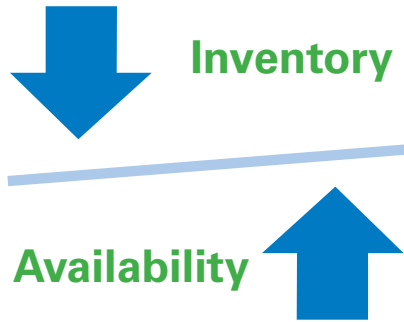

## Eaton® Fuller® FLEX Reman™



**For immediate assistance on truck down orders call 1-800-826-HELP (4357)**

- Same day/next day shipment available from our 15 logistics centers.
- No truck-down premium.
- 24-month standard warranty, upgradable to 3 years.\*
- The proven confidence of 100% Genuine Eaton components.

Standard Shift Bar Housing	
Trans. Model	FLEX Part #
FR-9210B	FR15210B-P
FR-11210B	
FR-12210B	
FR-13210B	
FR-14210B	
FR-15210B	
FRO-11210C	FRO16210C-P FRO16210C-C
FRO-12210C	
FRO-13210C	
FRO-14210C	
FRO-15210C	
FRO-16210C	
FRO-17210C	FRO18210C-P
FRO-18210C	
RTLO-14713A	RTLO16713A-P
RTLO-16713A	
RTLO-12913A	RTLO16913A-P
RTLO-14913A	
RTLO-16913A	
RTLO-18913A	RTLO18913A-P
RTLO-14718B	
RTLO-16718B	RTLO18718B-P
RTLO-18718B	
RTLO-14918B	RTLO18918B-P
RTLO-16918B	
RTLO-18918B	
RTLO-20918B	RTLO20918B-P
RTO-14908LL	
RTO-16908LL	RTO16908LL-P

Forward Shift Bar Housing	
Trans. Model	FLEX Part #
FRF-9210B	FRF15210B-P
FRF-11210B	
FRF-12210B	
FRF-13210B	
FRF-14210B	
FRF-15210B	
FROF-11210C	FROF16210C-P FROF16210C-C
FROF-12210C	
FROF-13210C	
FROF-14210C	
FROF-15210C	
FROF-16210C	
FROF-17210C	FROF18210C-P
FROF-18210C	
RTLOF-14713A	RTLOF16713A-P
RTLOF-16713A	
RTLOF-12913A	RTLOF16913A-P
RTLOF-14913A	
RTLOF-16913A	
RTLOF-18913A	RTLOF18913A-P
RTLOF-14718B	
RTLOF-16718B	RTLOF18718B-P
RTLOF-18718B	
RTLOF-14918B	RTLOF18918B-P
RTLOF-16918B	
RTLOF-18918B	
RTLOF-20918B	RTLOF20918B-P
RTOF-14908LL	
RTOF-16908LL	RTOF16908LL-P

\*For complete information refer to document TCWY0900.

-P = pump model -C = cooler model


# Determining Transmission Core Values by Model

Only models listed on the website are acceptable for return. As models are added to the program, new core values will also be established and posted on the website: <http://www.roadranger.com/rr/Aftermarket/transmissions/pricelist/index.htm>

Steps:

1. Go to the website
2. Enter the transmission model number with % signs on both sides of the model number as shown below
3. Highlight the radial button on "Part Description" as shown
4. Click on the "Submit" button
5. In the illustration below, all FRO-16210C cores have a \$2,200 core value before any deductions.

The result's page will show the "core value" in the far right hand column. If the search shows no results, the core you are returning either a) has no core value; b) the model number was entered incorrectly.

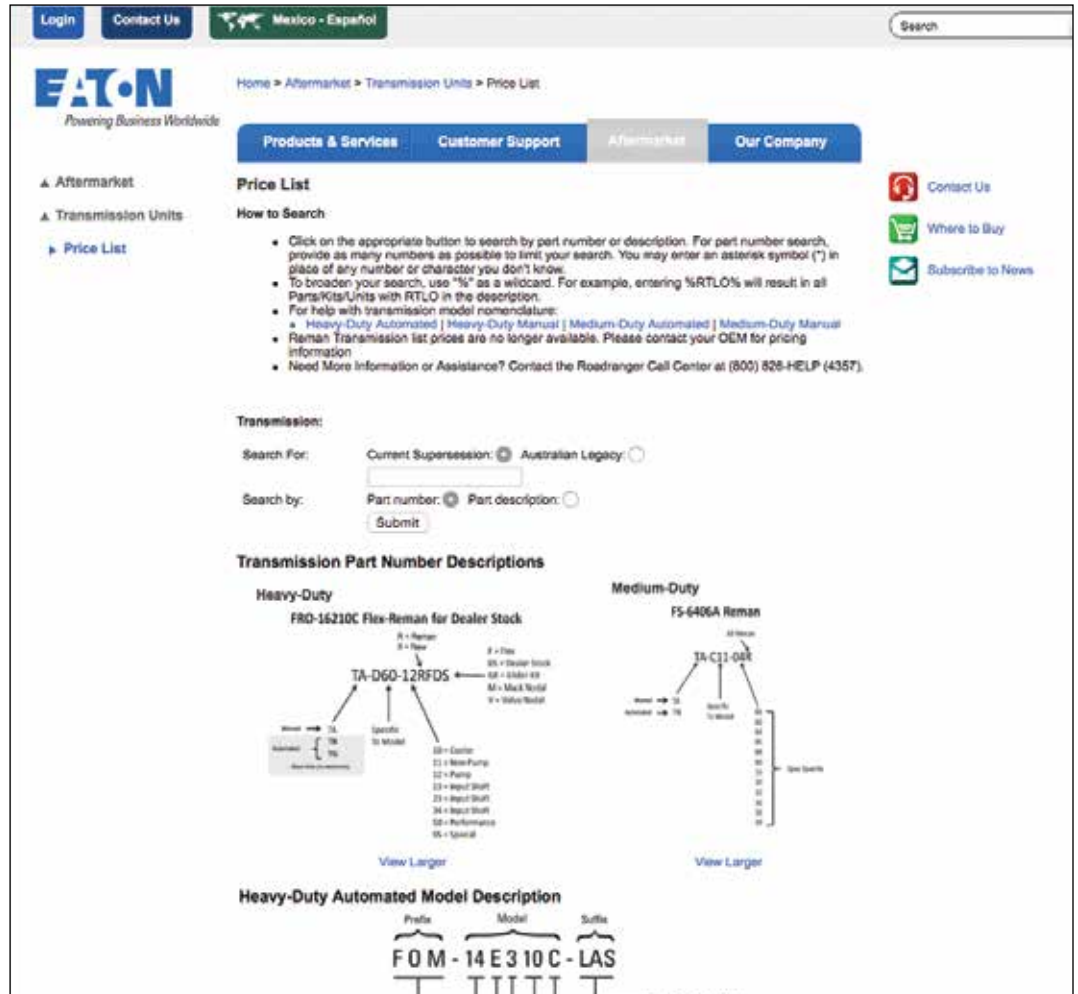

Fuller® Reman™ transmissions are available for most popular models. Participating dealers can carry them in stock or order them for next-day delivery from the OEM PDC or one of many Eaton locations across the U.S.

See your heavy truck dealer for more information or call the Roadranger Unit Exchange hotline today for instant inventory availability, ordering and specing assistance at 1-800-826-4357.

Dealers can reference the Roadranger Unit Exchange Program Guide, Item APSL0419.

BACKED BY  
**Roadranger**  
SUPPORT

For spec'ing or service assistance, call 1-800-826-HELP (4357) or visit [www.eaton.com/roadranger](http://www.eaton.com/roadranger). In Mexico, call 001-800-826-4357.

Roadranger: Eaton and trusted partners providing the best products and services in the industry, ensuring more time on the road.

Eaton  
Vehicle Group  
13100 E. Michigan Ave.  
Galesburg, MI 49053 USA  
800-826-HELP (4357)  
[www.eaton.com/roadranger](http://www.eaton.com/roadranger)

© 2019 Eaton  
All Rights Reserved. Printed in USA.  
APSL0147 0719

**Note:** Features and specifications listed in this document are subject to change without notice and represent the maximum capabilities of the software and products with all options installed. Although every attempt has been made to ensure the accuracy of information contained within, Eaton makes no representation about the completeness, correctness or accuracy and assumes no responsibility for any errors or omissions. Features and functionality may vary depending on selected options.

Eaton, Fuller, Roadranger, Solo, UltraShift and Fuller Advantage are registered trademarks of Eaton. All trademarks, logos and copyrights are those of their respective owners.