

Check Valves




Inline Check Valve

DT8P1-10/-11

DS8P1-10/-11


Body sold as an assembly only.
Order by model number.

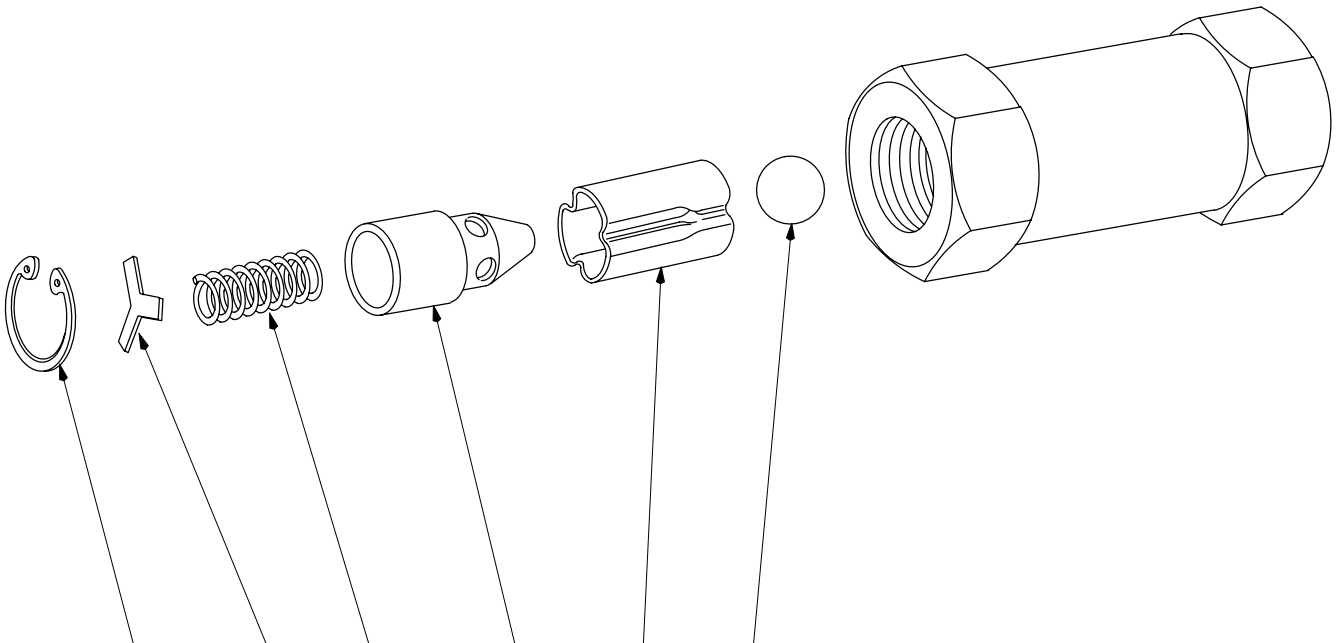

Retaining Ring	Washer	Spring	Poppet	Sleeve	Ball	Pipe Size	Cracking Pressure PSI	Model
92733	113714	113559	—	113715	1651	1/4	5	DT8P1-02-5-10
		216999					30	DT8P1-02-30-10
		114094					65	DT8P1-02-65-10
106642	123740	123761	123737	—	—	3/8	5	D*8P1-03-5-10
		217000					30	DT8P1-03-30-10
		123760					65	D*8P1-03-65-10
98702	125673	125779	125674	—	—	3/4	5	D*8P1-06-5-11
		222541					15	D*8P1-06-15-11
		418556					20	DT8P1-06-20-11
		216998					30	D*8P1-06-30-11
		425262					40	DT8P1-06-40-11
		580963					50	DT8P1-06-50-11
		125780					65	D*8P1-06-65-11
113752	125635	125631	125634	—	—	1-1/4	5	D*8P1-10-5-11
		312094					15	DT8P1-10-15-11
		216548					30	DT8P1-10-30-11
		257354					50	DT8P1-10-50-11
		125632					65	D*8P1-10-65-11
		582338					95	DT8P1-10-95-11

Model Code

 D * 8 P 1 - ** - ** - 1*



1 Model Series Directional control	4 Spool Action P - Poppet	7 Cracking Pressure 5 - 5 PSI 15 - 15 PSI 20 - 20 PSI 30 - 30 PSI 35 - 35 PSI 40 - 40 PSI 50 - 50 PSI 65 - 65 PSI 95 - 95 PSI
2 Mounting Connection S - Straight threaded T - Pipe threaded	5 Flow Direction 1 - One way flow	
3 Valve Type 8 - Inline	6 Valve Size Series 02 - 1/4 inch 03 - 3/8 inch 06 - 3/4 inch 10 - 1-1/4 inch	8 Design

For satisfactory service life of these components, use full flow filtration to provide fluid which meets ISO cleanliness code 16/13 or cleaner. Selections from pressure, return, and in-line filter series are recommended.