

Directional Controls




Service Parts Information

Cam Operated CETOP 3 Directional Control Valve DG20V-3-**(2)(L)-60

Spool Type	Model
0	916621
2	916622
6	916623
33	916620

Note

Right hand assembly shown for all models.
For left hand assembly all parts are re-versed except body.

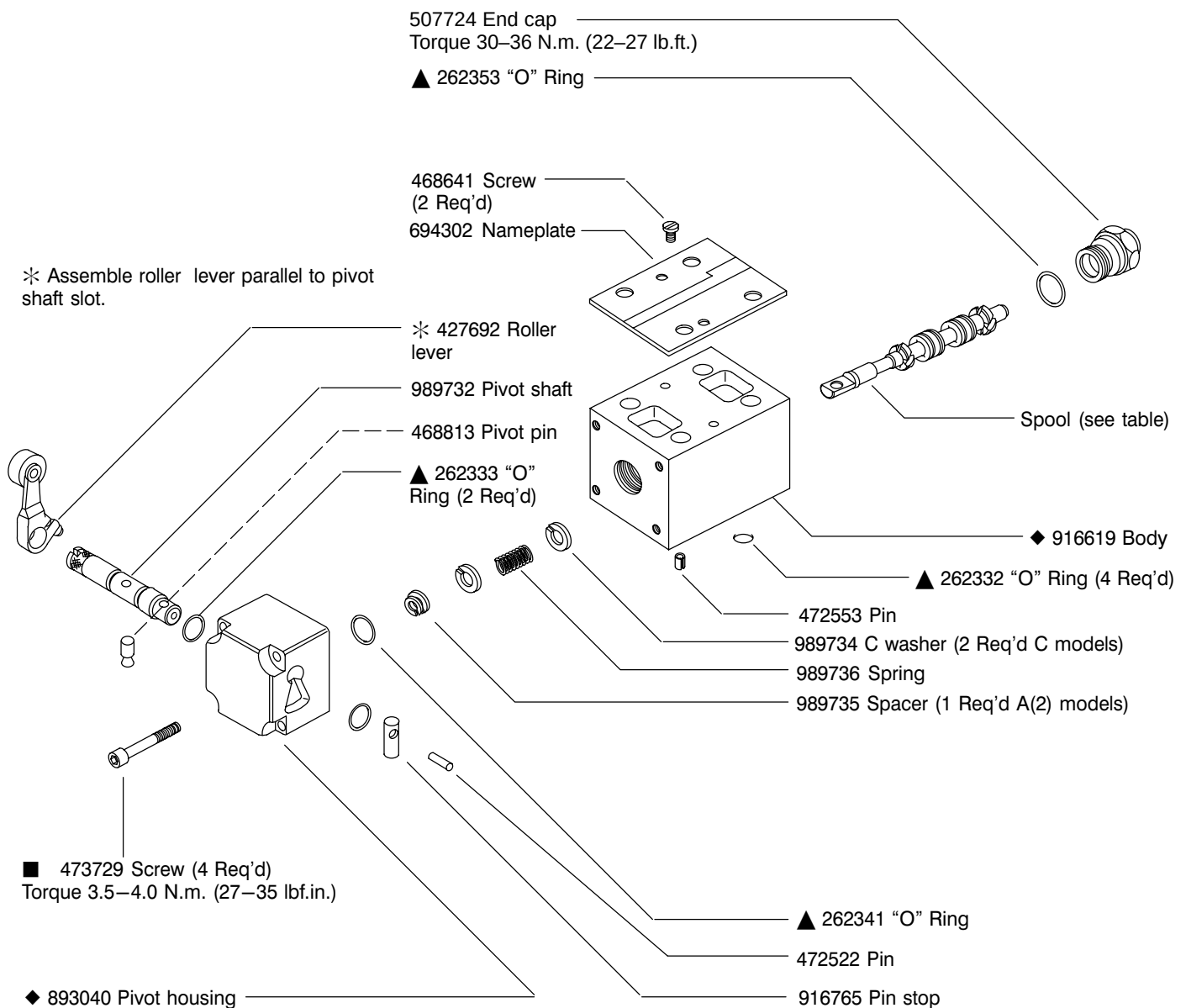

Model Code

DG	20	V	-	3	-	*	*	(2)	(L)	-	60
1	2	3		4	5	6	7	8		9	

1 D – Directional control valve
G – Subplate mounting

2 Cam lever operated

3 Rated pressure
V – 350 bar (5075 psi)

4 Interface
3 – ISO 4401–03 (CETOP 3 & NFPA D03)


5 Spool type (see table)

6 Spool/Spring arrangement
A – Spring offset, to cylinder “A”
C – Spring centered


7 Cam position
Blank – Spring offset to position # 3
2 – Spring offset to position # 1

8 Build type
L – Left hand build (lever on “B” port side of valve)
Omit – Right hand build (lever on “A” port side of valve)


9 Design

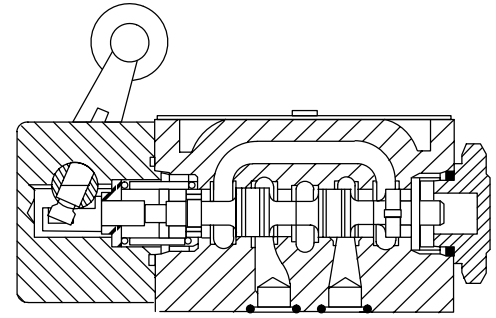

DG20V–3–*A–60 Sectional View
 Spring Offset, Offset To Cam Position # 3

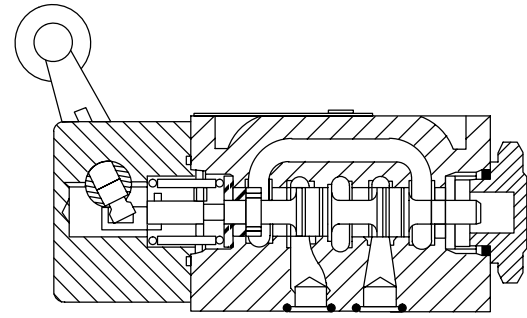

DG20V–3–*A2–60 Sectional View
 Spring Offset, Offset To Cam Position # 1

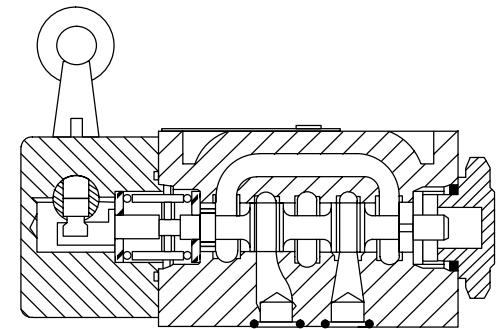

DG20V–3–*C–60 Sectional View
 Spring Centered