




Flow Control Valves

FRG-03-*-28-2*

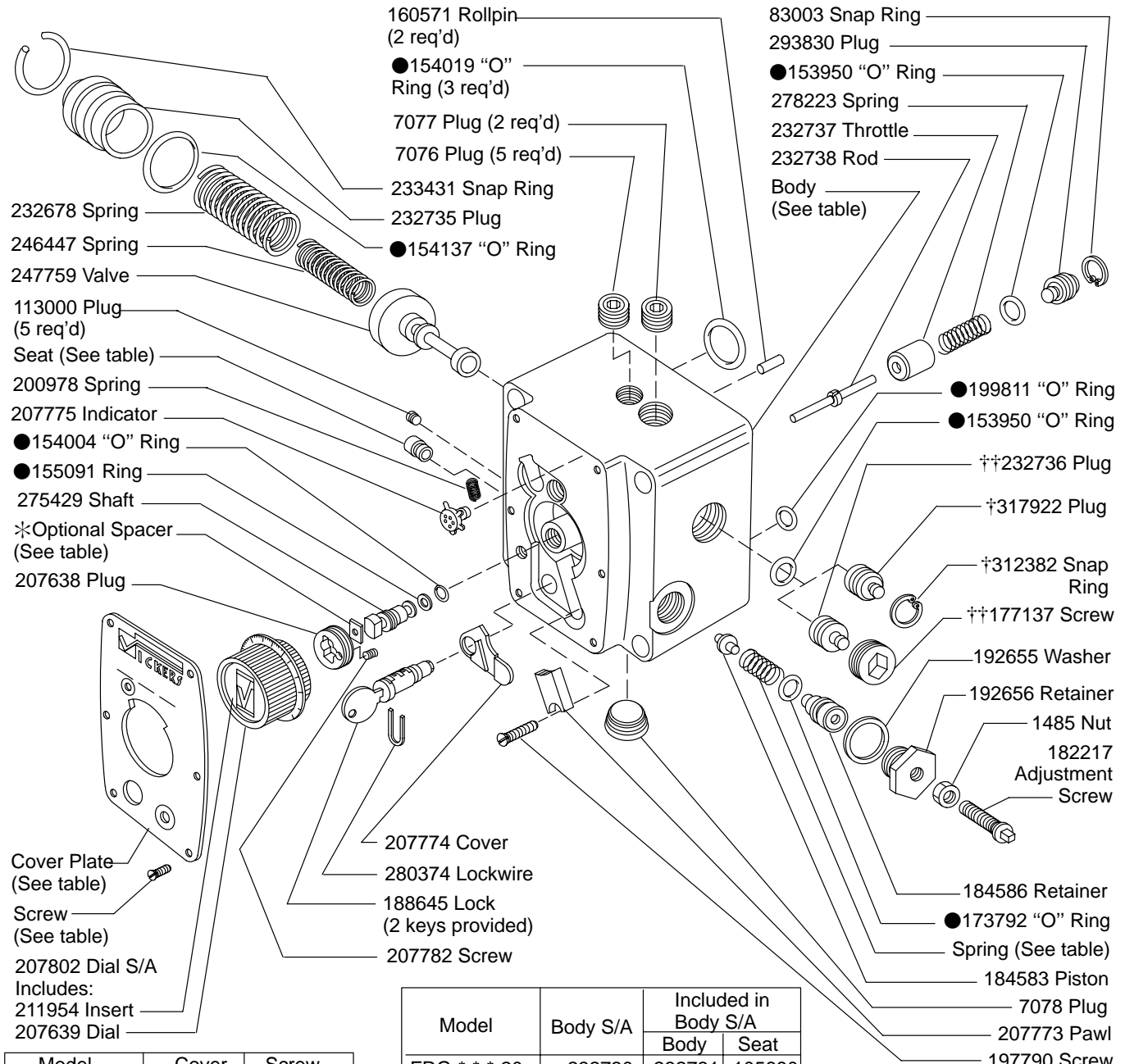

| Model | Cover Plate | Screw (6 req'd) |
|-------------|-------------|-----------------|
| FRG-*-**-20 | 232739 | 184173 |
| FRG-*-**-22 | 315976 | 3X-117655 |

| Model | Body S/A | Included in Body S/A | |
|-------------|----------|----------------------|--------|
| | | Body | Seat |
| FRG-*-**-20 | 232730 | 232731 | 105680 |
| FRG-*-**-22 | 330936 | 330938 | 105680 |


| Model | Pressure Adj. to PSI max. | Spring |
|-----------------|---------------------------|--------|
| FRG-*-B-*-20/22 | 1000 | 175071 |
| FRG-*-C-*-20/22 | 2000 | 175072 |
| FRG-*-F-*-20/22 | 3000 | 175073 |

Optional spacers (211026) are available to limit the maximum throttle opening as follows:

| Number of Spacers | Limit of Maximum Volume USgpm |
|-------------------|-------------------------------|
| 3 | 4.5 to 6 |
| 2 | 10 to 13 |
| 1 | 18 to 21 |


- † Used on -22 Design only
- †† Used on -20 Design only
- F3 equivalent 919398 Seal Kit
- Included in 919213 Seal Kit

FRG-03-*-28-21

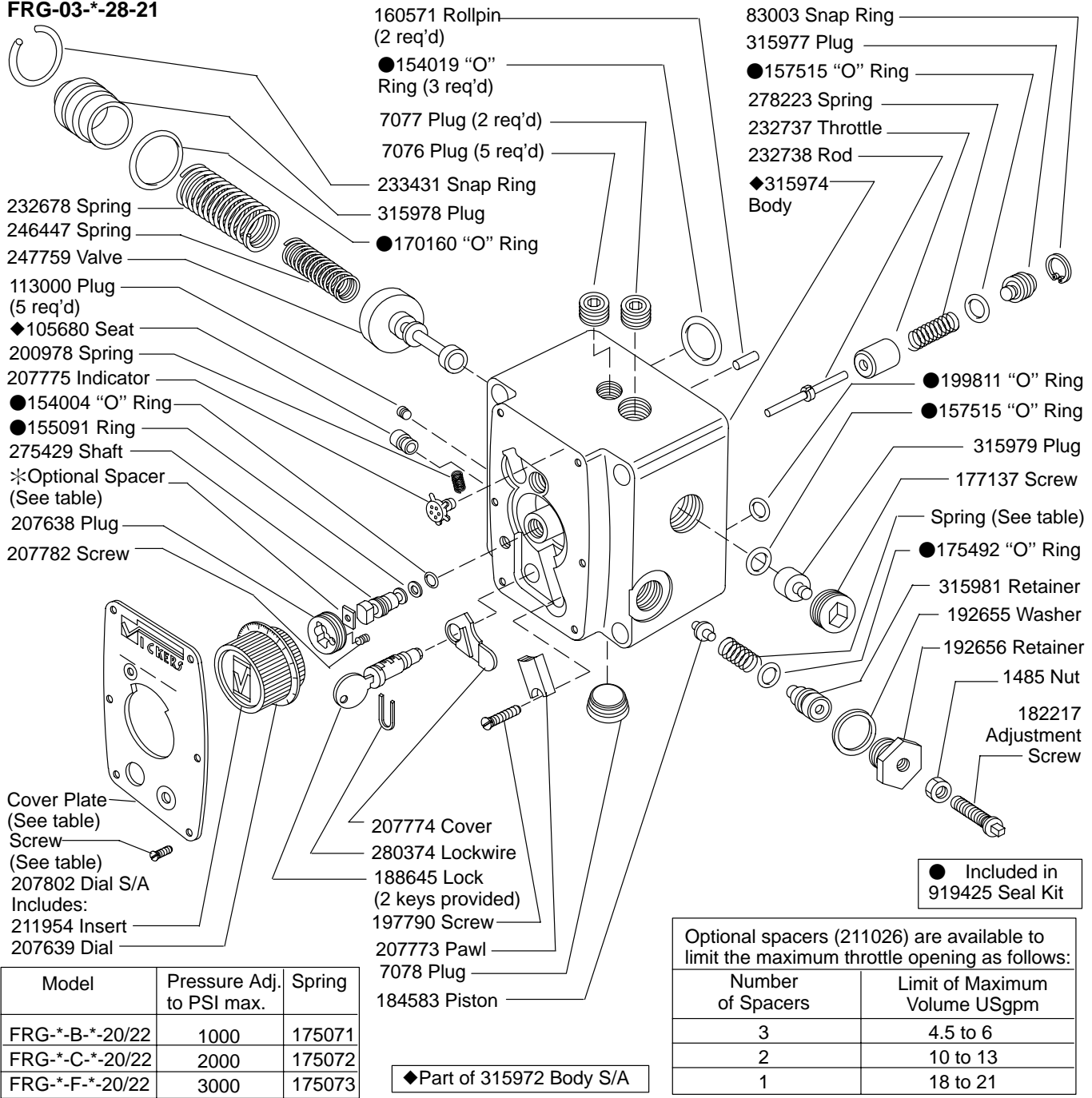

Model Code

 FRG - 03 - * - 28 - 2*



1 Model Series

FRG - Flow control, relief valve, gasket mounted

3 Maximum Adjustable Pressure

B - 1000 psi
C - 2000 psi
F - 3000 psi

4 Maximum Capacity

28 USgpm

2 Series

03

5 Design

For satisfactory service life of these components, use full flow filtration to provide fluid which meets ISO cleanliness code 18/15 or cleaner. Selections from Eaton OFF, OFR and OFRS filter series are recommended.

Printed in U.S.A.