


Relief Valves



Balanced Piston Type High Flow Relief Valve

CG-H10-*V-30

Model	■ Spring	Pressure Range PSI	■ Included in Cover S/A
CG-H10-BV-30	2280	125-1000	941286
CG-H10-CV-30	583937	500-2000	941287
CG-H10-FV-30	2281	1500-3000	941288

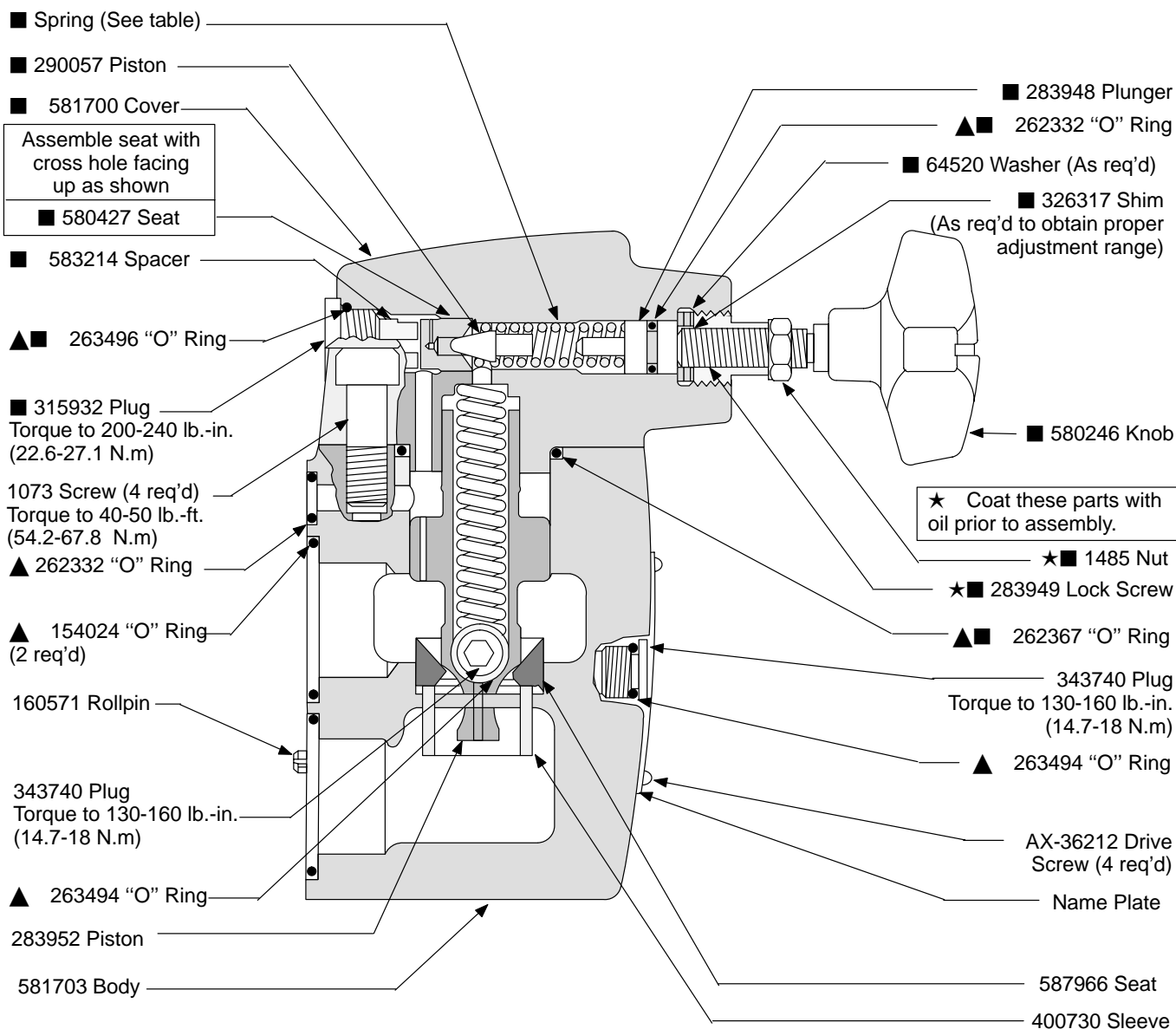


All seals, except interface, are F3. Use the F3 seal kit to service all units.

▲ Included in F3 Seal Kit 919920



Model Code Breakdown

 (F3) C G - H10 - * - V - 30



1 Seals

F3 - Multi-fluid capability (Viton® seals)

Viton is a registered trademark of E.I. DuPont

2 Model Series

CG - Relief valve, manifold or subplate mounted

3 Size

H10 - 1-1/4 inch high flow

4 Pressure Range

B - 125-1000
C - 500-2000
F - 1500-3000

5 Vent Pressure

V - High vent pressure

6 Design

For satisfactory service life of these components, use full flow filtration to provide fluid which meets ISO cleanliness code 18/15 or cleaner. Selections from Eaton OFP, OFR and OFRS filter series are recommended.

Printed in U.S.A.